


Internal Fasteners

Central Connector


- 90 degree, hidden connection used when profile ends are captivated
- Requires central connector profile milling machining service (pg. 10-20)

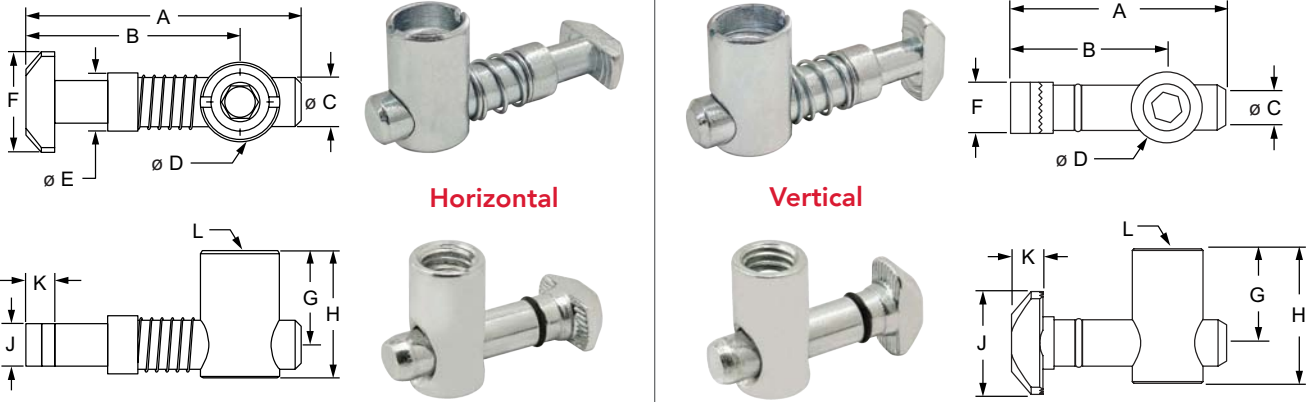

Part No.	Series	Orientation	Spring	Material	A	B	C	D	E	F	G	H	J	K	L	Weight
13187	15 40	Vertical	Yes	Steel	2.047"	1.594"	.374"	.590"	.444"	.307"	.669"	.945"	.748"	.217"	M12 x 12	.0485 kg
13188	15 40	Horizontal			2.047"	1.594"	.374"	.590"	.444"	.748"	.669"	.945"	.307"	.217"	M12 x 12	.0462 kg
13194	30	Vertical	No		32.80mm	23.80mm	6.90mm	10.80mm	—	7.80mm	14.00mm	20.00mm	15.30mm	4.80mm	M8 x 10	.0426 kg
13195	30	Horizontal			32.80mm	23.80mm	6.90mm	10.80mm	—	15.30mm	14.00mm	20.00mm	7.80mm	4.80mm	M8 x 10	.0426 kg
14012	45	Vertical	No		45.50mm	32.00mm	9.60mm	16.70mm	—	9.60mm	18.00mm	28.00mm	19.50mm	5.40mm	M12 x 12	.0558 kg
14013	45	Horizontal			45.50mm	32.00mm	9.60mm	16.70mm	—	19.50mm	18.00mm	28.00mm	9.60mm	5.40mm	M12 x 12	.0553 kg

Required Machining Services

Machining Type	Profile Machined	Reference Page
Central Connector Profile Milling	Mounting Profile	10-20

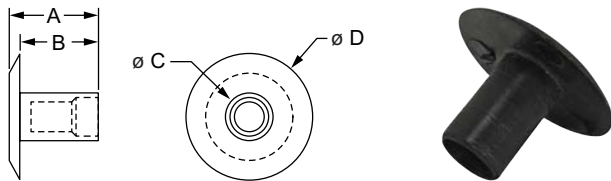

Central Connector Cover Cap

Part No.	Series	Material	A	B	C	D	Weight
13001	45	Black Nylon	12.00mm	10.50mm	6.40mm	17.00mm	.0022 Kg

Central Connector Assembly

Vertical Central Connector Shown

