



WORK CHALLENGES. WHEEL CHOICES.

WITH NORTON, YOU ALWAYS HAVE A CHOICE;

Our Norton RightCut line now offers a complete range of right angle grinder cut-off wheels for every application and tier:

- Long-lasting, ultra-thin .040" to intermediate wheels
- Most innovative, best-performing wheels with lowest total cost per cut
- Price-point wheels with solid, general purpose performance
- Specialty wheels for cutting stainless steel, carbon steel alloys and aluminum

KEY MARKETS

PIPELINE | PETROCHEMICAL | METAL FABRICATION CONSTRUCTION | FOUNDRY | WELDING



ONE SIZE DOESN'T FIT ALL.
WITH NORTON, YOU ALWAYS
HAVE A CHOICE.



As different as the company you keep, so are the jobs you do and, the tools you use.

Double your production with Norton BlueFire RightCut cut-off wheels. An advanced chemistry blend of abrasives that will put the hardest of applications to the test with over 50% more life. The true choice for the best value, with broadest versatility to lower production costs. And, that's money in the bank.

Fastest cut, and highest comfort, Norton Gemini RightCut has an ultra-thin design that delivers precision cuts on steel and non-ferrous materials. Fast, solid performance. Make the right choice more comfortable.

If you're just needing to get the job done, and performance isn't being measured, then sometimes being consistent like Norton Metal RightCut is a good place to start. Made with aluminum oxide it gets steel/ferrous metal jobs done right at a low cost.



Norton BlueFire RightCut

BETTER – Broadest Versatility, Over Twice the Life

SIZE (D x T x H)	5 PACK	10 PACK	20 PACK	25 PACK	250 PACK
Type 01/41					
4-1/2" x 1/16" x 7/8"	66252842159			66252843208	66253371660
5" x 1/16" x 7/8"	66252842169			66252843209	66253371661
6" x 1/16" x 7/8"	66252842174			66252843210	66253371662
Type 27/42					
4-1/2" x 1/16" x 5/8"-11		66252843223			
4-1/2" x 1/16" x 7/8"				66252843219	
5" x 1/16" x 7/8"				66252843220	
6" x 1/16" x 7/8"				66252843221	

BULK PACKED 250/CARTON, 5 INNER BOXES OF 50 WHEELS EACH. ORDER IN MULTIPLES OF 250 WHEELS.

Wheel Type/Thickness Application

TYPE 01/41 RIGHTCUT



 
.035, .040, .045, .050, 1/16

Type 01/41 straight cut-off wheels are designed for use on right angle grinder cut-off applications. All are supplied with full fiberglass reinforcing.



90° ANGLE

TYPE 27/42 RIGHTCUT



.040, .045, 1/16

Type 27/42 cut-off wheels are designed for use on right angle grinder cut-off applications. Their depressed center shape provides a recess for the hub, which allows flush cutting. All are supplied with full fiberglass reinforcing.



90° ANGLE



NORTON RIGHTCUT CUT-OFF WHEEL LINE



Norton Gemini RightCut
GOOD – Fastest Cut, Highest Comfort

SIZE (D x T x H)	5 PACK	10 PACK	20 PACK	25 PACK	250 PACK
Type 01/41					
4" x .045" x 5/8"				66243527956	
4-1/2" x .040" x 7/8"				66252843225	
4-1/2" x .045" x 7/8"	66252842160			66252823602	66252841213
5" x .040" x 7/8"				66252843226	
5" x .045" x 7/8"	66252842170			66252823603	66252841214
6" x .045" x 7/8"	66252842175			66252823604	66252841215
7" x .045" x 7/8"				66252832323	
Type 27/42					
4" x .045" x 5/8"				66252842180	
4-1/2" x .040" x 5/8"-11		66252843227			
4-1/2" x .045" x 5/8"-11		66252842025			
4-1/2" x .045" x 7/8"	66252842161			66252842026	66253370065
5" x .040" x 5/8"-11		66252843228			
5" x .045" x 5/8"-11		66252841939			
5" x .045" x 7/8"	66252842171			66252842036	66253370066
6" x .045" x 5/8"-11		66252830587			
6" x .045" x 7/8"	66252842176			66252842202	66253370067
7" x .045" x 7/8"			66252912626		
9" x 1/16" x 5/8"-11		66253019115			
Type 01/41 – Stainless Steel/Inox					
4-1/2" x .045" x 7/8"				66252841997	
5" x .045" x 7/8"				66252841998	
6" x .045" x 7/8"				66252841999	
7" x .045" x 7/8"					66252842000
Type 27/42 – Stainless Steel/Inox					
4-1/2" x .045" x 5/8"-11		66252841913			
4-1/2" x .045" x 7/8"				66252841912	
5" x .045" x 5/8"-11		66252841915			
5" x .045" x 7/8"				66252841914	
6" x .045" x 5/8"-11		66252841917			
6" x .045" x 7/8"				66252841916	
7" x .045" x 5/8"-11		66252841919			
7" x .045" x 7/8"					66252841918
Type 01/41 – Aluminum					
4-1/2" x .045" x 7/8"				66252841994	
5" x .045" x 7/8"				66252841995	
6" x .045" x 7/8"				66252841996	
Type 27/42 – 3/32 – Steel/Metal					
4-1/2" x 3/32" x 5/8"-11		66252841903			
4-1/2" x 3/32" x 7/8"				66252841940	
5" x 3/32" x 5/8"-11		66252841904			
5" x 3/32" x 7/8"				66252843587	
6" x 3/32" x 5/8"-11		66252841905			
6" x 3/32" x 7/8"				66252841906	
7" x 3/32" x 5/8"-11		66252841907			
7" x 3/32" x 7/8"					66252841908


Norton Metal Original RightCut
GOOD – Consistent Performance, Low Initial Price

SIZE (D x T x H)	5 PACK	10 PACK	25 PACK	50 PACK	250 PACK
Type 01/41					
4" x .040" x 5/8"				07660701616	
4-1/2" x .035" x 7/8"				66252843846	
4-1/2" x .040" x 7/8"	66252842158			07660701617	66253370222 66252840001
4-1/2" x 1/16" x 7/8"				66252843845	
5" x .040" x 7/8"	66252842168			07660701618	
6" x .040" x 7/8"	66252842173			07660702757	66253370223
7" x 1/16" x 7/8"				07660704732	
Type 27/42					
4" x .045" x 5/8"				07660705249	
4-1/2" x .045" x 7/8"				66252843604	
5" x .045" x 7/8"				66252843849	
6" x .045" x 7/8"				66252842015	
7" x 1/16" x 7/8"				07660705251	

Convenience and Economy

SMALL PACK CONVENIENCE
Prepackaged 5-packs of popular sizes and tiers to maximize turns and deliver testing opportunities for competitive conversions.

BULK PACK ECONOMICS
Overpacked 50-packs per carton for 250 wheels total to reduce initial purchase cost and drive volume savings for larger volume end users.

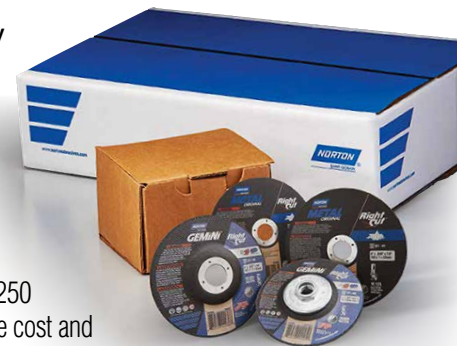

LIMITED TIME ONLY!
For every bulk pack purchased, receive a Norton RightCut Bluetooth Speaker FREE!
(while supplies last)

BULK PACKED 250/CARTON, 5 INNER BOXES OF 50 WHEELS EACH. ORDER IN MULTIPLES OF 250 WHEELS.

NORTON RIGHTCUT CUT-OFF WHEEL LINE



NORTON BLUEFIRE RIGHTCUT COMPETITIVE CROSSOVER

3M	CUII	
Flexovit	Razorblade	
Metabo	M-Calibur	
PFERD	SG-Plus	SG-Elastic
Walter	Zip+XTRA	XXtreme
Weiler	Tiger INOX	

Plus all competitors crossed over to Gemini RC and Norton Metal Original RC



NORTON GEMINI RIGHTCUT COMPETITIVE CROSSOVER

3M	Green Corps	High Performance	
CGW	Quickie Cut ZA60T		
DeWalt	XP Z60T		
Flexovit	RazorbladeEZ		
Metabo	Original Slicer LL		
Pearl	Slimcut Redline	Slimcut SRT	
SAIT	Z-tech	Sait .045	Saitech
Klingspor	Kronefx EDGE		
Tyrolit	Premium 2-in-1		
PFERD	PS-Forte		
Walter	ZipCut		
Weiler	Tiger LL	Tiger Zirc	

Plus all competitors crossed over to Norton Metal Original RC



NORTON METAL RIGHTCUT COMPETITIVE CROSSOVER

3M	General Purpose	
CGW	Super Quickie Cut A60T	
DeWalt	HP A60T	
Metabo	Original Slicer	
Pearl	Slimcut	Pro-V Slimcut
SAIT	Sait M.X.	Ultimate Cut
Weiler	Wolverine	
Tyrolit	Basic 2-in-1	

MAKE THE RIGHT CHOICE MORE COMFORTABLE.

For simple RIGHT choices, Norton RightCut provides the total performance cutting package:

**Norton BlueFire, Norton Gemini,
Norton Metal**

BECAUSE RIGHT CHOICES MATTER™

BEST – Refer to BETTER

BETTER – NORTON BlueFire RightCut

GOOD – NORTON Gemini RightCut & NORTON Metal RightCut

facebook.com/NortonIndustrial | youtube.com/NortonIndustrial | nortonabrasives.com

USA CUSTOMER SERVICE:

Toll Free Phone: 1 (800) 551-4413
Toll Free Fax: 1 (800) 551-4416

CANADA CUSTOMER SERVICE:

Toll Free Phone: 1 (800) 263-6565
Toll Free Fax: 1 (800) 561-9490

PRIMARY SPONSOR



NO-RISK TEST



FORM #8385 REV. 06/16

© Saint-Gobain June 2016. Norton, BlueFire, Gemini, RightCut and "Reshaping Your World" are registered trademarks; Metal is a trademark of Saint-Gobain Abrasives.

