



1.50" X 1.50" Lite Smooth Surface T-slotted Profile - Four Open T-slots

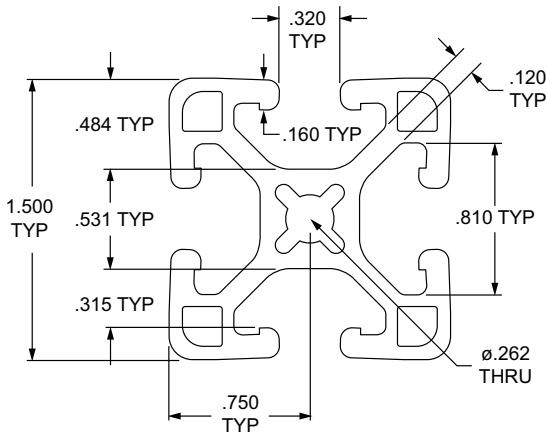

Part No.	Series	Stock Length	Material	Alloy (or comparable)	Finish	Drop Lock	Moment of Inertia	Surface Area	Yield Strength	Modulus of Elasticity	Weight
1515-LS	15	120", 242"	Aluminum	6005A – T61	Clear Anodize	2°	IX = 0.1921 <sup>in.4</sup> IY = 0.1921 <sup>in.4</sup>	0.882 in. <sup>2</sup>	35,000 psi	10,200,000 lb / in. <sup>2</sup>	0.0860 lb / in.
1515-LS-Black		Black Anodize									
1515-LS-Black-FB		Black Anodize									

1.50" X 1.50" Lite T-slotted Profile - Four Open T-slots

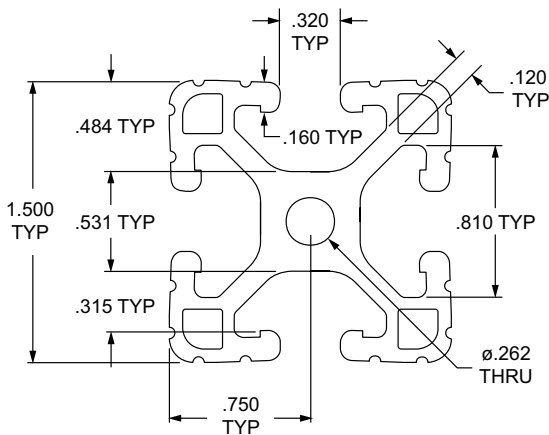

Part No.	Series	Stock Length	Material	Alloy (or comparable)	Finish	Drop Lock	Moment of Inertia	Surface Area	Yield Strength	Modulus of Elasticity	Weight
1515-Lite	15	120", 242"	Aluminum	6005A – T61	Clear Anodize	2°	IX = 0.1853 <sup>in.4</sup> IY = 0.1853 <sup>in.4</sup>	0.896 in. <sup>2</sup>	35,000 psi	10,200,000 lb / in. <sup>2</sup>	0.0873 lb / in.
1515-Lite-Black		Black Anodize									
1515-Lite-Black-FB		Black Anodize									
1515-Lite-Yellow		Yellow Powder Coat									

Standard Machining Services for 1.50" x 1.50"

Service No.	Series	Service Description	Reference Page
7010	15	Cut to Length	10-2
7050		Access Hole	10-5
7040		Anchor Counterbore	10-7
7060		Tap Profile End	10-3

Other machining services available in Section 10