

**NORTON**

SAINT-GOBAIN

**CATALOG #340**

STOCK ABRASIVE PRODUCTS

**DO-IT-YOURSELF  
& CONTRACTOR  
MARKET**



SANDING MADE **EASIER**™

Reshaping  
your  
world

### Our Mission

We offer powerful, precise, user-friendly solutions, which enable our customers to cut, shape and finish all materials even in the most complex and challenging applications. By working closely with end-users and our grinding expert partners, we design and provide customized solutions to secure the best option for performance, cost and safety.

### Our Expertise

Norton is the leading brand of Saint-Gobain Abrasives, with more than 135 years of experience in manufacturing abrasives.

We are committed to providing access to our expert's knowledge whenever you need it. Whether it is through ongoing training programs, or through on-line expert articles and white papers you can stay up-to-date with Norton where and when you need it.

Bring us your grinding challenges, we have solutions!

### Our Commitment

You be the final judge in performance! We are so confident of the superior performance of our abrasive products, as recommended for specific applications, that we invite in-plant tests against any other brand of abrasive product on the market. Contact your Norton Representative to find out more about our No Risk test policy or visit [www.nortonabrasives.com](http://www.nortonabrasives.com)



### Go Further

For a more comprehensive outline of products, safety and application information, visit our website at [www.nortonabrasives.com](http://www.nortonabrasives.com). We continually update it with our most current information.

Connect with us:



### Hand Sanding

|                                    |    |
|------------------------------------|----|
| Sanding Sheets . . . . .           | 6  |
| ProSand . . . . .                  | 7  |
| MultiSand . . . . .                | 8  |
| WoodSand . . . . .                 | 9  |
| MetalSand . . . . .                | 9  |
| SandWet . . . . .                  | 10 |
| Bulk Full Sheets . . . . .         | 11 |
| Abrasive Sanding Sponges . . . . . | 13 |
| ProSand . . . . .                  | 13 |
| MultiSand . . . . .                | 14 |
| SandWet . . . . .                  | 14 |
| Specialty . . . . .                | 15 |
| Sanding Rolls . . . . .            | 16 |

### Drywall Sanding

|  |    |
|--|----|
| Sanding Sheets . . . . .               | 17 |
| WallSand . . . . .                     | 17 |
| Abrasive Sanding Sponges . . . . .     | 19 |
| WallSand . . . . .                     | 19 |
| Sanding Discs and Rolls . . . . .      | 20 |
| MeshPower . . . . .                    | 20 |
| Tools/Accessories - WallSand . . . . . | 21 |

### Power Sanding

|                                      |    |
|--------------------------------------|----|
| Discs – Hook & Sand . . . . .        | 22 |
| ProSand Multi-Air Cyclonic . . . . . | 23 |
| ProSand UVH . . . . .                | 24 |
| MeshPower . . . . .                  | 25 |
| MultiSand – Paper . . . . .          | 26 |
| Discs – Stick & Sand . . . . .       | 27 |
| MultiSand – Paper . . . . .          | 27 |
| MultiSand – Cloth . . . . .          | 28 |
| Flap Discs . . . . .                 | 29 |
| Fiber Discs . . . . .                | 30 |
| Rapid Strip . . . . .                | 31 |
| Quick-Change . . . . .               | 32 |
| Detail/Profile MultiSand . . . . .   | 33 |
| Belts . . . . .                      | 34 |
| Red Heat . . . . .                   | 34 |
| ProSand . . . . .                    | 35 |
| MultiSand . . . . .                  | 36 |

### Cutting & Grinding

|   |    |
|---|----|
| Diamond Products . . . . .              | 38 |
| Grinding Wheels / Blades . . . . .      | 39 |
| Right Angle Grinder Cut-off . . . . .   | 39 |
| Depressed Center Wheels . . . . .       | 40 |
| Small Diameter Cut-off Blades . . . . . | 41 |
| Circular Saw Cut-off Blades . . . . .   | 42 |
| High-Speed Cut-off Blades . . . . .     | 43 |
| Chop Saw Cut-off Blades . . . . .       | 43 |
| Stationary Saw Cut-off Blades . . . . . | 44 |
| Mounted Points . . . . .                | 44 |
| Bench & Pedestal Wheels . . . . .       | 45 |
| Wire Products . . . . .                 | 46 |

### Surface Prep & Clean

|                                  |    |
|----------------------------------|----|
| Plastic Coverings . . . . .      | 47 |
| Painter's Plastic . . . . .      | 47 |
| Hand Masking Film . . . . .      | 47 |
| Masking Tape . . . . .           | 48 |
| Steel Wool . . . . .             | 49 |
| Non-Woven Pads & Rolls . . . . . | 50 |
| Rotolo Foam . . . . .            | 51 |
| Micro-Fiber Cloths . . . . .     | 52 |
| Safety Accessories . . . . .     | 53 |

### Woodworking

|                              |    |
|------------------------------|----|
| Discs . . . . .              | 54 |
| Multi-Air Cyclonic . . . . . | 54 |
| Heavy-Weight Paper . . . . . | 55 |
| Light-Weight Paper . . . . . | 57 |
| Disc Accessories . . . . .   | 62 |
| Belts . . . . .              | 65 |
| Sharpening Stones . . . . .  | 68 |

### Merchandising

|                           |    |
|---------------------------|----|
| Racking/Display . . . . . | 69 |
| Signage . . . . .         | 72 |

### General Information

|                        |    |
|------------------------|----|
| Trademarks . . . . .   | 3  |
| Part-to-Page . . . . . | 73 |

#### Norton Trademarks

All trademarks used in these pages are trademarks of Saint-Gobain Abrasives, unless otherwise indicated.

|                    |                     |                 |               |
|--------------------|---------------------|-----------------|---------------|
| Adalox®            | Hook & Sand™        | Norton®         | Speed-Lok®    |
| Black Ice™         | Job Pack™           | Norton Clipper® | Spiraband®    |
| BlueFire®          | 4x4 MaxCut™         | Norton SG®      | Stick & Sand® |
| Charger™           | Merit®              | NorZon®         | TufBak®       |
| Classic™           | MeshPower™          | NorZon® Plus    | ValuPlus™     |
| Drylce®            | Metalite®           | PowerFlex™      | WallSand™     |
| DUO®               | MetalSand™          | ProSand®        | WoodSand™     |
| Durite®            | MultiSand™          | Rapid Strip™    | and more      |
| Gemini®            | Multi-Air®          | Red Heat®       |               |
| Get It. Finished.™ | Multi-Air Cyclonic® | SandWet™        |               |
| Clamp & Sand™      | No-Fil®             | Slicer™         |               |
| Handy Pack™        | Norax®              | Soft Touch®     |               |

**NORTON**

SAINT-GOBAIN

# ProSand®

## OUR PRODUCT EVOLUTION IS YOUR CUSTOMER'S **EASIEST SANDING SOLUTION**



### GET IT. **FINISHED.**™

With Norton ProSand, we've packaged the best sanding sheets and sponges into a new look while raising the performance and durability level in order to deliver a new industry standard for sanding made easier.

# SIT, STAND, STACK OR HANG... THE OPTIONS ARE YOURS



SIT



STAND



STACK



HANG

The new retail friendly clamshell packaging for Norton ProSand Multi-Air Cyclonic and UVH discs provides a secure, rugged, durable, highly-visible package that allows customers to see, touch, and feel the disc. It also provides retailers a variety of display options including sitting, standing, stacking, or hanging the package of discs.



What material are you hand sanding?

|   |                              |                         |                                  |
|---|------------------------------|-------------------------|----------------------------------|
| <b>GENERAL<br/>WOOD, PAINT, PLASTIC, ETC.</b> | <b>DRYWALL &amp; PLASTER</b> | <b>METAL &amp; RUST</b> | <b>PRIMER, SEALER, TOP COATS</b> |
|---|------------------------------|-------------------------|----------------------------------|

What level of smoothness do you need?

| GRIT   | APPLICATION | GRIT   | APPLICATION | GRIT   | APPLICATION | GRIT       | APPLICATION   |
|--------|-------------|--------|-------------|--------|-------------|------------|---------------|
| Coarse | Stripping   | Coarse | First Coat  | Coarse | Stripping   | Fine       | Initial Coats |
| Medium | Smoothing   | Medium | Second Coat | Medium | Smoothing   | Super Fine | Between Coats |
| Fine   | Finishing   | Fine   | Final Coat  | Fine   | Polishing   | Ultra Fine | Final Finish  |

How large is the project?

|  |  |   |   |
|--|--|---|---|
| <b>Small to Medium Jobs with One Sanding Step:</b><br>Sanding Sponge   | <b>Small Touch-Up Jobs:</b><br>Sanding Sponge      | <b>Small to General Purpose Jobs:</b><br>Sanding Sponge | <b>Small to General Purpose Jobs:</b><br>Sanding Sponge   |
| <b>Medium to Larger Jobs with Multiple Sanding Steps:</b><br>Sandpaper | <b>Small to Medium DIY Jobs:</b><br>Sanding Screen | <b>Light Deburring and Cleaning:</b><br>Non-Woven Pad   | <b>Large Jobs With Focus on High-End Finish:<br/>(i.e. Automotive Refinishing)</b><br>Sandpaper |

Do you want high performance and productivity or lowest initial cost?

|   |   |  |  |
|---|---|--|--|
| <b>Performance:</b><br>ProSand Sheets & Sponges           | <b>Performance:</b><br>WallSand Screen                          | <b>Performance:</b><br>MetalSand Cloth Sheets, Metal Finishing Non-Woven | <b>Performance:</b><br>SandWet Sheets          |
| <b>Opening Price Point:</b><br>MultiSand Sheets & Sponges | <b>Opening Price Point:</b><br>WallSand Paper, WallSand Sponges | <b>Opening Price Point:</b><br>MultiSand Sponges                         | <b>Opening Price Point:</b><br>SandWet Sponges |



## ProSand

Premium abrasive provides superior cut on all surfaces, lasts substantially longer and cuts faster than conventional abrasives and has been open abrasive grain coated to resist clogging and loading during sanding. Available in a wide range of grits to tackle any job, ProSand Sheets are perfect for sanding paint, drywall, and wood.



Scan the QR code to view our video



### Grit Guide

| 60 COARSE   | 80 COARSE                      | 100 MEDIUM                              | 120 MEDIUM                               | 150 MEDIUM               | 180 FINE  | 220 VERY FINE                       | 320 EXTRA FINE        | 400 SUPER FINE |
|---|--------------------------------|---|--|--------------------------|---|-------------------------------------|-----------------------|----------------|
| Heavy removal, stripping, shaping, and dimensioning | Moderate removal and stripping | Moderate to light removal and stripping | Light stock removal and surface leveling | Fine surface preparation | Final surface smoothing and initial between coats | After priming, staining, or sealing | Between coats sanding | Final finish   |


### Features & Benefits

- Premium heat-treated abrasive offers faster cut and longer sanding life than 3X technology. Heat treating toughens the grain allowing it to stay sharp and last longer under extreme pressure, making it the most durable abrasive on the market. Super sharp edges allow grain to remove material faster.
- Increased backing weight. Fiber reinforcement and latex saturation offer better grain retention with higher flexibility for easy folding and unfolding without tearing.
- Non-pigmented, waterbased stearate, anti-clog (No-Fil) open coat design. Anti-clog provides best resistance to premature loading during sanding.
- No color dye in coating process so there is no chance of color transfer to work piece.

“ I shall continue to only have Norton abrasives in my shop. I've only come across one other brand that could compete in the past, but your ProSand is like a quantum leap above the rest. ”

- Jim Attwooll

### PERCENTAGE STOCK REMOVAL 80, 150, & 200 GRIT SEQUENCE

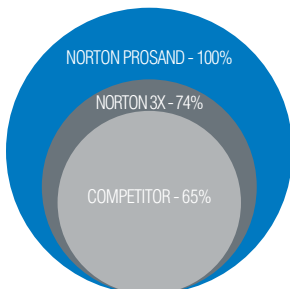

\* PERCENTAGE BASED ON TOTAL GRAMS CUT OVER 12 MINUTES OF SANDING ON RED OAK WITH VIBRATING SHEET SANDER

\* Results based on internal testing performed using a vibrating sheet sander. Performance data reflects cumulative stock removal of red oak panels over the course of an 80, 150, 220 grit sanding sequence.

| PART #                                    | UPC-A       | GRIT | GRADING                            | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|------------------------------------|--------------|----------------|
| <b>Handy Packs</b>                        |             |      |                                    |              |                |
| <b>9" x 11"</b>                           |             |      |                                    |              |                |
| 07660768156                               | 07660702612 | 5    | 400 Super Fine                     | 3            | 25**           |
| 07660768157                               | 07660702613 | 2    | 320 Extra Fine                     | 3            | 25**           |
| 07660768158                               | 07660702616 | 3    | 220 Very Fine                      | 3            | 25**           |
| 07660768159                               | 07660702617 | 0    | 180 Fine                           | 3            | 25**           |
| 07660768160                               | 07660702618 | 7    | 150 Medium                         | 3            | 25**           |
| 07660768161                               | 07660702619 | 4    | 120 Medium                         | 3            | 25**           |
| 07660768162                               | 07660702620 | 0    | 100 Medium                         | 3            | 25**           |
| 07660768163                               | 07660702621 | 7    | 80 Coarse                          | 3            | 25**           |
| 07660768164                               | 07660702622 | 4    | 60 Coarse                          | 3            | 25**           |
| 07660768182                               | 07660705386 | 2    | Asst. 1 each of 60, 100, 150 & 220 | 4            | 25**           |
| <b>4-1/2" x 4-1/2" - Stick &amp; Sand</b> |             |      |                                    |              |                |
| 07660768177                               | 07660705311 | 4    | 220 Very Fine                      | 4            | 20**           |
| 07660768183                               | 07660705312 | 1    | 150 Medium                         | 4            | 10**           |
| 07660768184                               | 07660705313 | 8    | 100 Medium                         | 4            | 10**           |
| 07660768185                               | 07660705314 | 5    | 60 Coarse                          | 4            | 10**           |
| <b>3-2/3" x 9" - Clamp &amp; Sand</b>     |             |      |                                    |              |                |
| 07660768178                               | 07660705315 | 2    | P220 Very Fine                     | 4            | 20**           |
| 07660768179                               | 07660705316 | 9    | P150 Medium                        | 4            | 20**           |
| 07660768180                               | 07660705317 | 6    | P100 Medium                        | 4            | 20**           |
| 07660768181                               | 07660705318 | 3    | P60 Coarse                         | 4            | 20**           |
| <b>Job Packs</b>                          |             |      |                                    |              |                |
| <b>9" x 11"</b>                           |             |      |                                    |              |                |
| 07660768165                               | 07660702632 | 3    | 400 Super Fine                     | 20           | 10**           |
| 07660768166                               | 07660702633 | 0    | 320 Extra Fine                     | 20           | 10**           |
| 07660768167                               | 07660702636 | 1    | 220 Very Fine                      | 20           | 10**           |
| 07660768168                               | 07660702637 | 8    | 180 Fine                           | 20           | 10**           |
| 07660768171                               | 07660702638 | 5    | 150 Medium                         | 20           | 10**           |
| 07660768172                               | 07660702639 | 2    | 120 Medium                         | 20           | 10**           |
| 07660768173                               | 07660702640 | 8    | 100 Medium                         | 20           | 10**           |
| 07660768174                               | 07660702641 | 5    | 80 Coarse                          | 20           | 10**           |
| 07660768175                               | 07660702642 | 2    | 60 Coarse                          | 20           | 10**           |
| <b>Accessories</b>                        |             |      |                                    |              |                |
| 07660705237                               | 07660705237 | 7    | 3-2/3" x 7" Ergonomic Hand Sander  | 1            | 8              |



## MultiSand

For general purpose hand or machine sanding wood, metal, plastic and fiberglass, as well as removing old paint.

### Grit Guide

| 36 EX. COARSE      | 50 COARSE     | 80 COARSE        | 100 MEDIUM                | 120 MEDIUM       | 150 MEDIUM             | 180 FINE                 | 220 VERY FINE         |
|--------------------|---------------|------------------|---------------------------|------------------|------------------------|--------------------------|-----------------------|
| Very Heavy Removal | Heavy Removal | Moderate Removal | Moderate To Light Removal | Surface Leveling | Fine Surface Smoothing | Fine Surface Preparation | Sanding Initial Coats |

| PART #                                    | UPC-A       | GRIT | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|-----------|--------------|----------------|
| <b>Handy Packs</b>                        |             |      |           |              |                |
| <b>9" x 11" (A215, A213, A211)</b>        |             |      |           |              |                |
| 07660747710                               | 07660747710 | 220  | Very Fine | 5            | 10             |
| 07660702769                               | 07660747710 | 1    | 220       | Very Fine    | 5 25**         |
| 07660747720                               | 07660747720 | 0    | 150       | Medium       | 5 10           |
| 07660702770                               | 07660747720 | 0    | 150       | Medium       | 5 25**         |
| 07660704154                               | 07660747725 | 5    | 120       | Medium       | 5 25**         |
| 07660747735                               | 07660747735 | 4    | 100       | Medium       | 5 10           |
| 07660702771                               | 07660747735 | 4    | 100       | Medium       | 5 25**         |
| 07660704153                               | 07660747740 | 8    | 80        | Coarse       | 5 25**         |
| 07660747750                               | 07660747750 | 7    | 60        | Coarse       | 3 10           |
| 07660702772                               | 07660747750 | 7    | 60        | Coarse       | 3 25**         |
| 07660747765                               | 07660747765 | 1    | Asst.     | 2 VF, 2F, 1M | 5 10           |
| 07660704155                               | 07660747765 | 1    | Asst.     | 2 VF, 2F, 1M | 5 25**         |
| <b>4-1/2" x 11" (A215, A213, A211)</b>    |             |      |           |              |                |
| 07660702050                               | 07660748353 | 9    | 150       | Medium       | 6 10**         |
| 07660702051                               | 07660748354 | 6    | 100       | Medium       | 6 10**         |
| 07660702052                               | 07660748355 | 3    | 60        | Coarse       | 4 10**         |
| <b>4-1/2" x 5-1/2" (A215, A213, A211)</b> |             |      |           |              |                |
| 07660705441                               | 07660748132 | 0    | 220       | Very Fine    | 6 10**         |
| 07660705442                               | 07660748300 | 3    | 150       | Medium       | 6 10**         |
| 07660705444                               | 07660748301 | 0    | 100       | Medium       | 6 10**         |
| 07660705445                               | 07660748302 | 7    | 60        | Coarse       | 6 10**         |
| 07660702057                               | 07660748130 | 6    | Asst.     | 2VF, 2F, 2M  | 6 10**         |
| <b>4-1/2" x 4-1/2" (A475, A213)</b>       |             |      |           |              |                |
| 07660705447                               | 07660749126 | 8    | 220       | Very Fine    | 5 10**         |
| 07660705446                               | 07660749127 | 5    | 150       | Medium       | 5 10**         |
| 07660705452                               | 07660749128 | 2    | 100       | Medium       | 5 10**         |
| <b>3-2/3" x 9" (A215, A213, A211)</b>     |             |      |           |              |                |
| 07660748295                               | 07660748295 | 2    | 150       | Medium       | 6 20**         |
| 07660748310                               | 07660748310 | 2    | 100       | Medium       | 6 20**         |
| 07660748325                               | 07660748325 | 6    | 60        | Coarse       | 6 20**         |
| 07660748335                               | 07660748335 | 5    | Asst.     | 3F, 2M, 1C   | 6 20**         |
| 07660702061                               | 07660748335 | 5    | Asst.     | 3F, 2M, 1C   | 6 10           |
| <b>3-2/3" x 25' Sheet Roll (A213)</b>     |             |      |           |              |                |
| 07660784250                               | 07660784250 | 3    | 150       | Medium       | 1 9**          |
| 07660784251                               | 07660784251 | 0    | 100       | Medium       | 1 9**          |
| 07660784252                               | 07660784252 | 7    | 60        | Coarse       | 1 9**          |

| PART #   | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|------|---------|--------------|----------------|
| <b>Job Packs – UPC Bar Coded</b>                                 |             |      |         |              |                |
| <b>9" x 11" (A215, A213, A211)</b>                               |             |      |         |              |                |
| 07660700354  | 07660700354 | 6    | 220A    | Very Fine    | 25 10**        |
| 07660700355  | 07660700355 | 3    | 180A    | Fine         | 25 10**        |
| 07660700356  | 07660700356 | 0    | 150C    | Medium       | 25 10**        |
| 07660700357  | 07660700357 | 7    | 120C    | Medium       | 25 10**        |
| 07660700358  | 07660700358 | 4    | 100C    | Medium       | 25 10**        |
| 07660768109  | 07660768109 | 6    | 80D     | Coarse       | 25 5           |
| 07660768108  | 07660768108 | 9    | 60D     | Coarse       | 25 5           |
| 07660768111  | 07660768111 | 9    | 50D     | Coarse       | 25 5           |
| 07660768110  | 07660768110 | 2    | 36D     | Ex. Coarse   | 25 5           |
| 07660700365  | 07660700365 | 2    | Asst.   | Asst.        | 25 10**        |
| <b>Rolls</b>   |             |      |         |              |                |
| <b>2-3/4" x 30/45 yds. Stick &amp; Sand Sheet Roll (A275)</b>    |             |      |         |              |                |
| 66261131681  | 66261131681 | 1    | P400B   | Very Fine    | 1 -            |
| 66261131683  | 66261131683 | 5    | P320B   | Very Fine    | 1 -            |
| 66261131685  | 66261131685 | 9    | P240B   | Very Fine    | 1 -            |
| 66261131686  | 66261131686 | 6    | P220B   | Very Fine    | 1 -            |
| 66261131687  | 66261131687 | 3    | P180B   | Fine         | 1 -            |
| 66261131688  | 66261131688 | 0    | P150B   | Medium       | 1 -            |
| 66261131689  | 66261131689 | 7    | P120B   | Medium       | 1 -            |
| 66261131690  | 66261131690 | 1    | P100B   | Medium       | 1 -            |
| <b>4-1/2" x 10 yds. (30') Stick &amp; Sand Sheet Roll (A296)</b> |             |      |         |              |                |
| 07660749247  | 07660749247 | 0    | P320C   | Very Fine    | 1 10**         |
| 07660749248  | 07660749248 | 7    | P220C   | Very Fine    | 1 10**         |
| 07660749249  | 07660749249 | 4    | P180C   | Fine         | 1 10**         |
| 07660749250  | 07660749250 | 0    | P150C   | Medium       | 1 10**         |
| 07660749251  | 07660749251 | 7    | P120C   | Medium       | 1 10**         |
| 07660749252  | 07660749252 | 4    | P100C   | Medium       | 1 10**         |
| 07660749254  | 07660749254 | 8    | P80C    | Coarse       | 1 10**         |
| <b>3-1/2" x 25 yds. (A211, A213)</b>                             |             |      |         |              |                |
| 07660704148  | 07660704148 | 7    | 150     | Medium       | 1 5            |
| 07660704147  | 07660704147 | 0    | 120     | Medium       | 1 5            |
| 07660704146  | 07660704146 | 3    | 100     | Medium       | 1 5            |
| 07660704145  | 07660704145 | 6    | 80      | Coarse       | 1 5            |
| <b>3-1/2" x 50 yds. (A213, A211)</b>                             |             |      |         |              |                |
| 07660784042  | 07660784042 | 4    | 150     | Medium       | 1 5            |
| 07660784024  | 07660784024 | 0    | 120     | Medium       | 1 5            |
| 07660784025  | 07660784025 | 7    | 100     | Medium       | 1 5            |
| 07660784002  | 07660784002 | 8    | 80      | Coarse       | 1 5            |

### Accessories

|  |   |             |             |   |   |   |
|--|---|-------------|-------------|---|---|---|
|  | <b>Rubber Hand Sanding Block</b>                    | 07660701889 | 07660743140 | 0 | 1 | 5 |
|  | <b>Hook and Loop Finishing Sander - Handy Packs</b> | 07660768239 | 07660768239 | 0 | 1 | 5 |

|  |  |             |             |   |   |    |
|--|--|-------------|-------------|---|---|----|
|  | <b>Hook and Loop Detail Sander - Handy Packs</b> | 07660768240 | 07660768240 | 6 | 1 | 5  |
|  | <b>Hook and Loop Detail Sander - Handy Packs</b> | 07660768275 | 07660768275 | 8 | 1 | 10 |





## WoodSand

For preparation of bare wood surfaces where stain or finishes are to be applied. The natural garnet abrasive imparts a fine, smooth finish on wood.

### Grit Guide

|                                   |                                      |  |  |   |  |   |
|-----------------------------------|--------------------------------------|--|--|---|--|---|
| <b>60 COARSE</b><br>Heavy Removal | <b>80 COARSE</b><br>Moderate Removal | <b>100 MEDIUM</b><br>Moderate to Light Removal | <b>120 MEDIUM</b><br>Surface Levelling | <b>150 MEDIUM</b><br>Fine Surface Preparation | <b>180 FINE</b><br>Final Surface Smoothing | <b>220 VERY FINE</b><br>Sanding Initial Coats |
|-----------------------------------|--------------------------------------|--|--|---|--|---|

| PART #             | UPC-A                 | GRIT  | GRADING     | QTY/<br>PACK | PACKS/<br>CASE |
|--------------------|-----------------------|-------|-------------|--------------|----------------|
| <b>Handy Packs</b> |                       |       |             |              |                |
| <b>9" x 11"</b>    |                       |       |             |              |                |
| 07660747965        | 076607 <b>47965</b> 5 | 220   | Very Fine   | 5            | 10             |
| 07660747980        | 076607 <b>47980</b> 8 | 150   | Medium      | 5            | 10             |
| 07660747990        | 076607 <b>47990</b> 7 | 100   | Medium      | 5            | 10             |
| 07660748010        | 076607 <b>48010</b> 1 | 60    | Coarse      | 3            | 10             |
| 07660748025        | 076607 <b>48025</b> 5 | Asst. | 2VF, 2F, 1M | 5            | 10             |
| <b>Job Packs</b>   |                       |       |             |              |                |
| <b>9" x 11"</b>    |                       |       |             |              |                |
| 07660701579        | 076607 <b>01579</b> 2 | 220A  | Very Fine   | 25           | 10**           |
| 07660701580        | 076607 <b>01580</b> 8 | 180A  | Fine        | 25           | 10**           |
| 07660705507        | 076607 <b>05507</b> 1 | 150A  | Medium      | 25           | 10**           |
| 07660705506        | 076607 <b>05506</b> 4 | 120A  | Medium      | 25           | 10**           |
| 07660705505        | 076607 <b>05505</b> 7 | 100A  | Medium      | 25           | 10**           |
| 07660705504        | 076607 <b>05504</b> 0 | 80A   | Coarse      | 25           | 10**           |

| PART #                           | UPC-A                 | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|----------------------------------|-----------------------|------|---------|--------------|----------------|
| <b>Job Packs – UPC Bar Coded</b> |                       |      |         |              |                |
| <b>9" x 11"</b>                  |                       |      |         |              |                |
| 07660701581                      | 076607 <b>01581</b> 5 | 150C | Medium  | 25           | 10**           |
| 07660701582                      | 076607 <b>01582</b> 2 | 120C | Medium  | 25           | 10**           |
| 07660701583                      | 076607 <b>01583</b> 9 | 100C | Medium  | 25           | 10**           |
| 07660701584                      | 076607 <b>01584</b> 6 | 80C  | Coarse  | 25           | 10**           |



## MetalSand

For removing rust, paint and scale from metal surfaces. Also used for light deburring and cleaning. The natural emery abrasive is coated onto a flexible cloth backing for increased durability.

### Grit Guide

|                                |                                   |                          |
|--------------------------------|-----------------------------------|--------------------------|
| <b>COARSE</b><br>Heavy Removal | <b>MEDIUM</b><br>Moderate Removal | <b>FINE</b><br>Polishing |
|--------------------------------|-----------------------------------|--------------------------|

| PART #             | UPC-A                 | GRIT   | GRADING    | QTY/PACK | PACKS/CASE |
|--------------------|-----------------------|--------|------------|----------|------------|
| <b>Handy Packs</b> |                       |        |            |          |            |
| <b>9" x 11"</b>    |                       |        |            |          |            |
| 07660747805        | 076607 <b>47805</b> 4 | Fine   | Fine       | 3        | 25**       |
| 07660747820        | 076607 <b>47820</b> 7 | Medium | Medium     | 3        | 25**       |
| 07660747835        | 076607 <b>47835</b> 1 | Coarse | Coarse     | 3        | 25**       |
| 07660747855        | 076607 <b>47855</b> 9 | Asst.  | 1F, 1M, 1C | 3        | 25**       |



## SandWet

For wet, oil or dry sanding primer, sealer, varnish, lacquer, enamel and other top coats.

- Flexible, fiber-reinforced backing
- Non-pigmented, water-based stearate (anti-clog) coating, open coat
- No color dye in coating process
- Superior sanding performance for a premium surface finish
- To increase sanding flexibility, soak in water for 15 minutes prior to use
- The wet dry sheets create an exceptionally smooth surface


### Grit Guide

|   |  |  |  |   |  |  |  |
|---|--|--|--|---|--|--|--|
| <b>220 VERY FINE</b><br>Sanding Initial Coats | <b>320 EXTRA FINE</b><br>Between Coats Sanding | <b>400 SUPER FINE</b><br>Sanding Prior To Final Coat | <b>600 ULTRA FINE</b><br>Sanding Final Lacquer Coats | <b>800 MICRO FINE</b><br>For Matte Finish | <b>1200 MICRO FINE</b><br>For Satin Finish | <b>1500 MICRO FINE</b><br>For High Gloss | <b>2000 MICRO FINE</b><br>Touch-Up Repairs |
|---|--|--|--|---|--|--|--|

| PART #             | UPC-A                 | GRIT  | GRADING        | QTY/<br>PACK | PACKS/<br>CASE |
|--------------------|-----------------------|-------|----------------|--------------|----------------|
| <b>Handy Packs</b> |                       |       |                |              |                |
| <b>9" x 11"</b>    |                       |       |                |              |                |
| 07660748052        | 076607 <b>48052</b> 1 | 2000  | Micro Fine     | 5            | 10             |
| 07660748053        | 076607 <b>48053</b> 8 | 1500  | Micro Fine     | 5            | 10             |
| 07660748054        | 076607 <b>48054</b> 5 | 1200  | Micro Fine     | 5            | 10             |
| 07660748055        | 076607 <b>48055</b> 2 | 800   | Micro Fine     | 5            | 10             |
| 07660748058        | 076607 <b>48058</b> 3 | 600   | Ultra Fine     | 5            | 10             |
| 07660702343        | 076607 <b>48058</b> 3 | 600   | Ultra Fine     | 5            | 25**           |
| 07660748060        | 076607 <b>48060</b> 6 | 400   | Super Fine     | 5            | 10             |
| 07660702344        | 076607 <b>48060</b> 6 | 400   | Super Fine     | 5            | 25**           |
| 07660748080        | 076607 <b>48080</b> 4 | 320   | Extra Fine     | 5            | 10             |
| 07660702345        | 076607 <b>48080</b> 4 | 320   | Extra Fine     | 5            | 25**           |
| 07660748090        | 076607 <b>48090</b> 3 | 220   | Very Fine      | 5            | 10             |
| 07660748110        | 076607 <b>48110</b> 8 | Asst. | 2 SF, 2EF, 1VF | 5            | 10             |

| PART #                           | UPC-A                 | GRIT | GRADING    | QTY/<br>PACK | PACKS/<br>CASE |
|----------------------------------|-----------------------|------|------------|--------------|----------------|
| <b>Job Packs – UPC Bar Coded</b> |                       |      |            |              |                |
| <b>9" x 11"</b>                  |                       |      |            |              |                |
| 07660701223                      | 076607 <b>01223</b> 4 | 600A | Ultra Fine | 25           | 10**           |
| 07660701224                      | 076607 <b>01224</b> 1 | 400A | Super Fine | 25           | 10**           |
| 07660701225                      | 076607 <b>01225</b> 8 | 320A | Extra Fine | 25           | 10**           |
| 07660701226                      | 076607 <b>01226</b> 5 | 220A | Very Fine  | 25           | 10**           |




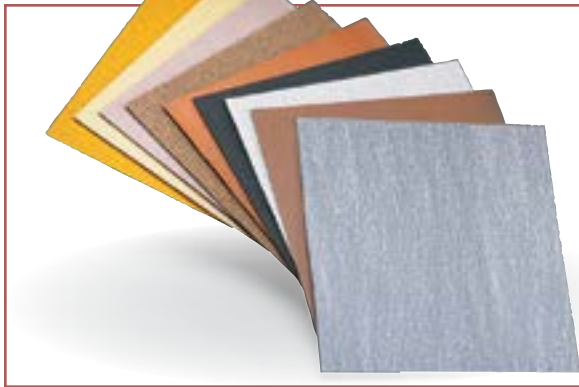

**Bulk Full Sheets**

**TIP**

How to Cut a 9" x 11" Full Sheet to Fit Your Sander

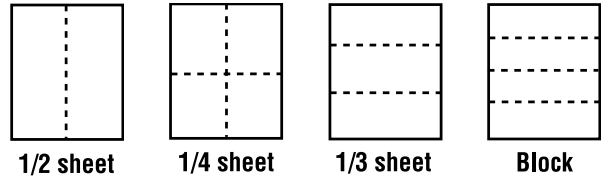

**ProSand No-Fil A259PS**

Premium, P-graded aluminum oxide abrasive with fiber-reinforced backing. Specially coated to resist loading and tearing for three times the life over conventional aluminum oxide products. First choice when performance counts on sanding tough finishes or looking for exceptional finish. High flexibility.

**Premium No-Fil A275 (B-wt)**

Premium, P-graded aluminum oxide abrasive resin bonded to a B-weight backing. Specially coated to resist loading and tearing over conventional aluminum oxide products.

**No-Fil PB273 (B-wt)**

P-graded aluminum oxide abrasive for fast cutting action and extended life with consistent finish. Flexible latex B-wt backing with a full resin bond and open coat allows for improved resistance to delamination. The water-based steared, non-pigmented No-Fil coating provides improved load resistance and no color transfer to the work piece.

**Adalox A211 (D-wt), A212 (A-wt), A213 (C-wt)**

For dry sanding hardwood, metal and composites by hand or machine. Long lasting, aluminum oxide abrasive is open coated on high tensile paper. A, C, D weight paper.

**E-Z Flex Metalite K225 (J-wt)**

For deburring, cleaning and polishing of metal. Rugged aluminum oxide abrasive is electro-coated onto a flexible cloth backing. Outperforms natural grains, like emery.

**Emery K622**

For scouring and polishing non-rated metals and utensils. Emery abrasive is durabonded onto a flexible cloth backing.

**Garnet A511 (A-wt), A513 (C-wt), A514 (D-wt)**

For rough through finish hand sanding of softer woods and cabinet work. Use dry on bare wood prior to coating. Natural garnet abrasive is electro-coated on high tensile paper. A, C, D weight paper.

**Tufbak Durite Waterproof T461 (C-wt)**

For sanding between coats of primers and other finishes on wood or metal with water or other lubricants. Diamond-like silicon carbide abrasive is electro-coated to a tough, waterproof paper backing.

**Tufbak Durite Waterproof T401 (A-wt), T414 (A-wt)**

For generating the ultimate finish in wet sanding applications. The premium ultra fine silicon carbide abrasive combined with a unique A-weight paper and strong resin bond system provides ultimate flexibility, long life and wet curl resistance.

**Tufbak Waterproof T280 (A-wt)**

For wet or dry sanding between coats as well as final sanding. The premium ultra fine P-graded aluminum oxide abrasive is coated on a durable waterproof paper providing an ultra fine finish with improved tear resistance.

**No-Fil Durite A475 (B-wt)**

For sanding between coats of primers and other finishes. The combination of sharp silicon carbide abrasive, a strong resin bond and special anti-clog coating gives it increased sanding life in dry applications.

| PART #  | UPC-A       | GRIT    | GRADING | QTY/<br>PACK | QTY/<br>CASE |
|---|-------------|---------|---------|--------------|--------------|
| <b>9" x 11" Bulk – UPC Bar Coded</b>                          |             |         |         |              |              |
| <b>ProSand A259PS (Aluminum Oxide) Paper - Open Coat</b>      |             |         |         |              |              |
| 07660702623   | 07660702623 | 1 P400B |         | 100          | 500          |
| 07660702624   | 07660702624 | 8 P320B |         | 100          | 500          |
| 07660702625   | 07660702625 | 5 P220B |         | 100          | 500          |
| 07660702626   | 07660702626 | 2 P180B |         | 100          | 500          |
| 07660702627   | 07660702627 | 9 P150B |         | 100          | 500          |
| 07660702628   | 07660702628 | 6 P120B |         | 100          | 500          |
| 07660702629   | 07660702629 | 3 P100B |         | 50           | 250          |
| 07660702630   | 07660702630 | 6 P80C  |         | 50           | 250          |
| 07660702631   | 07660702631 | 6 P60C  |         | 50           | 250          |
| <b>Adalox (A212, A213) (Aluminum Oxide) Paper – Open Coat</b> |             |         |         |              |              |
| 07660700156   | 07660700156 | 6 P220A |         | 100          | 500          |
| 07660700157   | 07660700157 | 3 P180A |         | 100          | 500          |
| 07660700158   | 07660700158 | 0 P150C |         | 100          | 500          |
| 07660700159   | 07660700159 | 7 P120C |         | 100          | 500          |
| 07660700160   | 07660700160 | 3 P100C |         | 100          | 500          |
| 07660700151   | 07660700151 | 1 P80C  |         | 50           | 250          |
| 07660700152   | 07660700152 | 8 P60D  |         | 50           | 250          |
| 07660700153   | 07660700153 | 5 P50D  |         | 50           | 250          |
| 07660700154   | 07660700154 | 2 P40D  |         | 25           | 125          |
| 07660700155   | 07660700155 | 9 P36D  |         | 25           | 125          |

| PART #   | UPC-A       | GRIT   | GRADING    | QTY/<br>PACK | QTY/<br>CASE |
|--|-------------|--------|------------|--------------|--------------|
| <b>9" x 11" Bulk – UPC Bar Coded</b>               |             |        |            |              |              |
| <b>Garnet (A511, A513, A514) Paper – Open Coat</b> |             |        |            |              |              |
| 07660701511  | 07660701511 | 2 220A |            | 100          | 500          |
| 07660701512  | 07660701512 | 9 180A |            | 100          | 500          |
| 07660701513  | 07660701513 | 6 150C |            | 100          | 500          |
| 07660701514  | 07660701514 | 3 120C |            | 100          | 500          |
| 07660701515  | 07660701515 | 0 100C |            | 100          | 500          |
| 07660701516  | 07660701516 | 7 80C  |            | 50           | 250          |
| 07660701517  | 07660701517 | 4 60C  |            | 50           | 250          |
| 07660701518  | 07660701518 | 1 50D  |            | 50           | 250          |
| <b>Tufbak Waterproof T280 Paper – Close Coat</b>   |             |        |            |              |              |
| 07660701293  | 07660701293 | 7 600C |            | 50           | 250          |
| 07660701294  | 07660701294 | 4 400C |            | 50           | 250          |
| 07660701295  | 07660701295 | 1 320C |            | 50           | 250          |
| 07660701296  | 07660701296 | 8 220C |            | 50           | 250          |
| <b>Emery K622 Cloth – Close Coat</b>               |             |        |            |              |              |
| 07660701308  | 07660701308 | 8 150X | Fine       | 50           | 250          |
| 07660701309  | 07660701309 | 5 100X | Medium     | 50           | 250          |
| 07660701307  | 07660701307 | 1 80X  | Coarse     | 25           | 125          |
| 66261101255  | 66261101255 | 3 50X  | Ex. Coarse | 25           | 125          |

## Bulk Full Sheets


| PART #  | UPC-A       | GRIT | GRADING | QTY/<br>PACK | QTY/<br>CASE |
|---|-------------|------|---------|--------------|--------------|
| <b>9" x 11" Bulk - Non UPC</b>                                |             |      |         |              |              |
| <b>Premium No-Fil A275 (Aluminum Oxide) Paper – Open Coat</b> |             |      |         |              |              |
| 66261131618   | 66261131618 | 7    | P1500B  | 100          | 500          |
| 66261131619   | 66261131619 | 3    | P1200B  | 100          | 500          |
| 66261131620   | 66261131620 | 0    | P1000B  | 100          | 500          |
| 66261131621   | 66261131621 | 7    | P800B   | 100          | 500          |
| 66261131622   | 66261131622 | 4    | P600B   | 100          | 500          |
| 66261131624   | 66261131624 | 8    | P400B   | 100          | 500          |
| 66261131626   | 66261131626 | 2    | P320B   | 100          | 500          |
| 66261131627   | 66261131627 | 9    | P280B   | 100          | 500          |
| 66261131628   | 66261131628 | 6    | P240B   | 100          | 500          |
| 66261131629   | 66261131629 | 3    | P220B   | 100          | 500          |
| 66261131630   | 66261131630 | 9    | P180B   | 100          | 500          |
| 66261131631   | 66261131631 | 6    | P150B   | 100          | 500          |
| 66261131632   | 66261131632 | 3    | P120B   | 100          | 500          |
| 66261131633   | 66261131633 | 0    | P100B   | 100          | 500          |
| 66261131634   | 66261131634 | 7    | P80B    | 50           | 250          |
| <b>No-Fil PB273 (Aluminum Oxide) Paper – Open Coat</b>        |             |      |         |              |              |
| 66623311870   | 66623311870 | 2    | P400B   | 100          | 500          |
| 66623311871   | 66623311871 | 9    | P320B   | 100          | 500          |
| 66623311879   | 66623311879 | 5    | P240B   | 100          | 500          |
| 66623311873   | 66623311873 | 6    | P220B   | 100          | 500          |
| 66623311874   | 66623311874 | 4    | P180B   | 100          | 500          |
| 66623311875   | 66623311875 | 7    | P150B   | 100          | 500          |
| 66623311876   | 66623311876 | 4    | P120B   | 100          | 500          |
| 66623311877   | 66623311877 | 1    | P100B   | 100          | 500          |
| 66623311878   | 66623311878 | 8    | P80B    | 50           | 250          |
| <b>A211, A212, A213 (Aluminum Oxide) Paper – Open Coat</b>    |             |      |         |              |              |
| 66261100245   | 66261100245 | 5    | P180A   | 100          | 500          |
| 66261100285   | 66261100285 | 1    | P150C   | 100          | 500          |
| 66261100290   | 66261100290 | 5    | P120C   | 100          | 500          |
| 66261100295   | 66261100295 | 0    | P100C   | 100          | 500          |
| 66261100315   | 66261100315 | 5    | P80C    | 50           | 250          |
| 66261100320   | 66261100320 | 9    | P60D    | 50           | 250          |
| 66261100325   | 66261100325 | 4    | P50D    | 50           | 250          |
| 66261100330   | 66261100330 | 8    | P40D    | 25           | 125          |
| 66261100335   | 66261100335 | 3    | P36D    | 25           | 125          |
| <b>Garnet A511, A513, A514 Paper – Open Coat</b>              |             |      |         |              |              |
| 66261101488   | 66261101488 | 5    | 220A    | 100          | 500          |
| 66261101489   | 66261101489 | 2    | 180A    | 100          | 500          |
| 66261101490   | 66261101490 | 8    | 150A    | 100          | 500          |
| 66261101495   | 66261101495 | 3    | 120A    | 100          | 500          |
| 66261101500   | 66261101500 | 4    | 100A    | 100          | 500          |
| 66261101505   | 66261101505 | 9    | 80A     | 50           | 250          |
| 66261101525   | 66261101525 | 7    | 150C    | 100          | 500          |
| 66261101530   | 66261101530 | 1    | 120C    | 100          | 500          |
| 66261101535   | 66261101535 | 6    | 100C    | 100          | 500          |
| 66261101555   | 66261101555 | 4    | 80C     | 50           | 250          |
| 66261101560   | 66261101560 | 8    | 60C     | 50           | 250          |
| <b>No-Fil Durite A475 (Silicon Carbide) Paper – Open Coat</b> |             |      |         |              |              |
| 66254487400   | 66254487400 | 6    | P320B   | 100          | 500          |
| 66254487399   | 66254487399 | 3    | P240B   | 100          | 500          |
| 66254487398   | 66254487398 | 6    | P220B   | 100          | 500          |
| 66254487397   | 66254487397 | 9    | P180B   | 100          | 500          |
| 66254487396   | 66254487396 | 2    | P150B   | 100          | 500          |
| 66254487395   | 66254487395 | 5    | P120B   | 100          | 500          |
| 66254487394   | 66254487394 | 8    | P100B   | 100          | 500          |
| 66254487393   | 66254487393 | 1    | P80B    | 50           | 250          |

| PART #   | UPC-A       | GRIT | GRADING | QTY/<br>PACK | QTY/<br>CASE |     |
|--|-------------|------|---------|--------------|--------------|-----|
| <b>9" x 11" Bulk - Non UPC (continued)</b>                                     |             |      |         |              |              |     |
| <b>Tufbak Durite T401/T414 (Silicon Carbide) Waterproof Paper – Close Coat</b> |             |      |         |              |              |     |
| 66261139377  | 66261139377 | 5    | P2500A  | 50           | 250          |     |
| 66261139378  | 66261139378 | 2    | P2000A  | 50           | 250          |     |
| 66261139379  | 66261139379 | 9    | P1500A  | 50           | 250          |     |
| 66261139380  | 66261139380 | 5    | P1200A  | 50           | 250          |     |
| 66261139381  | 66261139381 | 2    | P1000A  | 50           | 250          |     |
| 66261139382  | 66261139382 | 9    | 800A    | 50           | 250          |     |
| 66261139360  | 66261139360 | 7    | 600A    | 50           | 250          |     |
| 66261139361  | 66261139361 | 4    | 500A    | 50           | 250          |     |
| 66261139362  | 66261139362 | 1    | 400A    | 50           | 250          |     |
| 66261139363  | 66261139363 | 8    | 360A    | 50           | 250          |     |
| 66261139364  | 66261139364 | 5    | 320A    | 50           | 250          |     |
| 66261139365  | 66261139365 | 2    | 280A    | 50           | 250          |     |
| 66261139366  | 66261139366 | 9    | 240A    | 50           | 250          |     |
| 66261139367  | 66261139367 | 6    | 220A    | 50           | 250          |     |
| <b>Tufbak Durite T461 (Silicon Carbide) Waterproof Paper – Close Coat</b>      |             |      |         |              |              |     |
| 66261130334  | 66261130334 | 7    | 600C    | 50           | 250          |     |
| 66261130333  | 66261130333 | 0    | 400C    | 50           | 250          |     |
| 66261130332  | 66261130332 | 3    | 320C    | 50           | 250          |     |
| 66261130331  | 66261130331 | 6    | 240C    | 50           | 250          |     |
| 66261101150  | 66261101150 | 1    | 180C    | 50           | 250          |     |
| 66261101155  | 66261101155 | 6    | 150C    | 50           | 250          |     |
| 66261101160  | 66261101160 | 0    | 120C    | 50           | 250          |     |
| 66261101165  | 66261101165 | 5    | 100C    | 50           | 250          |     |
| 66261101170  | 66261101170 | 9    | 80C     | 50           | 250          |     |
| 66261101175  | 66261101175 | 4    | 60C     | 50           | 250          |     |
| <b>Metalite K225 (Aluminum Oxide) Cloth – Close Coat</b>                       |             |      |         |              |              |     |
| 66261126330  | 66261126330 | 6    | P600J   | 50           | 250          |     |
| 66261126331  | 66261126331 | 3    | P400J   | 50           | 250          |     |
| 66261126332  | 66261126332 | 0    | P320J   | 50           | 250          |     |
| 66261126333  | 66261126333 | 7    | P280J   | 50           | 250          |     |
| 66261126334  | 66261126334 | 4    | P240J   | 50           | 250          |     |
| 66261126335  | 66261126335 | 1    | P220J   | 50           | 250          |     |
| 66261126336  | 66261126336 | 8    | P180J   | 50           | 250          |     |
| 66261126337  | 66261126337 | 5    | P150J   | 50           | 250          |     |
| 66261126338  | 66261126338 | 2    | P120J   | 50           | 250          |     |
| 66261126339  | 66261126339 | 9    | P100J   | 50           | 250          |     |
| 66261126340  | 66261126340 | 5    | P80J    | 25           | 125          |     |
| 66261101861  | 66261101861 | 6    | 60X     | 25           | 125          |     |
| 66261101862  | 66261101862 | 3    | 50X     | 25           | 125          |     |
| <b>9" x 10" Bulk – Non UPC</b>   |             |      |         |              |              |     |
| <b>Adalox A215 (Aluminum Oxide)</b>  |             |      |         |              |              |     |
| 66261101385  | 66261101385 | 7    | 100     | Medium       | 50           | 250 |
| 66261101390  | 66261101390 | 1    | 60      | Coarse       | 50           | 250 |



## ProSand

Our super-sharp abrasive and new coating method make these sponges resist clogging, cut faster and last longer than general sanding sponges and up to 5X longer than conventional sandpaper. The various sizes and grit combinations offer maximum versatility and flexibility for sanding curved, contoured or flat surfaces of wood, metal, paint, plastic, and drywall.

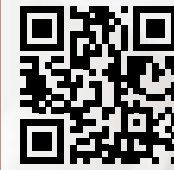

Scan the QR code to view our video



### Grit Guide

|  |
|--|
| <b>STRIPPING</b>   |
| Coarser grits remove heavy coatings or heavy stock                         |
| <b>SMOOTHING</b>   |
| Medium grits prepare surfaces for finishing                                |
| <b>FINISHING</b>   |
| Finer grits finish work prior to applying stain, sealer, varnish, or paint |

### Features & Benefits

- Durable, abrasive-coated foam lasts up to 5X longer than sandpaper with resistance to tearing
- High-performance, open-coat aluminum oxide grain cuts faster, lasts longer and resists clogging
- Flexible and conformable to shapes and contours making sanding of various surfaces and hard-to-reach areas easier
- Washable for extended life; rinse and reuse

| PART #   | UPC-A       | GRIT | GRADING      | QTY/ PACK | PACKS/ CASE |
|--|-------------|------|--------------|-----------|-------------|
| <b>ProSand 5X Small Area – 2PK</b>   |             |      |              |           |             |
| Ideal for small area paint and drywall repair. Firm sponge material and new ultra sharp grain offers faster cut and longer life.                     |             |      |              |           |             |
| <b>4-1/2" x 2-11/16" x 1"</b>  |             |      |              |           |             |
| 07660782063  | 07660782063 | 60   | Coarse       | 2         | 8**         |
| 07660782064  | 07660782064 | 8    | 120          | 2         | 8**         |
| 07660782065  | 07660782065 | 5    | 180          | 2         | 8**         |
| <b>ProSand 5X Small Area – 1PK</b>   |             |      |              |           |             |
| 07660782070  | 07660782070 | 9    | 36           | 1         | 16**        |
| 07660782071  | 07660782071 | 6    | 60           | 1         | 16**        |
| 07660782072  | 07660782072 | 3    | 120          | 1         | 16**        |
| 07660782073  | 07660782073 | 0    | 180          | 1         | 16**        |
| 07660782074  | 07660782074 | 7    | 220          | 1         | 16**        |
| 07660782088  | 07660782088 | 4    | Kit & Handle | 1         | 4**         |
| <b>ProSand 5X Small Area – Job Packs</b>   |             |      |              |           |             |
| 07660782086  | 07660782086 | 0    | 60           | 6         | 4**         |
| 07660782084  | 07660782084 | 6    | 120          | 6         | 4**         |
| 07660782085  | 07660782085 | 3    | 180          | 6         | 4**         |
| <b>ProSand 5X Single Angle</b>   |             |      |              |           |             |
| Excellent for sanding into tight areas and corners when doing paint and drywall repair.  |             |      |              |           |             |
| <b>4-1/2" x 3-1/2" x 1"</b>  |             |      |              |           |             |
| 07660782066  | 07660782066 | 2    | 80           | 1         | 16**        |
| 07660782067  | 07660782067 | 9    | 120          | 1         | 16**        |
| <b>ProSand 5X Multi Angle</b>  |             |      |              |           |             |
| Allows you to sand detailed surfaces such as crown molding and millwork that have unique profiles.   |             |      |              |           |             |
| <b>4-1/2" x 3-11/16" x 1"</b>  |             |      |              |           |             |
| 07660782068  | 07660782068 | 6    | 80           | 1         | 16**        |
| 07660782069  | 07660782069 | 3    | 120          | 1         | 16**        |
| <b>ProSand 5X Dual Angle</b>   |             |      |              |           |             |
| Dual angle sponge gives you the versatility to reach difficult areas easily. Perfect for drywall applications where inside corners meet the ceiling. |             |      |              |           |             |
| <b>4-1/2" x 2-7/8" x 1"</b>  |             |      |              |           |             |
| 07660782075  | 07660782075 | 4    | 80           | 1         | 16**        |
| 07660782076  | 07660782076 | 1    | 120          | 1         | 16**        |

| PART #  | UPC-A       | GRIT | GRADING     | QTY/ PACK  | PACKS/ CASE |
|---|-------------|------|-------------|------------|-------------|
| <b>ProSand 5X Contour Sanding Pads</b>  |             |      |             |            |             |
| Thin flexible pads allow you to sand areas that are rounded or contoured such as spindles, railings, casing and baseboards.   |             |      |             |            |             |
| <b>4-1/2" x 5-1/2" x 3/16"</b>  |             |      |             |            |             |
| 07660782079   | 07660782079 | 2    | 36          | Ex. Coarse | 2           |
| 07660782080   | 07660782080 | 8    | 60          | Coarse     | 2           |
| 07660782081   | 07660782081 | 5    | 120         | Medium     | 2           |
| 07660782082   | 07660782082 | 2    | 180         | Fine       | 2           |
| 07660782083   | 07660782083 | 9    | 220         | Very Fine  | 2           |
| 07660782221   | 07660782221 | 5    | 320         | Extra fine | 2           |
| <b>ProSand 5X Extra Large Single Angle</b>  |             |      |             |            |             |
| Designed for sanding larger areas specifically drywall joints. The easy to grip sponge delivers faster sanding and smoother finish over large areas.                        |             |      |             |            |             |
| <b>9" x 3-5/16" x 1"</b>  |             |      |             |            |             |
| 07660782077   | 07660782077 | 8    | 120         | Medium     | 1           |
| <b>ProSand 5X Sanding Sticks</b>  |             |      |             |            |             |
| Unique design, this sponge allows you to sand areas where other products cannot. Ideal for sanding between stair spindles or other areas that are tight and close together. |             |      |             |            |             |
| <b>9" x 1" x 1"</b>   |             |      |             |            |             |
| 07660768140   | 07660768140 | 5    | 36/60/100   | Asst.      | 1           |
| 07660768139   | 07660768139 | 3    | 120/180/220 | Asst.      | 1           |
| <b>ProSand 5X Corner Sanding Sponge</b>   |             |      |             |            |             |
| <b>4-1/2" x 2-3/4" x 2-3/4"</b>   |             |      |             |            |             |
| 07660768141   | 07660768141 | 6    | 120         | Medium     | 1           |
| <b>ProSand 5X Extra Large Drywall Sponge – Handy Packs</b>  |             |      |             |            |             |
| <b>3-5/16" x 9" x 1" Coated 4 Sides</b>   |             |      |             |            |             |
| 07660768276   | 07660768276 | 5    | 120         | Medium     | 1           |
| <b>ProSand 5X Extra Large Drywall Sponge – Job Pack</b>   |             |      |             |            |             |
| <b>3-5/16" x 9" x 1" Coated 4 Sides</b>   |             |      |             |            |             |
| 07660768277   | 07660768277 | 2    | 120         | Medium     | 3           |

“ The corner sponge rides with the irregularities and leaves no marks, while also making a great looking sharp inside corner.

- Jack Faville





### MultiSand

Offered in various styles and grits for general purpose sanding on a variety of materials.

| PART #  | UPC-A       | GRIT | GRADING | QTY/<br>PACK        | PACKS/<br>CASE |
|---|-------------|------|---------|---------------------|----------------|
| <b>MultiSand Small Area</b>   |             |      |         |                     |                |
| Small, flexible sponge for general purpose sanding of a variety of materials. Coated 4 sides. |             |      |         |                     |                |
| <b>4" x 2-3/4" x 1"</b>   |             |      |         |                     |                |
| 07660702081   | 07660702081 | 9    | F/M     | F/M Bonus Pack 6    | 6              |
| 07660702670   | 07660702081 | 9    | F/M     | F/M                 | 1              |
| 07660721775   | 07660721741 | 7    | F/VF    | F/VF                | 1              |
| 07660749502   | 07660749502 | 0    | F/M     | F/M                 | 1              |
| 07660749503   | 07660749503 | 7    | M/C     | M/C                 | 1              |
| <b>Bulk</b>   |             |      |         | <b>Sponges/Case</b> |                |
| 07660749504   | 07660749504 | 4    | F/M     | F/M Bar Coded       | -              |
| 07660749505   | 07660749505 | 1    | M/C     | M/C Bar Coded       | -              |
| 07660749506   | 07660749506 | 8    | F/F     | F/F Bar Coded       | -              |
| 07660749507   | 07660749507 | 5    | M/M     | M/M Bar Coded       | -              |
| 07660704735   | 07660704735 | 9    | M/C     | M/C                 | -              |
| 07660701875   | 07660701875 | 2    | M/M     | M/M                 | -              |
| 07660702600   | 07660702600 | 2    | F/M     | F/M                 | -              |

OS\* = Off Shelf Pre-Loaded Display and contains 75 each of 02081

| PART #   | UPC-A       | GRIT | GRADING  | QTY/<br>PACK        | PACKS/<br>CASE |
|--|-------------|------|----------|---------------------|----------------|
| <b>MultiSand Dual Angle</b>  |             |      |          |                     |                |
| Firm sponge with angled sides for sanding inside corners and crevices of hard to reach areas on a variety of materials. Coated 4 sides.        |             |      |          |                     |                |
| <b>4-7/8" x 2-7/8" x 1"</b>  |             |      |          |                     |                |
| 07660702082  | 07660702082 | 6    | F/M      | F/M Bonus Pack 6    | 6              |
| 07660700935  | 07660700935 | 7    | F/M      | F/M                 | 1              |
| 07660700936  | 07660700936 | 4    | M/C      | M/C                 | 1              |
| <b>MultiSand Contour Sanding Pads</b>  |             |      |          |                     |                |
| Thin, flexible, single-sided sponge for sanding small diameters and contours such as ceramics, spindles, turnings and railings. Coated 1 side. |             |      |          |                     |                |
| <b>4-1/2" x 5-1/2" x 3/16"</b>   |             |      |          |                     |                |
| 07660700937  | 07660700937 | 1    | Ex. Fine | Ex. Fine            | 2              |
| 07660700938  | 07660700938 | 8    | Fine     | Fine                | 2              |
| 07660700939  | 07660700939 | 5    | Medium   | Medium              | 2              |
| <b>Bulk</b>  |             |      |          | <b>Sponges/Case</b> |                |
| 07660702255  | 07660702255 | 4    | Ex. Fine | Ex. Fine            | 100            |
| 07660702256  | 07660702256 | 1    | Fine     | Fine                | 100            |
| 07660702257  | 07660702257 | 8    | Medium   | Medium              | 100            |



### SandWet Sponges


Premium Norton SandWet Waterproof Sponges deliver two-sided sanding that combines the performance of our premium Norton SandWet abrasive sheets with the convenience of a sanding sponge. Ideal for dust control, our sponges offer maximum versatility and flexibility for wet sanding of curved and flat surfaces of wood, metal, fiberglass and painted surfaces.


| PART #                      | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|-----------------------------|-------------|------|---------|--------------|----------------|
| <b>4-3/4" x 2-7/8" x 1"</b> |             |      |         |              |                |
| 07660768288                 | 07660768288 | 8    | 2000    | Ultra Fine   | 1              |
| 07660768289                 | 07660768289 | 5    | 1500    | Very Fine    | 1              |
| 07660768290                 | 07660768290 | 1    | 1000    | Fine         | 1              |





### Specialty


Specialty sponges are a cost-effective solution for sanding hard to reach surfaces on a variety of materials.

| PART #  | UPC-A                       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------------|------|---------|--------------|----------------|
|    | <b>Molding and Millwork</b> |      |         |              |                |
| Angled, flexible sanding abrasive for those hard to reach surfaces. Coated 4 sides. |                             |      |         |              |                |
| <b>4-7/8" x 3-1/2" x 1"</b>   |                             |      |         |              |                |
| 07660702286   | 076607 <b>02286</b>         | 8    | Medium  | 1            | 12**           |

| PART #  | UPC-A               | GRIT | GRADING    | QTY/<br>PACK | PACKS/<br>CASE |
|---|---------------------|------|------------|--------------|----------------|
|   | <b>SoftTouch</b>    |      |            |              |                |
| Coated on one side, these thin flexible sanding sponges are coated on closed cell foam to generate extremely consistent and uniformly fine scratch patterns necessary for applications such as sealer sanding and sanding between coats of primer or top coats. |                     |      |            |              |                |
| <b>4-1/2" x 5-1/2" x 3/16"</b>  |                     |      |            |              |                |
| 07660703078   | 076607 <b>03078</b> | 8    | Micro Fine | 20           | 80**           |
| 07660703077   | 076607 <b>03077</b> | 1    | Ultra Fine | 20           | 80**           |
| 07660703076   | 076607 <b>03076</b> | 4    | Super Fine | 20           | 80**           |
| 07660703075   | 076607 <b>03075</b> | 7    | Fine       | 20           | 80**           |
| 07660703074   | 076607 <b>03074</b> | 0    | Medium     | 20           | 80**           |

| PART #  | UPC-A                 | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|------|---------|--------------|----------------|
|            | <b>Profile - Bulk</b> |      |         |              |                |
| Small, firm-edge sponge for general-purpose sanding of profiles and radiuses. Coated 3 sides. |                       |      |         |              |                |
| <b>4" x 2-3/4" x 1/2"</b>   |                       |      |         |              |                |
| 63642536313   | 636425 <b>36313</b>   | 2    | Medium  | Medium       | 500            |

| PART #  | UPC-A                                 | GRIT | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|---------------------------------------|------|--------------|--------------|----------------|
|    | <b>Economy - Sander Sealer - Bulk</b> |      |              |              |                |
| Very flexible sponge coated with premium, silicon carbide abrasive for sanding primers, sealers, and between coats. Coated 2 sides. |                                       |      |              |              |                |
| <b>4-3/4" x 3-3/4" x 1/2"</b>   |                                       |      |              |              |                |
| <b>Sponges/Case</b>   |                                       |      |              |              |                |
| 63642552868   | 636425 <b>52868</b>                   | 5    | Very Fine    | Very Fine    | 250            |
| 63642552869   | 636425 <b>52869</b>                   | 2    | Medium       | Medium       | 250            |
| 63642552870   | 636425 <b>52870</b>                   | 8    | Coarse       | Coarse       | 250            |
| 63642502538   | 636425 <b>02538</b>                   | 2    | Extra Coarse | Extra Coarse | 250            |

| PART #   | UPC-A                                   | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|--|---|------|---------|--------------|----------------|
|  | <b>Economy - Flexible - Handy Packs</b> |      |         |              |                |
| Economical, fabric-backed foam for sanding a variety of materials. Coated 1 side.  |   |      |         |              |                |
| <b>3" x 4" x 1/2"</b>  |   |      |         |              |                |
| 07660700946  | 076607 <b>00946</b>                     | 3    | 150     | Fine         | 3              |
| 07660704030  | 076607 <b>00946</b>                     | 3    | 150     | Fine         | 3              |
| 07660700947  | 076607 <b>00947</b>                     | 0    | 100     | Medium       | 3              |
| 07660704031  | 076607 <b>00947</b>                     | 0    | 100     | Medium       | 3              |
| 07660700948  | 076607 <b>00948</b>                     | 7    | 60      | Coarse       | 3              |
| 07660704032  | 076607 <b>00948</b>                     | 7    | 60      | Coarse       | 3              |
| 07660701885  | 076607 <b>01885</b>                     | 4    | Asst.   | 1F, 1M, 1C   | 3              |
| <b>Economy - Flexible - Bulk</b>   |   |      |         |              |                |
| <b>3" x 4" x 1/2"</b>  |   |      |         |              |                |
| <b>Sponges/Case</b>  |   |      |         |              |                |
| 07660704069  | 076607 <b>04069</b>                     | 5    | 220     | Very Fine    | 108            |
| 07660700949  | 076607 <b>00949</b>                     | 4    | 150     | Fine         | 108            |
| 07660700950  | 076607 <b>00950</b>                     | 0    | 100     | Medium       | 108            |
| 07660704070  | 076607 <b>04070</b>                     | 1    | 80      | Coarse       | 108            |
| 07660701110  | 076607 <b>01110</b>                     | 7    | 60      | Coarse       | 108            |
| 07660704065  | 076607 <b>04065</b>                     | 7    | 150     | Fine         | 48             |
| 07660704066  | 076607 <b>04066</b>                     | 4    | 100     | Medium       | 48             |
| 07660704067  | 076607 <b>04067</b>                     | 1    | 80      | Coarse       | 48             |
| 07660704068  | 076607 <b>04068</b>                     | 8    | 60      | Coarse       | 48             |



## Abrasive Rolls

Available in three different backings. Choose the one that's best for your application,

- **Screen** – For sanding where life and load resistance are most important. Coated on both sides with silicon carbide abrasive, the open mesh design also allows you to rinse and reuse.
- **Paper** – For fast, easy sanding when long life and consistent finish are most important. High strength latex backing offers superior strength and reduced edge wear. PSA backing for easy on/off.
- **Cloth** – For general-purpose sanding where flexibility and tear resistance are most important. Cloth backing provides increased strength and durability.



### Screen

- sanding plastic pipe prior to gluing
- preparing copper pipe and fittings prior to soldering
- sanding softer materials where loading is a major problem such as plaster, wood, drywall, brass, etc.

| PART #                                   | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|------|---------|--------------|----------------|
| <b>Plumbers Waterproof Screen – Bulk</b> |             |      |         |              |                |
| <b>1-1/2" x 25 yds. (Durite Q421)</b>    |             |      |         |              |                |
| 66261107265                              | 66261107265 | 6    | 180     | 10           | 10             |
| 66261107270                              | 66261107270 | 0    | 120     | 10           | 10             |
| 66261107275                              | 66261107275 | 5    | 80      | 10           | 10             |

### Paper

- preparing primed and painted surfaces
- bare wood sanding

| PART #  | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|---------|--------------|----------------|
| <b>Aluminum Oxide PSA Paper Rolls – Bulk</b>                        |             |      |         |              |                |
| <b>4-1/2" x 10 yds. (30 ft.) Stick &amp; Sand Sheet Roll (A275)</b> |             |      |         |              |                |
| 66261131692   | 66261131692 | 7    | P220B   | 1            | 5              |
| 66261131693   | 66261131693 | 4    | P180B   | 1            | 5              |
| 66261131694   | 66261131694 | 1    | P150B   | 1            | 5              |
| 66261131695   | 66261131695 | 8    | P120B   | 1            | 5              |
| 66261131696   | 66261131696 | 5    | P100B   | 1            | 5              |
| 66261131697   | 66261131697 | 2    | P80B    | 1            | 5              |

### Cloth

- hand strapping and light deburring
- blending machine tool marks
- cleaning pipe and tubing

| PART #  | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|---------|--------------|----------------|
| <b>Cloth Handy Rolls – Handy Packs</b>                  |             |      |         |              |                |
| <b>1" x 10 ft. (K225)</b>                               |             |      |         |              |                |
| 07660748143   | 07660748143 | 6    | 320J    | Extra Fine   | 1 20**         |
| 07660748144   | 07660748144 | 3    | 180J    | Fine         | 1 20**         |
| 07660748145   | 07660748145 | 0    | 80J     | Medium       | 1 20**         |
| <b>Resin Cloth Rolls For Drum Sanders – Handy Packs</b> |             |      |         |              |                |
| <b>3" x 35 ft. (R228)</b>                               |             |      |         |              |                |
| 07660706048   | 07660706048 | 8    | 150X    | Fine         | 1 4            |
| 07660705291   | 07660705291 | 9    | 120X    | Fine         | 1 4            |
| 07660706049   | 07660706049 | 5    | 100X    | Medium       | 1 4            |

### Cloth continued

| PART #  | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|---------|--------------|----------------|
| <b>Aluminum Oxide Cloth Rolls – Bulk</b>      |             |      |         |              |                |
| <b>1" x 50 yds. (Metalite K225, K224)</b>     |             |      |         |              |                |
| 66261126266                                   | 66261126266 | 8    | P600J   | 1            | 5              |
| 66261126267                                   | 66261126267 | 5    | P400J   | 1            | 5              |
| 66261126268                                   | 66261126268 | 2    | P320J   | 1            | 5              |
| 66261126269                                   | 66261126269 | 9    | P280J   | 1            | 5              |
| 66261126270                                   | 66261126270 | 5    | P240J   | 1            | 5              |
| 66261126271                                   | 66261126271 | 2    | P220J   | 1            | 5              |
| 66261126272                                   | 66261126272 | 9    | P180J   | 1            | 5              |
| 66261126273                                   | 66261126273 | 6    | P150J   | 1            | 5              |
| 66261126274                                   | 66261126274 | 3    | P120J   | 1            | 5              |
| 66261126275                                   | 66261126275 | 0    | P100J   | 1            | 5              |
| 66261126276                                   | 66261126276 | 7    | P80J    | 1            | 5              |
| 66261127729                                   | 66261127729 | 7    | P60X    | 1            | 5              |
| 66261127728                                   | 66261127728 | 0    | P50X    | 1            | 5              |
| <b>1-1/2" x 50 yds. (Metalite K225, K224)</b> |             |      |         |              |                |
| 66261126278                                   | 66261126278 | 1    | P600J   | 1            | 5              |
| 66261126279                                   | 66261126279 | 8    | P400J   | 1            | 5              |
| 66261126280                                   | 66261126280 | 4    | P320J   | 1            | 5              |
| 66261126281                                   | 66261126281 | 1    | P280J   | 1            | 5              |
| 66261126282                                   | 66261126282 | 8    | P240J   | 1            | 5              |
| 66261126283                                   | 66261126283 | 5    | P220J   | 1            | 5              |
| 66261126284                                   | 66261126284 | 2    | P180J   | 1            | 5              |
| 66261126285                                   | 66261126285 | 9    | P150J   | 1            | 5              |
| 66261126286                                   | 66261126286 | 6    | P120J   | 1            | 5              |
| 66261126287                                   | 66261126287 | 3    | P100J   | 1            | 5              |
| 66261126288                                   | 66261126288 | 0    | P80J    | 1            | 5              |
| 66261127731                                   | 66261127731 | 0    | P60X    | 1            | 5              |
| 66261127730                                   | 66261127730 | 3    | P50X    | 1            | 5              |
| <b>2" x 50 yds. (Metalite K225, K224)</b>     |             |      |         |              |                |
| 66261126289                                   | 66261126289 | 7    | P600J   | 1            | 5              |
| 66261126290                                   | 66261126290 | 3    | P400J   | 1            | 5              |
| 66261126291                                   | 66261126291 | 0    | P320J   | 1            | 5              |
| 66261126292                                   | 66261126292 | 7    | P280J   | 1            | 5              |
| 66261126293                                   | 66261126293 | 4    | P240J   | 1            | 5              |
| 66261126294                                   | 66261126294 | 1    | P220J   | 1            | 5              |
| 66261126295                                   | 66261126295 | 8    | P180J   | 1            | 5              |
| 66261126296                                   | 66261126296 | 5    | P150J   | 1            | 5              |
| 66261126297                                   | 66261126297 | 2    | P120J   | 1            | 5              |
| 66261126298                                   | 66261126298 | 9    | P100J   | 1            | 5              |
| 66261126299                                   | 66261126299 | 6    | P80J    | 1            | 5              |
| 66261127733                                   | 66261127733 | 4    | P60X    | 1            | 5              |
| 66261127732                                   | 66261127732 | 7    | P50X    | 1            | 5              |

MultiSand Stick & Sand Sheet Rolls also available - See page 8





## WallSand Sheets – Paper and Screen

For sanding drywall compound and patching plaster prior to priming. Waterproof screen resists clogging because of its open mesh design. Just rinse and reuse. Paper sheets are the standard economical choice.



### Grit Guide

| 80 COARSE                       | 100 MEDIUM                       | 120 MEDIUM                   | 150 MEDIUM    | 180 FINE      | 220 VERY FINE | 320 EXTRA FINE | 400 SUPER FINE |
|---------------------------------|----------------------------------|------------------------------|---------------|---------------|---------------|----------------|----------------|
| Moderate Removal;<br>First Coat | Moderate Removal;<br>Second Coat | Light Removal;<br>Final Coat | Light Removal | Final Sanding | Final Sanding | Final Sanding  | Final Sanding  |

### Paper

| PART #                                    | UPC-A         | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|---------------|------|---------|--------------|----------------|
| <b>WallSand – Handy Packs</b>             |               |      |         |              |                |
| <b>4-3/16" x 11-1/4" Die-Cut (A221)</b>   |               |      |         |              |                |
| 07660702299                               | 07660703251 5 | 120D | Medium  | 5            | 10             |
| 07660702533                               | 07660703251 5 | 120D | Medium  | 5            | 20**           |
| 07660701888                               | 07660703252 2 | 100D | Medium  | 5            | 10             |
| 07660702534                               | 07660703252 2 | 100D | Medium  | 5            | 20**           |
| 07660701887                               | 07660703253 9 | 80D  | Coarse  | 5            | 10             |
| 07660702535                               | 07660703253 9 | 80D  | Coarse  | 5            | 20**           |
| <b>3-5/16" x 11" Die-Cut (A475)</b>       |               |      |         |              |                |
| 07660768243                               | 07660768243 7 | 150  | Fine    | 5            | 10**           |
| 07660768242                               | 07660768242 0 | 120  | Medium  | 5            | 10**           |
| <b>8" x 7" Hook &amp; Loop (A296)</b>     |               |      |         |              |                |
| 07660768102                               | 07660768102 7 | 150  | Fine    | 3            | 10             |
| 07660768103                               | 07660768103 4 | 100  | Medium  | 3            | 10             |
| <b>3-2/3" x 9" Hook &amp; Loop (A296)</b> |               |      |         |              |                |
| 07660768100                               | 07660768100 3 | 150  | Fine    | 3            | 10             |
| 07660768101                               | 07660768101 0 | 100  | Medium  | 3            | 10             |
| <b>WallSand – Job Packs</b>               |               |      |         |              |                |
| <b>4-3/16" x 11-1/4" Die-Cut (A221)</b>   |               |      |         |              |                |
| 07660701209                               | 07660701209 8 | 150D | Fine    | 25           | 10**           |
| 07660701208                               | 07660701208 1 | 120D | Medium  | 25           | 10**           |
| 07660704746                               | 07660704746 5 | 100D | Medium  | 25           | 10**           |
| 07660704747                               | 07660704747 2 | 80D  | Coarse  | 25           | 10**           |
| <b>4-3/16" x 11-1/4" Die-Cut (A475)</b>   |               |      |         |              |                |
| 07660701864                               | 07660701864 9 | 120  | Medium  | 25           | 10             |
| 07660701863                               | 07660701863 2 | 100  | Medium  | 25           | 10             |
| <b>3-5/16" x 11" Die-Cut (A475)</b>       |               |      |         |              |                |
| 07660701862                               | 07660701862 5 | 150  | Fine    | 25           | 10             |
| 07660701861                               | 07660701861 8 | 120  | Medium  | 25           | 10             |
| 07660701860                               | 07660701860 1 | 100  | Medium  | 25           | 10             |

| PART #  | UPC-A         | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|---|---------------|------|---------|--------------|----------------|
| <b>WallSand – Bulk</b>                                  |               |      |         |              |                |
| <b>3-5/16" x 11" Die-Cut (UPC Bar Coded) (A221)</b>     |               |      |         |              |                |
| 07660701302   | 07660701302 6 | 150D | Medium  | 50           | 5              |
| 07660701303   | 07660701303 3 | 120D | Medium  | 50           | 5              |
| 07660701304   | 07660701304 0 | 100D | Medium  | 50           | 5              |
| 07660701305   | 07660701305 7 | 80D  | Coarse  | 50           | 5              |
| <b>4-3/16" x 11-1/4" Die-Cut (Non UPC) (A221)</b>       |               |      |         |              |                |
| 66261104716   | 66261104716 6 | 150D | Medium  | 50           | 10             |
| 66261104717   | 66261104717 3 | 120D | Medium  | 50           | 10             |
| 66261104718   | 66261104718 0 | 100D | Medium  | 50           | 10             |
| 66261104719   | 66261104719 7 | 80D  | Coarse  | 50           | 10             |
| <b>3-5/16" x 12" (Non UPC) (A221)</b>                   |               |      |         |              |                |
| 66261104714   | 66261104714 2 | 100D | Medium  | 50           | 10             |
| <b>4-3/16" x 11-1/4" Die-Cut (UPC Bar Coded) (A475)</b> |               |      |         |              |                |
| 07660701919   | 07660701919 6 | 150  | Medium  | 100          | -              |
| 07660701920   | 07660701920 2 | 120  | Medium  | 100          | -              |
| 07660701921   | 07660701921 9 | 100  | Medium  | 100          | -              |
| <b>4-3/16" x 11-1/4" Die-Cut (Non UPC) (A221)</b>       |               |      |         |              |                |
| 07660768286   | 07660768286 4 | 150  | Medium  | 100          |                |
| 07660768285   | 07660768285 7 | 120  | Medium  | 100          |                |
| 07660768284   | 07660768284 0 | 100  | Medium  | 100          |                |
| 07660768283   | 07660768283 3 | 80   | Coarse  | 100          |                |

## WallSand Sheets – Paper and Screen

### Screen

| PART #                          | UPC-A       | GRIT  | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|---------------------------------|-------------|-------|-----------|--------------|----------------|
| <b>WallSand – Handy Packs</b>   |             |       |           |              |                |
| <b>4-3/16" x 11-1/4" (Q421)</b> |             |       |           |              |                |
| 07660721766                     | 07660704173 | 9 220 | Very Fine | 2            | 20**           |
| 07660768320                     | 07660704171 | 5 150 | Medium    | 2            | 20**           |
| 07660721767                     | 07660704169 | 2 120 | Medium    | 2            | 20**           |
| <b>WallSand – Job Packs</b>     |             |       |           |              |                |
| <b>4-3/16" x 11-1/4" (Q421)</b> |             |       |           |              |                |
| 07660721763                     | 07660702049 | 9 220 | Very Fine | 10           | 10**           |
| 07660768321                     | 07660768321 | 2 180 | Fine      | 10           | 10**           |
| 07660721764                     | 07660704748 | 9 150 | Fine      | 10           | 10**           |
| 07660721765                     | 07660704749 | 6 120 | Medium    | 10           | 10**           |
| 07660768318                     | 07660768318 | 2 100 | Medium    | 10           | 10**           |
| 07660768319                     | 07660768319 | 9 80  | Coarse    | 10           | 10**           |

| PART #  | UPC-A       | GRIT  | GRADING    | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|-------|------------|--------------|----------------|
| <b>WallSand – Bulk</b>                              |             |       |            |              |                |
| <b>3-5/16" x 11" Die-Cut (UPC Bar Coded) (Q421)</b> |             |       |            |              |                |
| 07660701312   | 07660701312 | 5 220 | Very Fine  | 25           | -              |
| 07660701311   | 07660701311 | 8 180 | Fine       | 25           | -              |
| 07660701222   | 07660701222 | 7 150 | Fine       | 25           | -              |
| 07660701300   | 07660701300 | 2 120 | Medium     | 25           | -              |
| 07660701301   | 07660701301 | 9 100 | Medium     | 25           | -              |
| <b>9" x 11" (Non UPC) (Q421)</b>                    |             |       |            |              |                |
| 66261100915   | 66261100915 | 7 400 | Super Fine | 25           | -              |
| 66261100920   | 66261100920 | 1 320 | Extra Fine | 25           | -              |
| 66261100935   | 66261100935 | 5 220 | Very Fine  | 25           | -              |
| 66261100940   | 66261100940 | 9 180 | Fine       | 25           | -              |
| 66261100945   | 66261100945 | 4 150 | Fine       | 25           | -              |
| 66261100950   | 66261100950 | 8 120 | Medium     | 25           | -              |
| 66261100955   | 66261100955 | 3 100 | Medium     | 25           | -              |
| 66261100960   | 66261100960 | 7 80  | Coarse     | 25           | -              |





## WallSand Sponges

Offered in various styles and grits for sanding of paint and drywall.

| PART #   | UPC-A                          | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|--|--------------------------------|------|---------|--------------|----------------|
|  | <b>WallSand – Small Area</b>   |      |         |              |                |
| Small area sanding abrasive for professional paint and drywall surface preparation. Coated 4 sides.                          |                                |      |         |              |                |
| <b>4" x 2-3/4" x 1" (Bulk)</b>   |                                |      |         |              |                |
| 07660702263  | 07660702263                    | 9    | F/M     | F/M          | - 24           |
|  | <b>WallSand – Single Angle</b> |      |         |              |                |
| Single angle flexible sanding abrasive is designed for easy gripping to sand hard to reach areas of drywall. Coated 4 sides. |                                |      |         |              |                |
| <b>4-7/8" x 2-7/8" x 1"</b>  |                                |      |         |              |                |
| 07660702284  | 07660702284                    | 4    | Fine    | Fine         | 1 24**         |
| 07660702285  | 07660702285                    | 1    | Medium  | Medium       | 1 24**         |
|  | <b>WallSand – Dual Angle</b>   |      |         |              |                |
| Extra firm sponge with angled sides for sanding inside corners of drywall compound. Coated 4 sides.                          |                                |      |         |              |                |
| <b>4-7/8" x 2-7/8" x 1"</b>  |                                |      |         |              |                |
| 07660700941  | 07660700941                    | 8    | F/M     | F/M          | 1 24**         |

| PART #   | UPC-A                                   | GRIT | GRADING                                      | QTY/<br>PACK | PACKS/<br>CASE |
|--|---|------|--|--------------|----------------|
|  | <b>WallSand – Corner Sanding Sponge</b> |      |  |              |                |
| Extra firm sponge with wider faces for dual sanding capabilities. Create near perfect corners of an inside drywall corner. Coated 2 sides. |   |      |  |              |                |
| <b>3-3/4" x 7" x 4-1/2"</b>  |   |      |  |              |                |
| 07660701715  | 07660701715                             | 4    | Medium                                       | Medium       | 1 8**          |
|  | <b>WallSand – Extra Large Area</b>      |      |  |              |                |
| Oversized extra firm sponge for easier sanding of the entire drywall joint surface. Large size is easy to hold. Coated 4 sides.            |   |      |  |              |                |
| <b>3-5/16" x 9" x 1"</b>   |   |      |  |              |                |
| 07660700944  | 07660700944                             | 9    | F/M  | F/M          | 1 24**         |
| 07660701845  | 07660700944                             | 9    | F/M  | F/M          | 1 5**          |
| 07660702487  | 07660702487                             | 9    | Hand Sander w/Clips,<br>1 Ex. Lg. Sponge Kit |              | 1 5**          |



## Discs and Rolls

### Mesh Application

MeshPower features a full ceramic abrasive grain which offers a superior cut rate over traditional aluminum oxide. Norton No-Fill technology works to prevent clogging for a better finish and longer life, saving operators time and money. It also allows the grain to wear evenly resulting in finer scratch pattern, and faster, more consistent results throughout the product life. Open mesh construction of the backing allows dust particles to flow freely through thousands of tiny holes, creating a virtually dust-free sanding environment.

### Paper Disc Application

Aluminum Oxide abrasive for ultra smooth finish of drywall compound. Anti-clog coating on disc decreases loading and promotes optimal dust collection. The rugged hook and loop fastening system assures quick and easy disc change.

### Paper Roll Application

Paper rolls offer an economical choice over precut sheets and screens. Generally preferred for larger jobs. Cut to desired length.

### Mesh Discs

| PART #                               | UPC-A                 | GRIT | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|--------------------------------------|-----------------------|------|-----------|--------------|----------------|
| <b>MeshPower – Bulk UPC Barcoded</b> |                       |      |           |              |                |
| <b>9" Ceramic</b>                    |                       |      |           |              |                |
| 07660768452                          | 076607 <b>68452</b> 3 | 220  | Very Fine | 15           | 15             |
| 07660768453                          | 076607 <b>68453</b> 0 | 180  | Fine      | 15           | 15             |
| 07660768454                          | 076607 <b>68454</b> 7 | 150  | Medium    | 15           | 15             |
| 07660768455                          | 076607 <b>68455</b> 4 | 120  | Medium    | 15           | 15             |
| 07660768456                          | 076607 <b>68456</b> 1 | 100  | Medium    | 15           | 15             |
| 07660768457                          | 076607 <b>68457</b> 8 | 80   | Coarse    | 15           | 15             |

For more information about MeshPower discs, please refer to page 25

### Paper Rolls


| PART #  | UPC-A                 | GRIT | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|------|--------------|----------------|
| <b>WallSand – Bulk – Non UPC</b>                      |                       |      |              |                |
| <b>3-1/2" x 50 yds. Rolls (A221, G215, A213)</b>      |                       |      |              |                |
| 66261134425   | 662611 <b>34425</b> 8 | 150  | 1            | 5              |
| 07660701654   | 076607 <b>01654</b> 6 | 120  | 1            | 5              |
| 07660701655   | 076607 <b>01655</b> 3 | 100  | 1            | 5              |
| 07660701656   | 076607 <b>01656</b> 0 | 80   | 1            | 5              |
| <b>Foam Roll – Bulk – Non UPC</b>                     |                       |      |              |                |
| <b>3-5/16" x 12 yds. Perforated Foam Drywall Roll</b> |                       |      |              |                |
| 07660768300   | 076607 <b>68300</b> 7 | 180  | 1            | 5              |

### Paper Discs

| PART #   | UPC-A                 | GRIT        | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|-------------|-----------|--------------|----------------|
| <b>WallSand – Handy Pack</b>                             |                       |             |           |              |                |
| <b>9" Hook and Loop Discs (A296)</b>                     |                       |             |           |              |                |
| 07660768421  | 076607 <b>68421</b> 9 | P220        | Very Fine | 3            | 5**            |
| 07660768420  | 076607 <b>68420</b> 2 | P180        | Very Fine | 3            | 5**            |
| 07660768237  | 076607 <b>68237</b> 6 | P150        | Fine      | 3            | 5**            |
| 07660768419  | 076607 <b>68419</b> 6 | P120        | Fine      | 3            | 5**            |
| 07660768238  | 076607 <b>68238</b> 3 | P100        | Medium    | 3            | 5**            |
| 07660768418  | 076607 <b>68418</b> 9 | P80         | Coarse    | 3            | 5**            |
| <b>WallSand – Bulk – UPC Coded</b>                       |                       |             |           |              |                |
| <b>9" Hook and Loop Discs (Porter Cable 7800) (A296)</b> |                       |             |           |              |                |
| 66261156659  | 662611 <b>56659</b> 9 | P220        | Very Fine | 15           | 15             |
| 66261158171  | 662611 <b>58171</b> 4 | P180        | Very Fine | 15           | 15             |
| 07660702463  | 076607 <b>02463</b> 3 | P150        | Fine      | 15           | 15             |
| 07660702464  | 076607 <b>02464</b> 0 | P120        | Fine      | 15           | 15             |
| 07660702465  | 076607 <b>02465</b> 7 | P100        | Medium    | 15           | 15             |
| 07660702466  | 076607 <b>02466</b> 4 | P80         | Coarse    | 15           | 15             |
| <b>Accessory</b>   |                       |             |           |              |                |
| <b>Back-up Pad</b>                                       |                       |             |           |              |                |
| 07660703292  | 076607 <b>03292</b> 8 | Back-up Pad |           | 1            | 10**           |

## WallSand Accessories

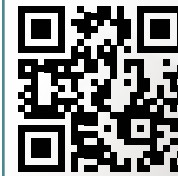


Norton WallSand Drywall Tools help deliver flawless results when sanding drywall. The lightweight, durable designs reduce fatigue and extend the life of the tool. The easy change handle allows you to convert from a hand sander to a pole sander for extra versatility. These premium products are guaranteed to help you achieve a fast and superior finish every time.



Scan the QR code to view our video



|   | PART #      | UPC-A         | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|---------------|--------------|----------------|
|    | 07660702411 | 07660702411 4 | 1            | 6**            |
| Easy snug clips tighten for secure fit. Firm handle provides solid grip. For use with die-cut drywall and plaster sanding sheets or screens on pages 15-16.   |             |               |              |                |
| <b>Hand Sander</b>  |             |               |              |                |
|   | 07660702412 | 07660702412 1 | 1            | 8**            |
| Use with threaded handle for sanding high walls and ceilings. For use with die cut drywall and plaster sanding sheets and screens on pages 15-16.   |             |               |              |                |
| <b>Pole Sander</b>  |             |               |              |                |
|    | 07660768104 | 07660768104 1 | 1            | 6**            |
| Ideal for sanding larger surface areas. The light-weight, circular design virtually eliminates flipping and allows change of direction up/down and left/right without lifting off the wall. Works with a 9" hook and loop sanding disc. |             |               |              |                |
| <b>9" 360 Disc Sander</b>   |             |               |              |                |
|    | 07660768241 | 07660768241 3 | 1            | 6**            |
| 9" 360 Disc Sander conveniently comes with a pole adaptor making this product ideal for sanding larger surface areas and increases the versatility to reach taller walls and ceilings. Works with 9" a hook and loop sanding disc.      |             |               |              |                |
| <b>9" 360 Disc Sander with Pole Adaptor</b>   |             |               |              |                |

|  | PART #      | UPC-A         | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|---------------|--------------|----------------|
|   | 07660768105 | 07660768105 8 | 1            | 6**            |
| Simultaneously sands both inside seams of a drywall corner. The light-weight, 90° design provides a smooth edge with less risk of wall damage commonly caused by sanding each side separately. Works with 8" x 7" hook and loop sanding sheet. |             |               |              |                |
| <b>Inside Corner Sander</b>  |             |               |              |                |
|    | 07660768106 | 07660768106 5 | 1            | 6**            |
| Ideal for sanding hard to reach areas. The light-weight, 1/3 sheet hook and loop design eliminates fumbling with wing nuts and clamps. Works with 3-2/3" x 9" hook and loop sanding sheet.   |             |               |              |                |
| <b>1/3 Sheet Sander</b>  |             |               |              |                |
|   | 07660768107 | 07660768107 2 | 1            | 6**            |
| Easily converts Norton hand sanders to pole sanders for extra flexibility in stairwells, on ceilings and hard-to-reach areas.  |             |               |              |                |
| <b>Pole Handle Adaptor</b>   |             |               |              |                |



I am in the remodeling business, and I end up doing a lot of drywall finishing and wall repair. I really like the 9" round disc sander for big open areas and valley and butt joints on drywall.

- Jack Faville





What material are you power sanding?

**GENERAL**  
WOOD, PAINT, PLASTIC,  
FIBERGLASS, ETC.

What power tool are you using?

|   |  |
|---|--|
| <b>Belt Sander:</b><br>Portable Belts, Benchstand Belts                   | <b>Random Orbital Sander:</b><br>Hook & Sand Discs, Stick & Sand Discs |
| <b>Right Angle Grinder:</b><br>Rapid Strip Discs, Flap Discs, Fiber Discs | <b>Palm Sander:</b><br>Hook & Sand Sheets, Stick & Sand Sheets         |
|   | <b>Detail Sander:</b><br>Model Specific Sheets                         |
|   | <b>Drill:</b><br>DrillSand Discs, Rapid Strip Wheels, Spirabands       |

How large is your project?

|  |                                    |
|--|------------------------------------|
| <b>Small DIY/Weekend Job:</b><br>Handy Packs   | <b>Large Hobbyist Job:</b><br>Bulk |
| <b>Multiple Day/Week Project:</b><br>Job Packs |                                    |

Do you want high performance and productivity or low initial cost?

|                                       |  |
|---------------------------------------|--|
| <b>Performance:</b><br>Norton ProSand | <b>Opening Price Point:</b><br>MultiSand |
|---------------------------------------|--|

What material are you cutting or grinding?

|   |  |
|---|--|
| <b>METAL</b><br>STEEL, STAINLESS,<br>IRON, SHEETMETAL | <b>MASONRY</b><br>CONCRETE BRICK, CINDER BLOCK,<br>CEMENT, PATIO STONE |
|---|--|

What power tool are you using?

|   |   |
|---|---|
| <b>Hand Held</b>                          | <b>Fixed Base</b>                         |
| <b>Circular Saws:</b><br>Cut-off Blades   | <b>Chop Saws:</b><br>Chop Saw Blades      |
| <b>High Speed Saws:</b><br>Cut-off Blades | <b>Stationary Saws:</b><br>Cut-off Blades |

How large is your project?

|  |                                    |
|--|------------------------------------|
| <b>Small DIY/Weekend Job:</b><br>Handy Packs   | <b>Large Hobbyist Job:</b><br>Bulk |
| <b>Multiple Day/Week Project:</b><br>Job Packs |                                    |

Do you want high performance and productivity or low initial cost?

|                                       |  |
|---------------------------------------|--|
| <b>Performance:</b><br>Diamond Blades | <b>Opening Price Point:</b><br>Abrasive Blades |
|---------------------------------------|--|

|   |  |  |   |   |   |  |   |  |
|---|--|--|---|---|---|--|---|--|
| <b>40 EXTRA COARSE</b><br>Heavy removal, stripping, dimensioning, and shaping | <b>60 COARSE</b><br>Moderate removal and stripping | <b>80 COARSE</b><br>Removing surface imperfections, sanding, and stripping | <b>100 MEDIUM</b><br>For light removal and smoothing of bare surfaces | <b>120 MEDIUM</b><br>Light stock removal and surface leveling | <b>150 MEDIUM</b><br>Fine surface preparation | <b>180 FINE</b><br>Final surface smoothing and initial between coats | <b>220 VERY FINE</b><br>After priming, staining, or sealing | <b>320 EXTRA FINE</b><br>Between coats sanding |
|---|--|--|---|---|---|--|---|--|



## ProSand Multi-Air Cyclonic

Revolutionary Norton ProSand Multi-Air Cyclonic Hook & Sand vacuum discs raise the bar in power sanding with a precision laser-cut, spiral-hole design that provides maximum dust extraction for a cleaner work environment with fewer disc changes and greater productivity.



Scan the QR code to view our video



### Grit Guide

| 40 EXTRA COARSE                                     | 60 COARSE                      | 80 COARSE  | 100 MEDIUM                                       | 120 MEDIUM                               | 150 MEDIUM               | 180 FINE  | 220 VERY FINE                       | 320 EXTRA FINE        |
|---|--------------------------------|--|--|--|--------------------------|---|-------------------------------------|-----------------------|
| Heavy removal, stripping, dimensioning, and shaping | Moderate removal and stripping | Removing surface imperfections, sanding, and stripping | For light removal and smoothing of bare surfaces | Light stock removal and surface leveling | Fine surface preparation | Final surface smoothing and initial between coats | After priming, staining, or sealing | Between coats sanding |

### Features & Benefits

- Precision laser-cut, spiral-hole hook and loop vacuum design removes material consistently throughout the life of the disc while maximizing dust extraction for a cleaner work environment
- Specialized multi-hole pattern allows for use on any random orbital sander regardless of hole pattern - including unique Festool®\* sander models
- Premium ceramic abrasive provides a superior cut on all surfaces, lasts substantially longer and removes material faster than conventional abrasives and uses a No-Fil coating to resist clogging/loading during sanding
- Unique fiber-reinforced latex/paper backing is flexible, strong, and tear-resistant



Clamshell Packaging

| PART #                                       | UPC-A                  | GRIT  | GRADING      | QTY/ PACK | PACKS/ CASE |
|--|------------------------|-------|--------------|-----------|-------------|
| <b>ProSand Hook &amp; Sand – Handy Packs</b> |                        |       |              |           |             |
| <b>5" Multi-Air Cyclonic Discs</b>           |                        |       |              |           |             |
| 07660703226                                  | 076607 <b>03226</b> 3  | P320B | Extra Fine   | 3         | 15          |
| 07660703227                                  | 076607 <b>03227</b> 0  | P220B | Very Fine    | 3         | 15          |
| 07660703228                                  | 076607 <b>03228</b> 8  | P180B | Fine         | 3         | 15          |
| 07660703229                                  | 076607 <b>03229</b> 4  | P150B | Medium       | 3         | 15          |
| 07660703230                                  | 076607 <b>03230</b> 0  | P120C | Medium       | 3         | 15          |
| 07660703231                                  | 076607 <b>03231</b> 7  | P100C | Medium       | 3         | 15          |
| 07660703232                                  | 076607 <b>03232</b> 4  | P80C  | Coarse       | 3         | 15          |
| 07660703233                                  | 076607 <b>03233</b> 1  | P60C  | Coarse       | 2         | 15          |
| 07660703234                                  | 076607 <b>03234</b> 8  | P40C  | Extra Coarse | 2         | 15          |
| <b>ProSand Hook &amp; Sand – Job Packs</b>   |                        |       |              |           |             |
| <b>5" Multi-Air Cyclonic Discs</b>           |                        |       |              |           |             |
| 07660703217                                  | 076607 <b>03217</b> 1  | P320B | Extra Fine   | 10        | 10**        |
| 07660703218                                  | 076607 <b>03218</b> 8  | P220B | Very Fine    | 10        | 10**        |
| 07660703219                                  | 076607 <b>03219</b> 5  | P180B | Fine         | 10        | 10**        |
| 07660703220                                  | 076607 <b>03220</b> 1  | P150B | Medium       | 10        | 10**        |
| 07660703221                                  | 076607 <b>03221</b> 8  | P120C | Medium       | 10        | 10**        |
| 07660703222                                  | 076607 <b>03222</b> 5  | P100C | Medium       | 10        | 10**        |
| 07660703223                                  | 076607 <b>03223</b> 2  | P80C  | Coarse       | 10        | 10**        |
| 07660703224                                  | 076607 <b>03224</b> 9  | P60C  | Coarse       | 10        | 10**        |
| 07660703225                                  | 076607 <b>03225</b> -6 | P40C  | Extra Coarse | 10        | 10**        |
| <b>6" Multi-Air Cyclonic Discs</b>           |                        |       |              |           |             |
| 07660705320                                  | 076607 <b>05320</b> 6  | P220B | Very Fine    | 10        | 10          |
| 07660705322                                  | 076607 <b>05322</b> 0  | P150B | Medium       | 10        | 10          |
| 07660705324                                  | 076607 <b>05324</b> 4  | P100C | Medium       | 10        | 10          |
| 07660705326                                  | 076607 <b>05326</b> 8  | P60C  | Coarse       | 10        | 10          |

| PART #   | UPC-A                 | GRIT  | GRADING      | QTY/ PACK | PACKS/ CASE |
|--|-----------------------|-------|--------------|-----------|-------------|
| <b>ProSand Hook &amp; Sand – Job Packs – Clamshell</b> |                       |       |              |           |             |
| <b>5" Multi-Air Cyclonic Discs</b>                     |                       |       |              |           |             |
| 07660704041  | 076607 <b>04041</b> 1 | P320B | Extra Fine   | 50        | 4           |
| 07660704038  | 076607 <b>04038</b> 1 | P220B | Very Fine    | 50        | 4           |
| 07660704037  | 076607 <b>04037</b> 4 | P180B | Fine         | 50        | 4           |
| 07660704036  | 076607 <b>04036</b> 7 | P150B | Medium       | 50        | 4           |
| 07660704035  | 076607 <b>04035</b> 0 | P120C | Medium       | 50        | 4           |
| 07660704034  | 076607 <b>04034</b> 3 | P100C | Medium       | 50        | 4           |
| 07660704033  | 076607 <b>04033</b> 6 | P80C  | Coarse       | 50        | 4           |
| 07660768459  | 076607 <b>68459</b> 2 | P60C  | Coarse       | 35        | 4           |
| 07660768460  | 076607 <b>68460</b> 8 | P40C  | Extra Coarse | 35        | 4           |
| <b>ProSand Hook &amp; Sand – Bulk</b>                  |                       |       |              |           |             |
| <b>5" Multi-Air Cyclonic Discs</b>                     |                       |       |              |           |             |
| 66623374368  | 666233 <b>74368</b> 0 | P60C  | Coarse       | 50        | 4           |
| 07660768279  | 076607 <b>68279</b> 6 | P40C  | Extra Coarse | 50        | 4           |
| <b>6" Multi-Air Cyclonic Discs</b>                     |                       |       |              |           |             |
| 07660705484  | 076607 <b>05484</b> 5 | P220B | Very Fine    | 50        | 4           |
| 07660705486  | 076607 <b>05486</b> 9 | P150B | Medium       | 50        | 4           |
| 07660705487  | 076607 <b>05487</b> 6 | P120C | Medium       | 50        | 4           |
| 07660705488  | 076607 <b>05488</b> 3 | P100C | Medium       | 50        | 4           |
| 07660705489  | 076607 <b>05489</b> 9 | P80C  | Coarse       | 50        | 4           |
| 07660705490  | 076607 <b>05490</b> 6 | P60C  | Coarse       | 50        | 4           |

“ The paper is solid and lasts a long time.

- Eric Clevinger, The Poplar Shop



Festool® is a registered trademark of TTS TOOLTECHNIC SYSTEMS AG & CO. KG



## ProSand UVH (Universal Vacuum Hole)

The patented Norton Hook & Sand Universal Vacuum Hole Discs offer superior results when used on high-speed power tools and can fit on both 5 and 8 hole random orbital sanders. The premium ceramic abrasive provides a superior cut on all surfaces, lasts substantially longer, and removes material faster than conventional abrasives. Our unique fiber-reinforced latex/paper backing is flexible, strong, and tear-resistant.




### Grit Guide

| 40 EXTRA COARSE                                     | 60 COARSE                      | 80 COARSE  | 100 MEDIUM                                       | 120 MEDIUM                               | 150 MEDIUM               | 180 FINE  | 220 VERY FINE                       | 320 EXTRA FINE        |
|---|--------------------------------|--|--|--|--------------------------|---|-------------------------------------|-----------------------|
| Heavy removal, stripping, dimensioning, and shaping | Moderate removal and stripping | Removing surface imperfections, sanding, and stripping | For light removal and smoothing of bare surfaces | Light stock removal and surface leveling | Fine surface preparation | Final surface smoothing and initial between coats | After priming, staining, or sealing | Between coats sanding |

### Features & Benefits

- Universal vacuum holes allow the discs to be used on 5 or 8 hole vacuum sanders
- Designed to increase dust extraction for a cleaner work environment
- Hook and loop fastener is easy to use and makes disc changes fast
- Premium ceramic abrasive provides a consistent finish and superior cut rate over traditional aluminum oxide discs
- Unique fiber-reinforced latex/paper backing is flexible, strong and tear resistant

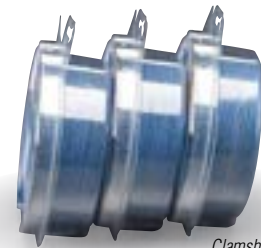

**NEW**

Clamshell Packaging

| PART #  | UPC-A                 | GRIT  | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|-------|--------------|--------------|----------------|
| <b>ProSand Hook &amp; Sand – Handy Pack</b>   |                       |       |              |              |                |
| <b>5" x 5 and 8 Hole – Universal Vac Hole</b> |                       |       |              |              |                |
| 07660768348                                   | 076607 <b>68348</b> 9 | P320B | Extra Fine   | 3            | 15             |
| 07660768349                                   | 076607 <b>68349</b> 6 | P220B | Very Fine    | 3            | 15             |
| 07660768350                                   | 076607 <b>68350</b> 2 | P180B | Fine         | 3            | 15             |
| 07660768351                                   | 076607 <b>68351</b> 9 | P150B | Medium       | 3            | 15             |
| 07660768352                                   | 076607 <b>68352</b> 6 | P120C | Medium       | 3            | 15             |
| 07660768353                                   | 076607 <b>68353</b> 3 | P100C | Medium       | 3            | 15             |
| 07660768354                                   | 076607 <b>68354</b> 0 | P80C  | Coarse       | 3            | 15             |
| 07660768355                                   | 076607 <b>68355</b> 7 | P60C  | Coarse       | 2            | 15             |
| 07660768356                                   | 076607 <b>68356</b> 4 | P40C  | Extra Coarse | 2            | 15             |
| <b>ProSand Hook &amp; Sand – Job Pack</b>     |                       |       |              |              |                |
| <b>5" x 5 and 8 Hole – Universal Vac Hole</b> |                       |       |              |              |                |
| 07660768357                                   | 076607 <b>68357</b> 1 | P320B | Extra Fine   | 10           | 10             |
| 07660768358                                   | 076607 <b>68358</b> 8 | P220B | Very Fine    | 10           | 10             |
| 07660768359                                   | 076607 <b>68359</b> 5 | P180B | Fine         | 10           | 10             |
| 07660768360                                   | 076607 <b>68360</b> 1 | P150B | Medium       | 10           | 10             |
| 07660768361                                   | 076607 <b>68361</b> 8 | P120C | Medium       | 10           | 10             |
| 07660768362                                   | 076607 <b>68362</b> 5 | P100C | Medium       | 10           | 10             |
| 07660768363                                   | 076607 <b>68363</b> 2 | P80C  | Coarse       | 10           | 10             |
| 07660768364                                   | 076607 <b>68364</b> 9 | P60C  | Coarse       | 10           | 10             |
| 07660768365                                   | 076607 <b>68365</b> 6 | P40C  | Extra Coarse | 10           | 10             |

| PART #  | UPC-A                 | GRIT  | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|-------|--------------|--------------|----------------|
| <b>ProSand Hook &amp; Sand – Job Pack – Clamshell</b> |                       |       |              |              |                |
| <b>5" x 5 and 8 Hole – Universal Vac Hole</b>         |                       |       |              |              |                |
| 07660768322   | 076607 <b>68322</b> 9 | P320B | Extra Fine   | 50           | 4              |
| 07660768323   | 076607 <b>68323</b> 6 | P220B | Very Fine    | 50           | 4              |
| 07660768324   | 076607 <b>68324</b> 3 | P180B | Fine         | 50           | 4              |
| 07660768325   | 076607 <b>68325</b> 0 | P150B | Medium       | 50           | 4              |
| 07660768326   | 076607 <b>68326</b> 7 | P120C | Medium       | 50           | 4              |
| 07660768327   | 076607 <b>68327</b> 4 | P100C | Medium       | 50           | 4              |
| 07660768328   | 076607 <b>68328</b> 1 | P80C  | Coarse       | 50           | 4              |
| 07660768461   | 076607 <b>68461</b> 5 | P60C  | Coarse       | 35           | 4              |
| 07660768462   | 076607 <b>68462</b> 2 | P40C  | Extra Coarse | 35           | 4              |
| <b>ProSand Hook &amp; Sand – Bulk</b>                 |                       |       |              |              |                |
| <b>5" x 5 and 8 Hole – Universal Vac Hole</b>         |                       |       |              |              |                |
| 07660768329   | 076607 <b>68329</b> 8 | P60C  | Coarse       | 50           | 4              |
| 07660768330   | 076607 <b>68330</b> 4 | P40C  | Extra Coarse | 50           | 4              |





## MeshPower

Powerful dust extraction for a breath of fresh air!

Sanding often times can be dusty and messy. With Norton MeshPower sanding discs we have created a product that provides virtually dust-free sanding; meaning a cleaner and healthier working environment, a better finish and a much more comfortable sanding experience.



### Grit Guide


|   |   |   |   |  |
|---|---|---|---|--|
| <b>80 COARSE</b><br>For moderate removal and leveling surface imperfections | <b>100, 120, 150 MEDIUM</b><br>For light removal and smoothing of bare surfaces | <b>180 FINE</b><br>For finish sanding and cleaning of bare surfaces | <b>220 VERY FINE</b><br>For very fine sanding of bare surfaces, primer and sealer sanding | <b>320 EXTRA FINE</b><br>For primer, sealer, and between coats sanding |
|---|---|---|---|--|

### Features & Benefits

- MeshPower discs are a multi-functional abrasive, designed with thousands of holes, created by the unique open mesh backing
- This mesh structure allows for powerful and effective dust extraction in any application.
- Patented Norton No-Fil technology works to prevent clogging for a better finish and longer life, saving operators time and money.
- It also allows the grain to wear evenly resulting in a finer scratch pattern, and faster, more consistent results throughout the product life.



### Competitive Benchmarking

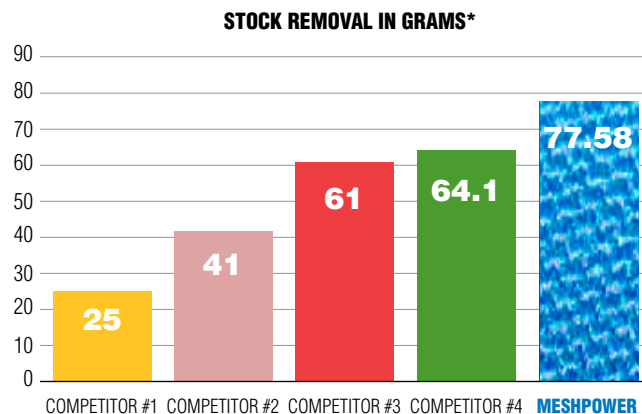

\*Results are based on 12 minutes of sanding on maple panel (80, 120, 220 grit).

| PART #                               | UPC-A               | GRIT | GRADING           | QTY/ PACK  | PKG./ CASE |
|--------------------------------------|---------------------|------|-------------------|------------|------------|
| <b>MeshPower – Handy Pack</b>        |                     |      |                   |            |            |
| <b>5" Ceramic</b>                    |                     |      |                   |            |            |
| 07660768451                          | 076607 <b>68451</b> | 6    | 80, 120, 150, 220 | Assorted   | 4 15       |
| <b>MeshPower – Job Pack</b>          |                     |      |                   |            |            |
| <b>5" Ceramic</b>                    |                     |      |                   |            |            |
| 07660768437                          | 076607 <b>68437</b> | 0    | 320               | Extra Fine | 10 10      |
| 07660768438                          | 076607 <b>68438</b> | 7    | 220               | Very Fine  | 10 10      |
| 07660768439                          | 076607 <b>68439</b> | 4    | 180               | Fine       | 10 10      |
| 07660768440                          | 076607 <b>68440</b> | 0    | 150               | Medium     | 10 10      |
| 07660768441                          | 076607 <b>68441</b> | 7    | 120               | Medium     | 10 10      |
| 07660768442                          | 076607 <b>68442</b> | 4    | 100               | Medium     | 10 10      |
| 07660768443                          | 076607 <b>68443</b> | 1    | 80                | Coarse     | 10 10      |
| <b>MeshPower – Bulk</b>              |                     |      |                   |            |            |
| <b>5" Ceramic</b>                    |                     |      |                   |            |            |
| 07660768444                          | 076607 <b>68444</b> | 8    | 320               | Extra Fine | 50 4       |
| 07660768445                          | 076607 <b>68445</b> | 5    | 220               | Very Fine  | 50 4       |
| 07660768446                          | 076607 <b>68446</b> | 2    | 180               | Fine       | 50 4       |
| 07660768447                          | 076607 <b>68447</b> | 9    | 150               | Medium     | 50 4       |
| 07660768448                          | 076607 <b>68448</b> | 6    | 120               | Medium     | 50 4       |
| 07660768449                          | 076607 <b>68449</b> | 3    | 100               | Medium     | 50 4       |
| 07660768450                          | 076607 <b>68450</b> | 9    | 80                | Coarse     | 50 4       |
| <b>6" Ceramic</b>                    |                     |      |                   |            |            |
| 66261170640                          | 662611 <b>70640</b> | 7    | 220               | Very Fine  | 50 4       |
| 66261170641                          | 662611 <b>70641</b> | 4    | 180               | Fine       | 50 4       |
| 66261170642                          | 662611 <b>70642</b> | 1    | 150               | Medium     | 50 4       |
| 66261170643                          | 662611 <b>70643</b> | 8    | 120               | Medium     | 50 4       |
| 66261170644                          | 662611 <b>70644</b> | 5    | 100               | Medium     | 50 4       |
| 66261170645                          | 662611 <b>70645</b> | 2    | 80                | Coarse     | 50 4       |
| <b>MeshPower - Bulk UPC Barcoded</b> |                     |      |                   |            |            |
| <b>9" Ceramic</b>                    |                     |      |                   |            |            |
| 07660768452                          | 076607 <b>68452</b> | 3    | 220               | Very Fine  | 15 15      |
| 07660768453                          | 076607 <b>68453</b> | 0    | 180               | Fine       | 15 15      |
| 07660768454                          | 076607 <b>68454</b> | 7    | 150               | Medium     | 15 15      |
| 07660768455                          | 076607 <b>68455</b> | 4    | 120               | Medium     | 15 15      |
| 07660768456                          | 076607 <b>68456</b> | 1    | 100               | Medium     | 15 15      |
| 07660768457                          | 076607 <b>68457</b> | 8    | 80                | Coarse     | 15 15      |



### MultiSand – Hook & Sand – Paper

Norton MultiSand Hook & Sand Discs offer a superior cut rate and consistent finish. The unique fiber-reinforced backing is edge tear-resistant and features a hook and loop backing that makes for quick and easy disc changes. Water-based zinc stearate coating reduces loading and prevents finish contamination.

#### Grit Guide

| 40 EXTRA COARSE | 60 COARSE        | 80 COARSE        | 100 MEDIUM                | 120 MEDIUM                | 150 MEDIUM                | 180 FINE                 | 220 VERY FINE         | 320 EXTRA FINE        |
|-----------------|------------------|------------------|---------------------------|---------------------------|---------------------------|--------------------------|-----------------------|-----------------------|
| Heavy removal   | Moderate removal | Moderate removal | Moderate to light removal | Moderate to light removal | Moderate to light removal | Fine surface preparation | Between coats sanding | Between coats sanding |

| PART #   | UPC-A                 | GRIT  | GRADING                       | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|-------|-------------------------------|--------------|----------------|
| <b>MultiSand Hook &amp; Sand – Handy Packs</b>       |                       |       |                               |              |                |
| <b>5" x 5 Hole (A296)</b>                            |                       |       |                               |              |                |
| 07660749166  | 076607 <b>49166</b> 4 | P150  | Medium                        | 4            | 15**           |
| 07660702206  | 076607 <b>02206</b> 6 | P120  | Medium                        | 4            | 15**           |
| 07660702207  | 076607 <b>02207</b> 3 | P80   | Coarse                        | 4            | 15**           |
| <b>5" x 8 Hole (A296)</b>                            |                       |       |                               |              |                |
| 07660749155  | 076607 <b>49155</b> 8 | P220  | Very Fine                     | 4            | 15**           |
| 07660749156  | 076607 <b>49156</b> 5 | P150  | Medium                        | 4            | 15**           |
| 07660702208  | 076607 <b>02208</b> 0 | P120  | Medium                        | 4            | 15**           |
| 07660749157  | 076607 <b>49157</b> 2 | P100  | Medium                        | 4            | 15**           |
| 07660702209  | 076607 <b>02209</b> 7 | P80   | Coarse                        | 4            | 15**           |
| 07660749158  | 076607 <b>49158</b> 9 | P60   | Coarse                        | 4            | 15**           |
| 07660749159  | 076607 <b>49159</b> 6 | Asst. | 2F, 1M, 1C                    | 4            | 15**           |
| <b>5" x 5 and 8 Hole – Universal Vac Hole (A296)</b> |                       |       |                               |              |                |
| 07660702001  | 076607 <b>02001</b> 7 | P220  | Very Fine                     | 4            | 15**           |
| 07660702003  | 076607 <b>02003</b> 1 | P150  | Medium                        | 4            | 15**           |
| 07660702005  | 076607 <b>02005</b> 5 | P100  | Medium                        | 4            | 15**           |
| 07660702007  | 076607 <b>02007</b> 9 | P60   | Coarse                        | 4            | 15**           |
| 07660702320  | 076607 <b>02320</b> 9 |       | Conversion Pad                | 1            | 15**           |
| <b>Kit</b>   |                       |       |                               |              |                |
| 5" Ergonomic Hook & Sand Hand Sander Disc Kit        |                       |       |                               |              |                |
| 07660703968  | 076607 <b>03968</b> 2 | Kit   | Pad with 5" Hook & Loop Discs | 1            | 10             |

| PART #   | UPC-A                 | GRIT | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|------|--------------|--------------|----------------|
| <b>MultiSand Hook &amp; Sand – Job Packs</b>         |                       |      |              |              |                |
| <b>5" x 5 Hole (A296)</b>                            |                       |      |              |              |                |
| 07660749209  | 076607 <b>49209</b> 8 | P320 | Extra Fine   | 25           | 10**           |
| 07660749210  | 076607 <b>49210</b> 4 | P220 | Very Fine    | 25           | 10**           |
| 07660749211  | 076607 <b>49211</b> 1 | P180 | Fine         | 25           | 10**           |
| 07660749212  | 076607 <b>49212</b> 8 | P150 | Medium       | 25           | 10**           |
| 07660749213  | 076607 <b>49213</b> 5 | P120 | Medium       | 25           | 10**           |
| 07660749214  | 076607 <b>49214</b> 2 | P100 | Medium       | 25           | 10**           |
| 07660749215  | 076607 <b>49215</b> 9 | P80  | Coarse       | 25           | 10**           |
| 07660749216  | 076607 <b>49216</b> 6 | P60  | Coarse       | 25           | 10**           |
| 07660749217  | 076607 <b>49217</b> 3 | P40  | Extra Coarse | 20           | 10**           |
| <b>5" x 8 Hole (A296)</b>                            |                       |      |              |              |                |
| 07660749218  | 076607 <b>49218</b> 0 | P220 | Very Fine    | 25           | 10**           |
| 07660749219  | 076607 <b>49219</b> 7 | P180 | Fine         | 25           | 10**           |
| 07660749220  | 076607 <b>49220</b> 3 | P150 | Medium       | 25           | 10**           |
| 07660749221  | 076607 <b>49221</b> 0 | P120 | Medium       | 25           | 10**           |
| 07660749222  | 076607 <b>49222</b> 7 | P100 | Medium       | 25           | 10**           |
| 07660749223  | 076607 <b>49223</b> 4 | P80  | Coarse       | 25           | 10**           |
| 07660749224  | 076607 <b>49224</b> 1 | P60  | Coarse       | 25           | 10**           |
| 07660749225  | 076607 <b>49225</b> 8 | P40  | Extra Coarse | 20           | 10**           |
| <b>5" x 5 and 8 Hole - Universal Vac Hole (A296)</b> |                       |      |              |              |                |
| 07660704056  | 076607 <b>04056</b> 5 | P320 | Extra Fine   | 25           | 10**           |
| 07660704057  | 076607 <b>04057</b> 2 | P220 | Very Fine    | 25           | 10**           |
| 07660704058  | 076607 <b>04058</b> 9 | P180 | Fine         | 25           | 10**           |
| 07660704059  | 076607 <b>04059</b> 6 | P150 | Medium       | 25           | 10**           |
| 07660704060  | 076607 <b>04060</b> 2 | P120 | Medium       | 25           | 10**           |
| 07660704061  | 076607 <b>04061</b> 9 | P100 | Medium       | 25           | 10**           |
| 07660704062  | 076607 <b>04062</b> 6 | P80  | Coarse       | 25           | 10**           |
| 07660704063  | 076607 <b>04063</b> 3 | P60  | Coarse       | 25           | 10**           |
| 07660704064  | 076607 <b>04064</b> 0 | P40  | Extra Coarse | 20           | 10**           |
| <b>6" x 6 Hole (A296)</b>                            |                       |      |              |              |                |
| 07660701635  | 076607 <b>01635</b> 5 | P220 | Very Fine    | 25           | 10**           |
| 07660701634  | 076607 <b>01634</b> 8 | P150 | Medium       | 25           | 10**           |
| 07660701637  | 076607 <b>01637</b> 9 | P120 | Medium       | 25           | 10**           |
| 07660701633  | 076607 <b>01633</b> 1 | P100 | Medium       | 25           | 10**           |
| 07660701636  | 076607 <b>01636</b> 2 | P80  | Coarse       | 25           | 10**           |
| 07660701632  | 076607 <b>01632</b> 4 | P60  | Coarse       | 25           | 10**           |



### MultiSand – Stick & Sand – Paper

Norton MultiSand Stick & Sand PSA Discs and Rolls feature a durable, sharp aluminum oxide grain for aggressive and cool cutting.

The non-pigmented, water-based anti-clog coating resists loading and won't contaminate the finish. Pressure sensitive adhesive allows for quick and easy disc changes.

#### Grit Guide

|   |                                      |                                      |  |  |  |   |   |  |
|---|--------------------------------------|--------------------------------------|--|--|--|---|---|--|
| <b>40 EXTRA COARSE</b><br>Heavy removal | <b>60 COARSE</b><br>Moderate removal | <b>80 COARSE</b><br>Moderate removal | <b>100 MEDIUM</b><br>Moderate to light removal | <b>120 MEDIUM</b><br>Moderate to light removal | <b>150 MEDIUM</b><br>Moderate to light removal | <b>180 FINE</b><br>Fine surface preparation | <b>220 VERY FINE</b><br>Between coats sanding | <b>320 EXTRA FINE</b><br>Between coats sanding |
|---|--------------------------------------|--------------------------------------|--|--|--|---|---|--|

| PART #  | UPC-A                 | GRIT | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|------|--------------|--------------|----------------|
| <b>MultiSand Stick &amp; Sand (PSA) – Handy Packs</b> |                       |      |              |              |                |
| <b>5" x No Hole Disc (A296)</b>                       |                       |      |              |              |                |
| 07660705454   | 076607 <b>48906</b> 7 | 120  | Medium       | 5            | 10**           |
| 07660705455   | 076607 <b>48907</b> 4 | 80   | Coarse       | 5            | 10**           |
| 07660705456   | 076607 <b>48908</b> 1 | 40   | Extra Coarse | 4            | 10**           |
| <b>5" x 8 Hole Disc (A296)</b>                        |                       |      |              |              |                |
| 07660701809   | 076607 <b>01809</b> 0 | 220  | Very Fine    | 5            | 15**           |
| 07660701811   | 076607 <b>01811</b> 3 | 150  | Fine         | 5            | 15**           |
| 07660701812   | 076607 <b>01812</b> 0 | 100  | Medium       | 4            | 15**           |
| 07660701815   | 076607 <b>01815</b> 1 | 60   | Coarse       | 4            | 15**           |
| <b>6" x No Hole Disc (A296)</b>                       |                       |      |              |              |                |
| 07660702498   | 076607 <b>48909</b> 8 | 120  | Fine         | 5            | 10             |
| 07660702499   | 076607 <b>48910</b> 4 | 80   | Coarse       | 5            | 10             |
| 07660702500   | 076607 <b>48911</b> 1 | 40   | Extra Coarse | 4            | 10             |

| PART #  | UPC-A                  | GRIT | GRADING    | QTY/<br>PACK | PACKS/<br>CASE |
|---|------------------------|------|------------|--------------|----------------|
| <b>MultiSand Stick &amp; Sand (PSA) – Job Packs</b> |                        |      |            |              |                |
| <b>5" x No Hole Disc Roll (A296)</b>                |                        |      |            |              |                |
| 07660749231   | 076607 <b>49231</b> 9  | P320 | Extra Fine | 50           | 10**           |
| 07660749232   | 076607 <b>49232</b> 6  | P220 | Very Fine  | 50           | 10**           |
| 07660749239   | 076607 <b>49239</b> 5  | P150 | Fine       | 50           | 10**           |
| 07660749236   | 076607 <b>49236</b> 4  | P100 | Medium     | 50           | 10**           |
| 07660749238   | 076607 <b>49238</b> 8  | P80  | Coarse     | 50           | 10**           |
| 07660749237   | 076607 <b>49237</b> 1  | P60  | Coarse     | 50           | 10**           |
| <b>5" x 5 Hole Disc Roll (A296)</b>                 |                        |      |            |              |                |
| 07660701647   | 076607 <b>01647</b> 8  | P220 | Very Fine  | 50           | 10**           |
| 07660701646   | 076607 <b>01646</b> 1  | P180 | Fine       | 50           | 10**           |
| 07660701645   | 076607 <b>01645</b> 4  | P150 | Fine       | 50           | 10**           |
| 07660701644   | 076607 <b>01644</b> 7  | P120 | Medium     | 50           | 10**           |
| 07660701643   | 076607 <b>01643</b> 0  | P100 | Medium     | 50           | 10**           |
| 07660701642   | 076607 <b>01642</b> 3  | P80  | Coarse     | 50           | 10**           |
| 07660701641   | 076607 <b>01641</b> 6  | P60  | Coarse     | 50           | 10**           |
| <b>6" x No Hole Disc Roll (A296)</b>                |                        |      |            |              |                |
| 07660749240   | 076607 <b>49240</b> 1  | P220 | Very Fine  | 50           | 10**           |
| 07660749242   | 076607 <b>49242</b> 5  | P150 | Fine       | 50           | 10**           |
| 07660749244   | 076607 <b>49244</b> 9  | P100 | Medium     | 50           | 10**           |
| 07660749246   | 076607 <b>49246</b> -3 | P80  | Coarse     | 50           | 10**           |
| <b>6" x 6 Hole Disc Roll (A296)</b>                 |                        |      |            |              |                |
| 07660701650   | 076607 <b>01650</b> 8  | P150 | Fine       | 50           | 10**           |
| 07660701651   | 076607 <b>01651</b> 5  | P100 | Medium     | 50           | 10**           |
| 07660701652   | 076607 <b>01652</b> 2  | P80  | Coarse     | 50           | 10**           |





## MultiSand – Stick & Sand – Cloth

Norton MultiSand Cloth Stick & Sand PSA Discs are used for a variety of applications including rough sanding of primed and painted surfaces, stripping paint and primers, and heavy stock removal of wood, metal, plastic, and fiberglass.

### Applications:

#### Electric Random Orbital Sanders

For use on contours or flat surfaces for light- to medium-pressure grinding, blending, leveling, and finishing applications.

#### Stationary Disc Sanders

Used in woodworking and metalworking for stock removal, sanding/grinding flat surfaces, dimensioning and finishing.

### Grit Guide

| 36<br>EXTRA COARSE | 40<br>EXTRA COARSE | 50<br>COARSE  | 60<br>COARSE     | 80<br>COARSE     | 100<br>MEDIUM             | 120<br>MEDIUM             | 150<br>MEDIUM             | 180<br>FINE              | 220<br>VERY FINE      | 320<br>EXTRA FINE     |
|--------------------|--------------------|---------------|------------------|------------------|---------------------------|---------------------------|---------------------------|--------------------------|-----------------------|-----------------------|
| Very heavy removal | Heavy removal      | Heavy removal | Moderate removal | Moderate removal | Moderate to light removal | Moderate to light removal | Moderate to light removal | Fine surface preparation | Between coats sanding | Between coats sanding |

| PART #  | UPC-A       | GRIT | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|--------------|--------------|----------------|
| <b>Cloth Stick &amp; Sand Orbital/Bench Discs – Handy Packs</b>     |             |      |              |              |                |
| <b>5" Adhesive-Backed Aluminum Oxide Cloth (R228)</b>               |             |      |              |              |                |
| 07660701994   | 07660701994 | 120X | Medium       | 2            | 15**           |
| 07660701996   | 07660701996 | 80X  | Coarse       | 2            | 15**           |
| 07660701998   | 07660701998 | 50X  | Coarse       | 2            | 15**           |
| <b>6" Adhesive-Backed Aluminum Oxide Cloth (R228)</b>               |             |      |              |              |                |
| 07660701986   | 07660701986 | 220X | Very Fine    | 2            | 15**           |
| 07660701987   | 07660701987 | 120X | Medium       | 2            | 15**           |
| 07660701989   | 07660701989 | 80X  | Coarse       | 2            | 15**           |
| 07660701991   | 07660701991 | 50X  | Coarse       | 2            | 15**           |
| <b>8" Adhesive-Backed Aluminum Oxide Cloth (R228)</b>               |             |      |              |              |                |
| 07660701981   | 07660701981 | 100X | Medium       | 3            | 15**           |
| <b>9" Adhesive-Backed Aluminum Oxide Cloth (R228)</b>               |             |      |              |              |                |
| 07660705278   | 07660705278 | 180X | Fine         | 2            | 15**           |
| 07660701973   | 07660701973 | 120X | Medium       | 2            | 15**           |
| 07660701975   | 07660701975 | 80X  | Coarse       | 2            | 15**           |
| <b>Cloth Adhesive-Backed Aluminum Oxide (R228) – Bulk – Non UPC</b> |             |      |              |              |                |
| <b>5"</b>   |             |      |              |              |                |
| 66261136581   | 66261136581 | 180X | Fine         | 50           | 250            |
| 66261136582   | 66261136582 | 150X | Medium       | 50           | 250            |
| 66261136583   | 66261136583 | 120X | Medium       | 50           | 250            |
| 66261136584   | 66261136584 | 100X | Medium       | 50           | 250            |
| 66261136585   | 66261136585 | 80X  | Coarse       | 50           | 250            |
| 66261136586   | 66261136586 | 60X  | Coarse       | 50           | 250            |
| 66261136587   | 66261136587 | 50X  | Coarse       | 50           | 250            |
| 66261136588   | 66261136588 | 40X  | Extra Coarse | 50           | 250            |
| 66261136589   | 66261136589 | 36X  | Extra Coarse | 50           | 250            |

| PART #  | UPC-A       | GRIT   | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|--------|--------------|--------------|----------------|
| <b>Cloth Adhesive-Backed Aluminum Oxide (R228) – Bulk – Non UPC</b> |             |        |              |              |                |
| <b>6"</b>   |             |        |              |              |                |
| 66261136592   | 66261136592 | 5 180X | Fine         | 50           | 250            |
| 66261136593   | 66261136593 | 2 120X | Medium       | 50           | 250            |
| 66261136594   | 66261136594 | 9 100X | Medium       | 50           | 250            |
| 66261136595   | 66261136595 | 6 80X  | Coarse       | 50           | 250            |
| 66261136596   | 66261136596 | 3 60X  | Coarse       | 50           | 250            |
| <b>8"</b>   |             |        |              |              |                |
| 66261136355   | 66261136355 | 6 120X | Medium       | 50           | 250            |
| 66261136354   | 66261136354 | 9 80X  | Coarse       | 50           | 250            |
| 66261136576   | 66261136576 | 5 60X  | Coarse       | 50           | 250            |
| 66261136352   | 66261136352 | 5 50X  | Coarse       | 50           | 250            |
| 66261136351   | 66261136351 | 8 40X  | Extra Coarse | 50           | 250            |
| 66261136350   | 66261136350 | 1 36X  | Extra Coarse | 50           | 250            |
| <b>9"</b>   |             |        |              |              |                |
| 66261125615   | 66261125615 | 5 120X | Medium       | 25           | 50             |
| 66261125616   | 66261125616 | 2 80X  | Coarse       | 25           | 50 <i>NS</i>   |
| <b>10"</b>  |             |        |              |              |                |
| 66261136600   | 66261136600 | 7 100X | Medium       | 25           | 50             |
| 66261136601   | 66261136601 | 4 80X  | Coarse       | 25           | 50             |
| 66261136602   | 66261136602 | 1 60X  | Coarse       | 25           | 50             |
| 66261136607   | 66261136607 | 6 50X  | Coarse       | 25           | 50             |
| 66261136604   | 66261136604 | 5 40X  | Extra Coarse | 25           | 50             |
| 66261136606   | 66261136606 | 9 36X  | Extra Coarse | 25           | 50             |
| <b>12"</b>  |             |        |              |              |                |
| 66261136613   | 66261136613 | 7 120X | Medium       | 25           | 50             |
| 66261136614   | 66261136614 | 4 100X | Medium       | 25           | 50             |
| 66261136615   | 66261136615 | 1 80X  | Coarse       | 25           | 50             |
| 66261136620   | 66261136620 | 5 60X  | Coarse       | 25           | 50             |
| 66261136625   | 66261136625 | 0 50X  | Coarse       | 25           | 50             |
| 66261136630   | 66261136630 | 4 40X  | Extra Coarse | 25           | 50             |
| 66261136635   | 66261136635 | 9 36X  | Extra Coarse | 25           | 50             |

*NS Non-Stock Item*



## Flap Disc

Our Norton flap disc portfolio offers right angle grinding versatility with a product that can grind and finish in a single operation. The abrasive flaps are adhered to a rigid backing plate. It is the back plate that provides stability during operation with cooler cut, less vibration and smoother finish without gouging.

Applications: Grinding, stock removal, edge chamfering/beveling, weld blending, deburring/deflashing, rust removal, blending, cleaning and finishing

**NOTE: Use at 15°-25° angle. More severe angles will weaken edges.**



### Grit Guide

| 24 GRIT       | 36 GRIT       | 40 GRIT          | 60 GRIT          | 80 GRIT                 |
|---------------|---------------|------------------|------------------|-------------------------|
| Heavy Removal | Heavy Removal | Moderate Removal | Moderate Removal | Final Surface Smoothing |

 
### Flap Disc Shapes



GRIND AT FLATTER ANGLES: 0° - 15°

#### Type 27 Flat - The Best Choice for Finishing

- Used primarily on flat surfaces
- The best choice for blending and smooth finishing



GRIND AT STEEPER ANGLES: 15° - 25°

#### Type 29 Conical - The Best Choice for Aggressive Stock Removal

- Conical flap discs have angled flaps and may be used on both contoured and edge work
- The angle provides greater surface contact for stock removal on flat surfaces
- The best choice when speed and stock removal are primary considerations

### Abrasive Flap Density



#### Standard Density

- Excellent for heavy-duty applications and rapid stock removal

| PART #  | UPC-A       | GRIT  | TYPE    | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|-------|---------|--------------|----------------|
| <b>Norton BlueFire Flap Discs - Handy Packs</b> |             |       |         |              |                |
| <b>4-1/2" x 5/8"-11 Hub (R884P)</b>             |             |       |         |              |                |
| 07660703213                                     | 07660703213 | 3 P80 | Type 29 | 1            | 5**            |
| 07660703212                                     | 07660703212 | 6 P60 | Type 29 | 1            | 5**            |
| 07660703211                                     | 07660703211 | 9 P40 | Type 29 | 1            | 5**            |
| <b>7" x 5/8"-11 Hub (R884P)</b>                 |             |       |         |              |                |
| 07660703207                                     | 07660703207 | 2 P80 | Type 27 | 1            | 5**            |
| 07660703206                                     | 07660703206 | 5 P60 | Type 27 | 1            | 5**            |
| 07660703205                                     | 07660703205 | 8 P40 | Type 27 | 1            | 5**            |
| <b>Norton Metal Flap Discs - Bulk - Non UPC</b> |             |       |         |              |                |
| <b>4-1/2" x 5/8"-11 Hub (R828T)</b>             |             |       |         |              |                |
| 66254419997                                     | 66254419997 | 0 P80 | Type 29 | 10           | 10             |
| 66254419996                                     | 66254419996 | 3 P60 | Type 29 | 10           | 10             |
| 66254419994                                     | 66254419994 | 9 P40 | Type 29 | 10           | 10             |
| <b>4-1/2" x 7/8" (R828T)</b>                    |             |       |         |              |                |
| 66254419987                                     | 66254419987 | 1 80  | Type 29 | 10           | 10             |
| 66254419984                                     | 66254419984 | 0 60  | Type 29 | 10           | 10             |
| 66254419978                                     | 66254419978 | 9 40  | Type 29 | 10           | 10             |
| 66254419963                                     | 66254419963 | 5 36  | Type 29 | 10           | 10             |
| <b>7" x 5/8"-11 (R828T)</b>                     |             |       |         |              |                |
| 66254420013                                     | 66254420013 | 3 P80 | Type 29 | 10           | 10             |
| 66254420012                                     | 66254420012 | 6 P60 | Type 29 | 10           | 10             |
| 66254420010                                     | 66254420010 | 2 P40 | Type 29 | 10           | 10             |
| <b>7" x 7/8"-11 (R828T)</b>                     |             |       |         |              |                |
| 66254420007                                     | 66254420007 | 2 60  | Type 29 | 10           | 10             |
| 66254420006                                     | 66254420006 | 5 40  | Type 29 | 10           | 10             |
| 66254420004                                     | 66254420004 | 1 36  | Type 29 | 10           | 10             |



## Fiber Disc

The most heavy-duty coated abrasive, Norton Fiber Discs feature resin-over-resin construction on heavy-duty vulcanized fiber backing. Designed for applications ranging from paint stripping and weld grinding to heavy metal removal. For use with back-up pads on portable angle grinders.



### Grit Guide

| 16 GRIT       | 24 GRIT       | 36 GRIT       | 50 GRIT                   | 60 GRIT                   | 80 GRIT                 | 100 GRIT                | 120 GRIT                |
|---------------|---------------|---------------|---------------------------|---------------------------|-------------------------|-------------------------|-------------------------|
| Heavy Removal | Heavy Removal | Heavy Removal | Moderate to Light Removal | Moderate to Light Removal | Final Surface Smoothing | Final Surface Smoothing | Final Surface Smoothing |

| PART #                               | UPC-A       | DESCRIPTION                    | QTY/<br>PACK | PACKS/<br>CASE |
|--------------------------------------|-------------|--------------------------------|--------------|----------------|
| <b>Conversion Kits – Handy Packs</b> |             |                                |              |                |
| <b>4-1/2" x 7/8"</b>                 |             |                                |              |                |
| 07660701693                          | 07660701693 | 5 1 Pad, 2-50 Medium A/O Fiber | 1            | 5**            |
| <b>7" x 7/8"</b>                     |             |                                |              |                |
| 07660701703                          | 07660701703 | 1 1 Pad, 2-50 Medium A/O Fiber | 1            | 5**            |

| PART #   | UPC-A       | GRIT | GRADING | STD/<br>PACK |   |
|--|-------------|------|---------|--------------|---|
| <b>Air-Cooled Rubber Back-up Pads – Bulk – Non UPC</b> |             |      |         |              |   |
| 63642502122  | 63642502122 | 3    | 4-1/2"  | Medium       | 5 |
| 63642543421  | 63642543421 | 4    | 5"      | Medium       | 5 |
| 63642543425  | 63642543425 | 2    | 7"      | Hard         | 5 |
| 63642543422  | 63642543422 | 1    | 7"      | Medium       | 5 |
| 63642543426  | 63642543426 | 9    | 9"      | Hard         | 5 |
| 63642543423  | 63642543423 | 8    | 9"      | Medium       | 5 |

| PART #   | UPC-A       | GRIT | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|------|--------------|----------------|
| <b>Norton BlueFire Zirconia Alumina Fiber – Bulk – Non UPC</b> |             |      |              |                |
| <b>4-1/2" x 7/8" (Norton BlueFire F826)</b>                    |             |      |              |                |
| 66261138452  | 66261138452 | 0 80 | 25           | 25             |
| 66261138453  | 66261138453 | 7 60 | 25           | 25             |
| 66261138454  | 66261138454 | 4 50 | 25           | 25             |
| 66261138456  | 66261138456 | 8 36 | 25           | 25             |
| 66261138457  | 66261138457 | 5 24 | 25           | 25             |
| <b>5" x 7/8" (Norton BlueFire F826)</b>                        |             |      |              |                |
| 66261138600  | 66261138600 | 5 80 | 25           | 25             |
| 66261138601  | 66261138601 | 2 60 | 25           | 25             |
| 66261138561  | 66261138561 | 9 50 | 25           | 25             |
| 66261138562  | 66261138562 | 6 36 | 25           | 25             |
| 66261138563  | 66261138563 | 3 24 | 25           | 25             |
| <b>7" x 7/8" (Norton BlueFire F826)</b>                        |             |      |              |                |
| 66261138590  | 66261138590 | 9 80 | 25           | 25             |
| 66261138591  | 66261138591 | 6 60 | 25           | 25             |
| 66261138592  | 66261138592 | 3 50 | 25           | 25             |
| 66261138593  | 66261138593 | 0 36 | 25           | 25             |
| 66261138594  | 66261138594 | 7 24 | 25           | 25             |
| <b>Ceramic Alumina Fiber – Bulk – Non UPC</b>                  |             |      |              |                |
| <b>4-1/2" x 7/8" (FX965)</b>                                   |             |      |              |                |
| 66623365598  | 66623365598 | 3 80 | 25           | 25             |
| 66623355604  | 66623355604 | 4 60 | 25           | 25             |
| 66623355603  | 66623355603 | 7 50 | 25           | 25             |
| 66623355602  | 66623355602 | 0 36 | 25           | 25             |
| 66623355601  | 66623355601 | 3 24 | 25           | 25             |
| <b>5" x 7/8" (FX965)</b>                                       |             |      |              |                |
| 66623366015  | 66623366015 | 4 80 | 25           | 25             |
| 66623355600  | 66623355600 | 6 60 | 25           | 25             |
| 66623355599  | 66623355599 | 3 50 | 25           | 25             |
| 66623355598  | 66623355598 | 6 36 | 25           | 25             |
| 66623355597  | 66623355597 | 9 24 | 25           | 25             |
| <b>7" x 7/8" (FX965)</b>                                       |             |      |              |                |
| 66623365600  | 66623365600 | 3 80 | 25           | 25             |
| 66623355596  | 66623355596 | 2 60 | 25           | 25             |
| 66623355595  | 66623355595 | 5 50 | 25           | 25             |
| 66623355594  | 66623355594 | 8 36 | 25           | 25             |
| 66623355578  | 66623355578 | 8 24 | 25           | 25             |

## Fiber Discs

| PART #                                       | UPC-A       | GRIT  | QTY/<br>PACK | QTY/<br>CASE |
|--|-------------|-------|--------------|--------------|
| <b>Aluminum Oxide Fiber – Bulk – Non UPC</b> |             |       |              |              |
| <b>4-1/2" x 7/8" (F240)</b>                  |             |       |              |              |
| 66623353314                                  | 66623353314 | 4 120 | 25           | 25           |
| 66623353313                                  | 66623353313 | 7 100 | 25           | 25           |
| 66623353312                                  | 66623353312 | 8 80  | 25           | 25           |
| 66623353311                                  | 66623353311 | 3 60  | 25           | 25           |
| 66623353310                                  | 66623353310 | 6 50  | 25           | 25           |
| 66623353306                                  | 66623353306 | 9 36  | 25           | 25           |
| 66623353309                                  | 66623353309 | 0 24  | 25           | 25           |
| <b>5" x 7/8" (F240)</b>                      |             |       |              |              |
| 66623357282                                  | 66623357282 | 2 120 | 25           | 25           |
| 66623357281                                  | 66623357281 | 5 100 | 25           | 25           |
| 66623357280                                  | 66623357280 | 8 80  | 25           | 25           |
| 66623357279                                  | 66623357279 | 2 60  | 25           | 25           |
| 66623357278                                  | 66623357278 | 5 50  | 25           | 25           |
| 66623357277                                  | 66623357277 | 8 36  | 25           | 25           |
| 66623357276                                  | 66623357276 | 1 24  | 25           | 25           |
| 05539510684                                  | 05539510684 | 4 16  | 25           | 25           |
| <b>7" x 7/8" (F240)</b>                      |             |       |              |              |
| 66623357289                                  | 66623357289 | 1 120 | 25           | 25           |
| 66623357288                                  | 66623357288 | 4 100 | 25           | 25           |
| 66623357287                                  | 66623357287 | 7 80  | 25           | 25           |
| 66623357286                                  | 66623357286 | 0 60  | 25           | 25           |
| 66623357285                                  | 66623357285 | 3 50  | 25           | 25           |
| 66623357284                                  | 66623357284 | 6 36  | 25           | 25           |
| 66623357283                                  | 66623357283 | 9 24  | 25           | 25           |
| 05539510693                                  | 05539510693 | 6 16  | 25           | 25           |

| PART #   | UPC-A       | GRIT | QTY/<br>PACK | QTY/<br>CASE |
|--|-------------|------|--------------|--------------|
| <b>Aluminum Oxide Fiber – Bulk – UPC Bar Coded</b> |             |      |              |              |
| <b>4-1/2" x 7/8" (F240)</b>                        |             |      |              |              |
| 07660702045  | 07660702045 | 1 80 | 25           | 25           |
| 07660768186  | 07660768186 | 7 60 | 25           | 25           |
| 07660702046  | 07660702046 | 8 50 | 25           | 25           |
| 07660702047  | 07660702047 | 5 36 | 25           | 25           |
| 07660702048  | 07660702048 | 2 24 | 25           | 25           |
| 07660768187  | 07660768187 | 4 16 | 25           | 25           |
| <b>5" x 7/8" (F240)</b>                            |             |      |              |              |
| 07660768188  | 07660768188 | 1 80 | 25           | 25           |
| 07660768189  | 07660768189 | 8 60 | 25           | 25           |
| 07660701909  | 07660701909 | 7 50 | 25           | 25           |
| 07660701910  | 07660701910 | 3 36 | 25           | 25           |
| 07660701911  | 07660701911 | 0 24 | 25           | 25           |
| 07660701915  | 07660701915 | 8 16 | 25           | 25           |
| <b>7" x 7/8" (F240)</b>                            |             |      |              |              |
| 07660768190  | 07660768190 | 4 80 | 25           | 25           |
| 07660701912  | 07660701912 | 7 50 | 25           | 25           |
| 07660701913  | 07660701913 | 4 36 | 25           | 25           |
| 07660701914  | 07660701914 | 1 24 | 25           | 25           |
| 07660701916  | 07660701916 | 5 16 | 25           | 25           |



## Rapid Strip

Non-woven depressed center discs have three components: strong synthetic fiber mesh and quality abrasives, bonded together by a smear-resistant adhesive.

Rapid Strip discs have an open web construction that enables aggressive cutting action while maintaining a cool, non-loading surface.

| PART #                                       | UPC-A       | GRADING  | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|----------|--------------|----------------|
| <b>Non-Woven – Drill Mount – Handy Packs</b> |             |          |              |                |
| <b>4" x 1/2"</b>                             |             |          |              |                |
| 07660702536                                  | 07660702536 | 4 Coarse | 1            | 5**            |
| 07660701217                                  | 07660701217 | 3 Coarse | 1            | 10**           |
| <b>4" x 1"</b>                               |             |          |              |                |
| 07660705466                                  | 07660701220 | 3 Coarse | 1            | 5**            |

| PART #  | UPC-A       | GRADING        | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|----------------|--------------|----------------|
| <b>Non-Woven – Depressed Center – Handy Packs</b> |             |                |              |                |
| <b>4-1/2" x 5/8-11 Hub</b>                        |             |                |              |                |
| 07660704015                                       | 07660704015 | 2 Extra Coarse | 1            | 5**            |
| <b>7" x 5/8"-11 Hub</b>                           |             |                |              |                |
| 07660704013                                       | 07660704013 | 8 Extra Coarse | 1            | 5**            |



### Quick-Change Disc

The tool-free, twist-on and off fastening systems of Norton quick-change discs make fast work of disc changes and maximize productivity by minimizing downtime.

**Fiber**

- Weld grinding
- Metal removal


**Non-Woven**

- Removing surface defects
- Blending mill marks, tool marks and uneven finishes

**Type TR (Type III)**

- Features a roll-on/roll-off style plastic fastener
- Equivalent to 3M™ Roloc™ fastening system

| PART #                        | UPC-A       | GRIT  | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|-------------------------------|-------------|-------|---------|--------------|----------------|
| <b>Fiber – Handy Packs</b>    |             |       |         |              |                |
| <b>2" Speed-Lok TR (F244)</b> |             |       |         |              |                |
| 07660702399                   | 07660702399 | 5 120 | Fine    | 5            | 10**           |
| 07660702400                   | 07660702400 | 8 50  | Medium  | 5            | 10**           |
| 07660702401                   | 07660702401 | 5 24  | Coarse  | 5            | 10**           |

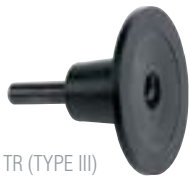

TR (TYPE III)

| PART #   | UPC-A       | GRIT  | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|-------|---------|--------------|----------------|
| <b>Back-up Pads – Handy Packs</b>                |             |       |         |              |                |
| <b>2" Drill Mount Back-up Pad</b>                |             |       |         |              |                |
| 07660702395                                      | 07660702395 | 7     |         | 1            | 10**           |
| <b>Non-Woven – Handy Packs</b>                   |             |       |         |              |                |
| <b>2" Speed-Lok TR</b>                           |             |       |         |              |                |
| 07660702396                                      | 07660702396 | 4 320 |         | 5            | 10**           |
| 07660702397                                      | 07660702397 | 1 120 |         | 5            | 10**           |
| 07660702398                                      | 07660702398 | 8 80  |         | 5            | 10**           |
| <b>3" Drill Mount Back-up Pad – Quick Change</b> |             |       |         |              |                |
| 07660702388                                      | 07660702388 | 9     |         | 1            | 10**           |
| <b>3" Speed-Lok TR</b>                           |             |       |         |              |                |
| 07660702389                                      | 07660702389 | 6 320 |         | 5            | 10**           |
| 07660702390                                      | 07660702390 | 2 120 |         | 5            | 10**           |
| 07660702391                                      | 07660702391 | 9 80  |         | 5            | 10**           |







## MultiSand – Detail / Profile

A wide variety of products for small, hard-to-reach areas that cannot be sanded with conventional power tools, such as random orbital sanders and belt sanders. Designed for profiles, moldings, and contoured surfaces.

### Grit Guide

|                                      |                                      |  |  |  |   |   |
|--------------------------------------|--------------------------------------|--|--|--|---|---|
| <b>60 COARSE</b><br>Moderate removal | <b>80 COARSE</b><br>Moderate removal | <b>100 MEDIUM</b><br>Moderate to light removal | <b>120 MEDIUM</b><br>Moderate to light removal | <b>150 MEDIUM</b><br>Moderate to light removal | <b>180 FINE</b><br>Fine surface preparation | <b>220 VERY FINE</b><br>Between coats sanding |
|--------------------------------------|--------------------------------------|--|--|--|---|---|

| PART #  | UPC-A                 | GRIT | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|------|-----------|--------------|----------------|
| <b>For Black &amp; Decker Sandstorm / Mega Mouse / Multi-Sander</b>   |                       |      |           |              |                |
| <b>4-3/16" x 6-3/4" Iron Shape Sheets, Hook and Loop, 8 Vac Holes</b> |                       |      |           |              |                |
| 07660701149   | 076607 <b>01149</b> 7 | P220 | Very Fine | 5            | 6**            |
| 07660701148   | 076607 <b>01148</b> 0 | P180 | Fine      | 5            | 6**            |
| 07660701147   | 076607 <b>01147</b> 3 | P120 | Medium    | 5            | 6**            |
| 07660701146   | 076607 <b>01146</b> 6 | P80  | Coarse    | 5            | 6**            |

| PART #  | UPC-A                 | GRIT | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|---|-----------------------|------|-----------|--------------|----------------|
| <b>For Corner Cat/Mouse</b>                             |                       |      |           |              |                |
| <b>3-7/8" x 5-1/2" Iron Shape Sheets, Hook and Loop</b> |                       |      |           |              |                |
| 07660702704   | 076607 <b>02704</b> 7 | P220 | Very Fine | 5            | 6**            |
| 07660702705   | 076607 <b>02705</b> 4 | P180 | Fine      | 5            | 6**            |
| 07660702706   | 076607 <b>02706</b> 1 | P120 | Medium    | 5            | 6**            |
| 07660702707   | 076607 <b>02707</b> 8 | P80  | Coarse    | 5            | 6**            |

| PART #   | UPC-A                 | GRIT | GRADING          | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|------|------------------|--------------|----------------|
| <b>For Black &amp; Decker / Craftsman Mouse Sander</b>   |                       |      |                  |              |                |
| <b>3" x 1-1/8" Detail Sanding Replaceable Fingertips</b> |                       |      |                  |              |                |
| 07660721602  | 076607 <b>21602</b> 1 |      | Asst. 5C, 5M, 5F | 15           | 6**            |
| <b>3" x 7" Iron Shape Sheets Hook and Loop</b>           |                       |      |                  |              |                |
| 07660702314  | 076607 <b>02314</b> 8 | P220 | Very Fine        | 5            | 6**            |
| 07660702315  | 076607 <b>02315</b> 5 | P180 | Fine             | 5            | 6**            |
| 07660702316  | 076607 <b>02316</b> 2 | P120 | Medium           | 5            | 6**            |
| 07660702317  | 076607 <b>02317</b> 9 | P80  | Coarse           | 5            | 6**            |
| 07660702318  | 076607 <b>02318</b> 6 |      | 2VF, 2F, 1M      | 5            | 6**            |





## Red Heat

Norton Red Heat belts utilize a premium ceramic alumina grain delivering a superior cut rate to anything on the market. This ceramic grain “micro-fractures” during the sanding process, leaving a razor sharp edge throughout the life of the belt. It’s symmetrically-shaped design leaves a much finer scratch pattern compared to other abrasives, allowing for an aggressive cut without deep scratches that might be seen after staining or finishing. Combine all of this with a heavy cotton backing and you have ultimate durability and longevity.



Scan the QR code to view our video



### Grit Guide

|                |                |                  |                 |
|----------------|----------------|------------------|-----------------|
| <b>36 GRIT</b> | <b>50 GRIT</b> | <b>60 GRIT</b>   | <b>120 GRIT</b> |
| Heavy Removal  | Heavy Removal  | Moderate Removal | Light Removal   |

### Features & Benefits

- Utilizes ceramic alumina abrasive for five times the product life over conventional abrasives on the hardest woods and finishes
- Symmetrical shape of the ceramic alumina grain allows the belt to cut aggressively while leaving a finer scratch on the surface which results in a superior finish and less time sanding
- The super-sharp micro-fracturing ceramic grain cuts cooler and resists loading which minimizes belt changes
- Heavy cotton backing is durable and tear resistant

| PART #   | UPC-A                 | GRIT | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|------|--------------|--------------|----------------|
| <b>Red Heat Benchstand Belts – Bulk – Non UPC Barcoded</b> |                       |      |              |              |                |
| <b>4" x 36" (Red Heat R955P)</b>                           |                       |      |              |              |                |
| 07660768122  | 076607 <b>68122</b> 5 | 120  | Fine         | 1            | 5              |
| 07660768123  | 076607 <b>68123</b> 2 | 80   | Medium       | 1            | 5              |
| 07660768124  | 076607 <b>68124</b> 9 | 50   | Coarse       | 1            | 5              |
| <b>6" x 48" (Red Heat R955P)</b>                           |                       |      |              |              |                |
| 07660768126  | 076607 <b>68126</b> 3 | 120  | Fine         | 1            | 10             |
| 07660768127  | 076607 <b>68127</b> 0 | 80   | Medium       | 1            | 10             |
| 07660768128  | 076607 <b>68128</b> 7 | 50   | Coarse       | 1            | 10             |
| 07660768129  | 076607 <b>68129</b> 4 | 36   | Extra Coarse | 1            | 10             |



## ProSand

Next generation Norton ProSand BlueFire Zirconia Alumina Portable Belts feature a self-sharpening abrasive design with an anti-static technology to remove material faster with less dust generated to deliver an attractive surface finish.




### Grit Guide

|                |                |                  |                 |
|----------------|----------------|------------------|-----------------|
| <b>36 GRIT</b> | <b>50 GRIT</b> | <b>60 GRIT</b>   | <b>120 GRIT</b> |
| Heavy Removal  | Heavy Removal  | Moderate Removal | Light Removal   |

| PART #   | UPC-A                 | GRIT | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|------|--------------|--------------|----------------|
| <b>ProSand BlueFire Portable Belts – Handy Packs</b> |                       |      |              |              |                |
| <b>3" x 18"</b>                                      |                       |      |              |              |                |
| 07660702229  | 076607 <b>49600</b> 3 | P120 | Fine         | 2            | 5**            |
| 07660702230  | 076607 <b>49602</b> 7 | P80  | Medium       | 2            | 5**            |
| 07660702231  | 076607 <b>49604</b> 1 | P50  | Coarse       | 2            | 5**            |
| <b>3" x 21"</b>                                      |                       |      |              |              |                |
| 07660702225  | 076607 <b>49610</b> 2 | P120 | Fine         | 2            | 5**            |
| 07660702226  | 076607 <b>49611</b> 9 | P80  | Medium       | 2            | 5**            |
| 07660702227  | 076607 <b>49612</b> 6 | P50  | Coarse       | 2            | 5**            |
| 07660702228  | 076607 <b>49613</b> 3 | P36  | Extra Coarse | 2            | 5**            |
| <b>3" x 24"</b>                                      |                       |      |              |              |                |
| 07660768231  | 076607 <b>68231</b> 4 | P120 | Fine         | 2            | 5**            |
| 07660768232  | 076607 <b>68232</b> 1 | P80  | Medium       | 2            | 5**            |
| 07660768233  | 076607 <b>68233</b> 8 | P50  | Coarse       | 2            | 5**            |
| 07660768234  | 076607 <b>68234</b> 5 | P36  | Extra Coarse | 2            | 5**            |
| <b>4" x 24"</b>                                      |                       |      |              |              |                |
| 07660768235  | 076607 <b>68235</b> 2 | P120 | Fine         | 2            | 5**            |
| 07660705472  | 076607 <b>05472</b> 2 | P80  | Medium       | 2            | 5**            |
| 07660705473  | 076607 <b>05473</b> 9 | P50  | Coarse       | 2            | 5**            |
| 07660705474  | 076607 <b>05474</b> 6 | P36  | Extra Coarse | 2            | 5**            |

| PART #   | UPC-A                 | GRIT  | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|--|-----------------------|-------|--------------|--------------|----------------|
| <b>ProSand BlueFire Portable Belts – Job Packs</b> |                       |       |              |              |                |
| <b>3" x 18"</b>                                    |                       |       |              |              |                |
| 07660749256  | 076607 <b>49256</b> 2 | P120  | Fine         | 5            | 5**            |
| 07660749258  | 076607 <b>49258</b> 6 | P80   | Medium       | 5            | 5**            |
| 07660749259  | 076607 <b>49259</b> 3 | P50   | Coarse       | 5            | 5**            |
| <b>3" x 21"</b>                                    |                       |       |              |              |                |
| 07660749262  | 076607 <b>49262</b> 3 | P120  | Very Fine    | 5            | 5**            |
| 07660749264  | 076607 <b>49264</b> 7 | P80   | Medium       | 5            | 5**            |
| 07660749265  | 076607 <b>49265</b> 4 | P50   | Coarse       | 5            | 5**            |
| 07660749266  | 076607 <b>49266</b> 1 | P36   | Extra Coarse | 5            | 5**            |
| <b>3" x 24"</b>                                    |                       |       |              |              |                |
| 07660749268  | 076607 <b>49268</b> 5 | P120  | Very Fine    | 5            | 5**            |
| 07660749270  | 076607 <b>49270</b> 8 | P80   | Medium       | 5            | 5**            |
| 07660749271  | 076607 <b>49271</b> 5 | P50   | Coarse       | 5            | 5**            |
| 07660749272  | 076607 <b>49272</b> 2 | P36   | Extra Coarse | 5            | 5**            |
| <b>4" x 24"</b>                                    |                       |       |              |              |                |
| 07660749274  | 076607 <b>49274</b> 6 | P120  | Very Fine    | 5            | 5**            |
| 07660749276  | 076607 <b>49276</b> 0 | P80   | Medium       | 5            | 5**            |
| 07660749277  | 076607 <b>49277</b> 7 | P50   | Coarse       | 5            | 5**            |
| 07660749278  | 076607 <b>49278</b> 4 | P36   | Extra Coarse | 5            | 5**            |
| <b>Belt Cleaning Stick – Handy Packs</b>           |                       |       |              |              |                |
| <b>6" x 1-3/8" x 1-3/8"</b>                        |                       |       |              |              |                |
| 07660701717  | 076607 <b>01717</b> 8 | Stick |              | 1            | 10**           |

**STOCK REMOVAL IN GRAMS OVER 6 MINUTES OF SANDING**  
ON HARD MAPLE ON BELT SANDER

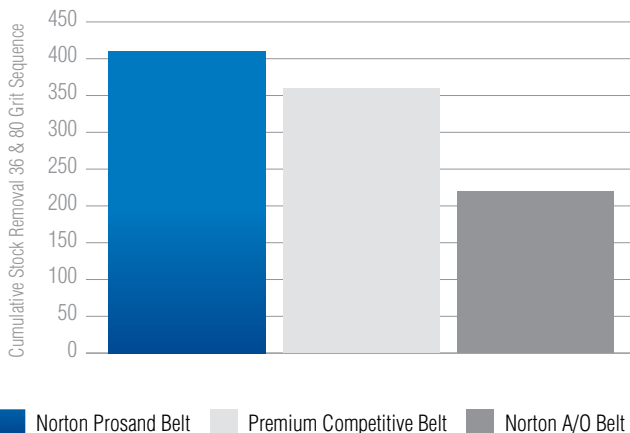



## MultiSand – Aluminum Oxide Portable / Benchstand Belts

MultiSand Aluminum Oxide Portable and Benchstand Belts are ideal for all your metal and woodworking applications. Found in a wide variety of grits and sizes they can be used for tackling the following projects:

- Heavy stock removal
- Finish sanding
- Deburring of steel
- Polishing
- Dimensioning and shaping
- Removing saw marks

### Grit Guide

|                                 |                                 |                                 |                                    |                                  |                                  |                                  |                                       |
|---------------------------------|---------------------------------|---------------------------------|------------------------------------|----------------------------------|----------------------------------|----------------------------------|---------------------------------------|
| <b>36 GRIT</b><br>Heavy Removal | <b>40 GRIT</b><br>Heavy Removal | <b>50 GRIT</b><br>Heavy Removal | <b>80 GRIT</b><br>Moderate Removal | <b>100 GRIT</b><br>Light Removal | <b>120 GRIT</b><br>Light Removal | <b>180 GRIT</b><br>Light Removal | <b>220 GRIT</b><br>Very Light Removal |
|---------------------------------|---------------------------------|---------------------------------|------------------------------------|----------------------------------|----------------------------------|----------------------------------|---------------------------------------|

| PART #   | UPC-A       | GRIT  | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|-------|--------------|--------------|----------------|
| <b>MultiSand Aluminum Oxide Portable Belts – Handy Packs</b> |             |       |              |              |                |
| <b>3" x 18" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660702244  | 07660748430 | 7 120 | Fine         | 2            | 5**            |
| 07660702245  | 07660748450 | 5 80  | Medium       | 2            | 5**            |
| 07660702246  | 07660748465 | 9 50  | Coarse       | 2            | 5**            |
| <b>3" x 21" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660702240  | 07660748490 | 1 120 | Fine         | 2            | 5**            |
| 07660702241  | 07660748505 | 2 80  | Medium       | 2            | 5**            |
| 07660702242  | 07660748520 | 5 50  | Coarse       | 2            | 5**            |
| 07660702243  | 07660748521 | 2 36  | Extra Coarse | 2            | 5**            |
| <b>3" x 24" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660702236  | 07660748600 | 4 120 | Fine         | 2            | 5**            |
| 07660702237  | 07660748620 | 2 80  | Medium       | 2            | 5**            |
| 07660702238  | 07660748630 | 1 50  | Coarse       | 2            | 5**            |
| 07660702239  | 07660748631 | 8 36  | Extra Coarse | 2            | 5**            |
| <b>4" x 24" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660702233  | 07660748710 | 0 120 | Fine         | 2            | 5**            |
| 07660702234  | 07660748725 | 4 80  | Medium       | 2            | 5**            |
| 07660702235  | 07660748740 | 7 50  | Coarse       | 2            | 5**            |
| <b>MultiSand Aluminum Oxide Portable Belts – Job Packs</b>   |             |       |              |              |                |
| <b>3" x 18" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660700969  | 07660700969 | 2 120 | Very Fine    | 5            | 5**            |
| 07660700968  | 07660700968 | 5 80  | Medium       | 5            | 5**            |
| 07660700964  | 07660700964 | 7 50  | Coarse       | 5            | 5**            |
| <b>3" x 21" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660705287  | 07660705287 | 2 220 | Extra Fine   | 5            | 5**            |
| 07660702062  | 07660702062 | 8 120 | Very Fine    | 5            | 5**            |
| 07660702064  | 07660702064 | 2 80  | Medium       | 5            | 5**            |
| 07660701740  | 07660701740 | 6 50  | Coarse       | 5            | 5**            |
| 07660701741  | 07660701741 | 3 36  | Extra Coarse | 5            | 5**            |
| <b>3" x 24" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660702065  | 07660702065 | 9 120 | Very Fine    | 5            | 5**            |
| 07660702066  | 07660702066 | 6 100 | Fine         | 5            | 5**            |
| 07660702067  | 07660702067 | 3 80  | Medium       | 5            | 5**            |
| 07660701742  | 07660701742 | 0 50  | Coarse       | 5            | 5**            |
| 07660701743  | 07660701743 | 7 36  | Extra Coarse | 5            | 5**            |
| <b>4" x 24" (R215, R255)</b>                                 |             |       |              |              |                |
| 07660705285  | 07660705285 | 8 180 | Ex Fine      | 5            | 5**            |
| 07660702068  | 07660702068 | 0 120 | Very Fine    | 5            | 5**            |
| 07660702069  | 07660702069 | 7 80  | Medium       | 5            | 5**            |
| 07660701744  | 07660701744 | 4 50  | Coarse       | 5            | 5**            |
| 07660701745  | 07660701745 | 1 36  | Extra Coarse | 5            | 5**            |

| PART #  | UPC-A       | GRIT  | GRADING      | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|-------|--------------|--------------|----------------|
| <b>MultiSand Aluminum Oxide Portable Belts – Bulk – UPC Bar Coded</b> |             |       |              |              |                |
| <b>2-1/2" x 16" (R215, R255)</b>                                      |             |       |              |              |                |
| 78072780448   | 78072780448 | 7 120 | Fine         | 10           | 50             |
| 78072780449   | 78072780449 | 4 80  | Medium       | 10           | 50             |
| 78072780450   | 78072780450 | 0 50  | Coarse       | 10           | 50             |
| 78072780451   | 78072780451 | 7 36  | Extra Coarse | 5            | 25             |
| <b>3" x 18" (R215, R255)</b>  |             |       |              |              |                |
| 78072727992   | 78072727992 | 6 120 | Fine         | 10           | 50             |
| 78072727993   | 78072727993 | 3 80  | Medium       | 10           | 50             |
| 78072727994   | 78072727994 | 0 50  | Coarse       | 10           | 50             |
| 78072780447   | 78072780447 | 0 36  | Extra Coarse | 5            | 25             |
| <b>3" x 21" (R215, R255)</b>  |             |       |              |              |                |
| 78072727922   | 78072727922 | 3 120 | Fine         | 10           | 50             |
| 78072727923   | 78072727923 | 0 100 | Medium       | 10           | 50             |
| 78072727924   | 78072727924 | 7 80  | Medium       | 10           | 50             |
| 78072727925   | 78072727925 | 4 60  | Coarse       | 10           | 50             |
| 78072727926   | 78072727926 | 1 50  | Coarse       | 10           | 50             |
| 78072727927   | 78072727927 | 8 40  | Extra Coarse | 10           | 50             |
| 78072781846   | 78072781846 | 3 36  | Extra Coarse | 5            | 25             |
| <b>3" x 24" (R215, R255)</b>  |             |       |              |              |                |
| 78072727932   | 78072727932 | 2 120 | Fine         | 10           | 50             |
| 78072727933   | 78072727933 | 9 100 | Medium       | 10           | 50             |
| 78072727934   | 78072727934 | 6 80  | Medium       | 10           | 50             |
| 78072727935   | 78072727935 | 3 60  | Coarse       | 10           | 50             |
| 78072727936   | 78072727936 | 0 50  | Coarse       | 10           | 50             |
| 78072727937   | 78072727937 | 7 40  | Extra Coarse | 10           | 50             |
| 78072781847   | 78072781847 | 7 36  | Extra Coarse | 5            | 25             |
| <b>4" x 21-3/4" (R215, R255)</b>                                      |             |       |              |              |                |
| 78072780440   | 78072780440 | 1 80  | Medium       | 10           | 50             |
| <b>4" x 24" (R215, R255)</b>  |             |       |              |              |                |
| 78072727942   | 78072727942 | 1 120 | Fine         | 10           | 50             |
| 78072727943   | 78072727943 | 8 100 | Medium       | 10           | 50             |
| 78072727944   | 78072727944 | 5 80  | Medium       | 10           | 50             |
| 78072727945   | 78072727945 | 2 60  | Coarse       | 10           | 50             |
| 78072727946   | 78072727946 | 9 50  | Coarse       | 10           | 50             |
| 78072727947   | 78072727947 | 6 40  | Extra Coarse | 10           | 50             |
| 78072780438   | 78072780438 | 8 36  | Extra Coarse | 5            | 25             |

## MultiSand – Aluminum Oxide Portable / Benchstand Belts

| PART #   | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |      |
|--|-------------|------|---------|--------------|----------------|------|
| <b>MultiSand Aluminum Oxide Benchstand Belts – Handy Packs</b> |             |      |         |              |                |      |
| <b>1" x 42" (R215, R255)</b>                                   |             |      |         |              |                |      |
| 07660701966  | 07660701966 | 0    | Asst.   | 1F, 1M, 1C   | 3              | 10** |
| <b>4" x 36" (R215, R255)</b>                                   |             |      |         |              |                |      |
| 07660748665  | 07660748665 | 3    | 220X    | Very Fine    | 1              | 6**  |
| 07660748660  | 07660748660 | 8    | 120     | Fine         | 1              | 6**  |
| 07660748675  | 07660748675 | 2    | 80      | Medium       | 1              | 6**  |
| 07660748690  | 07660748690 | 5    | 50      | Coarse       | 1              | 6**  |
| <b>6" x 48" (R215, R255)</b>                                   |             |      |         |              |                |      |
| 07660705282  | 07660705282 | 7    | 220     | Very Fine    | 1              | 10** |
| 07660701722  | 07660701722 | 2    | 120     | Fine         | 1              | 10** |
| 07660705279  | 07660705279 | 7    | 100     | Medium       | 1              | 10** |
| 07660701721  | 07660701721 | 5    | 80      | Medium       | 1              | 10** |
| 07660701720  | 07660701720 | 8    | 50      | Coarse       | 1              | 10** |

| PART #  | UPC-A       | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |     |
|---|-------------|------|---------|--------------|----------------|-----|
| <b>MultiSand Aluminum Oxide Benchstand Belts – Bulk – UPC Bar Coded</b> |             |      |         |              |                |     |
| <b>4" x 36" (R215, R255)</b>  |             |      |         |              |                |     |
| 78072727957   | 78072727957 | 5    | 120X    | Fine         | 10             | 50  |
| 78072727958   | 78072727958 | 2    | 100X    | Medium       | 10             | 50  |
| 78072727959   | 78072727959 | 9    | 80X     | Medium       | 10             | 50  |
| 78072727960   | 78072727960 | 5    | 60X     | Coarse       | 10             | 50  |
| 78072727961   | 78072727961 | 2    | 50X     | Coarse       | 10             | 50  |
| 78072727962   | 78072727962 | 9    | 40X     | Extra Coarse | 10             | 50  |
| 78072727963   | 78072727963 | 6    | 36X     | Extra Coarse | 10             | 50  |
| <b>6" x 48" (R215, R255)</b>  |             |      |         |              |                |     |
| 78072727981   | 78072727981 | 0    | 120X    | Fine         | 10             | 20  |
| 78072727982   | 78072727982 | 7    | 100X    | Medium       | 10             | 20  |
| 78072727983   | 78072727983 | 4    | 80X     | Medium       | 10             | 20  |
| 78072727984   | 78072727984 | 1    | 60X     | Coarse       | 10             | 20  |
| 78072727985   | 78072727985 | 8    | 50X     | Coarse       | 10             | 20  |
| 78072727986   | 78072727986 | 5    | 40X     | Extra Coarse | 10             | 20  |
| 78072727987   | 78072727987 | 2    | 36X     | Extra Coarse | 10             | 20  |
| <b>MultiSand Aluminum Oxide Benchstand Belts – Bulk – Non UPC</b>       |             |      |         |              |                |     |
| <b>1" x 42" (R215, R255)</b>  |             |      |         |              |                |     |
| 78072720875   | 78072720875 | 9    | 180X    | Very Fine    | 50             | 200 |
| 78072720885   | 78072720885 | 8    | 120X    | Fine         | 50             | 200 |
| 78072720890   | 78072720890 | 2    | 100X    | Medium       | 50             | 200 |
| 78072720895   | 78072720895 | 7    | 80X     | Medium       | 50             | 200 |
| 78072720900   | 78072720900 | 8    | 60X     | Coarse       | 50             | 200 |
| 78072720905   | 78072720905 | 3    | 50X     | Coarse       | 50             | 200 |
| 78072720910   | 78072720910 | 7    | 40X     | Extra Coarse | 50             | 200 |






## Blades/Cups/Specialty


Norton Clipper Diamond Blades are the choice of professionals because of their faster cut rate, constant depth of cut and less downtime versus standard abrasives blades. Choose Norton Clipper Charger for maximum productivity, longest life and lowest total cost. Choose Norton Clipper Classic for high productivity. Choose Norton Clipper ValuPlus for quality and value.

Photo not intended for instruction. Always comply with OSHA and ANSI B7.1. For more info visit our website.

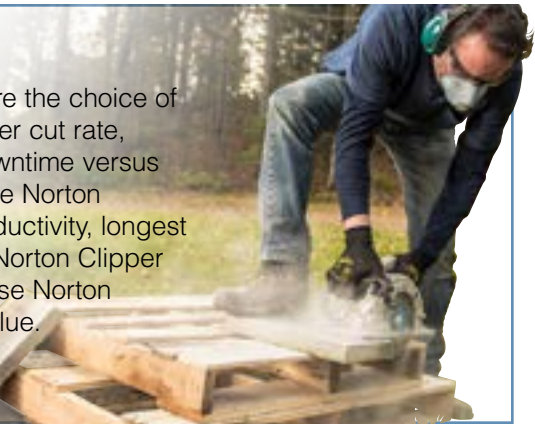

### Segmented Rim

- Most aggressive cutting action for use on the widest variety of materials.
- Typically used on high speed, walk-behind and masonry saw blades.

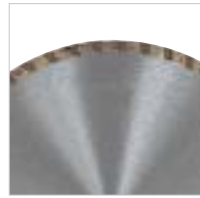


### Turbo Rim

- Aggressive cutting action with a smoother quality cut.
- For use on harder materials such as granite, marble and stone, to reduce chipping.



### Continuous Rim

- Provides the smoothest cut.
- For use on porcelain, ceramic tile, marble and other hard materials requiring a high quality cut.

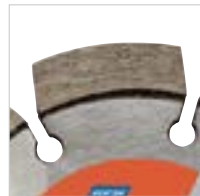

### Tuck Pointing

- Economical for small to medium tuck pointing jobs. High quality performance for heavy grout removal or mortar jointing.
- Heavy duty wide segment reduces wear in abrasive materials.

| PART #  | UPC-A       | SIZE                           | MAX RPM | QTY/ PKG |
|---|-------------|--------------------------------|---------|----------|
| <b>Norton Clipper Charger High-Performance Blades</b>       |             |                                |         |          |
| <b>Continuous Rim - Turbo</b>                               |             |                                |         |          |
| 07660705475   | 07660705475 | 4" x .080" x 7/8"-5/8-20mm     | 15000   | 1        |
| 07660704023   | 07660704023 | 4-1/2" x .080" x 7/8"-5/8-20mm | 13300   | 1        |
| 07660704022   | 07660704022 | 7" x .090" x DM-7/8-5/8        | 8370    | 1        |
| <b>Norton Clipper Classic General-Purpose Blades</b>        |             |                                |         |          |
| <b>Combination Pack</b>                                     |             |                                |         |          |
| 07660705344   | 07660705344 | 4-1/2" x .080" x 7/8"-5/8-20mm | 13300   | 5        |
| <b>Continuous Rim - Turbo</b>                               |             |                                |         |          |
| 07660704018   | 07660704018 | 4" x .080" x 7/8"-5/8-20mm     | 15000   | 5 (bulk) |
| 07660702792   | 07660702792 | 4" x .080" x 7/8"-5/8-20mm     | 5000    | 1        |
| 07660704017   | 07660704017 | 4-1/2" x .080" x 7/8"-5/8-20mm | 13300   | 5 (bulk) |
| 07660702790   | 07660702790 | 4-1/2" x .080" x 7/8"-5/8-20mm | 13300   | 1        |
| 07660704016   | 07660704016 | 9" x .090" x DM-7/8-5/8        | 8370    | 5 (bulk) |
| 07660702787   | 07660702787 | 7" x .090" x DM-7/8-5/8        | 8370    | 1        |
| 07660702780   | 07660702780 | 10" x .100" x 1-7/8"-5/8       | 6115    | 1        |
| <b>Segmented Rim</b>  |             |                                |         |          |
| 07660702791   | 07660702791 | 7" x .080" x 7/8"-5/8-20mm     | 15000   | 1        |
| 07660702789   | 07660702789 | 4-1/2" x .080" x 7/8"-5/8-20mm | 13300   | 1        |
| 70184684463   | 70184684463 | 4-1/2" x .080" x 7/8"-5/8-20mm | 13300   | 5 (bulk) |
| 07660702786   | 07660702786 | 7" x .090" x DM-7/8-5/8        | 8370    | 1        |
| 70184684464   | 70184684464 | 2 7" x .090" x DM-7/8-5/8      | 8370    | 5 (bulk) |
| 07660701201   | 07660701201 | 2 10" x .100" x 1-7/8"-5/8     | 6115    | 1        |
| 70184681383   | 70184681383 | 9 12" x .110" x 1/20"mm        | 6300    | 1        |
| 70184681309   | 70184681309 | 9 14" x .110" x 1/20"mm        | 5460    | 1        |
| 07660701230   | 07660701230 | 2 16" x .125" x 1/20"mm        | 4500    | 1        |
| <b>Cup Wheels - Single Row For Fast Stock Removal</b>       |             |                                |         |          |
| 70184682555   | 70184682555 | 9 4" x 5/8"-11                 | 15000   | 1        |
| 70184682593   | 70184682593 | 5 7" x 5/8"-11                 | 8370    | 1        |
| <b>Cup Wheels - Double Row For Long Life, Smooth Finish</b> |             |                                |         |          |
| 70184682586   | 70184682586 | 3 4" x 5/8"-11                 | 15000   | 1        |
| 70184682595   | 70184682595 | 5 7" x 5/8"-11                 | 8370    | 1        |

| PART #  | UPC-A       | SIZE                               | MAX RPM | QTY/ PKG |
|---|-------------|------------------------------------|---------|----------|
| <b>Norton Clipper Classic General-Purpose Blades</b>      |             |                                    |         |          |
| <b>Wet/Dry Cutting Continuous Rim</b>                     |             |                                    |         |          |
| 07660702793   | 07660702793 | 4" x .080" x 7/8"-5/8-20mm         | 15000   | 1        |
| 07660701194   | 07660701194 | 4-1/2" x .080" x 7/8"-5/8-20mm     | 13300   | 1        |
| 07660702788   | 07660702788 | 7" x .090" x DM-7/8-5/8            | 8370    | 1        |
| 07660702785   | 07660702785 | 6 8" x .070" x 5/8"                | 7640    | 1        |
| 07660702784   | 07660702784 | 9 10" x .070" x 5/8"               | 6115    | 1        |
| <b>Norton Clipper ValuPlus General-Purpose Blades</b>     |             |                                    |         |          |
| <b>Continuous Rim</b>                                     |             |                                    |         |          |
| 70184684087   | 70184684087 | 3 4" x .080" x 7/8"-5/8-20mm       | 15000   | 1        |
| 70184684088   | 70184684088 | 0 4-1/2" x .080" x 7/8"-5/8-20mm   | 13300   | 1        |
| 70184684089   | 70184684089 | 7 7" x .090" x DM-7/8-5/8          | 8370    | 1        |
| <b>Turbo Rim</b>  |             |                                    |         |          |
| 70184684105   | 70184684105 | 4 4" x .080" x 7/8", 5/8, 20mm     | 15000   | 1        |
| 70184684106   | 70184684106 | 1 4-1/2" x .086" x 7/8", 5/8, 20mm | 3300    | 1        |
| 70184684107   | 70184684107 | 8 7" x .090" x DM, 7/8, 5/8        | 8370    | 1        |
| <b>Segmented Rim</b>                                      |             |                                    |         |          |
| 70184684098   | 70184684098 | 9 4" x .080" x 7/8"-5/8-20mm       | 15000   | 1        |
| 70184684099   | 70184684099 | 6 4-1/2" x .080" x 7/8"-5/8-20mm   | 13300   | 1        |
| 70184684100   | 70184684100 | 9 7" x .090" x DM-7/8-5/8          | 8370    | 1        |
| <b>Specialty</b>  |             |                                    |         |          |
| <b>Norton Clipper DUO - High Speed General-Purpose</b>    |             |                                    |         |          |
| 70184683611   | 70184683611 | 1 12" x .110" x 1"/20mm            | 6300    | 1        |
| 70184683612   | 70184683612 | 8 14" x .110" x 1"/20mm            | 5460    | 1        |
| <b>Norton Clipper 4x4 MaxCut</b>                          |             |                                    |         |          |
| 70184645927   | 70184645927 | 3 12" x .118" x 1"/20mm            | 6300    | 1        |
| 70184645926   | 70184645926 | 6 14" x .125" x 1"/20mm            | 5460    | 1        |
| <b>Norton Clipper Rescue/Demolition</b>                   |             |                                    |         |          |
| 70184684361   | 70184684361 | 4 14" x .140" x 1"/20mm            | 5460    | 1        |
| <b>Norton Clipper Slicer - Flush Cut- Dry - Turbo Rim</b> |             |                                    |         |          |
| 70184684546   | 70184684546 | 5 4-1/2" x .040" x 7/8"            | 13300   | 1        |
| 70184684545   | 70184684545 | 8 5" x .040" x 7/8"                | 12000   | 1        |
| <b>Tuck Pointing</b>                                      |             |                                    |         |          |
| 70184684020   | 70184684020 | 0 4" x .250" x 7/8"-5/8            | 15000   | 1        |
| 70184681779   | 70184681779 | 0 7" x .250" x 7/8"-5/8-20mm       | 8370    | 1        |

## Right Angle Grinder Cut-Off

The Norton offering of thin, unique cut-off blades delivers a full range of sizes and thicknesses for high-demand applications like cutting and cleaning metal studs, masonry stainless steel, tubing and sheet metal.



### Features & Benefits

- Fastest cutting wheels in the market
- Will deliver a fast cut with longer life without added operator pressure
- Reinforced to tackle tough portable and fixed-base cut-off applications

### SPEC CHECK

#### Metal

Steel, Stainless, Iron, Sheet metal

#### Masonry

Concrete, Brick, Cinder block, Patio stones

#### Aluminum

Aluminum, Bronze, Copper

| PART #  | UPC-A           | SIZE                     | MAX RPM | W/LS/<br>CASE |
|---|-----------------|--------------------------|---------|---------------|
| <b>Right Angle Cut-off Blades (Type 01/41) – Bulk – UPC Bar Coded</b>   |                 |                          |         |               |
| <b>Metal – Aluminum Oxide</b>   |                 |                          |         |               |
| 07660701616   | 07660701616     | 4" x .040" x 5/8"        | 15280   | 25            |
| 07660701617   | 07660701617     | 4-1/2" x .040" x 7/8"    | 13580   | 25            |
| 07660701618   | 07660701618     | 5" x .040" x 7/8"        | 12225   | 25            |
| 07660702757   | 07660702757     | 6" x .040" x 7/8"        | 10185   | 25            |
| <b>Masonry – Silicon Carbide</b>  |                 |                          |         |               |
| 07660701620   | 07660701620     | 4" x 1/16" x 5/8"        | 15280   | 15            |
| 07660701621   | 07660701621     | 4-1/2" x 1/16" x 7/8"    | 13580   | 15            |
| 07660701622   | 07660701622     | 5" x 1/16" x 7/8"        | 12225   | 25            |
| <b>Metal – Gemini Aluminum Oxide</b>                                    |                 |                          |         |               |
| 66243527956   | 66243527956     | 4" x .040" x 5/8"        | 15280   | 25            |
| 66252823602   | 66252823602     | 4-1/2" x .045" x 7/8"    | 13580   | 25            |
| 66252823603   | 66252823603     | 5" x .045" x 7/8"        | 12225   | 25            |
| 66252823604   | 66252823604     | 6" x .045" x 7/8"        | 10185   | 25            |
| 66243527955   | 66243527955     | 4" x 3/32" x 5/8"        | 15280   | 25            |
| 66252823599   | 66252823599     | 4-1/2" x 3/32" x 7/8"    | 13580   | 25            |
| 66252823600   | 66252823600     | 5" x 3/32" x 7/8"        | 12225   | 25            |
| 66252823601   | 66252823601     | 6" x 3/32" x 7/8"        | 10185   | 25            |
| <b>Metal – BlueFire Zirconia Alumina/Aluminum Oxide</b>                 |                 |                          |         |               |
| 66252843208   | 66252843208     | 4-1/2" x 1/16" x 7/8"    | 13580   | 25            |
| 66252843209   | 66252843209     | 5" x 1/16" x 7/8"        | 12225   | 25            |
| 66252843210   | 66252843210     | 6" x 1/16" x 7/8"        | 10185   | 25            |
| <b>Right Angle Cut-off Blades (Type 01/41) – Job Packs (Pole Packs)</b> |                 |                          |         |               |
| <b>Metal – Aluminum Oxide</b>   |                 |                          |         |               |
| 07660703987   | 07660703987     | 4" x .040" x 5/8"        | 15280   | 5/20          |
| 07660703988   | 07660703988     | 4-1/2" x .040" x 7/8"    | 13580   | 5/20          |
| <b>Right Angle Cut-off Blades (Type 27/42) – Bulk – UPC Bar Coded</b>   |                 |                          |         |               |
| <b>Metal – Aluminum Oxide</b>   |                 |                          |         |               |
| 07660705249   | 07660705249     | 4" x .045" x 5/8"        | 15280   | 25            |
| 66252843604   | 66252843604     | 4-1/2" x .045" x 7/8"    | 13580   | 25            |
| 66252842015   | 66252842015     | 6" x .045" x 7/8"        | 10185   | 25            |
| 07660705251   | MTO 07660705251 | 7" x 1/16" x 7/8"        | 8600    | 10            |
| <b>Metal – Gemini Aluminum Oxide</b>                                    |                 |                          |         |               |
| 66252842180   | 66252842180     | 4" x .045" x 5/8"        | 15280   | 25            |
| 66252842026   | 66252842026     | 4-1/2" x .045" x 7/8"    | 13580   | 25            |
| 66252842025   | 66252842025     | 4-1/2" x .045" x 5/8"-11 | 13580   | 10            |
| 66252842036   | 66252842036     | 5" x .045" x 7/8"        | 12225   | 25            |
| 66252841939   | 66252841939     | 5" x .045" x 5/8"-11     | 12225   | 10            |
| 66252842202   | 66252842202     | 6" x .045" x 7/8"        | 10185   | 25            |
| 66252830587   | 66252830587     | 6" x .045" x 5/8"-11     | 10185   | 10            |
| 66252912626   | 66252912626     | 7" x 1/16" x 7/8"        | 8600    | 20            |

MTO - Make to Order



## Depressed Center Wheels

The depressed center design allows the flange/lock nut to recess within the wheel so that it can be used for various grinding and cutting applications. Depressed center wheels are designed to handle the most severe right angle grinding applications, from heavy stock removal to rough blending. Depressed center wheels may also be referred to as raised hub wheels or by their shape designation of "Type," with Type 27 being the most popular.

### 1/4" are designed for grinding:

- offhand stock removal of all types of metal and masonry
- smoothing welds
- pipe beveling

### 1/8" are designed to be used for both light grinding or cutting:

- offhand cut-off of all metal and masonry materials
- notching or cleaning pipes and weld beads

### .125" are designed to be used at a 90° angle for cutting only



### Professionals Want Choices

Norton NorZon Plus is the highest performance line in the industry. Invented and made in America, now improved and expanded.



### Performance on Fire

Engineered with a proprietary NorZon grain upgrade, the Norton BlueFire design offers faster removal rate, longer product life and increased productivity for better performance value.



### The Right Choice Every Time

The re-engineered Norton Gemini RightCut 100% aluminum oxide wheels provide thinner, faster cutting with a burr-free, precision cut and improved operator comfort.

| PART #  | UPC-A       | SIZE                             | MAX RPM | WHLs/ CASE |
|---|-------------|----------------------------------|---------|------------|
| <b>Accessory For Right Angle Grinders – Handy Packs</b>         |             |                                  |         |            |
| <b>Adaptor Kit</b>  |             |                                  |         |            |
| 07660789275   | 07660789275 | 1 Adaptor kit for 7" & 9" wheels | N/A     | 1          |
| <b>Depressed Center Wheels (Type 27) - Bulk - UPC Bar Coded</b> |             |                                  |         |            |
| <b>Metal – NorZon Plus, For Grinding</b>                        |             |                                  |         |            |
| 66252842178   | 66252842178 | 3" x 1/4" x 3/8"                 | 18000   | 25         |
| 66252843328   | 66252843328 | 4-1/2" x 1/4" x 7/8"             | 13580   | 25         |
| 66252843326   | 66252843326 | 4-1/2" x 1/4" x 5/8"-11          | 13580   | 10         |
| 66252843334   | 66252843334 | 5" x 1/4" x 7/8"                 | 12225   | 25         |
| 66252843332   | 66252843332 | 5" x 1/4" x 5/8"-11              | 12225   | 10         |
| 66252809376   | 66252809376 | 6" x 1/4" x 7/8"                 | 10185   | 20         |
| 66252917880   | 66252917880 | 7" x 1/4" x 7/8"                 | 8600    | 20         |
| 66252917881   | 66252917881 | 7" x 1/4" x 5/8"-11              | 8600    | 10         |
| 66253021633   | 66253021633 | 9" x 1/4" x 7/8"                 | 6600    | 20         |
| 66253021634   | 66253021634 | 9" x 1/4" x 5/8"-11              | 6600    | 10         |

| PART #   | UPC-A       | SIZE                     | MAX RPM | WHLs/ CASE |
|--|-------------|--------------------------|---------|------------|
| <b>Depressed Center Wheels (Type 27) – Bulk – UPC Bar Coded</b>    |             |                          |         |            |
| <b>Metal – NorZon Plus, For Light Grinding and Cutting</b>         |             |                          |         |            |
| 66252842177  | 66252842177 | 3" x 1/8" x 3/8"         | 18000   | 25         |
| 66252842004  | 66252842004 | 4" x 1/8" x 3/8"         | 15280   | 25         |
| 66252842005  | 66252842005 | 4" x 1/8" x 5/8"         | 15280   | 25         |
| 66252843324  | 66252843324 | 4-1/2" x 1/8" x 7/8"     | 13580   | 25         |
| 66252843323  | 66252843323 | 4-1/2" x 1/8" x 5/8"-11  | 13580   | 10         |
| 66252843331  | 66252843331 | 5" x 1/8" x 7/8"         | 12225   | 25         |
| 66252938854  | 66252938854 | 7" x 1/8" x 7/8"         | 8600    | 20         |
| 66252938855  | 66252938855 | 7" x 1/8" x 5/8"-11      | 8600    | 10         |
| 66253048896  | 66253048896 | 9" x 1/8" x 7/8"         | 6600    | 20         |
| 66253048897  | 66253048897 | 9" x 1/8" x 5/8"-11      | 6600    | 10         |
| <b>Metal – NorZon Plus, For Pipe Notching</b>                      |             |                          |         |            |
| 66252939184  | 66252939184 | 7" x 1/8" x 5/8"-11      | 8600    | 10         |
| 66253049066  | 66253049066 | 9" x 1/8" x 5/8"-11      | 6600    | 10         |
| <b>Depressed Center Wheels (Type 27/42) - Bulk - UPC Bar Coded</b> |             |                          |         |            |
| <b>Metal – NorZon Plus, For Cutting Only</b>                       |             |                          |         |            |
| 66252842001  | 66252842001 | 4" x .125" x 3/8"        | 15280   | 25         |
| 66252843322  | 66252843322 | 4-1/2" x .125" x 7/8"    | 13580   | 25         |
| 66252843321  | 66252843321 | 4-1/2" x .125" x 5/8"-11 | 13580   | 10         |



## Depressed Center Wheels

| PART #   | UPC-A                 | SIZE                    | MAX RPM | WHLs/ CASE |
|--|-----------------------|-------------------------|---------|------------|
| <b>Depressed Center Wheel (Type 27) – Bulk – UPC Bar Coded</b>           |                       |                         |         |            |
| <b>Metal – BlueFire Zirconia Alumina, For Grinding</b>                   |                       |                         |         |            |
| 66252843179  | 662528 <b>43179</b> 9 | 4" x 1/4" x 3/8"        | 15280   | 25         |
| 66252843177  | 662528 <b>43177</b> 5 | 4" x 1/4" x 5/8"        | 15280   | 25         |
| 66252843214  | 662528 <b>43214</b> 7 | 4-1/2" x 1/4" x 7/8"    | 13580   | 25         |
| 66252843213  | 662528 <b>43213</b> 0 | 4-1/2" x 1/4" x 5/8"-11 | 13580   | 10         |
| 66252843218  | 662528 <b>43218</b> 5 | 5" x 1/4" x 7/8"        | 12225   | 25         |
| 66252843217  | 662528 <b>43217</b> 8 | 5" x 1/4" x 5/8"-11     | 12225   | 10         |
| 66252843236  | 662528 <b>43236</b> 9 | 7" x 1/4" x 7/8"        | 8600    | 20         |
| 66252843235  | 662528 <b>43235</b> 2 | 7" x 1/4" x 5/8"-11     | 8600    | 10         |
| 66252843247  | 662528 <b>43247</b> 5 | 9" x 1/4" x 7/8"        | 6600    | 20         |
| 66252843246  | 662528 <b>43246</b> 8 | 9" x 1/4" x 5/8"-11     | 6600    | 10         |
| <b>Metal – BlueFire Zirconia Alumina, For Light Grinding and Cutting</b> |                       |                         |         |            |
| 66252843178  | 662528 <b>43178</b> 2 | 4" x 1/8" x 3/8"        | 15280   | 25         |
| 66252843212  | 662528 <b>43212</b> 3 | 4-1/2" x 1/8" x 7/8"    | 13580   | 25         |
| 66252843211  | 662528 <b>43211</b> 6 | 4-1/2" x 1/8" x 5/8"-11 | 13580   | 10         |
| 66252843216  | 662528 <b>43216</b> 1 | 5" x 1/8" x 7/8"        | 12225   | 25         |
| 66252843215  | 662528 <b>43215</b> 4 | 5" x 1/8" x 5/8"-11     | 12225   | 10         |
| 66252843234  | 662528 <b>43234</b> 5 | 7" x 1/8" x 7/8"        | 8600    | 20         |
| 66252843233  | 662528 <b>43233</b> 8 | 7" x 1/8" x 5/8"-11     | 8600    | 10         |
| 66252843245  | 662528 <b>43245</b> 1 | 9" x 1/8" x 7/8"        | 6600    | 20         |
| 66252843244  | 662528 <b>43244</b> 4 | 9" x 1/8" x 5/8"-11     | 6600    | 10         |
| <b>Metal – Gemini Aluminum Oxide, For Grinding</b>                       |                       |                         |         |            |
| 66252842179  | 662528 <b>42179</b> 0 | 3" x 1/4" x 3/8"        | 18000   | 25         |
| 66252842018  | 662528 <b>42018</b> 1 | 4" x 1/4" x 3/8"        | 15280   | 25         |
| 66252842019  | 662528 <b>42019</b> 9 | 4" x 1/4" x 5/8"        | 15280   | 25         |
| 66252843594  | 662528 <b>43594</b> 0 | 4-1/2" x 1/4" x 7/8"    | 13580   | 25         |
| 66252843593  | 662528 <b>43593</b> 3 | 4-1/2" x 1/4" x 5/8"-11 | 13580   | 10         |
| 66252843598  | 662528 <b>43598</b> 8 | 5" x 1/4" x 7/8"        | 12225   | 25         |
| 66252801865  | 662528 <b>01865</b> 5 | 6" x 1/4" x 7/8"        | 10185   | 20         |
| 66252940098  | 662529 <b>40098</b> 5 | 7" x 1/4" x 7/8"        | 8600    | 20         |
| 66252940148  | 662529 <b>40148</b> 7 | 7" x 1/4" x 5/8"-11     | 8600    | 10         |
| 66253048991  | 662530 <b>48991</b> 7 | 9" x 1/4" x 7/8"        | 6600    | 20         |
| 66253049104  | 662530 <b>49104</b> 0 | 9" x 1/4" x 5/8"-11     | 6600    | 10         |
| <b>Metal – Gemini Aluminum Oxide, For Light Grinding and Cutting</b>     |                       |                         |         |            |
| 66252842016  | 662528 <b>42016</b> 8 | 4" x 1/8" x 3/8"        | 15280   | 25         |
| 66252842017  | 662528 <b>42017</b> 5 | 4" x 1/8" x 5/8"        | 15280   | 25         |
| 66252843591  | 662528 <b>43591</b> 9 | 4-1/2" x 1/8" x 7/8"    | 13580   | 25         |
| 66252843590  | 662528 <b>43590</b> 1 | 4-1/2" x 1/8" x 5/8"-11 | 13580   | 10         |
| 66252843596  | 662528 <b>43596</b> 4 | 5" x 1/8" x 7/8"        | 12225   | 25         |
| 66252801864  | 662528 <b>01864</b> 8 | 6" x 1/8" x 7/8"        | 10185   | 20         |
| 66252939207  | 662529 <b>39207</b> 5 | 7" x 1/8" x 7/8"        | 8600    | 20         |
| 66252939259  | 662529 <b>39259</b> 4 | 7" x 1/8" x 5/8"-11     | 8600    | 10         |
| 66253048994  | 662530 <b>48994</b> 8 | 9" x 1/8" x 7/8"        | 6600    | 20         |
| 66253048983  | 662530 <b>48983</b> 2 | 9" x 1/8" x 5/8"-11     | 6600    | 10         |

| PART #  | UPC-A                 | SIZE                    | MAX RPM | WHLs/ CASE |
|---|-----------------------|-------------------------|---------|------------|
| <b>Depressed Center Wheel (Type 27/42) – Bulk – UPC Bar Coded</b> |                       |                         |         |            |
| <b>Metal – Gemini Aluminum Oxide, For Cutting</b>                 |                       |                         |         |            |
| 66252912626   | 662529 <b>12626</b> 7 | 7" x 1/16" x 7/8"       | 8600    | 20         |
| <b>Depressed Center Wheel (Type 27) – Bulk – UPC Bar Coded</b>    |                       |                         |         |            |
| <b>Metal – Aluminum Oxide, For Grinding</b>                       |                       |                         |         |            |
| 66252842011   | 662528 <b>42011</b> 3 | 4" x 1/4" x 5/8"        | 15280   | 25         |
| 66252843607   | 662528 <b>43607</b> 6 | 4-1/2" x 1/4" x 7/8"    | 13580   | 25         |
| 66252843605   | 662528 <b>43605</b> 3 | 4-1/2" x 1/4" x 5/8"-11 | 13580   | 10         |
| 66252843614   | 662528 <b>43614</b> 5 | 5" x 1/4" x 7/8"        | 12225   | 25         |
| 66252843613   | 662528 <b>43613</b> 8 | 5" x 1/4" x 5/8"-11     | 12225   | 10         |
| 07660775936   | 076607 <b>75936</b> 8 | 7" x 1/4" x 7/8"        | 8600    | 5          |
| 07660775940   | 076607 <b>75940</b> 5 | 7" x 1/4" x 5/8"-11     | 8600    | 5          |
| 07660775938   | 076607 <b>75938</b> 2 | 9" x 1/4" x 5/8"-11     | 6600    | 5          |
| <b>Metal – Aluminum Oxide, For Light Grinding and Cutting</b>     |                       |                         |         |            |
| 66252842014   | 662528 <b>42014</b> 4 | 4" x 1/8" x 5/8"        | 15280   | 25         |
| 66252843611   | 662528 <b>43611</b> 4 | 4-1/2" x 1/8" x 7/8"    | 13580   | 25         |
| 66252843609   | 662528 <b>43609</b> 0 | 4-1/2" x 1/8" x 5/8"-11 | 13580   | 10         |
| 66252843616   | 662528 <b>43616</b> 9 | 5" x 1/8" x 7/8"        | 12225   | 25         |
| 66252843615   | 662528 <b>43615</b> 1 | 5" x 1/8" x 5/8"-11     | 12225   | 10         |
| 07660775956   | 076607 <b>75956</b> 4 | 7" x 1/8" x 7/8"        | 8600    | 5          |
| 07660702678   | 076607 <b>02678</b> 1 | 7" x 1/8" x 5/8"-11     | 8600    | 10         |
| <b>Depressed Center Wheels (Type 27) – Bulk – UPC Bar Coded</b>   |                       |                         |         |            |
| <b>Masonry – Silicon Carbide, For Grinding</b>                    |                       |                         |         |            |
| 66252843600   | 076607 <b>43600</b> 8 | 4-1/2" x 1/4" x 7/8"    | 13580   | 25         |
| 66252843599   | 076607 <b>43599</b> 5 | 4-1/2" x 1/4" x 5/8"-11 | 13580   | 10         |
| 66252843602   | 662528 <b>43602</b> 1 | 5" x 1/4" x 7/8"        | 12225   | 25         |
| 07660775942   | 076607 <b>75942</b> 9 | 7" x 1/4" x 5/8"-11     | 8600    | 5          |

*MTO - Make to Order*





### Small Diameter Reinforced Cut-off Blades

Small diameter cut-off wheels are designed for traditional cut-off applications and feature full fiberglass reinforcing. Used on small cut-off tools for fast cut-off and slotting of all types of metal.

| PART #   | UPC-A                 | SIZE              | MAX RPM | WHLs/ CASE |
|--|-----------------------|-------------------|---------|------------|
| <b>Small Diameter Cut-off Blades (Type 01/41) – Handy Packs</b>          |                       |                   |         |            |
| <b>Metal – Aluminum Oxide</b>  |                       |                   |         |            |
| 66252835553  | 662528 <b>35553</b> 8 | 3" x 1/16" x 3/8" | 25465   | 25         |
| 07660747769  | 076607 <b>47769</b> 9 | Mandrel Accessory |         | 5          |
| <b>Small Diameter Cut-off Blades (Type 01/41) – UPC Bar Coded</b>        |                       |                   |         |            |
| <b>Metal – Aluminum Oxide</b>  |                       |                   |         |            |
| 07660789451  | 076607 <b>89451</b> 9 | 3" x .035" x 3/8" | 25465   | 25         |
| 07660789453  | 076607 <b>89453</b> 3 | 4" x .035" x 3/8" | 19100   | 25         |
| <b>Small Diameter Cut-off Blades (Type 01/41) – Bulk – UPC Bar Coded</b> |                       |                   |         |            |
| <b>Metal – BlueFire Zirconia Alumina</b>                                 |                       |                   |         |            |
| 66252843174  | 662528 <b>43174</b> 4 | 3" x .035" x 3/8" | 25465   | 25         |
| 66252843175  | 662528 <b>43175</b> 1 | 3" x 1/16" x 3/8" | 25465   | 25         |
| 66252843173  | 662528 <b>43173</b> 7 | 4" x .035" x 3/8" | 19100   | 25         |
| 66252843171  | 662528 <b>43171</b> 3 | 4" x 1/16" x 3/8" | 19100   | 25         |
| 66252843172  | 662528 <b>43172</b> 0 | 4" x 1/8" x 3/8"  | 19100   | 25         |

| PART #   | UPC-A                 | SIZE              | MAX RPM | WHLs/ CASE |
|--|-----------------------|-------------------|---------|------------|
| <b>Small Diameter Cut-off Blades (Type 01/41) – Bulk – Non UPC</b> |                       |                   |         |            |
| <b>Metal – Aluminum Oxide</b>                                      |                       |                   |         |            |
| 66243411393  | 662434 <b>11393</b> 2 | 2" x .035" x 1/4" | 30560   | 25         |
| 66243411395  | 662434 <b>11395</b> 6 | 2" x 1/16" x 1/4" | 30560   | 25         |
| 66243411402  | 662434 <b>11402</b> 1 | 2" x 1/8" x 1/4"  | 30560   | 25         |
| 66243510627  | 662435 <b>10627</b> 8 | 3" x .035" x 1/4" | 25465   | 25         |
| 66243510628  | 662435 <b>10628</b> 5 | 3" x .035" x 3/8" | 25465   | 25         |
| 66243510645  | 662435 <b>10645</b> 2 | 3" x 1/16" x 1/4" | 25465   | 25         |
| 66243510647  | 662435 <b>10647</b> 6 | 3" x 1/16" x 3/8" | 25465   | 25         |
| 66243510650  | 662435 <b>10650</b> 6 | 3" x 1/8" x 1/4"  | 25465   | 25         |
| 66243510651  | 662435 <b>10651</b> 3 | 3" x 1/8" x 3/8"  | 25465   | 25         |
| 66243510629  | 662435 <b>10629</b> 2 | 4" x .035" x 1/4" | 19100   | 25         |
| 66243510630  | 662435 <b>10630</b> 8 | 4" x .035" x 3/8" | 19100   | 25         |
| 66243510654  | 662435 <b>10654</b> 4 | 4" x 1/16" x 1/4" | 19100   | 25         |
| 66243510655  | 662435 <b>10655</b> 1 | 4" x 1/16" x 3/8" | 19100   | 25         |
| 66243510658  | 662435 <b>10658</b> 2 | 4" x 1/8" x 1/4"  | 19100   | 25         |
| 66243510659  | 662435 <b>10659</b> 9 | 4" x 1/8" x 3/8"  | 19100   | 25         |



### Circular Saw Reinforced Cut-off Blades

Used for deburring, cleaning, slotting and cutting of all types of metal and masonry. This includes cutting sheet metal and roof decking.

| PART #   | UPC-A                 | SIZE                   | MAX RPM | WHLs/ CASE |
|--|-----------------------|------------------------|---------|------------|
| <b>Circular Saw Reinforced Cut-off Blades (Type 01/41) – Handy Packs</b> |                       |                        |         |            |
| <b>Metal – Aluminum Oxide</b>  |                       |                        |         |            |
| 07660789000  | 076607 <b>89000</b> 9 | 6-1/2" x 1/8" x DM-5/8 | 9405    | 20         |
| 07660789005  | 076607 <b>89005</b> 4 | 7" x 1/8" x DM-5/8     | 8730    | 20         |
| 07660789010  | 076607 <b>89010</b> 8 | 8" x 1/8" x DM-5/8     | 7640    | 20         |
| <b>Masonry – Silicon Carbide</b>   |                       |                        |         |            |
| 07660789050  | 076607 <b>89050</b> 4 | 6-1/2" x 1/8" x DM-5/8 | 9405    | 20         |
| 07660789055  | 076607 <b>89055</b> 9 | 7" x 1/8" x DM-5/8     | 8730    | 20         |
| 07660789070  | 076607 <b>89070</b> 2 | 8" x 1/8" x DM-5/8     | 7640    | 20         |

| PART #  | UPC-A                            | SIZE                   | MAX RPM | WHLs/ CASE |
|---|----------------------------------|------------------------|---------|------------|
| <b>Circular Saw Reinforced Cut-off Blades (Type 01/41) – Bulk – UPC Bar Coded</b> |                                  |                        |         |            |
| <b>Metal – Aluminum Oxide</b>   |                                  |                        |         |            |
| 07660789098   | 076607 <b>89098</b> 6            | 6-1/2" x 1/8" x DM-5/8 | 9405    | 10         |
| 07660789097   | 076607 <b>89097</b> 9            | 7" x 1/8" x DM-5/8     | 8730    | 25**       |
| 07660789096   | 076607 <b>89096</b> 2            | 8" x 1/8" x DM-5/8     | 7640    | 10         |
| <b>Masonry – Silicon Carbide</b>  |                                  |                        |         |            |
| 07660789089   | <i>MTO</i> 076607 <b>89089</b> 4 | 6-1/2" x 1/8" x DM-5/8 | 9405    | 10         |
| 07660789088   | 076607 <b>89088</b> 7            | 7" x 1/8" x DM-5/8     | 8730    | 25**       |
| 07660789086   | 076607 <b>89086</b> 3            | 8" x 1/8" x DM-5/8     | 7640    | 10         |

*MTO - Make to Order*



## High-Speed Reinforced Cut-off Blades

For deburring, cleaning, slotting and cutting of all types of metal and masonry.

### Universal Arbor Blades

Two blade sizes in one. A 20mm bushing is included in the 1" molded arbor hole. The wheel with bushing can be mounted directly on a 20mm arbor. Or, the bushing can be removed exposing a 1" arbor hole which can be mounted to any 1" saw arbor. Once the 20mm bushing is removed, it cannot be replaced.

### Road Construction Blade

Used on walk-behind machine for sawing green concrete, cured concrete and asphalt.

| PART #  | UPC-A       | SIZE                  |                 | MAX RPM | WHLs/ CASE |
|---|-------------|-----------------------|-----------------|---------|------------|
| <b>High Speed Reinforced Cut-off Blades (Type 01/41) – Bulk – UPC Bar Coded</b> |             |                       |                 |         |            |
| <b>Metal – Aluminum Oxide</b>   |             |                       |                 |         |            |
| 07660705494   | 07660705494 | 4 12" x 1/8" x 1"20mm | Universal Arbor | 6300    | 10         |
| 07660705496   | 07660705496 | 8 14" x 1/8" x 1"20mm | Universal Arbor | 5400    | 10         |
| 66252830886   | 66252830886 | 2 16" x 1/8" x 1"20mm | Universal Arbor | 4800    | 10         |
| <b>Masonry – Silicon Carbide</b>  |             |                       |                 |         |            |
| 07660705493   | 07660705493 | 7 12" x 1/8" x 1"20mm | Universal Arbor | 6300    | 10         |
| 07660705495   | 07660705495 | 1 14" x 1/8" x 1"20mm | Universal Arbor | 5400    | 10         |
| 70184623029   | 70184623029 | 2 16" x 1/8" x 1"20mm | Universal Arbor | 4800    | 10         |



## Chop Saw Reinforced Cut-off Blades

For use on low horsepower cut-off machines. These machines can be easily moved, but the workpiece is carried to the machine. Especially popular in the construction industry because of its portability and ability to provide a straight, clean cut.

### Primary uses include:

- Cutting metal studs, rebar, angle iron, and tubing

| PART #   | UPC-A       | SIZE               | MAX RPM | WHLs/ CASE |
|--|-------------|--------------------|---------|------------|
| <b>Chop Saw Reinforced (Type 01/41) – Bulk – UPC Bar Coded</b> |             |                    |         |            |
| <b>Metal – BlueFire Zirconia Alumina/Aluminum Oxide</b>        |             |                    |         |            |
| 66252843254  | 66252843254 | 3 14" x 7/64" x 1" | 4365    | 10         |
| <b>Metal – Aluminum Oxide</b>                                  |             |                    |         |            |
| 07660789400  | 07660789400 | 7 12" x 7/64" x 1" | 4365    | 5          |
| 07660789399  | 07660789399 | 4 14" x 7/64" x 1" | 4365    | 5          |
| <b>Metal – Aluminum Oxide (Steel Stud)</b>                     |             |                    |         |            |
| 07660789405  | 07660789405 | 2 14" x 7/64" x 1" | 4365    | 10         |

| PART #   | UPC-A       | SIZE               | MAX RPM | WHLs/ CASE |
|--|-------------|--------------------|---------|------------|
| <b>Chop Saw Reinforced (Type 01/41) – Bulk – UPC Bar Coded</b> |             |                    |         |            |
| <b>Metal – Gemini Aluminum Oxide</b>                           |             |                    |         |            |
| 66253207554  | 66253207554 | 5 12" x 7/64" x 1" | 5095    | 10         |
| 66253306627  | 66253306627 | 6 14" x 7/64" x 1" | 4365    | 10         |
| 66253410198  | 66253410198 | 3 16" x 7/64" x 1" | 3820    | 10         |



## Stationary Saw Reinforced Cut-off Blades

For use on a range of fixed base, higher horsepower cut-off machines where the workpiece is carried to the machine. Designed for higher cut-off production of all types of metal and masonry:

- Heavy bar stock, rebar, thick wall tubing and pipe

| PART #   | UPC-A               | SIZE                        | MAX RPM | WHLs/ CASE |
|--|---------------------|-----------------------------|---------|------------|
| <b>Stationary Saw Cut-off Blades (Type 01/41) – Bulk – UPC Bar Coded</b> |                     |                             |         |            |
| <b>Metal – Aluminum Oxide</b>  |                     |                             |         |            |
| 07660789390  | 076607 <b>89390</b> | 1 10" x 3/32" x 5/8"        | 6110    | 5          |
| 07660789392  | 076607 <b>89392</b> | 5 12" x 1/8" x 1"           | 5095    | 10         |
| 07660789395  | 076607 <b>89395</b> | 6 14" x 1/8" x 1"           | 4365    | 10         |
| <b>Gemini – Aluminum Oxide</b>   |                     |                             |         |            |
| 66253410183  | 662534 <b>10183</b> | 9 16" x 5/32" x 1" Fast Cut | 3820    | 10         |
| 69078609033  | 690786 <b>09033</b> | 5 20" x 3/16" x 1" Fast Cut | 2170    | 5          |
| <b>Masonry – Silicon Carbide</b>   |                     |                             |         |            |
| 07660789391  | 076607 <b>89391</b> | 8 10" x 3/32" x 5/8"        | 6110    | 5          |



## Mounted Points – Handy Packs

For removing burrs and flash finishing any kind of metal surface in a confined area. Fast stock removal and free cutting action. Use "A" or "B" shapes for medium to heavy duty blending. Use "W" shapes for offhand and precision grinding of medium to heavy stock.

### TECH TIP

Use "A" or "B" shapes for medium to heavy duty blending. Use "W" shapes for offhand and precision grinding of medium to heavy stock.



| PART #                              | UPC-A               | SIZE                     | SHAPE | MAX RPM | WHLs/ CASE |
|-------------------------------------|---------------------|--------------------------|-------|---------|------------|
| <b>Mounted Points – Handy Packs</b> |                     |                          |       |         |            |
| <b>1/4" Shank</b>                   |                     |                          |       |         |            |
| 07660724376                         | 076607 <b>24376</b> | 8 1" x 1-1/4" 1/4" shank | A2    | 34240   | 1/25       |
| 07660724419                         | 076607 <b>24419</b> | 2 3/8" x 3/4" 1/4" shank | B52   | 78340   | 1/25       |
| 07660724549                         | 076607 <b>24549</b> | 6 3/4" x 3/4" 1/4" shank | W204  | 36510   | 1/25       |
| 07660724564                         | 076607 <b>24564</b> | 9 1" x 1/2" 1/4" shank   | W218  | 37890   | 1/25       |

Max. RPM valid to 1/2" overhang. See package insert for other overhangs.



### Bench & Pedestal Wheels

Bring back your high-speed dry grinders! The fastest cutting wheels on the market are also the coolest. A constant supply of sharp cutting points with the Norton patented SG (ceramic alumina) grain gives the Premium Norton Bench & Pedestal wheels an incredible burn-free cut with controlled micro fracturing of the grain. Great for all bench and pedestal operations, especially hollow grinding of plane blades and chisels.



### Arbor Adapter Bushings

| DIAMETER.  | CENTER HOLE | 1/2" | 5/8" | 3/4" | 7/8" | 1" | 1-1/4" |
|------------|-------------|------|------|------|------|----|--------|
| 5", 6", 7" | 1"          | •    | •    | •    | •    |    |        |
| 8"         | 1"          |      | •    | •    | •    |    |        |
| 10"        | 1-1/4"      |      |      | •    | •    | •  |        |
| 12"        | 1-1/2"      |      |      |      |      | •  | •      |

NOTE: Each 5", 6", 7", 8", 10" and 12" wheel is supplied with additional arbor bushings, so one specification can meet the needs of several machines with different arbor sizes.

| PART #  | UPC-A       | SIZE                                  | GRIT                | QTY/ PKG | PKG/ CASE |
|---|-------------|---------------------------------------|---------------------|----------|-----------|
| <b>Premium Blue Ceramic Alumina (I-Grade)</b> |             |                                       |                     |          |           |
| 07660704685                                   | 07660704685 | 7 6" x 3/4" x 1"                      | 3SG46-I             | 1        | 5         |
| 07660704684                                   | 07660704684 | 0 6" x 3/4" x 1"                      | 3SG60-I             | 1        | 5         |
| 07660704683                                   | 07660704683 | 3 6" x 3/4" x 1"                      | 3SG80-I             | 1        | 5         |
| 07660704682                                   | 07660704682 | 6 6" x 3/4" x 1"                      | 3SG100-I            | 1        | 5         |
| 07660704659                                   | 07660704659 | 8 8" x 1" x 1"                        | 3SG60-I             | 1        | 5         |
| 07660704657                                   | 07660704657 | 4 8" x 1" x 1"                        | 3SG100-I            | 1        | 5         |
| <b>Premium Blue Ceramic Alumina (K-Grade)</b> |             |                                       |                     |          |           |
| 07660705411                                   | 07660705411 | 1 6" x 3/4" x 1"                      | 3SG46-K             | 1        | 5         |
| 07660705412                                   | 07660705412 | 8 6" x 3/4" x 1"                      | 3SG80-K             | 1        | 5         |
| 07660705413                                   | 07660705413 | 5 6" x 1" x 1"                        | 3SG46-K             | 1        | 5         |
| 07660705414                                   | 07660705414 | 2 6" x 1" x 1"                        | 3SG80-K             | 1        | 5         |
| 07660705421                                   | 07660705421 | 0 8" x 1" x 1"                        | 3SG46-K             | 1        | 5         |
| 07660705422                                   | 07660705422 | 7 8" x 1" x 1"                        | 3SG80-K             | 1        | 5         |
| <b>White Aluminum Oxide</b>                   |             |                                       |                     |          |           |
| 07660788248                                   | 07660788248 | 6 6" x 3/4" x 1"                      | Extra Fine 150      | 1        | 5         |
| 07660788247                                   | 07660788247 | 9 6" x 3/4" x 1"                      | Fine 100            | 1        | 5         |
| 07660788246                                   | 07660788246 | 2 6" x 3/4" x 1"                      | Medium 60           | 1        | 5         |
| 07660788263                                   | 07660788263 | 9 6" x 1" x 1"                        | Extra Fine 150      | 1        | 5         |
| 07660788262                                   | 07660788262 | 2 6" x 1" x 1"                        | Fine 100            | 1        | 5         |
| 07660788261                                   | 07660788261 | 5 6" x 1" x 1"                        | Medium 60           | 1        | 5         |
| 07660788283                                   | 07660788283 | 7 8" x 1" x 1"                        | Extra Fine 150      | 1        | 5         |
| 07660788282                                   | 07660788282 | 0 8" x 1" x 1"                        | Fine 100            | 1        | 5         |
| 07660788281                                   | 07660788281 | 3 8" x 1" x 1"                        | Medium 60           | 1        | 5         |
| <b>Dressing Sticks – Handy Packs</b>          |             |                                       |                     |          |           |
| 07660710466                                   | 07660710466 | 3 1" x 1" x 6" Stick                  | Silicon Carbide-Med | 1        | 10**      |
| 66260148820                                   | 66260148820 | 7 Diamond Dresser with Handle - IAGHD |                     | 1        | 5         |

| PART #  | UPC-A       | SIZE                | GRIT           | MAX ROM | WHEEL/ CASE |
|---|-------------|---------------------|----------------|---------|-------------|
| <b>Silicon Carbide For Non-Metal (Green) – Handy Packs</b>            |             |                     |                |         |             |
| 66252837190   | 66252837190 | 3 6" x 3/4" x 1"    | Medium 60      | 4140    | 1           |
| 66252837191   | 66252837191 | 0 6" x 3/4" x 1"    | Fine 100       | 4140    | 1           |
| 66252837192   | 66252837192 | 7 6" x 3/4" x 1"    | Extra Fine 150 | 4140    | 1           |
| 66252837187   | 66252837187 | 3 6" x 1" x 1"      | Medium 60      | 4140    | 1           |
| 66252837193   | 66252837193 | 4 6" x 1" x 1"      | Fine 100       | 4140    | 1           |
| 66252837194   | 66252837194 | 1 6" x 1" x 1"      | Extra Fine 150 | 4140    | 1           |
| 66252942300   | 66252942300 | 7 7" x 1" x 1"      | Medium 60      | 3600    | 1           |
| 66252942301   | 66252942301 | 4 7" x 1" x 1"      | Fine 100       | 3600    | 1           |
| 66252942302   | 66252942302 | 1 7" x 1" x 1"      | Extra Fine 150 | 3600    | 1           |
| 66253044087   | 66253044087 | 1 8" x 1" x 1"      | Medium 60      | 3600    | 1           |
| 66253044534   | 66253044534 | 0 8" x 1" x 1"      | Fine 100       | 3600    | 1           |
| 66253044535   | 66253044535 | 7 8" x 1" x 1"      | Extra Fine 150 | 3600    | 1           |
| 66253144536   | 66253144536 | 3 10" x 1" x 1-1/4" | Medium 60      | 2485    | 1           |
| 66253160366   | 66253160366 | 4 10" x 1" x 1-1/4" | Fine 100       | 2485    | 1           |
| 66253263359   | 66253263359 | 2 12" x 2" x 1-1/4" | Medium 60      | 2070    | 1           |
| 66253263360   | 66253263360 | 8 12" x 2" x 1-1/4" | Fine 100       | 2070    | 1           |
| <b>General Purpose Aluminum Oxide For Metal (Brown) – Handy Packs</b> |             |                     |                |         |             |
| 07660788201   | 07660788201 | 1 5" x 1/2" x 1"    | Fine 100       | 4965    | 1           |
| 07660788202   | 07660788202 | 8 5" x 1/2" x 1"    | Medium 60      | 4965    | 1           |
| 07660788205   | 07660788205 | 9 5" x 3/4" x 1"    | Fine 100       | 4965    | 1           |
| 07660788210   | 07660788210 | 3 5" x 3/4" x 1"    | Medium 60      | 4965    | 1           |
| 07660788225   | 07660788225 | 7 5" x 1" x 1"      | Medium 60      | 4965    | 1           |
| 07660788235   | 07660788235 | 6 6" x 3/4" x 1"    | Fine 100       | 4140    | 1           |
| 07660788240   | 07660788240 | 0 6" x 3/4" x 1"    | Medium 60      | 4140    | 1           |
| 07660788245   | 07660788245 | 5 6" x 3/4" x 1"    | Coarse 36      | 4140    | 1           |
| 07660788250   | 07660788250 | 9 6" x 1" x 1"      | Fine 100       | 4140    | 1           |
| 07660788255   | 07660788255 | 4 6" x 1" x 1"      | Medium 60      | 4140    | 1           |
| 07660788260   | 07660788260 | 8 6" x 1" x 1"      | Coarse 36      | 4140    | 1           |
| 07660788265   | 07660788265 | 3 7" x 1" x 1"      | Fine 100       | 3600    | 1           |
| 07660788270   | 07660788270 | 7 7" x 1" x 1"      | Medium 60      | 3600    | 1           |
| 07660788275   | 07660788275 | 2 7" x 1" x 1"      | Coarse 36      | 3600    | 1           |
| 07660788280   | 07660788280 | 6 8" x 1" x 1"      | Fine 100       | 3600    | 1           |
| 07660788285   | 07660788285 | 1 8" x 1" x 1"      | Medium 60      | 3600    | 1           |
| 07660788286   | 07660788286 | 8 8" x 1" x 1"      | Coarse 36      | 3600    | 1           |
| 07660788290   | 07660788290 | 5 10" x 1" x 1-1/4" | Medium 60      | 2485    | 1           |
| 07660788295   | 07660788295 | 0 10" x 1" x 1-1/4" | Coarse 36      | 2485    | 1           |
| 66253263054   | 66253263054 | 6 12" x 2" x 1-1/2" | Very Coarse 24 | 2070    | 1           |
| 66253263055   | 66253263055 | 3 12" x 2" x 1-1/2" | Coarse 36      | 2070    | 1           |
| 66253263056   | 66253263056 | 0 12" x 2" x 1-1/2" | Medium 60      | 2070    | 1           |

















## Wire Brushes

The Norton Metal line of wire wheels and brushes provides excellent performance for deburring and removing rust, corrosion and dirt from various surfaces, including steel, ferrous metals, and stainless steel. The bright, clean, easy-to-read, packaging in English and French makes for easy and simple product-to-application selection.

### Features & Benefits:

- For use with angle grinders, bench grinders, or drills depending on your application/requirements
- Perfect for removing rust, scale, paint, and dirt from metal and other surfaces
- Ideal for preparing metal or rubber for gluing
- For stripping paint from wood surfaces or for roughening surfaces

| PART #  | TYPE                               | SIZE         | MAX RPM | QTY/ PACK | PACKS/ CASE |
|---|------------------------------------|--------------|---------|-----------|-------------|
|  076607 <b>68422</b> 6   | Knot Brush Cup<br>Carbon Steel     | 3" x 5/8"-11 | 15,000  | 1         | 4           |
|  076607 <b>68423</b> 3 | Knot Brush Cup<br>Stainless        | 3" x 5/8"-11 | 15,000  | 1         | 4           |
|  076607 <b>68424</b> 0 | Crimped Cup<br>Carbon Steel        | 3" x 5/8"-11 | 15,000  | 1         | 4           |
|  076607 <b>68425</b> 7 | Knot Wheel Brush<br>Stainless      | 4" x 5/8"-11 | 12,500  | 1         | 5           |
|  076607 <b>68426</b> 4 | Knot Wire Wheel<br>Carbon Steel    | 4" x 5/8"-11 | 12,500  | 1         | 5           |
|  076607 <b>68427</b> 1 | Coarse Crimped Wire Wheel<br>Brass | 4"           | 4,500   | 1         | 6           |
|  076607 <b>68428</b> 8 | Crimped Wire Cup<br>Brass          | 3"           | 4,500   | 1         | 6           |

| PART #  | TYPE                                      | SIZE | MAX RPM | QTY/ PACK | PACKS/ CASE |
|---|---|------|---------|-----------|-------------|
|  076607 <b>68429</b> 5   | Coarse Crimped Wire Wheel<br>Brass        | 3"   | 4,500   | 1         | 6           |
|  076607 <b>68430</b> 1 | Coarse Crimped Wire End<br>Brush<br>Brass | 1"   | 4,500   | 1         | 6           |
|  076607 <b>68431</b> 8 | Crimped Wire Brush Set<br>Brass           | —    | 4,500   | 6         | 5           |
|  076607 <b>68432</b> 5 | Coarse Crimped Wire Brush<br>Brass        | 2"   | 4,500   | 1         | 6           |
|  076607 <b>68433</b> 2 | Coarse Crimped Wire Wheel<br>Brass        | 2"   | 4,500   | 1         | 6           |
|  076607 <b>68434</b> 9 | Coarse Crimped Wire Wheel<br>Brass        | 6"   | 4,500   | 1         | 5           |
|  076607 <b>68435</b> 6 | Crimped Wire Brush<br>Brass               | 8"   | 4,500   | 1         | 5           |



## Norton Painter's Plastic

Our multi-purpose plastic sheeting protects virtually any area from sanding dust and paint overspray with ease – even after repositioning. Mono films and linear low density plastics (LLDPE) don't compare.



### Features & Benefits

- Resists tearing and solvent bleed-through with lightweight .31 mil High-Density Polyethylene (HDPE) plastic
- Holds in place as it clings to horizontal or vertical surfaces during taping with its natural electrostatic properties
- Attracts and holds sanding debris for a dust free finish
- Drapes easily over furniture

| PART #                   | UPC-A                 | SIZE          | QTY/PACK | PACKS/CASE |
|--------------------------|-----------------------|---------------|----------|------------|
| <b>Painter's Plastic</b> |                       |               |          |            |
| 07660768142              | 076607 <b>68142</b> 3 | 9' x 400 ft.  | 1        | 1          |
| 07660768143              | 076607 <b>68143</b> 0 | 12' x 400 ft. | 1        | 1          |

*Note: pallet quantity is 96 rolls*



## Norton Hand Masking Film

Norton Hand Masking Film is specially designed to resist paint flaking during multiple-coat paint applications. Paint overspray adheres to the outside layer of plastic, preventing flaking into the base coat and resulting in a cleaner overall work space. Offered in four different sizes with a .375 mil thickness, this clear film will allow you to achieve a high quality job in less time and protect from overspray.

| PART #                                   | UPC-A                 | SIZE       | QTY/PACK | PACKS/CASE |
|--|-----------------------|------------|----------|------------|
| <b>Pre-folded Masking Film – .375mil</b> |                       |            |          |            |
| 07660768305                              | 076607 <b>68305</b> 2 | 24" x 180' | 1        | 12         |
| 07660768306                              | 076607 <b>68306</b> 9 | 48" x 180' | 1        | 12         |
| 07660768307                              | 076607 <b>68307</b> 6 | 72" x 90'  | 1        | 12         |
| 07660768308                              | 076607 <b>68308</b> 3 | 99" x 90'  | 1        | 12         |



### Premium Grade Clean Release Tape

The premium grade, clean release tape comes in a full range of widths for maximum versatility. It has been designed to extremely high standards with tough adhesive strength and maximum flexibility, which means it conforms easily and contours to regular surfaces. Leaves no residue and stays in place until you take it off.

| PART #                                  | UPC-A                 | SIZE              | QTY/PACK | PACKS/CASE |
|---|-----------------------|-------------------|----------|------------|
| <b>Premium Grade Clean Release Tape</b> |                       |                   |          |            |
| 07660702450                             | 076607 <b>02450</b> 3 | 3/4" x 60 yards   | 1        | 48         |
| 07660702451                             | 076607 <b>02451</b> 0 | 1" x 60 yards     | 1        | 36         |
| 07660702452                             | 076607 <b>02452</b> 7 | 1-1/2" x 60 yards | 1        | 24         |
| 07660702453                             | 076607 <b>02453</b> 4 | 2" x 60 yards     | 1        | 24         |







### Norton Steel Wool

The perfect all-purpose choice for professional contractors and do-it yourselfers. Made of thin bundled fibers, the soft abrasive can be used for cleaning, smoothing and polishing with grades varying from extra coarse #4 for heavy stripping to super fine #0000 for finishing. Color-coded packaging and grade indicator make it easy to choose the right coarseness for the job at hand, whether it's removing rust, dirt, varnish, or stripping paint from exterior woodwork. This product has been designed get into those hard-to-reach areas and compress to any shape for endless uses.

#### Application/Grit Recommendation Guide



#### Features & Benefits

- Ideal for most household projects, including removing rust, dirt, varnish, or stripping paint from exterior woodwork
- Thin metal fibers bundled together easily compress to any shape so pads can be used in hard-to-reach areas and contoured surfaces
- Available in grades ranging from extra course #4 for heavy stripping to super fine #0000 for finishing and polishing
- Color coded packaging and grade indicator chart make finding the right grit easy

| PART #            | UPC-A                 | GRIT            | QTY/ PACK | PACKS/ CASE |
|-------------------|-----------------------|-----------------|-----------|-------------|
| <b>Steel Wool</b> |                       |                 |           |             |
| 07660768112       | 076607 <b>68112</b> 6 | 0000 Super Fine | 12        | 6           |
| 07660768113       | 076607 <b>68113</b> 3 | 000 Extra Fine  | 12        | 6           |
| 07660768114       | 076607 <b>68114</b> 0 | 00 Very Fine    | 12        | 6           |
| 07660768115       | 076607 <b>68115</b> 7 | 0 Fine          | 12        | 6           |
| 07660768116       | 076607 <b>68116</b> 4 | 1 Medium        | 12        | 6           |
| 07660768117       | 076607 <b>68117</b> 1 | 2 Medium/Coarse | 12        | 6           |
| 07660768118       | 076607 <b>68118</b> 8 | 3 Coarse        | 12        | 6           |
| 07660768335       | 076607 <b>68335</b> 9 | 4 Extra Coarse  | 12        | 6           |



| PART #                                    | UPC-A                 | GRIT     | GRADING         | QTY/ PACK | PACKS/ CASE |
|---|-----------------------|----------|-----------------|-----------|-------------|
| <b>Synthetic Steel Wool – Handy Packs</b> |                       |          |                 |           |             |
| <b>4-3/8" x 5-1/2"</b>                    |                       |          |                 |           |             |
| 07660701726                               | 076607 <b>01726</b> 0 | White    | 0000 Super Fine | 2         | 10**        |
| 07660701727                               | 076607 <b>01727</b> 7 | Gray     | 000 Extra Fine  | 2         | 10**        |
| 07660701728                               | 076607 <b>01728</b> 4 | Green    | 0 Fine          | 2         | 10**        |
| 07660701729                               | 076607 <b>01729</b> 1 | Charcoal | 1 Medium        | 2         | 10**        |

#### Features & Benefits

- Synthetic non-woven hand pads made of a nylon web with abrasive grain and resin bond
- They are designed for applications ranging from heavy-duty cleaning to polishing
- Compatible with both solvent-based and water-based stains and finishes



### Non-Woven Pads and Rolls

Non-woven pads are an ideal replacement for steel wool for heavy-duty cleaning and stripping through finishing to light-duty polishing.

- Flexible - can be cut or folded
- Won't rust, shred or splinter
- Washable and reusable
- Use with/without chemicals

### Starting Recommendation Guide

Least Aggressive

Most Aggressive

| #456 (WHITE)<br>NON-ABRASIVE   | #748 (GRAY)<br>MICRO FINE<br>SILICON CARBIDE   | #796 (GREEN)<br>VERY FINE<br>ALUMINUM OXIDE                        | #747 (MAROON)<br>VERY FINE<br>ALUMINUM OXIDE  | #740 (BROWN)<br>MEDIUM<br>ALUMINUM OXIDE | #180 (GREEN)<br>EXTRA COARSE   |
|--|--|--|---|--|--|
| <b>Cleaning Pad</b>  | <b>Final Shine Pad</b>   | <b>Scouring Pad</b>  | <b>General Purpose Pad</b>  | <b>Heavy Duty Pad</b>                    | <b>Stripping Pad</b>   |
| <b>0000 Super Fine Steel Wool Equivalent</b>   | <b>000 Extra Fine Steel Wool Equivalent</b>  | <b>0 Fine Steel Wool Equivalent</b>                                | <b>N/A</b>  | <b>N/A</b>                               | <b>3 Extra Coarse Steel Wool Equivalent</b>  |
| Cleaning<br>• glass<br>• fiberglass<br>• porcelain<br>• ceramic<br>• chrome<br>• copper<br>• stainless steel<br>Wood<br>• highlighting<br>• rubbing<br>Use with liquid detergent | Light Cleaning<br>• steel<br>• non-steel<br>Denibbing plastic<br>Defuzzing wood<br>Finishing areas for blending<br>Final rub | Removing<br>• stains/marks<br>• rust<br>• corrosion<br>• oxidation | Cleaning<br>Finishing<br>Deburring<br>• machinery<br>• tools<br>Removing Rust<br>Defuzzing Wood<br>Light Deburring<br>Preparing surfaces for painting intricate parts | Removing Rust<br>Deburring<br>Blending   | Use with chemical strippers for heavy duty stripping and scrubbing of surfaces to remove paint, varnish and other coatings |

| PART #                                 | UPC-A               | GRIT | GRADING | QTY/<br>PACK              | PACKS/<br>CASE |
|--|---------------------|------|---------|---------------------------|----------------|
| <b>Non-Woven Pads – Handy Packs</b>    |                     |      |         |                           |                |
| <b>4-3/8" x 11"</b>                    |                     |      |         |                           |                |
| 07660748146                            | 076607 <b>48146</b> | 7    | Gray    | Between Coats Finishing   | 1 20**         |
| 07660748147                            | 076607 <b>48147</b> | 4    | Green   | Paint & Varnish Stripping | 1 20**         |
| 07660748148                            | 076607 <b>48148</b> | 1    | Maroon  | Metal Finishing           | 1 20**         |
| <b>Non-Woven Pads – Bulk – Non-UPC</b> |                     |      |         |                           |                |
| <b>6" x 9" Hand Pads</b>               |                     |      |         |                           |                |
| 66261045600                            | 662610 <b>45600</b> | 6    | White   | (456)                     | 10 6           |
| 66261074800                            | 662610 <b>74800</b> | 2    | Gray    | (748)                     | 20 3           |
| 66261079600                            | 662610 <b>79600</b> | 3    | Green   | (796)                     | 20 3           |
| 66261074700                            | 662610 <b>74700</b> | 5    | Maroon  | (747)                     | 20 3           |
| 66261074000                            | 662610 <b>74000</b> | 6    | Brown   | (740)                     | 20 2           |
| <b>Hand Pad Holder – Bulk</b>          |                     |      |         |                           |                |
| <b>3-1/4" x 5-1/2"</b>                 |                     |      |         |                           |                |
| 66261047583                            | 662610 <b>47583</b> | 0    | Holder  |                           | 1 -            |

| PART #                        | UPC-A               | GRIT | GRADING | QTY/<br>PACK | PACKS/<br>CASE |
|-------------------------------|---------------------|------|---------|--------------|----------------|
| <b>Non-Woven Rolls – Bulk</b> |                     |      |         |              |                |
| <b>2" x 15 ft. Pad Rolls</b>  |                     |      |         |              |                |
| 66261008108                   | 662610 <b>08108</b> | 6    | Asst.   | 1F,1VF,1UF   | 1 1            |



## Rotolo Foam

Rotolo Foam pre-cut sheets are conveniently packaged in a roll form and perforated every 5-1/2". They are ideal for fine sanding on round edges, contours and curves, and deliver an outstanding finish.

| PART #   | UPC-A       | GRIT   | SIZE         | QTY/<br>PACK | PACKS/<br>CASE |
|--|-------------|--------|--------------|--------------|----------------|
| <b>Rotolo Foam Rolls</b>   |             |        |              |              |                |
| <b>4-1/2" x 82' (115mm x 25m) Perforated Every 5-1/2" (A275)</b> |             |        |              |              |                |
| 66623357616  | 66623357616 | 5 1000 | 4-1/2" x 82' | 1            | 2              |
| 66623357613  | 66623357613 | 4 800  | 4-1/2" x 82' | 1            | 2              |
| 66623357612  | 66623357612 | 7 600  | 4-1/2" x 82' | 1            | 2              |
| 66623357611  | 66623357611 | 0 500  | 4-1/2" x 82' | 1            | 2              |
| 66623357608  | 66623357608 | 0 400  | 4-1/2" x 82' | 1            | 2              |
| 66623357606  | 66623357606 | 6 320  | 4-1/2" x 82' | 1            | 2              |
| 78072757602  | 78072757602 | 5 240  | 4-1/2" x 82' | 1            | 2              |
| 78072757600  | 78072757600 | 1 220  | 4-1/2" x 82' | 1            | 2              |
| 78072757599  | 78072757599 | 8 180  | 4-1/2" x 82' | 1            | 2              |
| 78072757584  | 78072757584 | 4 150  | 4-1/2" x 82' | 1            | 2              |
| 78072735316  | 78072735316 | 9 120  | 4-1/2" x 82' | 1            | 2              |





## Micro-Fiber

Micro-Fiber Cloths have edges that collect debris as opposed to pushing it away. The particles are trapped in between the fibers and can be rinsed or machine washed to release heavily embedded particles. Micro-fiber products can be washed up to 300+ times without losing cleaning and trapping abilities, which will save you labor time and additional costs of multiple cleaning products and chemicals.




- Cleaning Cloth (Blue) is used for general wet or dry cleaning applications
- Dry Tack Cloth (Red) has a low profile to resist snagging and pick up embedded debris
- Polishing Cloth (Yellow) is ideal for streak-free cleaning of mirrors and optical lenses

### TECH TIP

Micro-fiber is virtually scratch resistant but may pick up debris that can scratch. Clean micro-fiber products often for best results.



| PART #                                      | UPC-A       | GRIT | GRADING   | QTY/<br>PACK | PACKS/<br>CASE |
|---|-------------|------|-----------|--------------|----------------|
| <b>Cleaning Micro-Fiber Cloth (Blue)</b>    |             |      |           |              |                |
| 07660705300                                 | 07660705300 | 8    | Cleaning  | Blue         | - 20           |
| <b>Dry Tack Micro-Fiber Cloth (Red)</b>     |             |      |           |              |                |
| 07660706038                                 | 07660706038 | 9    | Dry Tack  | Red          | 1 12**         |
| 07660704025                                 | 07660704025 | 1    | Dry Tack  | Red          | - 20           |
| <b>Polishing Micro-Fiber Cloth (Yellow)</b> |             |      |           |              |                |
| 07660705301                                 | 07660705301 | 5    | Polishing | Yellow       | - 20           |
| <b>Tack Cloth</b>                           |             |      |           |              |                |
| 07660749008                                 | 07660749008 | 7    |           | Tack Cloth   | 1 144          |
|   |             |      |           |              | 12 boxes of 12 |

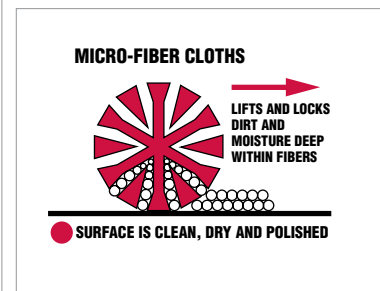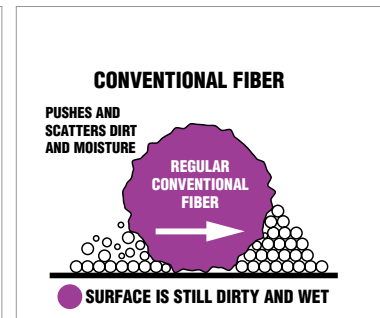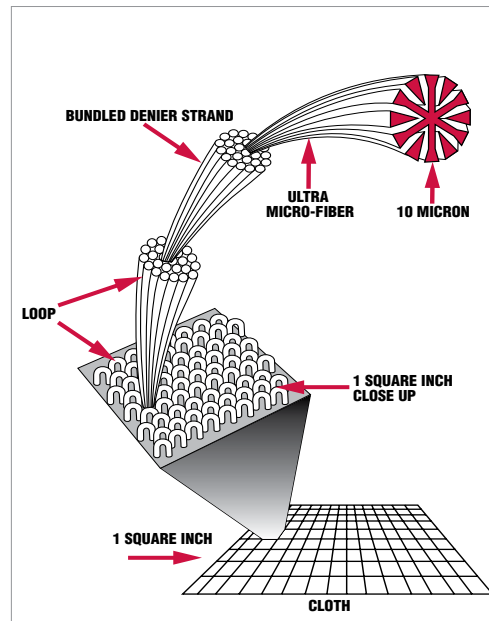



## Nitrile Gloves

Norton Nitrile Disposable Gloves provide options for safety and comfort while tackling even the toughest repair jobs. Available in a full range of styles and sizes, including:


- Blue General-Purpose 4 mil Nitrile Gloves - ideal for smaller projects or when changing gloves frequently is necessary.
- Black Heavy-Duty 6 mil Nitrile Gloves - designed for longer use in more difficult applications.
- Orange Heavy-Duty 7 mil Nitrile Gloves - feature a "diamond" pattern texture to allow for excellent gripping properties. Perfect for jobs you need extra grip to hold onto tools or containers.

| PART #                           | UPC-A       | DESCRIPTION                                     | QTY/<br>PACK | PACKS/<br>CASE |
|----------------------------------|-------------|---|--------------|----------------|
| <b>Disposable Nitrile Gloves</b> |             |   |              |                |
| 66623390700                      | 66623390700 | 6 4 mil Nitrile Gloves (Blue) Medium            | 100          | 10             |
| 66623390701                      | 66623390701 | 3 4 mil Nitrile Gloves (Blue) Large             | 100          | 10             |
| 66623390702                      | 66623390702 | 0 4 mil Nitrile Gloves (Blue) XL                | 100          | 10             |
| 66623390703                      | 66623390703 | 7 4 mil Nitrile Gloves (Blue) XXL               | 100          | 10             |
| 66623390704                      | 66623390704 | 4 6 mil Nitrile Gloves (Black) Medium           | 100          | 10             |
| 66623390705                      | 66623390705 | 1 6 mil Nitrile Gloves (Black) Large            | 100          | 10             |
| 66623390706                      | 66623390706 | 8 6 mil Nitrile Gloves (Black) XL               | 100          | 10             |
| 66623390707                      | 66623390707 | 5 6 mil Nitrile Gloves (Black) XXL              | 100          | 10             |
| 66623390708                      | 66623390708 | 2 7 mil Textured Nitrile Gloves (Orange) Medium | 50           | 10             |
| 66623390709                      | 66623390709 | 9 7 mil Textured Nitrile Gloves (Orange) Large  | 50           | 10             |
| 66623390710                      | 66623390710 | 5 7 mil Textured Nitrile Gloves (Orange) XL     | 50           | 10             |
| 66623390711                      | 66623390711 | 2 7 mil Textured Nitrile Gloves (Orange) XXL    | 50           | 10             |



## Multi-Air Cyclonic


Revolutionary Norton Multi-Air Cyclonic hook and loop vacuum discs raise the bar in power sanding with a precision laser-cut, spiral-hole design that provides maximum dust extraction for a cleaner work environment with fewer disc changes and greater productivity.

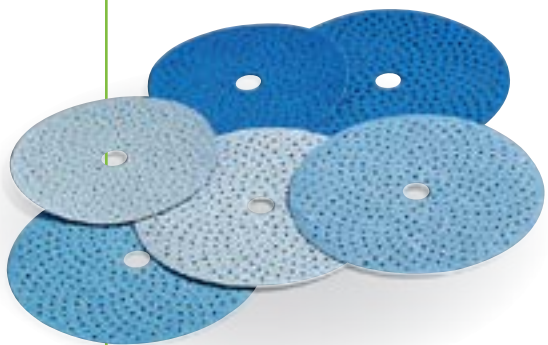

### Features & Benefits

- Precision laser-cut, spiral-hole hook and loop vacuum design removes material consistently throughout the life of the disc while maximizing dust extraction for a cleaner work environment
- Specialized multi-hole pattern allows for use on any random orbital sander regardless of hole pattern - including unique Festool® sander models
- Premium ceramic abrasive provides a superior cut on all surfaces, lasts substantially longer and removes material faster than conventional abrasives and uses a No-Fil coating to resist clogging/loading during sanding
- Unique fiber-reinforced latex/paper backing is flexible, strong, and tear-resistant

| PART #  | UPC-A       | GRIT | MIN./PKG. | STD. PKG. |     |
|---|-------------|------|-----------|-----------|-----|
| <b>5" x 11/16" A975 No-Fil Multi-Air Cyclonic</b> |             |      |           |           |     |
| 77696007745                                       | 77696007745 | 0    | 80        | 50        | 200 |
| 77696007753                                       | 77696007753 | 5    | 120       | 50        | 200 |
| 77696007755                                       | 77696007755 | 9    | 150       | 50        | 200 |
| 77696007756                                       | 77696007756 | 6    | 180       | 50        | 200 |
| 77696007757                                       | 77696007757 | 3    | 220       | 50        | 200 |
| 77696007760                                       | 77696007760 | 3    | 240       | 50        | 200 |
| 77696007762                                       | 77696007762 | 7    | 280       | 50        | 200 |
| 77696007763                                       | 77696007763 | 4    | 320       | 50        | 200 |
| 77696007765                                       | 77696007765 | 8    | 400       | 50        | 200 |
| 77696007768                                       | 77696007768 | 9    | 500       | 50        | 200 |
| 77696007791                                       | 77696007791 | 7    | 600       | 50        | 200 |
| 77696007793                                       | 77696007793 | 1    | 800       | 50        | 200 |
| 77696007795                                       | 77696007795 | 5    | 1000      | 50        | 200 |
| <b>6" x 11/16" A975 No-Fil Multi-Air Cyclonic</b> |             |      |           |           |     |
| 77696007770                                       | 77696007770 | 2    | 80        | 50        | 200 |
| 77696007773                                       | 77696007773 | 3    | 120       | 50        | 200 |
| 77696007774                                       | 77696007774 | 0    | 150       | 50        | 200 |
| 77696007775                                       | 77696007775 | 7    | 180       | 50        | 200 |
| 77696007776                                       | 77696007776 | 4    | 220       | 50        | 200 |
| 77696007777                                       | 77696007777 | 1    | 240       | 50        | 200 |
| 77696007778                                       | 77696007778 | 8    | 280       | 50        | 200 |
| 77696007781                                       | 77696007781 | 8    | 320       | 50        | 200 |
| 77696007784                                       | 77696007784 | 9    | 400       | 50        | 200 |
| 77696007785                                       | 77696007785 | 6    | 500       | 50        | 200 |
| 77696007786                                       | 77696007786 | 3    | 600       | 50        | 200 |
| 77696007787                                       | 77696007787 | 0    | 800       | 50        | 200 |
| 77696007788                                       | 77696007788 | 7    | 1000      | 50        | 200 |

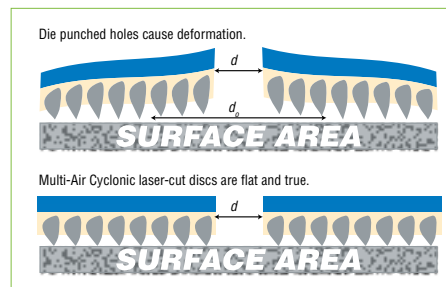

### Improved Dust Extraction / Increased Productivity

The upgrade to precise, flat, laser-cut holes instead of die-punched holes, dramatically increases surface area contact allowing Multi-Air Cyclonic discs to improve productivity by 32% versus conventional multi-hole sanding and by 60% versus non-vacuum sanding. The end result is more holes for dust extraction, more abrasive coverage for a better cut and no deformation - for full surface contact utilizing all the cutting power of the premium ceramic grain.



## Heavy-Weight Paper Discs

Heavy E- or F-weight paper backing discs for more demanding paper disc applications. Choose between Stick & Sand PSA backing or Hook & Sand hook and loop backing

Available packaged as individual standard or vacuum discs, or as a linked disc roll format which allows for easy application, removal, and dispensing.

### Grit Guide

| 36 GRIT                          | 40 GRIT                          | 60 GRIT                          | 80 GRIT                          | 100 GRIT                       | 120 GRIT                       |
|----------------------------------|----------------------------------|----------------------------------|----------------------------------|--------------------------------|--------------------------------|
| Roughing to intermediate sanding | Roughing to intermediate sanding | Roughing to intermediate sanding | Roughing to intermediate sanding | Intermediate to finish sanding | Intermediate to finish sanding |



### Norton SG H920 Ceramic Alumina

- Best choice for more demanding stock removal applications
- Durable and friable Norton seeded gel ceramic alumina abrasive ensures fast, aggressive, yet cool cutting action and maximum life
- Strong F-weight paper, synthetically-coated, provides maximum durability and resistance to edge chipping and shedding
- Closed coat and sharp grain make this a premiere product for soldered and welded areas



### Norton BlueFire H822 Zirconia Alumina

- Better choice for aggressive metalworking applications
- Patented zirconia alumina abrasive provides 2X-3X life over aluminum oxide products
- Strong F-weight paper, synthetically-coated for excellent durability and chip resistance
- Non-stearated (no anti-loading agents) for non-contaminating

| PART #                                     | UPC-A               | GRIT  | ROLLS/<br>PACK | DISCS/<br>ROLL |
|--|---------------------|-------|----------------|----------------|
| <b>Norton SG H920 Ceramic Alumina</b>      |                     |       |                |                |
| <b>5" Stick &amp; Sand Disc Rolls</b>      |                     |       |                |                |
| 66261149870                                | 662611 <b>49870</b> | 8 120 | 4              | 100            |
| 66261149872                                | 662611 <b>49872</b> | 2 80  | 4              | 100            |
| 66261149873                                | 662611 <b>49873</b> | 9 60  | 4              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b>      |                     |       |                |                |
| 66261149874                                | 662611 <b>49874</b> | 6 120 | 4              | 100            |
| 66261149876                                | 662611 <b>49876</b> | 0 80  | 4              | 100            |
| PART #                                     | UPC-A               | GRIT  | MIN/<br>PACK   | STD/<br>PACK   |
| <b>Norton SG H920 Ceramic Alumina</b>      |                     |       |                |                |
| <b>5" Hook &amp; Sand Individual Discs</b> |                     |       |                |                |
| 66261149867                                | 662611 <b>49867</b> | 8 120 | 50             | 250            |
| 66261149866                                | 662611 <b>49866</b> | 1 100 | 50             | 250            |
| 66261149865                                | 662611 <b>49865</b> | 4 80  | 50             | 250            |
| 66261149864                                | 662611 <b>49864</b> | 7 60  | 50             | 250            |

| PART #                                       | UPC-A               | GRIT  | ROLLS/<br>PACK | DISCS/<br>ROLL |
|--|---------------------|-------|----------------|----------------|
| <b>Norton BlueFire H822 Zirconia Alumina</b> |                     |       |                |                |
| <b>5" Stick &amp; Sand Disc Rolls</b>        |                     |       |                |                |
| 66261137308                                  | 662611 <b>37308</b> | 1 100 | 4              | 100            |
| 66261137309                                  | 662611 <b>37309</b> | 8 80  | 4              | 100            |
| 66261137310                                  | 662611 <b>37310</b> | 4 60  | 4              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b>        |                     |       |                |                |
| 66261137322                                  | 662611 <b>37322</b> | 7 120 | 4              | 100            |
| 66261137323                                  | 662611 <b>37323</b> | 4 80  | 4              | 100            |
| <b>8" Stick &amp; Sand Disc Rolls</b>        |                     |       |                |                |
| 66261137333                                  | 662611 <b>37333</b> | 3 120 | 4              | 50             |

## Heavy-Weight Paper Discs



### Norton BlueFire H875P Zirconia Alumina

- Better choice for soft material applications
- Next-generation, self-sharpening zirconia alumina abrasive provides 2-3 times the life of aluminum oxide discs, longer life versus original zirconia alumina discs, improved cut rate, and minimal heat
- Strong E-weight latex/paper backing resists tearing while staying conformable and flexible
- Open coat contributes to minimized loading

| PART #  | UPC-A       | GRIT | ROLLS/<br>PACK | DISCS/<br>ROLL |
|---|-------------|------|----------------|----------------|
| <b>Norton BlueFire H875P Zirconia Alumina</b>                         |             |      |                |                |
| <b>5" Stick &amp; Sand Disc Rolls</b>                                 |             |      |                |                |
| 66261124977   | 66261124977 | 5 80 | 4              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b>                                 |             |      |                |                |
| 66261125573   | 66261125573 | 8 80 | 4              | 100            |
| PART #  | UPC-A       | GRIT | MIN/<br>PACK   | STD/<br>PACK   |
| <b>Norton BlueFire H875P Zirconia Alumina</b>                         |             |      |                |                |
| <b>5" Stick &amp; Sand Individual Discs</b>                           |             |      |                |                |
| 66261125244   | 66261125244 | 7 80 | 50             | 200            |
| 66261125307   | 66261125307 | 9 40 | 50             | 200            |
| 66261125436   | 66261125436 | 6 36 | 50             | 200            |
| <b>6" Stick &amp; Sand Individual Discs</b>                           |             |      |                |                |
| 66261123573   | 66261123573 | 0 80 | 50             | 200            |
| 66261123574   | 66261123574 | 7 40 | 50             | 200            |
| 66261123575   | 66261123575 | 4 36 | 50             | 200            |
| <b>8" Stick &amp; Sand Individual Discs</b>                           |             |      |                |                |
| 66261123576   | 66261123576 | 1 80 | 25             | 100            |
| 66261123577   | 66261123577 | 8 40 | 25             | 100            |
| 66261123578   | 66261123578 | 5 36 | 25             | 100            |
| <b>6" x 6 Hole Die #3371 Stick &amp; Sand Individual Vacuum Discs</b> |             |      |                |                |
| 66261123580   | 66261123580 | 8 40 | 50             | 200            |
| <b>8" x 8 Hole Die #3370 Stick &amp; Sand Individual Vacuum Discs</b> |             |      |                |                |
| 66261123582   | 66261123582 | 2 80 | 25             | 100            |
| 66261123584   | 66261123584 | 6 36 | 25             | 100            |
| <b>5" Hook &amp; Sand Individual Discs</b>                            |             |      |                |                |
| 66261125444   | 66261125444 | 1 80 | 25             | 100            |
| 66261125684   | 66261125684 | 1 40 | 25             | 100            |
| <b>6" Hook &amp; Sand Individual Discs</b>                            |             |      |                |                |
| 66261123588   | 66261123588 | 4 80 | 25             | 100            |
| 66261123589   | 66261123589 | 1 40 | 25             | 100            |
| 66261123590   | 66261123590 | 7 36 | 25             | 100            |
| <b>8" Hook &amp; Sand Individual Discs</b>                            |             |      |                |                |
| 66261123591   | 66261123591 | 4 80 | 25             | 100            |
| 66261123592   | 66261123592 | 1 40 | 25             | 100            |
| 66261123593   | 66261123593 | 8 36 | 25             | 100            |
| <b>8" x 8 Hole Die #3370 Hook &amp; Sand Individual Vacuum Discs</b>  |             |      |                |                |
| 66261123596   | 66261123596 | 9 80 | 25             | 100            |
| 66261123598   | 66261123598 | 3 36 | 25             | 100            |





## Light-Weight Paper Discs

Light-weight B- or C-weight paper backing discs. Available with ceramic alumina, aluminum oxide, or silicon carbide grain. Choose between Stick & Sand PSA backing or Hook & Sand hook and loop backing

Available packaged as individual standard or vacuum discs, or as a linked disc roll format which allows for easy application, removal, and dispensing.

### Grit Guide

|                                  |                           |                       |                      |
|----------------------------------|---------------------------|-----------------------|----------------------|
| <b>60 - 80 GRIT</b>              | <b>80 - 240 GRIT</b>      | <b>240 - 800 GRIT</b> | <b>800 - 2000</b>    |
| Roughing to intermediate sanding | Intermediate to finishing | Fine finishing        | Ultra fine finishing |



### Norton Drylce A975 Ceramic Alumina

- Best choice for the most demanding sanding applications
- P-graded seeded-gel ceramic alumina abrasive for fastest cut rate and longest life of any paper disc
- Unique fiber reinforced, flexible B or C-weight latex saturated backing delivers 50% - 60% improvement in tear strength while retaining flexibility
- Water-based, non-pigmented stearate No-Fil coating and open coat provide maximum load resistance and no color transfer to work

| PART #                                | UPC-A                 | GRIT | ROLLS/<br>PACK | DISCS/<br>ROLL |
|---------------------------------------|-----------------------|------|----------------|----------------|
| <b>A975 No-Fil Ceramic Alumina</b>    |                       |      |                |                |
| <b>5" Stick &amp; Sand Disc Rolls</b> |                       |      |                |                |
| 66254480230                           | 662544 <b>80230</b> 6 | 800  | 4              | 100            |
| 66623305608                           | 666233 <b>05608</b> 7 | 600  | 4              | 100            |
| 66261155377                           | 662611 <b>55377</b> 3 | 400  | 4              | 100            |
| 66261155378                           | 662611 <b>55378</b> 0 | 320  | 4              | 100            |
| 66261155380                           | 662611 <b>55380</b> 3 | 240  | 4              | 100            |
| 66261142474                           | 662611 <b>42474</b> 5 | 220  | 4              | 100            |
| 66261140498                           | 662611 <b>40498</b> 3 | 180  | 4              | 100            |
| 66261140499                           | 662611 <b>40499</b> 0 | 150  | 4              | 100            |
| 66261140500                           | 662611 <b>40500</b> 3 | 120  | 4              | 100            |
| 66261140501                           | 662611 <b>40501</b> 0 | 100  | 4              | 100            |
| 66261140502                           | 662611 <b>40502</b> 7 | 80   | 4              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b> |                       |      |                |                |
| 63642506200                           | 636425 <b>06200</b> 4 | 800  | 4              | 100            |
| 63642506199                           | 636425 <b>06199</b> 1 | 600  | 4              | 100            |
| 63642506198                           | 636425 <b>06198</b> 4 | 500  | 4              | 100            |
| 66261155373                           | 662611 <b>55373</b> 5 | 400  | 4              | 100            |
| 66261155374                           | 662611 <b>55374</b> 2 | 320  | 4              | 100            |
| 66261155376                           | 662611 <b>55376</b> 6 | 240  | 4              | 100            |
| 66261148340                           | 662611 <b>48340</b> 7 | 220  | 4              | 100            |
| 66261140508                           | 662611 <b>40508</b> 9 | 180  | 4              | 100            |
| 66261140509                           | 662611 <b>40509</b> 6 | 150  | 4              | 100            |
| 66261140510                           | 662611 <b>40510</b> 2 | 120  | 4              | 100            |
| 66261140511                           | 662611 <b>40511</b> 9 | 100  | 4              | 100            |
| 66261140512                           | 662611 <b>40512</b> 6 | 80   | 4              | 100            |

| PART #   | UPC-A                 | GRIT | MIN/<br>PACK | STD/<br>PACK |
|--|-----------------------|------|--------------|--------------|
| <b>A975 No-Fil Ceramic Alumina</b>                                   |                       |      |              |              |
| <b>5" Hook &amp; Sand Individual Discs</b>                           |                       |      |              |              |
| 66254480232  | 662544 <b>80232</b> 0 | 800  | 50           | 200          |
| 66254480233  | 662544 <b>80233</b> 7 | 500  | 50           | 200          |
| 66261149537  | 662611 <b>49537</b> 0 | 400  | 50           | 200          |
| 66261149538  | 662611 <b>49538</b> 7 | 320  | 50           | 200          |
| 66261149540  | 662611 <b>49540</b> 0 | 240  | 50           | 200          |
| 66261149541  | 662611 <b>49541</b> 7 | 220  | 50           | 200          |
| 66261140518  | 662611 <b>40518</b> 8 | 180  | 50           | 200          |
| 66261140519  | 662611 <b>40519</b> 5 | 150  | 50           | 200          |
| 66261140520  | 662611 <b>40520</b> 1 | 120  | 50           | 200          |
| 66261140521  | 662611 <b>40521</b> 8 | 100  | 50           | 200          |
| 66261140522  | 662611 <b>40522</b> 5 | 80   | 50           | 200          |
| <b>6" Hook &amp; Sand Individual Discs</b>                           |                       |      |              |              |
| 63642506377  | 636425 <b>06377</b> 3 | 1500 | 50           | 200          |
| 63642506376  | 636425 <b>06376</b> 6 | 1200 | 50           | 200          |
| 63642506375  | 636425 <b>06375</b> 9 | 1000 | 50           | 200          |
| 63642506204  | 636425 <b>06204</b> 2 | 800  | 50           | 200          |
| 63642506203  | 636425 <b>06203</b> 5 | 600  | 50           | 200          |
| 63642506202  | 636425 <b>06202</b> 8 | 500  | 50           | 200          |
| 66261149542  | 662611 <b>49542</b> 4 | 400  | 50           | 200          |
| 66261149543  | 662611 <b>49543</b> 1 | 320  | 50           | 200          |
| 66261149546  | 662611 <b>49546</b> 2 | 220  | 50           | 200          |
| 66261140528  | 662611 <b>40528</b> 7 | 180  | 50           | 200          |
| 66261140529  | 662611 <b>40529</b> 4 | 150  | 50           | 200          |
| 66261140530  | 662611 <b>40530</b> 0 | 120  | 50           | 200          |
| 66261140531  | 662611 <b>40531</b> 7 | 100  | 50           | 200          |
| 66261140532  | 662611 <b>40532</b> 4 | 80   | 50           | 200          |
| <b>5" x 5 Hole Die #3328 Hook &amp; Sand Individual Vacuum Discs</b> |                       |      |              |              |
| 66261140515  | 662611 <b>40515</b> 7 | 120  | 50           | 200          |
| 66261140517  | 662611 <b>40517</b> 1 | 80   | 50           | 200          |

Light-Weight Paper Discs *continued*



Norton A275OP Aluminum Oxide

- Better choice for high-performance dry finishing on all materials
- Premium P-graded, heat treated, toughened aluminum oxide abrasive delivers superior life, fast cut rate, consistent finish
- Unique fiber reinforced, flexible B-weight latex saturated backing provides 50% - 60% improvement in tear strength while retaining flexibility
- Water-based, non-pigmented stearate No-Fil coating and open coat provide maximum load resistance and no color transfer to work
- 5" and 6" individual PSA discs in fine grits have a tabbed, white translucent liner to protect the PSA adhesive from airborne contaminants; the tab allows easier removal of the paper liner


| PART #                                    | UPC-A       | GRIT  | ROLLS/<br>PACK | DISCS/<br>ROLL |
|---|-------------|-------|----------------|----------------|
| <b>A275 No-Fil Aluminum Oxide</b>         |             |       |                |                |
| <b>3-1/2" Stick &amp; Sand Disc Rolls</b> |             |       |                |                |
| 66261136368                               | 66261136368 | 6 400 | 4              | 100            |
| 66261136369                               | 66261136369 | 3 320 | 4              | 100            |
| 66261136370                               | 66261136370 | 9 280 | 4              | 100            |
| 66261136372                               | 66261136372 | 3 220 | 4              | 100            |
| 66261136373                               | 66261136373 | 0 180 | 4              | 100            |
| 66261136375                               | 66261136375 | 4 120 | 4              | 100            |
| 66261136376                               | 66261136376 | 1 80  | 4              | 100            |
| <b>5" Stick &amp; Sand Disc Rolls</b>     |             |       |                |                |
| 66261131451                               | 66261131451 | 0 800 | 6              | 100            |
| 66261131452                               | 66261131452 | 7 600 | 6              | 100            |
| 66261131453                               | 66261131453 | 4 500 | 6              | 100            |
| 66261131454                               | 66261131454 | 1 400 | 6              | 100            |
| 66261131456                               | 66261131456 | 5 320 | 6              | 100            |
| 66261131458                               | 66261131458 | 9 280 | 6              | 100            |
| 66261131459                               | 66261131459 | 6 220 | 6              | 100            |
| 66261131460                               | 66261131460 | 2 180 | 6              | 100            |
| 66261131461                               | 66261131461 | 9 150 | 6              | 100            |
| 66261131462                               | 66261131462 | 6 120 | 6              | 100            |
| 66261131463                               | 66261131463 | 3 100 | 6              | 100            |
| 66261131464                               | 66261131464 | 0 80  | 6              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b>     |             |       |                |                |
| 66261131468                               | 66261131468 | 8 800 | 6              | 100            |
| 66261131469                               | 66261131469 | 5 600 | 6              | 100            |
| 66261131470                               | 66261131470 | 1 500 | 6              | 100            |
| 66261131471                               | 66261131471 | 8 400 | 6              | 100            |
| 66261131473                               | 66261131473 | 2 320 | 6              | 100            |
| 66261131474                               | 66261131474 | 9 280 | 6              | 100            |
| 66261131475                               | 66261131475 | 6 240 | 6              | 100            |
| 66261131476                               | 66261131476 | 3 220 | 6              | 100            |
| 66261131477                               | 66261131477 | 0 180 | 6              | 100            |
| 66261131478                               | 66261131478 | 7 150 | 6              | 100            |
| 66261131479                               | 66261131479 | 4 120 | 6              | 100            |
| 66261131480                               | 66261131480 | 0 100 | 6              | 100            |
| 66261131481                               | 66261131481 | 7 80  | 6              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b>     |             |       |                |                |
| 66261131609                               | 66261131609 | 5 320 | 4              | 100            |
| 66261131612                               | 66261131612 | 5 220 | 4              | 100            |
| 66261131613                               | 66261131613 | 2 180 | 4              | 100            |
| 66261131614                               | 66261131614 | 9 150 | 4              | 100            |
| 66261131615                               | 66261131615 | 6 120 | 4              | 100            |
| 66261131617                               | 66261131617 | 0 80  | 4              | 100            |

| PART #  | UPC-A       | GRIT   | MIN/<br>PACK | STD/<br>PACK |
|---|-------------|--------|--------------|--------------|
| <b>A275 No-Fil Aluminum Oxide</b>                               |             |        |              |              |
| <b>5" x 5 Hole Die #3329 Stick &amp; Sand Vacuum Disc Rolls</b> |             |        |              |              |
| 66261131488   | 66261131488 | 6 400  | 6            | 100          |
| 66261131490   | 66261131490 | 9 320  | 6            | 100          |
| 66261131492   | 66261131492 | 3 240  | 6            | 100          |
| 66261131493   | 66261131493 | 0 220  | 6            | 100          |
| 66261131494   | 66261131494 | 7 180  | 6            | 100          |
| 66261131495   | 66261131495 | 4 150  | 6            | 100          |
| 66261131496   | 66261131496 | 1 120  | 6            | 100          |
| 66261131497   | 66261131497 | 8 100  | 6            | 100          |
| 66261131498   | 66261131498 | 5 80   | 6            | 100          |
| <b>6" x 6 Hole Die #3333 Stick &amp; Sand Vacuum Disc Rolls</b> |             |        |              |              |
| 66261131503   | 66261131503 | 6 600  | 6            | 100          |
| 66261131505   | 66261131505 | 0 400  | 6            | 100          |
| 66261131507   | 66261131507 | 4 320  | 6            | 100          |
| 66261131508   | 66261131508 | 1 280  | 6            | 100          |
| 66261131509   | 66261131509 | 8 240  | 6            | 100          |
| 66261131510   | 66261131510 | 4 220  | 6            | 100          |
| 66261131511   | 66261131511 | 1 180  | 6            | 100          |
| 66261131512   | 66261131512 | 8 150  | 6            | 100          |
| 66261131513   | 66261131513 | 5 120  | 6            | 100          |
| 66261131514   | 66261131514 | 2 100  | 6            | 100          |
| 66261131515   | 66261131515 | 9 80   | 6            | 100          |
| <b>5" Stick &amp; Sand Individual Discs</b>                     |             |        |              |              |
| 66261131449   | 66261131449 | 7 1200 | 100          | 400          |
| 66261131450   | 66261131450 | 3 1000 | 100          | 400          |
| <b>6" Stick &amp; Sand Individual Discs</b>                     |             |        |              |              |
| 66261131465   | 66261131465 | 7 1500 | 100          | 400          |
| 66261131466   | 66261131466 | 4 1200 | 100          | 400          |
| 66261131467   | 66261131467 | 1 1000 | 100          | 400          |
| <b>3" Hook &amp; Sand Individual Discs</b>                      |             |        |              |              |
| 66261147434   | 66261147434 | 4 1500 | 50           | 200          |
| 66261135900   | 66261135900 | 9 1000 | 50           | 200          |
| 66261131519   | 66261131519 | 7 800  | 50           | 200          |
| 66261136996   | 66261136996 | 1 600  | 50           | 200          |
| 66261131521   | 66261131521 | 0 500  | 50           | 200          |
| 66261136995   | 66261136995 | 4 400  | 50           | 200          |
| 66261131524   | 66261131524 | 1 320  | 50           | 200          |
| 66261131526   | 66261131526 | 5 240  | 50           | 200          |
| 66261131527   | 66261131527 | 2 220  | 50           | 200          |
| 66261131528   | 66261131528 | 9 180  | 50           | 200          |
| 66261140385   | 66261140385 | 6 150  | 50           | 200          |
| 66261128688   | 66261128688 | 6 120  | 50           | 200          |
| 66261144926   | 66261144926 | 7 100  | 50           | 200          |
| 66261131532   | 66261131532 | 6 80   | 50           | 200          |
| <b>5" Hook &amp; Sand Individual Discs</b>                      |             |        |              |              |
| 66261131533   | 66261131533 | 3 1500 | 100          | 400          |
| 66261131534   | 66261131534 | 0 1200 | 100          | 400          |
| 66261131535   | 66261131535 | 7 1000 | 100          | 400          |
| 66261131536   | 66261131536 | 4 800  | 100          | 400          |
| 66261131537   | 66261131537 | 1 600  | 100          | 400          |
| 66261131538   | 66261131538 | 8 500  | 100          | 400          |
| 66261131539   | 66261131539 | 5 400  | 100          | 400          |
| 66261131541   | 66261131541 | 8 320  | 100          | 400          |
| 66261131542   | 66261131542 | 5 280  | 100          | 400          |
| 66261131543   | 66261131543 | 2 240  | 100          | 400          |
| 66261131544   | 66261131544 | 9 220  | 100          | 400          |
| 66261131545   | 66261131545 | 6 180  | 100          | 400          |
| 66261131546   | 66261131546 | 3 150  | 100          | 400          |
| 66261131547   | 66261131547 | 0 120  | 100          | 400          |
| 66261131548   | 66261131548 | 7 100  | 100          | 400          |
| 66261131549   | 66261131549 | 4 80   | 100          | 400          |

Light-Weight Paper Discs *continued*

| PART #                                     | UPC-A         | GRIT | MIN/<br>PACK | STD/<br>PACK |
|--|---------------|------|--------------|--------------|
| <b>A275 No-Fil Aluminum Oxide</b>          |               |      |              |              |
| <b>6" Hook &amp; Sand Individual Discs</b> |               |      |              |              |
| 66261131550                                | 66261131550 0 | 1500 | 100          | 400          |
| 66261131551                                | 66261131551 7 | 1200 | 100          | 400          |
| 66261131552                                | 66261131552 4 | 1000 | 100          | 400          |
| 66261131553                                | 66261131553 1 | 800  | 100          | 400          |
| 66261131554                                | 66261131554 8 | 600  | 100          | 400          |
| 66261131555                                | 66261131555 5 | 500  | 100          | 400          |
| 66261131556                                | 66261131556 2 | 400  | 100          | 400          |
| 66261131558                                | 66261131558 6 | 320  | 100          | 400          |
| 66261131559                                | 66261131559 3 | 280  | 100          | 400          |
| 66261131560                                | 66261131560 9 | 240  | 100          | 400          |
| 66261131561                                | 66261131561 6 | 220  | 100          | 400          |
| 66261131562                                | 66261131562 3 | 180  | 100          | 400          |
| 66261131563                                | 66261131563 0 | 150  | 100          | 400          |
| 66261131564                                | 66261131564 7 | 120  | 100          | 400          |
| 66261131565                                | 66261131565 4 | 100  | 100          | 400          |
| 66261131566                                | 66261131566 1 | 80   | 100          | 400          |
| <b>8" Hook &amp; Sand Individual Discs</b> |               |      |              |              |
| 66261131661                                | 66261131661 3 | 180  | 100          | 400          |
| 66261131662                                | 66261131662 0 | 120  | 100          | 400          |

| PART #   | UPC-A         | GRIT | MIN/<br>PACK | STD/<br>PACK |
|--|---------------|------|--------------|--------------|
| <b>A275 No-Fil Aluminum Oxide</b>                                    |               |      |              |              |
| <b>5" x 5 Hole Die #3328 Hook &amp; Sand Individual Vacuum Discs</b> |               |      |              |              |
| 66261131571  | 66261131571 5 | 600  | 100          | 40           |
| 66261131573  | 66261131573 9 | 400  | 100          | 40           |
| 66261131575  | 66261131575 3 | 320  | 100          | 40           |
| 66261131578  | 66261131578 4 | 220  | 100          | 40           |
| 66261131579  | 66261131579 1 | 180  | 100          | 40           |
| 66261131580  | 66261131580 7 | 150  | 100          | 40           |
| 66261131581  | 66261131581 4 | 120  | 100          | 40           |
| 66261131582  | 66261131582 1 | 100  | 100          | 40           |
| 66261131583  | 66261131583 8 | 80   | 100          | 40           |
| <b>6" x 6 Hole Die #3371 Hook &amp; Sand Individual Vacuum Discs</b> |               |      |              |              |
| 66261131584  | 66261131584 5 | 1500 | 100          | 40           |
| 66261131586  | 66261131586 9 | 1000 | 100          | 40           |
| 66261131587  | 66261131587 6 | 800  | 100          | 40           |
| 66261131588  | 66261131588 3 | 600  | 100          | 40           |
| 66261131590  | 66261131590 6 | 400  | 100          | 40           |
| 66261131592  | 66261131592 0 | 320  | 100          | 40           |
| 66261131595  | 66261131595 1 | 220  | 100          | 40           |
| 66261131596  | 66261131596 8 | 180  | 100          | 40           |
| 66261131597  | 66261131597 5 | 150  | 100          | 40           |
| 66261131598  | 66261131598 2 | 120  | 100          | 40           |
| 66261131599  | 66261131599 9 | 100  | 100          | 40           |
| 66261131600  | 66261131600 2 | 80   | 100          | 40           |

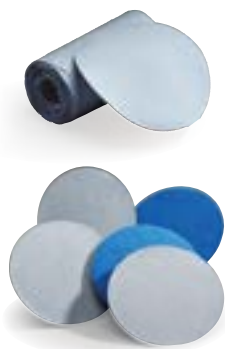

Norton Durite A475  
Silicon Carbide

- Better choice for hard-to-sand surfaces and wood applications
- Sharp and hard, P-graded, silicon carbide abrasive easily penetrates the hardest material and veneers to create finer finishes where finish is critical
- Flexible, B-weight fiber reinforced, latex paper backing provides flexibility and resistance to tearing
- Water-based, non-pigmented stearate No-Fil coating and open coat provide maximum load resistance and no color transfer to work

| PART #                                     | UPC-A         | GRIT | ROLLS/<br>PACK | DISCS/<br>ROLL |
|--|---------------|------|----------------|----------------|
| <b>A475 No-Fil Silicon Carbide</b>         |               |      |                |                |
| <b>5" Stick &amp; Sand Link Disc Rolls</b> |               |      |                |                |
| 66254421217                                | 66254421217 4 | 600  | 4              | 100            |
| 66261065293                                | 66261065293 4 | 400  | 4              | 100            |
| 66254487444                                | 66254487444 0 | 320  | 4              | 100            |
| 66254487443                                | 66254487443 3 | 240  | 4              | 100            |
| 66254487442                                | 66254487442 6 | 220  | 4              | 100            |
| 66254487441                                | 66254487441 9 | 180  | 4              | 100            |
| 66254487440                                | 66254487440 2 | 150  | 4              | 100            |
| 66254487418                                | 66254487418 1 | 120  | 4              | 100            |
| 66254487417                                | 66254487417 4 | 100  | 4              | 100            |
| 66254487415                                | 66254487415 0 | 80   | 4              | 100            |
| <b>6" Stick &amp; Sand Link Disc Rolls</b> |               |      |                |                |
| 66254487450                                | 66254487450 1 | 320  | 4              | 100            |
| 66254487449                                | 66254487449 5 | 220  | 4              | 100            |
| 66254487448                                | 66254487448 8 | 180  | 4              | 100            |
| 66254487447                                | 66254487447 1 | 120  | 4              | 100            |
| 66254487446                                | 66254487446 4 | 80   | 4              | 100            |
| PART #                                     | UPC-A         | GRIT | MIN/<br>PACK   | STD/<br>PACK   |
| <b>A475 No-Fil Silicon Carbide</b>         |               |      |                |                |
| <b>5" Hook &amp; Sand Individual Discs</b> |               |      |                |                |
| 66261052254                                | 66261052254 1 | 1000 | 100            | 400            |
| 66261052267                                | 66261052267 1 | 800  | 100            | 400            |

Light-Weight Paper Discs *continued*



PB273 Aluminum Oxide

- Good choice for sanding paint, primer, plastics, fiberglass, and whitewood at a low initial price
- P-graded, aluminum oxide abrasive for fast cutting action and extended life with consistent finish
- Flexible latex B-weight backing, with a full resin bond and open coat provides improved resistance to delamination; no delamination to back-up pad
- Water-based stearate, non-pigmented, No-Fil coating provides improved load resistance with no color transfer to work

| PART #                                | UPC-A       | GRIT | ROLLS/<br>PACK | DISCS/<br>ROLL |
|---------------------------------------|-------------|------|----------------|----------------|
| <b>PB273 No-Fil Aluminum Oxide</b>    |             |      |                |                |
| <b>5" Stick &amp; Sand Disc Rolls</b> |             |      |                |                |
| 66623362921                           | 66623362921 | 2    | 4              | 100            |
| 66623362922                           | 66623362922 | 9    | 4              | 100            |
| 66623362923                           | 66623362923 | 6    | 4              | 100            |
| 66623362924                           | 66623362924 | 3    | 4              | 100            |
| 66623362925                           | 66623362925 | 0    | 4              | 100            |
| 66623362926                           | 66623362926 | 7    | 4              | 100            |
| 66623362927                           | 66623362927 | 4    | 4              | 100            |
| 66623362928                           | 66623362928 | 1    | 4              | 100            |
| 66623362929                           | 66623362929 | 8    | 4              | 100            |
| 66623362930                           | 66623362930 | 4    | 4              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b> |             |      |                |                |
| 66623362931                           | 66623362931 | 1    | 4              | 100            |
| 66623362932                           | 66623362932 | 8    | 4              | 100            |
| 66623362933                           | 66623362933 | 5    | 4              | 100            |
| 66623362934                           | 66623362934 | 2    | 4              | 100            |
| 66623362935                           | 66623362935 | 9    | 4              | 100            |
| 66623362936                           | 66623362936 | 6    | 4              | 100            |
| 66623362937                           | 66623362937 | 3    | 4              | 100            |
| 66623362938                           | 66623362938 | 0    | 4              | 100            |
| 66623362939                           | 66623362939 | 7    | 4              | 100            |
| 69957352447                           | 69957352447 | 3    | 4              | 100            |
| 66623362940                           | 66623362940 | 3    | 4              | 100            |

| PART #   | UPC-A       | GRIT | MIN/<br>PACK | STD/<br>PACK |
|--|-------------|------|--------------|--------------|
| <b>PB273 No-Fil Aluminum Oxide</b>                           |             |      |              |              |
| <b>5" Stick &amp; Sand Individual Disc</b>                   |             |      |              |              |
| 69957348223  | 69957348223 | 0    | 100          | 400          |
| 69957348206  | 69957348206 | 3    | 100          | 400          |
| 69957348204  | 69957348204 | 9    | 100          | 400          |
| 69957348203  | 69957348203 | 2    | 100          | 400          |
| 69957348201  | 69957348201 | 8    | 100          | 400          |
| 69957348200  | 69957348200 | 1    | 100          | 400          |
| 69957348198  | 69957348198 | 1    | 100          | 400          |
| <b>5" Hook &amp; Sand Individual Disc</b>                    |             |      |              |              |
| 66623362941  | 66623362941 | 0    | 100          | 400          |
| 66623362942  | 66623362942 | 7    | 100          | 400          |
| 66623362943  | 66623362943 | 4    | 100          | 400          |
| 66623362944  | 66623362944 | 1    | 100          | 400          |
| 66623362945  | 66623362945 | 8    | 100          | 400          |
| 66623362946  | 66623362946 | 5    | 100          | 400          |
| 66623362947  | 66623362947 | 2    | 100          | 400          |
| 66623362948  | 66623362948 | 9    | 100          | 400          |
| 66623362949  | 66623362949 | 6    | 100          | 400          |
| 66623365788  | 66623365788 | 8    | 100          | 400          |
| 66623362950  | 66623362950 | 2    | 100          | 400          |
| <b>6" Hook &amp; Sand Individual Disc</b>                    |             |      |              |              |
| 66623362951  | 66623362951 | 9    | 100          | 400          |
| 66623362952  | 66623362952 | 6    | 100          | 400          |
| 66623362953  | 66623362953 | 3    | 100          | 400          |
| 66623362954  | 66623362954 | 0    | 100          | 400          |
| 66623362955  | 66623362955 | 7    | 100          | 400          |
| 66623362956  | 66623362956 | 4    | 100          | 400          |
| 66623362957  | 66623362957 | 1    | 100          | 400          |
| 66623362958  | 66623362958 | 8    | 100          | 400          |
| 66623362959  | 66623362959 | 5    | 100          | 400          |
| 66623365789  | 66623365789 | 5    | 100          | 400          |
| 66623362960  | 66623362960 | 1    | 100          | 400          |
| <b>5" x 8 Hole Die #3392 Hook &amp; Sand Individual Disc</b> |             |      |              |              |
| 66623366077  | 66623366077 | 2    | 100          | 400          |
| 66623366075  | 66623366075 | 8    | 100          | 400          |
| 66623366074  | 66623366074 | 1    | 100          | 400          |
| 66623369778  | 66623369778 | 5    | 100          | 400          |
| 66623366071  | 66623366071 | 0    | 100          | 400          |
| <b>6" x 6 Hole Die #3371 Hook &amp; Sand Individual Disc</b> |             |      |              |              |
| 66623367400  | 66623367400 | 7    | 100          | 400          |
| 66623367399  | 66623367399 | 4    | 100          | 400          |
| 66623367398  | 66623367398 | 7    | 100          | 400          |
| 66623367394  | 66623367394 | 9    | 100          | 400          |



Light-Weight Paper Discs *continued*




Norton Gold A296  
Aluminum Oxide

- Good choice for sanding a broad range of substrates including primed or painted surfaces, wood, composites, aluminum, and ferrous metals
- P-graded premium aluminum oxide abrasive produces a quick, cool cut and a more consistent surface finish
- Strong B-weight latex/paper backing resists tearing while staying conformable and flexible
- Water-based, non-loading (No-Fil) stearate coating minimizes clogging and increases disc life

| PART #  | UPC-A       | GRIT | ROLLS/<br>PACK | DISCS/<br>ROLL |
|---|-------------|------|----------------|----------------|
| <b>A296 No-Fil Aluminum Oxide</b>                               |             |      |                |                |
| <b>5" Stick &amp; Sand Disc Rolls</b>                           |             |      |                |                |
| 66261149821   | 66261149821 | 0    | 4              | 100            |
| 66261149822   | 66261149822 | 7    | 4              | 100            |
| 66261149823   | 66261149823 | 4    | 4              | 100            |
| 66261149824   | 66261149824 | 1    | 4              | 100            |
| 66261149825   | 66261149825 | 8    | 4              | 100            |
| 66261149826   | 66261149826 | 5    | 4              | 100            |
| 66261149827   | 66261149827 | 2    | 4              | 100            |
| 66261149828   | 66261149828 | 9    | 4              | 100            |
| 66261149829   | 66261149829 | 6    | 4              | 100            |
| 66261149830   | 66261149830 | 2    | 4              | 100            |
| 66261149831   | 66261149831 | 9    | 4              | 100            |
| <b>6" Stick &amp; Sand Disc Rolls</b>                           |             |      |                |                |
| 66261149833   | 66261149833 | 3    | 4              | 100            |
| 66261149834   | 66261149834 | 0    | 4              | 100            |
| 66261149835   | 66261149835 | 7    | 4              | 100            |
| 66261149836   | 66261149836 | 4    | 4              | 100            |
| 66261149837   | 66261149837 | 1    | 4              | 100            |
| 66261149838   | 66261149838 | 8    | 4              | 100            |
| 66261149839   | 66261149839 | 5    | 4              | 100            |
| 66261149840   | 66261149840 | 1    | 4              | 100            |
| 66261149841   | 66261149841 | 8    | 4              | 100            |
| 66261149842   | 66261149842 | 5    | 4              | 100            |
| 66261149847   | 66261149847 | 0    | 4              | 100            |
| <b>5" x 5 Hole Die #3329 Stick &amp; Sand Vacuum Disc Rolls</b> |             |      |                |                |
| 66261130258   | 66261130258 | 6    | 4              | 100            |
| 66261130260   | 66261130260 | 9    | 4              | 100            |
| 66261130261   | 66261130261 | 6    | 4              | 100            |
| 66261130262   | 66261130262 | 3    | 4              | 100            |
| 66261130263   | 66261130263 | 0    | 4              | 100            |
| 66261130265   | 66261130265 | 4    | 4              | 100            |
| 66261130266   | 66261130266 | 1    | 4              | 100            |
| <b>6" x 6 Hole Die #3333 Stick &amp; Sand Vacuum Disc Rolls</b> |             |      |                |                |
| 66261130268   | 66261130268 | 5    | 4              | 100            |
| 66261130271   | 66261130271 | 5    | 4              | 100            |
| 66261130272   | 66261130272 | 2    | 4              | 100            |
| 66261130273   | 66261130273 | 9    | 4              | 100            |
| 66261130274   | 66261130274 | 6    | 4              | 100            |
| 66261130275   | 66261130275 | 3    | 4              | 100            |
| 66261130276   | 66261130276 | 0    | 4              | 100            |

| PART #   | UPC-A       | GRIT | MIN/<br>PACK | STD/<br>PACK |
|--|-------------|------|--------------|--------------|
| <b>A296 No-Fil Aluminum Oxide</b>                                    |             |      |              |              |
| <b>5" Hook &amp; Sand Individual Discs</b>                           |             |      |              |              |
| 66261149899  | 66261149899 | 9    | 100          | 400          |
| 66261149900  | 66261149900 | 2    | 100          | 400          |
| 66261149902  | 66261149902 | 6    | 100          | 400          |
| 66261149903  | 66261149903 | 3    | 100          | 400          |
| 66261149904  | 66261149904 | 0    | 100          | 400          |
| 66261149905  | 66261149905 | 7    | 100          | 400          |
| 66261149906  | 66261149906 | 4    | 100          | 400          |
| 66261149907  | 66261149907 | 1    | 100          | 400          |
| 66261130224  | 66261130224 | 1    | 100          | 400          |
| <b>6" Hook &amp; Sand Individual Discs</b>                           |             |      |              |              |
| 66261149908  | 66261149908 | 8    | 100          | 400          |
| 66261149909  | 66261149909 | 5    | 100          | 400          |
| 66261149911  | 66261149911 | 8    | 100          | 400          |
| 66261149912  | 66261149912 | 5    | 100          | 400          |
| 66261149913  | 66261149913 | 2    | 100          | 400          |
| 66261149914  | 66261149914 | 9    | 100          | 400          |
| 66261149915  | 66261149915 | 6    | 100          | 400          |
| 66261149916  | 66261149916 | 3    | 100          | 400          |
| <b>5" x 5 Hole Die #3828 Hook &amp; Sand Individual Vacuum Discs</b> |             |      |              |              |
| 66261130226  | 66261130226 | 5    | 50           | 200          |
| 66261130227  | 66261130227 | 2    | 50           | 200          |
| 66261130230  | 66261130230 | 2    | 50           | 200          |
| 66261130231  | 66261130231 | 9    | 50           | 200          |
| 66261130232  | 66261130232 | 6    | 50           | 200          |
| 66261130233  | 66261130233 | 3    | 50           | 200          |
| 66261130234  | 66261130234 | 0    | 50           | 200          |
| 66261130235  | 66261130235 | 7    | 50           | 200          |
| 66261130236  | 66261130236 | 4    | 50           | 200          |
| <b>5" x 8 Hole Die #3392 Hook &amp; Sand Individual Vacuum Discs</b> |             |      |              |              |
| 66261130238  | 66261130238 | 8    | 50           | 200          |
| 66261130239  | 66261130239 | 5    | 50           | 200          |
| 66261130240  | 66261130240 | 1    | 50           | 200          |
| 66261130241  | 66261130241 | 8    | 50           | 200          |
| 66261130242  | 66261130242 | 5    | 50           | 200          |
| 66261130243  | 66261130243 | 2    | 50           | 200          |
| 66261130244  | 66261130244 | 9    | 50           | 200          |
| 66261130245  | 66261130245 | 6    | 50           | 200          |
| <b>6" x 6 Hole Die #3371 Hook &amp; Sand Individual Vacuum Discs</b> |             |      |              |              |
| 66261130250  | 66261130250 | 0    | 50           | 200          |
| 66261130251  | 66261130251 | 7    | 50           | 200          |
| 66261130253  | 66261130253 | 1    | 50           | 200          |
| 66261130255  | 66261130255 | 5    | 50           | 200          |

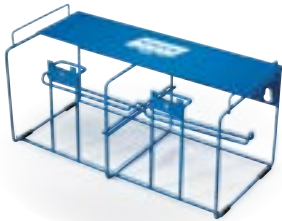

### PSA Disc Roll Dispenser

- Norton Disc Roll Dispensers feature heavy-duty construction and a rubberized finish to protect your product, as well as the finish on your workpiece
- These versatile dispensers are designed to accommodate any 5" or 6" disc roll or sheet roll
- Can be attached to a wall or stacked for multi-grit or multi-diameter operations
- Discs are individually dispensed and removed from the roll by a cutter bar

| PART #                         | UPC-A                 | DESCRIPTION                        | STD. PKG. |
|--------------------------------|-----------------------|------------------------------------|-----------|
| <b>PSA Disc Roll Dispenser</b> |                       |                                    |           |
| 63642542772                    | 636425 <b>42772</b> 8 | Single Disc Roll Dispenser         | 1         |
| 63642502981                    | 636425 <b>02981</b> 6 | Double Disc Roll Dispenser (shown) | 1         |



### Multi-Air Foam Interface Pads

- Designed for use with fine grit Multi-Air Cyclonic hook and loop sanding discs to improve both surface finish and cut rate
- Use with Multi-Air disc back-up pads
- Align the interface pad with the Multi-Air back-up pad then simply attach the disc to the interface pad because the holes do not have to be lined up

| PART #                               | UPC-A                 | DESCRIPTION                  | STD. PKG. |
|--------------------------------------|-----------------------|------------------------------|-----------|
| <b>Multi-Air Foam Interface Pads</b> |                       |                              |           |
| 63642585864                          | 636425 <b>85864</b> 5 | 5" Diameter x 1/2" Thick Pad | 8         |
| 07660719359                          | 076607 <b>19359</b> 9 | 6" Diameter x 1/2" Thick Pad | 12        |



### Multi-Air Hook and Loop Back-up Pads with Vacuum Holes

- Innovative design optimized for maximum air flow and powerful dust extraction
- Pads are engineered with a durable urethane foam, heat-resistant plastic, a molded-in 5/16"-24 spindle, and hooked face
- Holes in the disc do not have to be matched up with the holes in the pad, so changeover is fast and easy

| PART #  | UPC-A                 | DESCRIPTION   | MAX. RPM | STD. PKG. |
|---|-----------------------|---|----------|-----------|
| <b>Multi-Air Hook &amp; Loop Back-Up Pads with Vacuum Holes</b> |                       |   |          |           |
| 66623376000   | 666233 <b>76000</b> 7 | 5" (125mm) with 5/16"-24 Shank, Medium-Density Urethane Pad | 15,000   | 5         |
| 63642506160   | 636425 <b>06160</b> 1 | 6" (150mm) with 5/16"-24 Shank, Medium-Density Urethane Pad | 15,000   | 5         |



### Low-Profile Pads for Dual Action / Random Orbital Sanders

- Soft density low-profile pads utilize 1/2" thick foam for fine finish sanding and offer moderate conformability
- Medium low-profile pads have 1/2" thick urethane foam for intermediate and finish sanding
- Available with PSA or hook and loop faces; both designs are shock resistant and have a fiberglass backing plate with a riveted 5/16"-24 threaded shank for added strength and increased heat resistance
- Available with standard hole patterns for vacuum-assist sanding

| PART #  | UPC-A                 | DESCRIPTION  | MAX. RPM | STD. PKG. |
|---|-----------------------|--|----------|-----------|
| <b>Low Profile Pads for DA/Random Orbital Sanders</b> |                       |  |          |           |
| 63642506128   | 636425 <b>06128</b> 1 | 3" Hook and Loop Soft Low-Profile                                | 12,000   | 10*       |
| 66261085302   | 662610 <b>85302</b> 7 | 3-1/4" Hook & Loop Buffering Pad                                 | 12,000   | 5*        |
| 63642506126   | 636425 <b>06126</b> 7 | 5" PSA Soft Low-Profile  | 12,000   | 5*        |
| 63642506131   | 636425 <b>06131</b> 1 | 5" PSA Medium Low-Profile  | 15,000   | 5*        |
| 63642506132   | 636425 <b>06132</b> 8 | 5" PSA Medium Low-Profile with 5 vacuum holes                    | 15,000   | 5*        |
| 63642506129   | 636425 <b>06129</b> 8 | 5" Hook and Loop Soft Low-Profile                                | 12,000   | 5*        |
| 63642506135   | 636425 <b>06135</b> 9 | 5" Hook and Loop Medium Low-Profile                              | 15,000   | 5*        |
| 63642506136   | 636425 <b>06136</b> 6 | 5" Hook and Loop Medium Low-Profile with 5 vacuum holes          | 15,000   | 5*        |
| 63642506127   | 636425 <b>06127</b> 4 | 6" PSA Soft Low-Profile  | 12,000   | 5*        |
| 63642506133   | 636425 <b>06133</b> 5 | 6" PSA Medium Low-Profile  | 15,000   | 5*        |
| 63642506130   | 636425 <b>06130</b> 4 | 6" Hook and Loop Soft Low-Profile                                | 12,000   | 5*        |
| 63642506137   | 636425 <b>06137</b> 3 | 6" Hook and Loop Medium Low-Profile                              | 15,000   | 5*        |
| 63642506138   | 636425 <b>06138</b> 0 | 6" Hook and Loop Medium Low-Profile with 6 vacuum holes          | 15,000   | 5*        |
| 63642543712   | 636425 <b>43712</b> 3 | 8" Hook and Loop Medium Low-Profile with 8 vacuum holes, 5 screw | 1,500    | 5*        |

\* Packed in individual clamshell



### Tapered Pads for Dual Action / Random Orbital Sanders

- Designed with medium density polyurethane foam and a tapered edge for conformability, these pads are firm enough for flat surfaces, yet soft enough for severe curves and contours
- Available with either PSA (vinyl) or hook and loop faces in vacuum or non-vacuum
- The 5" and 6" pads are shock resistant and have a fiberglass backing plate with a riveted 5/16"-24 threaded shank for use on random orbital or dual action sanders
- The 8" pads have a 5/8"-11 threaded female hub

| PART #  | UPC-A                 | DESCRIPTION   | MAX. RPM | STD. PKG. |
|---|-----------------------|---|----------|-----------|
| <b>Tapered Pads for DA/Random Orbital Sanders</b> |                       |   |          |           |
| 63642506139                                       | 636425 <b>06139</b> 7 | 5" PSA Medium Tapered                               | 15,000   | 5*        |
| 63642506140                                       | 636425 <b>06140</b> 3 | 5" PSA Medium Tapered with 5 vacuum holes           | 15,000   | 5*        |
| 63642506143                                       | 636425 <b>06143</b> 4 | 5" Hook and Loop Medium Tapered                     | 15,000   | 5*        |
| 63642506141                                       | 636425 <b>06141</b> 0 | 6" PSA Medium Tapered                               | 15,000   | 5*        |
| 63642506142                                       | 636425 <b>06142</b> 7 | 6" PSA Medium Tapered with 6 vacuum holes           | 15,000   | 5*        |
| 63642506145                                       | 636425 <b>06145</b> 8 | 6" Hook and Loop Medium Tapered                     | 15,000   | 5*        |
| 63642506146                                       | 636425 <b>06146</b> 5 | 6" Hook and Loop Medium Tapered with 6 vacuum holes | 15,000   | 5*        |
| 63642543112                                       | 636425 <b>43112</b> 1 | 8" PSA Medium Tapered                               | 6,000    | 5*        |
| 63642543704                                       | 636425 <b>43704</b> 8 | 8" Hook and Loop Medium Tapered                     | 3,200    | 5*        |

\* Packed in individual clamshell



### Hook and Loop Foam Interface Pads

- Designed for use with our fine grit hook and loop sanding discs
- Improve both surface finish and cut rate
- Use with hook and loop back-up pads

| PART #                                     | UPC-A                 | DESCRIPTION                       | STD. PKG. |
|--|-----------------------|-----------------------------------|-----------|
| <b>Foam Hook &amp; Loop Interface Pads</b> |                       |                                   |           |
| 63642505457                                | 636425 <b>05457</b> 3 | 3" Diameter, 1/2" Thick Interface | 10        |
| 63642542089                                | 636425 <b>42089</b> 7 | 6" Diameter, 1/2" Thick Interface | 5         |
| 63642502161                                | 636425 <b>02161</b> 2 | 5" Diameter, 3/4" Thick Interface | 2         |
| 63642502162                                | 636425 <b>02162</b> 9 | 6" Diameter, 3/4" Thick Interface | 20        |



### Half Moon Hand Pad

- The unique half moon pad uses a standard 5" hook and loop disc folded in half, which adheres to the hooks on the pad face
- The straight edge of the pad allows the operator to sand corners, contours, narrow crevices and minute imperfections without over-sanding

| PART #                    | UPC-A                 | DESCRIPTION               | STD. PKG. |
|---------------------------|-----------------------|---------------------------|-----------|
| <b>Half Moon Hand Pad</b> |                       |                           |           |
| 63642502768               | 636425 <b>02768</b> 3 | 5" Hook and Loop Hand Pad | 10        |



### Polishing Adapter Pad

- Converts your standard hook and loop pad into a soft polishing pad
- The foam adapter is 3/8" thick and is excellent for fine grits where minimal removal is required
- It is ideal for either flat or contour surfaces

| PART #                       | UPC-A                 | DESCRIPTION                  | MAX. RPM | STD. PKG. |
|------------------------------|-----------------------|------------------------------|----------|-----------|
| <b>Polishing Adapter Pad</b> |                       |                              |          |           |
| 63642503121                  | 636425 <b>03121</b> 5 | 5" Hook and Loop Adapter Pad | 3,786    | 10        |



### Disc Hand Pads

- Hand pads eliminate finger sanding
- The ultra-thin 3/16" thick pad is composed of a single layer of neoprene foam and is designed for maximum flexibility - producing excellent finishes
- The 1" thick pad is composed of two layers, neoprene and polyester foam, for excellent conformability and softness, resulting in fine finishes
- Each pad has an elastic hand strap to hold it firmly in place
- Available with either PSA (vinyl) faces or hook and loop face

| PART #                | UPC-A                 | DESCRIPTION                           | STD. PKG. |
|-----------------------|-----------------------|---------------------------------------|-----------|
| <b>Disc Hand Pads</b> |                       |                                       |           |
| 63642503111           | 636425 <b>03111</b> 6 | 5" x 3/16" Thick Soft Foam PSA        | 10        |
| 63642502842           | 636425 <b>02842</b> 0 | 5" x 1" Thick Soft Foam PSA           | 10        |
| 63642503117           | 636425 <b>03117</b> 8 | 5" x 1" Thick Soft Foam Hook and Loop | 10        |



### Ergonomic Hand Sanders

- The ergonomic palm sander is uniquely designed to be user-friendly, with finger indentations for the operator
- It quickly converts standard 5" and 6" hook and loop discs into hand sanders for finishing flat surfaces

| PART #                       | UPC-A                 | DESCRIPTION                  | STD. PKG. |
|------------------------------|-----------------------|------------------------------|-----------|
| <b>Ergonomic Hand Sander</b> |                       |                              |           |
| 63642503147                  | 636425 <b>03147</b> 5 | 5" Hook and Loop Hand Sander | 5         |
| 63642503726                  | 636425 <b>03726</b> 2 | 6" Hook and Loop Hand Sander | 5         |




### Panel and Adhesive Cleaner

- Removes adhesives, tar, grease, wax, body sealers, undercoating sprays, and silicone from most surfaces
- Aggressive cleaner is safe to use on most paint applications
- Packaged with squirt dispenser
- Use as directed

| PART #                            | UPC-A                 | DESCRIPTION                | STD. PKG. |
|-----------------------------------|-----------------------|----------------------------|-----------|
| <b>Panel and Adhesive Cleaner</b> |                       |                            |           |
| 07660782780                       | 076607 <b>82780</b> 7 | Panel and Adhesive Cleaner | 12        |



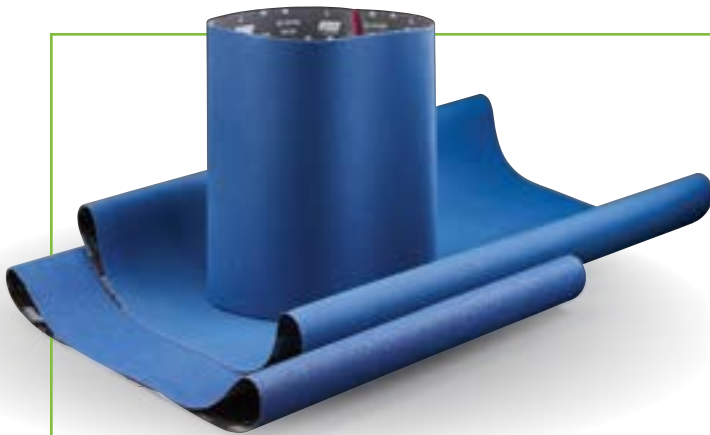

## Wide Belts – Cloth

Cloth woodworking wide belts are used for rough stock removal and dimensioning.

Our FastTrack express belt service has an extensive range of sizes and specifications with exceptional leadtimes.

| W x L     | Z/A  |             | A/O   |
|-----------|------|-------------|-------|
|           | GRIT | Y-WT. X-WT. |       |
| 4" x 90"  | 36   | 60846       | 60000 |
|           | 40   | 60847       | 60001 |
|           | 50   | 60848       | 60002 |
|           | 60   | 60849       | 60003 |
|           | 80   | 60850       | 60004 |
|           | 100  | 60851       | 60005 |
|           | 120  | 60852       | 60006 |
|           | 150  |             | 60007 |
|           | 180  |             | 60008 |
| 220       |      | 60009       |       |
| 4" x 132" | 36   | 60863       | 60019 |
|           | 40   | 60864       | 60020 |
|           | 50   | 60865       | 60021 |
|           | 60   | 60866       | 60022 |
|           | 80   | 60867       | 60023 |
|           | 100  | 60868       | 60024 |
|           | 120  | 60869       | 60025 |
|           | 150  |             | 60026 |
|           | 180  |             | 60027 |
| 220       |      | 60028       |       |
| 6" x 80"  | 36   | 60889       | 60038 |
|           | 40   | 60890       | 60039 |
|           | 50   | 60891       | 60040 |
|           | 60   | 60892       | 60041 |
|           | 80   | 60893       | 60042 |
|           | 100  | 60894       | 60043 |
|           | 120  | 60895       | 60044 |
|           | 150  |             | 60045 |
|           | 180  |             | 60046 |
| 220       |      | 60047       |       |
| 6" x 89"  | 36   | 60906       | 60058 |
|           | 40   | 60907       | 60059 |
|           | 50   | 60908       | 60060 |
|           | 60   | 60909       | 60061 |
|           | 80   | 60910       | 60062 |
|           | 100  | 60911       | 60063 |
|           | 120  | 60912       | 60064 |
|           | 150  |             | 60065 |
|           | 180  |             | 60066 |
| 220       |      | 60067       |       |
| 6" x 90"  | 36   | 60913       | 60068 |
|           | 40   | 60914       | 60069 |
|           | 50   | 60915       | 60070 |
|           | 60   | 60916       | 60071 |
|           | 80   | 60917       | 60072 |
|           | 100  | 60918       | 60073 |
|           | 120  | 60919       | 60074 |
|           | 150  |             | 60075 |
|           | 180  |             | 60076 |
| 220       |      | 60077       |       |

| W x L     | Z/A  |             | A/O   |
|-----------|------|-------------|-------|
|           | GRIT | Y-WT. X-WT. |       |
| 6" x 108" | 36   | 60920       | 60078 |
|           | 40   | 60921       | 60079 |
|           | 50   | 60922       | 60080 |
|           | 60   | 60923       | 60081 |
|           | 80   | 60924       | 60082 |
|           | 100  | 60925       | 60083 |
|           | 120  | 60926       | 60084 |
|           | 150  |             | 60085 |
|           | 180  |             | 60086 |
| 220       |      | 60087       |       |
| 6" x 132" | 36   | 60938       | 60098 |
|           | 40   | 60939       | 60099 |
|           | 50   | 60940       | 60100 |
|           | 60   | 60941       | 60101 |
|           | 80   | 60942       | 60102 |
|           | 100  | 60943       | 60103 |
|           | 120  | 60944       | 60104 |
|           | 150  |             | 60105 |
|           | 180  |             | 60106 |
| 220       |      | 60107       |       |
| 6" x 144" | 36   | 60955       | 60108 |
|           | 40   | 60956       | 60109 |
|           | 50   | 60957       | 60110 |
|           | 60   | 60958       | 60111 |
|           | 80   | 60959       | 60112 |
|           | 100  | 60960       | 60113 |
|           | 120  | 60961       | 60114 |
|           | 150  |             | 60115 |
|           | 180  |             | 60116 |
| 220       |      | 60117       |       |
| 6" x 158" | 36   | 60962       | 60118 |
|           | 40   | 60963       | 60119 |
|           | 50   | 60964       | 60120 |
|           | 60   | 60965       | 60121 |
|           | 80   | 60966       | 60122 |
|           | 100  | 60967       | 60123 |
|           | 120  | 60968       | 60124 |
|           | 150  |             | 60125 |
|           | 180  |             | 60126 |
| 220       |      | 60127       |       |
| 6" x 159" | 36   | 60969       | 60128 |
|           | 40   | 60970       | 60129 |
|           | 50   | 60971       | 60130 |
|           | 60   | 60972       | 60131 |
|           | 80   | 60973       | 60132 |
|           | 100  | 60974       | 60133 |
|           | 120  | 60975       | 60134 |
|           | 150  |             | 60135 |
|           | 180  |             | 60136 |
| 220       |      | 60137       |       |

| W x L     | Z/A  |             | A/O   |
|-----------|------|-------------|-------|
|           | GRIT | Y-WT. X-WT. |       |
| 6" x 168" | 36   | 60976       | 60138 |
|           | 40   | 60977       | 60139 |
|           | 50   | 60978       | 60140 |
|           | 60   | 60979       | 60141 |
|           | 80   | 60980       | 60142 |
|           | 100  | 60981       | 60143 |
|           | 120  | 60982       | 60144 |
|           | 150  |             | 60145 |
|           | 180  |             | 60146 |
| 220       |      | 60147       |       |
| 6" x 186" | 36   | 60993       | 60158 |
|           | 40   | 60994       | 60159 |
|           | 50   | 60995       | 60160 |
|           | 60   | 60996       | 60161 |
|           | 80   | 60997       | 60162 |
|           | 100  | 60998       | 60163 |
|           | 120  | 60999       | 60164 |
|           | 150  |             | 60165 |
|           | 180  |             | 60166 |
| 220       |      | 60167       |       |
| 18" x 48" | 36   | 61010       | 60178 |
|           | 40   | 61011       | 60179 |
|           | 50   | 61012       | 60180 |
|           | 60   | 61013       | 60181 |
|           | 80   | 61014       | 60182 |
|           | 100  | 61015       | 60183 |
|           | 120  | 61016       | 60184 |
|           | 150  |             | 60185 |
|           | 180  |             | 60186 |
| 220       |      | 60187       |       |
| 18" x 72" | 36   | 61017       | 60188 |
|           | 40   | 61018       | 60189 |
|           | 50   | 61019       | 60190 |
|           | 60   | 61020       | 60191 |
|           | 80   | 61021       | 60192 |
|           | 100  | 61022       | 60193 |
|           | 120  | 61023       | 60194 |
|           | 150  |             | 60195 |
|           | 180  |             | 60196 |
| 220       |      | 60197       |       |
| 18" x 75" | 36   | 61024       | 60198 |
|           | 40   | 61025       | 60199 |
|           | 50   | 61026       | 60200 |
|           | 60   | 61027       | 60201 |
|           | 80   | 61028       | 60202 |
|           | 100  | 61029       | 60203 |
|           | 120  | 61030       | 60204 |
|           | 150  |             | 60205 |
|           | 180  |             | 60206 |
| 220       |      | 60207       |       |

| W x L     | Z/A  |             | A/O   |
|-----------|------|-------------|-------|
|           | GRIT | Y-WT. X-WT. |       |
| 18" x 85" | 36   | 61031       | 60208 |
|           | 40   | 61032       | 60209 |
|           | 50   | 61033       | 60210 |
|           | 60   | 61034       | 60211 |
|           | 80   | 61035       | 60212 |
|           | 100  | 61036       | 60213 |
|           | 120  | 61037       | 60214 |
|           | 150  |             | 60215 |
|           | 180  |             | 60216 |
| 220       |      | 60217       |       |
| 19" x 48" | 36   | 61038       | 60218 |
|           | 40   | 61039       | 60219 |
|           | 50   | 61040       | 60220 |
|           | 60   | 61041       | 60221 |
|           | 80   | 61042       | 60222 |
|           | 100  | 61043       | 60223 |
|           | 120  | 61044       | 60224 |
|           | 150  |             | 60225 |
|           | 180  |             | 60226 |
| 220       |      | 60227       |       |
| 24" x 48" | 36   | 61075       | 60248 |
|           | 40   | 61076       | 60249 |
|           | 50   | 61077       | 60250 |
|           | 60   | 61078       | 60251 |
|           | 80   | 61079       | 60252 |
|           | 100  | 61080       | 60253 |
|           | 120  | 61081       | 60254 |
|           | 150  |             | 60255 |
|           | 180  |             | 60256 |
| 220       |      | 60257       |       |
| 24" x 55" | 36   | 61083       | 60258 |
|           | 40   | 61084       | 60259 |
|           | 50   | 61085       | 60260 |
|           | 60   | 61086       | 60261 |
|           | 80   | 61087       | 60262 |
|           | 100  | 61088       | 60263 |
|           | 120  | 61089       | 60264 |
|           | 150  |             | 60265 |
|           | 180  |             | 60266 |
| 220       |      | 60267       |       |
| 24" x 60" | 36   | 61091       | 60268 |
|           | 40   | 61092       | 60269 |
|           | 50   | 61093       | 60270 |
|           | 60   | 61094       | 60271 |
|           | 80   | 61095       | 60272 |
|           | 100  | 61096       | 60273 |
|           | 120  | 61097       | 60274 |
|           | 150  |             | 60275 |
|           | 180  |             | 60276 |
| 220       |      | 60277       |       |

### Wide Belts – Cloth

| W x L      | Z/A<br>Y-WT.<br>GRIT | A/O<br>X-WT.<br>076607- | 076607- | W x L      | Z/A<br>Y-WT.<br>GRIT | A/O<br>X-WT.<br>076607- | 076607- | W x L      | Z/A<br>Y-WT.<br>GRIT | A/O<br>X-WT.<br>076607- | 076607- | W x L      | Z/A<br>Y-WT.<br>GRIT | A/O<br>X-WT.<br>076607- | 076607- |
|------------|----------------------|-------------------------|---------|------------|----------------------|-------------------------|---------|------------|----------------------|-------------------------|---------|------------|----------------------|-------------------------|---------|
|            |                      |                         |         |            |                      |                         |         |            |                      |                         |         |            |                      |                         |         |
| 24" x 72"  | 36                   | 61099                   | 60278   | 25" x 72"  | 36                   | 61147                   | 60338   | 30" x 103" | 36                   | 61195                   | 60398   | 36" x 75"  | 36                   | 61243                   | 60458   |
|            | 40                   | 61100                   | 60279   |            | 40                   | 61148                   | 60339   |            | 40                   | 61196                   | 60399   |            | 40                   | 61244                   | 60459   |
|            | 50                   | 61101                   | 60280   |            | 50                   | 61149                   | 60340   |            | 50                   | 61197                   | 60400   |            | 50                   | 61245                   | 60460   |
|            | 60                   | 61102                   | 60281   |            | 60                   | 61150                   | 60341   |            | 60                   | 61198                   | 60401   |            | 60                   | 61246                   | 60461   |
|            | 80                   | 61103                   | 60282   |            | 80                   | 61151                   | 60342   |            | 80                   | 61199                   | 60402   |            | 80                   | 61247                   | 60462   |
|            | 100                  | 61104                   | 60283   |            | 100                  | 61152                   | 60343   |            | 100                  | 61200                   | 60403   |            | 100                  | 61248                   | 60463   |
|            | 120                  | 61105                   | 60284   |            | 120                  | 61153                   | 60344   |            | 120                  | 61201                   | 60404   |            | 120                  | 61249                   | 60464   |
|            | 150                  |                         | 60285   |            | 150                  |                         | 60345   |            | 150                  |                         | 60405   |            | 150                  |                         | 60465   |
|            | 180                  |                         | 60286   |            | 180                  |                         | 60346   |            | 180                  |                         | 60406   |            | 180                  |                         | 60466   |
|            | 220                  |                         | 60287   |            | 220                  |                         | 60347   |            | 220                  |                         | 60407   |            | 220                  |                         | 60467   |
| 24" x 75"  | 36                   | 61107                   | 60288   | 25" x 75"  | 36                   | 61155                   | 60348   | 35" x 75"  | 36                   | 61203                   | 60408   | 36" x 84"  | 36                   | 61251                   | 60468   |
|            | 40                   | 61108                   | 60289   |            | 40                   | 61156                   | 60349   |            | 40                   | 61204                   | 60409   |            | 40                   | 61252                   | 60469   |
|            | 50                   | 61109                   | 60290   |            | 50                   | 61157                   | 60350   |            | 50                   | 61205                   | 60410   |            | 50                   | 61253                   | 60470   |
|            | 60                   | 61110                   | 60291   |            | 60                   | 61158                   | 60351   |            | 60                   | 61206                   | 60411   |            | 60                   | 61254                   | 60471   |
|            | 80                   | 61111                   | 60292   |            | 80                   | 61159                   | 60352   |            | 80                   | 61207                   | 60412   |            | 80                   | 61255                   | 60472   |
|            | 100                  | 61112                   | 60293   |            | 100                  | 61160                   | 60353   |            | 100                  | 61208                   | 60413   |            | 100                  | 61256                   | 60473   |
|            | 120                  | 61113                   | 60294   |            | 120                  | 61161                   | 60354   |            | 120                  | 61209                   | 60414   |            | 120                  | 61257                   | 60474   |
|            | 150                  |                         | 60295   |            | 150                  |                         | 60355   |            | 150                  |                         | 60415   |            | 150                  |                         | 60475   |
|            | 180                  |                         | 60296   |            | 180                  |                         | 60356   |            | 180                  |                         | 60416   |            | 180                  |                         | 60476   |
|            | 220                  |                         | 60297   |            | 220                  |                         | 60357   |            | 220                  |                         | 60417   |            | 220                  |                         | 60477   |
| 24" x 84"  | 36                   | 61115                   | 60298   | 25" x 103" | 36                   | 61163                   | 60358   | 36" x 48"  | 36                   | 61211                   | 60418   | 36" x 103" | 36                   | 61259                   | 60478   |
|            | 40                   | 61116                   | 60299   |            | 40                   | 61164                   | 60359   |            | 40                   | 61212                   | 60419   |            | 40                   | 61260                   | 60479   |
|            | 50                   | 61117                   | 60300   |            | 50                   | 61165                   | 60360   |            | 50                   | 61213                   | 60420   |            | 50                   | 61261                   | 60480   |
|            | 60                   | 61118                   | 60301   |            | 60                   | 61166                   | 60361   |            | 60                   | 61214                   | 60421   |            | 60                   | 61262                   | 60481   |
|            | 80                   | 61119                   | 60302   |            | 80                   | 61167                   | 60362   |            | 80                   | 61215                   | 60422   |            | 80                   | 61263                   | 60482   |
|            | 100                  | 61120                   | 60303   |            | 100                  | 61168                   | 60363   |            | 100                  | 61216                   | 60423   |            | 100                  | 61264                   | 60483   |
|            | 120                  | 61121                   | 60304   |            | 120                  | 61169                   | 60364   |            | 120                  | 61217                   | 60424   |            | 120                  | 61265                   | 60484   |
|            | 150                  |                         | 60305   |            | 150                  |                         | 60365   |            | 150                  |                         | 60425   |            | 150                  |                         | 60485   |
|            | 180                  |                         | 60306   |            | 180                  |                         | 60366   |            | 180                  |                         | 60426   |            | 180                  |                         | 60486   |
|            | 220                  |                         | 60307   |            | 220                  |                         | 60367   |            | 220                  |                         | 60427   |            | 220                  |                         | 60487   |
| 24" x 103" | 36                   | 61123                   | 60308   | 30" x 72"  | 36                   | 61171                   | 60368   | 36" x 55"  | 36                   | 61219                   | 60428   | 37" x 48"  | 36                   | 61267                   | 60488   |
|            | 40                   | 61124                   | 60309   |            | 40                   | 61172                   | 60369   |            | 40                   | 61220                   | 60429   |            | 40                   | 61268                   | 60489   |
|            | 50                   | 61125                   | 60310   |            | 50                   | 61173                   | 60370   |            | 50                   | 61221                   | 60430   |            | 50                   | 61269                   | 60490   |
|            | 60                   | 61126                   | 60311   |            | 60                   | 61174                   | 60371   |            | 60                   | 61222                   | 60431   |            | 60                   | 61270                   | 60491   |
|            | 80                   | 61127                   | 60312   |            | 80                   | 61175                   | 60372   |            | 80                   | 61223                   | 60432   |            | 80                   | 61271                   | 60492   |
|            | 100                  | 61128                   | 60313   |            | 100                  | 61176                   | 60373   |            | 100                  | 61224                   | 60433   |            | 100                  | 61272                   | 60493   |
|            | 120                  | 61129                   | 60314   |            | 120                  | 61177                   | 60374   |            | 120                  | 61225                   | 60434   |            | 120                  | 61273                   | 60494   |
|            | 150                  |                         | 60315   |            | 150                  |                         | 60375   |            | 150                  |                         | 60435   |            | 150                  |                         | 60495   |
|            | 180                  |                         | 60316   |            | 180                  |                         | 60376   |            | 180                  |                         | 60436   |            | 180                  |                         | 60496   |
|            | 220                  |                         | 60317   |            | 220                  |                         | 60377   |            | 220                  |                         | 60437   |            | 220                  |                         | 60497   |
| 25" x 48"  | 36                   | 61131                   | 60318   | 30" x 75"  | 36                   | 61179                   | 60378   | 36" x 60"  | 36                   | 61227                   | 60438   | 37" x 60"  | 36                   | 61275                   | 60498   |
|            | 40                   | 61132                   | 60319   |            | 40                   | 61180                   | 60379   |            | 40                   | 61228                   | 60439   |            | 40                   | 61276                   | 60499   |
|            | 50                   | 61133                   | 60320   |            | 50                   | 61181                   | 60380   |            | 50                   | 61229                   | 60440   |            | 50                   | 61277                   | 60500   |
|            | 60                   | 61134                   | 60321   |            | 60                   | 61182                   | 60381   |            | 60                   | 61230                   | 60441   |            | 60                   | 61278                   | 60501   |
|            | 80                   | 61135                   | 60322   |            | 80                   | 61183                   | 60382   |            | 80                   | 61231                   | 60442   |            | 80                   | 61279                   | 60502   |
|            | 100                  | 61136                   | 60323   |            | 100                  | 61184                   | 60383   |            | 100                  | 61232                   | 60443   |            | 100                  | 61280                   | 60503   |
|            | 120                  | 61137                   | 60324   |            | 120                  | 61185                   | 60384   |            | 120                  | 61233                   | 60444   |            | 120                  | 61281                   | 60504   |
|            | 150                  |                         | 60325   |            | 150                  |                         | 60385   |            | 150                  |                         | 60445   |            | 150                  |                         | 60505   |
|            | 180                  |                         | 60326   |            | 180                  |                         | 60386   |            | 180                  |                         | 60446   |            | 180                  |                         | 60506   |
|            | 220                  |                         | 60327   |            | 220                  |                         | 02488   |            | 220                  |                         | 60447   |            | 220                  |                         | 60507   |
| 25" x 60"  | 36                   | 61139                   | 60328   | 30" x 84"  | 36                   | 61187                   | 60388   | 36" x 72"  | 36                   | 61235                   | 60448   | 37" x 72"  | 36                   | 61283                   | 60508   |
|            | 40                   | 61140                   | 60329   |            | 40                   | 61188                   | 60389   |            | 40                   | 61236                   | 60449   |            | 40                   | 61284                   | 60509   |
|            | 50                   | 61141                   | 60330   |            | 50                   | 61189                   | 60390   |            | 50                   | 61237                   | 60450   |            | 50                   | 61285                   | 60510   |
|            | 60                   | 61142                   | 60331   |            | 60                   | 61190                   | 60391   |            | 60                   | 61238                   | 60451   |            | 60                   | 61286                   | 60511   |
|            | 80                   | 61143                   | 60332   |            | 80                   | 61191                   | 60392   |            | 80                   | 61239                   | 60452   |            | 80                   | 61287                   | 60512   |
|            | 100                  | 61144                   | 60333   |            | 100                  | 61192                   | 60393   |            | 100                  | 61240                   | 60453   |            | 100                  | 61288                   | 60513   |
|            | 120                  | 61145                   | 60334   |            | 120                  | 61193                   | 60394   |            | 120                  | 61241                   | 60454   |            | 120                  | 61289                   | 60514   |
|            | 150                  |                         | 60335   |            | 150                  |                         | 60395   |            | 150                  |                         | 60455   |            | 150                  |                         | 60515   |
|            | 180                  |                         | 60336   |            | 180                  |                         | 60396   |            | 180                  |                         | 60456   |            | 180                  |                         | 60516   |
|            | 220                  |                         | 60337   |            | 220                  |                         | 60397   |            | 220                  |                         | 60457   |            | 220                  |                         | 60517   |


## Wide Belts – Cloth

| W x L      | GRIT | Z/A   | A/O   | W x L      | GRIT  | Z/A   | A/O   | W x L      | GRIT | Z/A   | A/O   | W x L      | GRIT | Z/A   | A/O   |
|------------|------|-------|-------|------------|-------|-------|-------|------------|------|-------|-------|------------|------|-------|-------|
|            |      | Y-WT. | X-WT. |            |       | Y-WT. | X-WT. |            |      | Y-WT. | X-WT. |            |      | Y-WT. | X-WT. |
| 37" x 75"  | 36   | 61291 | 60518 | 42" x 84"  | 36    | 61331 | 60598 | 44" x 75"  | 36   | 61379 | 60668 | 51" x 103" | 36   | 61427 | 60748 |
|            | 40   | 61292 | 60519 |            | 40    | 61332 | 60599 |            | 40   | 61380 | 60669 |            | 40   | 61428 | 60749 |
|            | 50   | 61293 | 60520 |            | 50    | 61333 | 60600 |            | 50   | 61381 | 60670 |            | 50   |       | 60750 |
|            | 60   | 61294 | 60521 |            | 60    | 61334 | 60601 |            | 60   | 61382 | 60671 |            | 60   | 61430 | 60751 |
|            | 80   | 61295 | 60522 |            | 80    | 61335 | 60602 |            | 80   | 61383 | 60672 |            | 80   | 61431 | 60752 |
|            | 100  | 61296 | 60523 |            | 100   | 61336 | 60603 |            | 100  | 61384 | 60673 |            | 100  | 61432 | 60753 |
|            | 120  | 61297 | 60524 |            | 120   | 61337 | 60604 |            | 120  | 61385 | 60674 |            | 120  | 61433 | 60754 |
|            | 150  |       | 60525 |            | 150   |       | 60605 |            | 150  |       | 60675 |            | 150  |       | 60755 |
|            | 180  |       | 60526 |            | 180   |       | 60606 |            | 180  |       | 60676 |            | 180  |       | 60756 |
| 220        |      | 60527 | 220   |            | 60607 | 220   |       | 60677      | 220  |       | 60757 |            |      |       |       |
| 37" x 103" | 36   | 61299 | 60528 | 43" x 60"  | 36    | 61339 | 60618 | 44" x 85"  | 36   | 60387 | 60678 | 52" x 75"  | 36   | 61435 | 60758 |
|            | 40   | 61300 | 60529 |            | 40    | 61340 | 60619 |            | 40   | 61388 | 60679 |            | 40   | 61436 | 60759 |
|            | 50   | 61301 | 60530 |            | 50    | 61341 | 60620 |            | 50   | 62389 | 60680 |            | 50   | 61437 | 60760 |
|            | 60   | 61302 | 60531 |            | 60    | 61342 | 60621 |            | 60   | 63390 | 60681 |            | 60   | 61438 | 60761 |
|            | 80   | 61303 | 60532 |            | 80    | 61343 | 60622 |            | 80   | 64391 | 60682 |            | 80   | 61439 | 60762 |
|            | 100  | 61304 | 60533 |            | 100   | 61344 | 60623 |            | 100  | 65392 | 60683 |            | 100  | 61440 | 60763 |
|            | 120  | 61305 | 60534 |            | 120   | 61345 | 60624 |            | 120  | 66393 | 60684 |            | 120  | 61441 | 60764 |
|            | 150  |       | 60535 |            | 150   |       | 60625 |            | 150  |       | 60685 |            | 150  |       | 60765 |
|            | 180  |       | 60536 |            | 180   |       | 60626 |            | 180  |       | 60686 |            | 180  |       | 60766 |
| 220        |      | 60537 | 220   |            | 60627 | 220   |       | 60687      | 220  |       | 60767 |            |      |       |       |
| 38" x 103" | 36   |       | 60538 | 43" x 72"  | 36    | 61347 | 60628 | 44" x 103" | 36   | 61395 | 60698 | 52" x 85"  | 36   | 61443 | 60768 |
|            | 40   |       | 60539 |            | 40    | 61348 | 60629 |            | 40   | 61396 | 60699 |            | 40   | 61444 | 60769 |
|            | 50   |       | 60540 |            | 50    | 61349 | 60630 |            | 50   | 61397 | 60700 |            | 50   | 61445 | 60770 |
|            | 60   |       | 60541 |            | 60    | 61350 | 60631 |            | 60   | 61398 | 60701 |            | 60   | 61446 | 60771 |
|            | 80   |       | 60542 |            | 80    | 61351 | 60632 |            | 80   | 61399 | 60702 |            | 80   | 61447 | 60772 |
|            | 100  |       | 60543 |            | 100   | 61352 | 60633 |            | 100  | 61400 | 60703 |            | 100  | 61448 | 60773 |
|            | 120  |       | 60544 |            | 120   | 61353 | 60634 |            | 120  | 61401 | 60704 |            | 120  | 61449 | 60774 |
|            | 150  |       | 60545 |            | 150   |       | 60635 |            | 150  |       | 60705 |            | 150  |       | 60775 |
|            | 180  |       | 60546 |            | 180   |       | 60636 |            | 180  |       | 60706 |            | 180  |       | 60776 |
| 220        |      | 60547 | 220   |            | 60637 | 220   |       | 60707      | 220  |       | 60777 |            |      |       |       |
| 40" x 75"  | 36   | 61307 | 60548 | 43" x 75"  | 36    | 61355 | 60638 | 50" x 75"  | 36   | 61403 | 60718 | 52" x 103" | 36   | 61451 | 60778 |
|            | 40   | 61308 | 60549 |            | 40    | 61356 | 60639 |            | 40   | 60404 | 60719 |            | 40   | 61452 | 60779 |
|            | 50   | 61309 | 60550 |            | 50    | 61357 | 60640 |            | 50   | 61405 | 60720 |            | 50   | 61453 | 60780 |
|            | 60   | 61310 | 60551 |            | 60    | 61358 | 60641 |            | 60   | 61406 | 60721 |            | 60   | 61454 | 60781 |
|            | 80   | 61311 | 60552 |            | 80    | 61359 | 60642 |            | 80   | 61407 | 60722 |            | 80   | 61455 | 60782 |
|            | 100  | 61312 | 60553 |            | 100   | 61360 | 60643 |            | 100  | 61408 | 60723 |            | 100  | 61456 | 60783 |
|            | 120  | 61313 | 60554 |            | 120   | 61361 | 60644 |            | 120  | 61409 | 60724 |            | 120  | 61457 | 60784 |
|            | 150  |       | 60555 |            | 150   |       | 60645 |            | 150  |       | 60725 |            | 150  |       | 60785 |
|            | 180  |       | 60556 |            | 180   |       | 60646 |            | 180  |       | 60726 |            | 180  |       | 60786 |
| 220        |      | 60557 | 220   |            | 60647 | 220   |       | 60727      | 220  |       | 60787 |            |      |       |       |
| 42" x 72"  | 36   | 61315 | 60568 | 43" x 85"  | 36    | 61363 | 60648 | 50" x 84"  | 36   | 61411 | 60728 |            |      |       |       |
|            | 40   | 61316 | 60569 |            | 40    | 61364 | 60649 |            | 40   | 61412 | 60729 |            |      |       |       |
|            | 50   | 61317 | 60570 |            | 50    | 61365 | 60650 |            | 50   | 61413 | 60730 |            |      |       |       |
|            | 60   | 61318 | 60571 |            | 60    | 61366 | 60651 |            | 60   | 61414 | 60731 |            |      |       |       |
|            | 80   | 61319 | 60572 |            | 80    | 61367 | 60652 |            | 80   | 61415 | 60732 |            |      |       |       |
|            | 100  | 61320 | 60573 |            | 100   | 61368 | 60653 |            | 100  | 61416 | 60733 |            |      |       |       |
|            | 120  | 61321 | 60574 |            | 120   | 61369 | 60654 |            | 120  | 61417 | 60734 |            |      |       |       |
|            | 150  |       | 60575 |            | 150   |       | 60655 |            | 150  |       | 60735 |            |      |       |       |
|            | 180  |       | 60576 |            | 180   |       | 60656 |            | 180  |       | 60736 |            |      |       |       |
| 220        |      | 60577 | 220   |            | 60657 | 220   |       | 60737      |      |       |       |            |      |       |       |
| 42" x 75"  | 36   | 61323 | 60578 | 43" x 103" | 36    | 61371 | 60658 | 50" x 103" | 36   | 61419 | 60738 |            |      |       |       |
|            | 40   | 61324 | 60579 |            | 40    | 61372 | 60659 |            | 40   | 61420 | 60739 |            |      |       |       |
|            | 50   | 61325 | 60580 |            | 50    | 61373 | 60660 |            | 50   | 61421 | 60740 |            |      |       |       |
|            | 60   | 61326 | 60581 |            | 60    | 61374 | 60661 |            | 60   | 61422 | 60741 |            |      |       |       |
|            | 80   | 61327 | 60582 |            | 80    | 61375 | 60662 |            | 80   | 61423 | 60742 |            |      |       |       |
|            | 100  | 61328 | 60583 |            | 100   | 61376 | 60663 |            | 100  | 61424 | 60743 |            |      |       |       |
|            | 120  | 61329 | 60584 |            | 120   | 61377 | 60664 |            | 120  | 61425 | 60744 |            |      |       |       |
|            | 150  |       | 60585 |            | 150   |       | 60665 |            | 150  |       | 60745 |            |      |       |       |
|            | 180  |       | 60586 |            | 180   |       | 60666 |            | 180  |       | 60746 |            |      |       |       |
| 220        |      | 60587 | 220   |            | 60667 | 220   |       | 60747      |      |       |       |            |      |       |       |



## Sharpening Stones

Norton has been the world leader in sharpening stones for over 100 years for every professional market. Our retail packaged line rings the same quality to the DIY market. The Knife & Scissor Sharpener is the entry level design that provides a quick and portable tool for 100s of sharpening applications. Abrasive Stones are designed for lower costs, lower usage sharpening applications. Diamond Stones are the latest addition which provides the optimum in performance and life. Each stone is specifically designed for a popular sharpening application and packaged to sell.

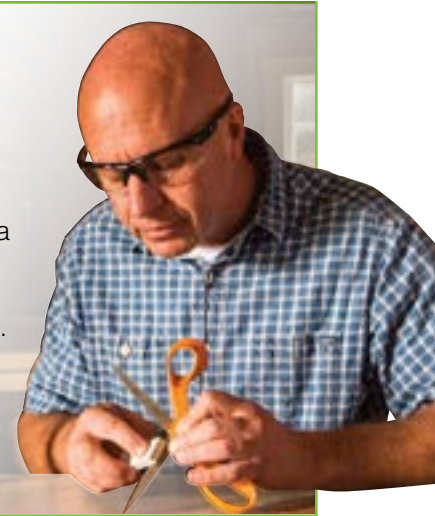

| PART #  | UPC-A       | SIZE                      | GRIT        | QTY/<br>PKG | PKG/<br>CASE |
|---|-------------|---------------------------|-------------|-------------|--------------|
| <b>Abrasive Sharpening Stones - Handy Packs</b> |             |                           |             |             |              |
| <b>Axe &amp; Hatchet Sharpener</b>              |             |                           |             |             |              |
| 07660785316                                     | 07660785316 | 5 3" x 5/8" round         | Combination | 1           | 10           |
| <b>Pocket Knife Sharpener</b>                   |             |                           |             |             |              |
| 07660787937                                     | 07660787937 | 0 3" x 7/8" x 3/8" w/case | Medium      | 1           | 5**          |
| 07660787600                                     | 07660787600 | 3 3" x 7/8" x 3/8"        | Medium      | 1           | 5**          |
| <b>Economy Tool &amp; Knife Sharpener</b>       |             |                           |             |             |              |
| 07660787933                                     | 07660787933 | 2 6" x 2" x 3/4"          | Combination | 1           | 5**          |
| 07660787934                                     | 07660787934 | 9 8" x 2" x 3/4"          | Combination | 1           | 10           |
| <b>High Quality Tool &amp; Knife Sharpener</b>  |             |                           |             |             |              |
| 07660787935                                     | 07660787935 | 6 6" x 2" x 3/4"          | Combination | 1           | 5**          |
| <b>Chisel &amp; Planer Blade Sharpener</b>      |             |                           |             |             |              |
| 07660787936                                     | 07660787936 | 3 8" x 2" x 3/4"          | Combination | 1           | 10           |
| <b>Household Knife &amp; Tool Sharpener</b>     |             |                           |             |             |              |
| 07660787939                                     | 07660787939 | 4 7" x 1" x 1/2"          | Fine        | 1           | 5**          |
| <b>Farm Tool Sharpener</b>                      |             |                           |             |             |              |
| 07660787730                                     | 07660787730 | 7 10" x 1-1/4" x 3/4"     | Coarse      | 1           | 10           |
| <b>Lawn &amp; Garden Tool Sharpener</b>         |             |                           |             |             |              |
| 07660787938                                     | 07660787938 | 7 9-1/2" x 1-3/8" x 1/2"  | Coarse      | 1           | 10           |
| <b>Sharpening Stone Oil</b>                     |             |                           |             |             |              |
| 07660787940                                     | 07660787940 | 0 4-1/2 oz                | N/A         | 1           | 5**          |

| PART #   | UPC-A       | SIZE                   | GRIT                | QTY/<br>PKG | PKG/<br>CASE |
|--|-------------|------------------------|---------------------|-------------|--------------|
| <b>Diamond Stones - Handy Packs</b>                          |             |                        |                     |             |              |
| <b>Bench Stone</b>   |             |                        |                     |             |              |
| 66253268081  | 66253268081 | 7 6" x 2-1/2"          | Fine                | 1           | 2            |
| 66253268082  | 66253268082 | 4 6" x 2-1/2"          | Coarse              | 1           | 2            |
| <b>Mechanical - Handy Packs</b>                              |             |                        |                     |             |              |
| <b>Knife &amp; Scissors Sharpener</b>                        |             |                        |                     |             |              |
| 07660787520  | 07660787520 | 4 2-1/2" x 6"          | Carbide             | 1           | 12           |
| <i>Sharpeners come in Red, Yellow, and Green (4 of each)</i> |             |                        |                     |             |              |
| <b>Rubbing Bricks - Bulk</b>                                 |             |                        |                     |             |              |
| 61463687830  | 61463687830 | 0 8" x 2" x 2"         | Plain               | 1           | 5            |
| 61463687840  | 61463687840 | 9 6" x 2" x 2"         | Fluted              | 1           | 5            |
| 61463687845  | 61463687845 | 4 8" x 2" x 2"         | Fluted              | 1           | 5            |
| 61463687800  | 61463687800 | 3 6" x 3" x 1"         | Fluted w/<br>handle | 1           | 5            |
| 61463687795  | 61463687795 | 2 8" x 3-1/2" x 1-1/2" | Fluted w/<br>handle | 1           | 5            |





## Racking

Modular designs for mix and match display needs

## Racking



### Short Peg Rack

Part number **07660702270**

- UPC-A number 07660702270 7
- holds 4", 4-1/2", 5" bulk depressed center wheels, cut-off blades or fibre discs
- over tag area for price label
- empty wire displayer
- 6 units/box



### Record Slot Wheel Rack

Part number **07660702269**

- UPC-A number 07660702269 1
- holds 12", 14" or 16" bulk cut-off blades, chop saw blades or diamond blades
- can fit 2 SKUs per rack or 1 SKU, doubled up
- display at base due to product weight
- wire displayer (product not included)
- 2 units/box



### Single Stack Blade Rack

Part number **07660702273**

- UPC-A number 07660702273 8
- holds 6-1/2", 7", 8", 10" bulk cut-off blades
- holds 7" bulk diamond blades
- holds 5", 7", 9" bulk fibre discs
- display on pegboard or shelf
- front plate for pricing and store info
- empty wire displayer
- 2 units/box



### Pocket Wheel Rack

Part number **07660705347**

- UPC-A number 07660705347 3
- holds 12" blades in bottom pocket and 12" or 14" in top pocket
- fits 2 SKUs per rack or 1 SKU, double faced
- design more evenly distributes product weight and provides enhanced visibility of item(s)
- wire displayer (product not included)
- 1 unit/box



### Long Peg Rack

Part number **07660702271**

- UPC-A number 07660702271 4
- holds 7" hubbed depressed center wheels
- holds other mid-size diameter discs requiring better dispersement of product weight
- over tag area for price label
- empty wire displayer
- 2 units/box



### Basket Bench Wheel Rack

Part number **07660702272**

- UPC-A number 07660702272 1
- holds 6" - 8" bench & pedestal wheel boxes
- can also hold 7" job pack circular saw cut-off blade boxes
- front plate for pricing and store info
- wire displayer (product not included)
- 2 units/box

## Racking



### 3-Way 9" x 11" Handy Pack Sheet Rack

Part number **07660702296**

- UPC-A number 07660702296 7
- vertical, space saving 3-pocket rack for 9" x 11" handy packs
- sits on counter/shelf, mounts to an upright beam using washers on back to bolt through or hangs on pegboard
- price tag area per grit
- each pocket fits 15 packs
- 1 unit/box



### Wire Tray For Bulk Portable Belts

Part number **07660702266**

- UPC-A number 07660702266 0 (2 trays/box)
- modular unit for displaying portable belts on pegboard
- set belt boxes on wire tray to hold belts and identify size and grit
- can also be used for other products as a shelf unit
- multiple racks can be positioned vertically and/or side by side for maximum impact



### 9" x 11" Handy Pack Spacesaver Merchandiser

Part number **07660748932**

- UPC-A number 07660748932 6
- space saving 3-pocket rack hangs on pegboard to display 9" x 11" Handy Pack sheets
- can be used horizontal (as shown) or vertical
- each pocket fits 15-20 packs
- 1 unit/box




### Flap Disc Rack

Part number **07660704157**

- UPC-A number 07660704157 9
- holds 4" or 4-1/2" flap discs (handy packs or bulk)
- merchandises 3 ways: hangs on pegboard, mounts to an upright beam, or sits on a shelf/counter
- wire rack comes with header (product not included)
- 2/pack

## Racking

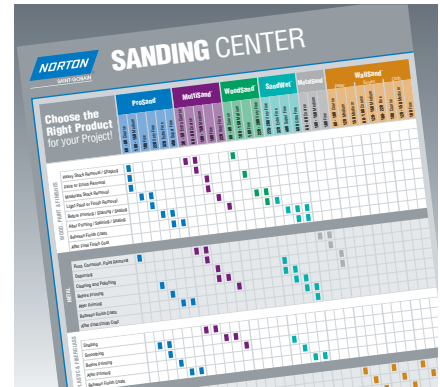

### 9" x 11" Sheet Merchandiser

Part number **07660701113**

- UPC-A number 07660701113 8
- displays 9" x 11" bulk sheets, job packs, and handy packs
- individual, stackable trays from bottom to top for sturdy, free-standing counter display or pegboard/wall mounting without front to back movement
- durable wire gauge to withstand wear; won't bend or sag
- full width, front plate for quick product identification
- 4 trays/box

### Product Identification Strips

Part number **07660703963**

- UPC-A number 07660703963 7
- must order with 9" x 11" Sheet Merchandiser (#01113)
- adhesive backed label for quick attachment
- color coded to match product category, bilingual
- individual grit labels provided to customize at retail
- 1 set/envelope

### Grit Guide Header

Part number **07660701967**

- UPC-A number 07660701967 7
- use with 9" x 11" Sheet Merchandiser (#01113) or any hand sanding set
- 11"w x 12"h header for selecting the right 9" x 11" sheet by application
- color coded to packaging, bilingual
- 1 unit/box



## Off-Shelf Display

Unique solutions for effectively and prominently showcasing products in high-traffic areas.

### MultiSand Bonus Pack Display

Part number **07660702670**

- UPC-A number 07660702670 5
- 75 Fine/Medium Sponges of 02081
- Dimensions -  
(assembled): 42"H x 17"W x 17"D  
(shippable): 21"H x 17"W x 17"D
- Weight - 25 lbs.
- Cube - 3.5 cu. ft.

## Signage (24" w x 12" h)

Self-selling signage and cross merchandising solutions




Cutting and Grinding Header:

Part number **07660721890** UPC-A number 07660721890 2 1/1



Power Sanding Header:

Part number **07660721891** UPC-A number 07660721891 9 1/1

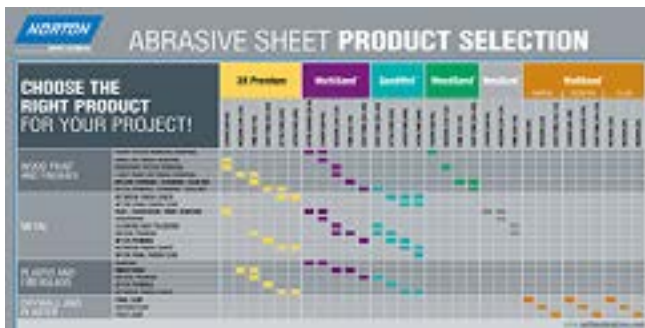

Sheet Guide Header:

Part number **07660721888** UPC-A number 07660721888 9 1/1



ProSand Sponge Header:

Part number **07660710104** UPC-A number 07660710104 4 1/1



ProSand Sheet Header:

Part number **07660710101** UPC-A number 07660710101 3 1/1



Logo Header:

Part number **07660721886** UPC-A number 07660721886 5 1/1



| UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE   | UPC-A       | PAGE |
|-------------|------|-------------|------|-------------|------|-------------|------|-------------|--------|-------------|------|
| 05539510684 | 31   | 07660701512 | 11   | 07660701887 | 17   | 07660702240 | 36   | 07660702620 | 7      | 07660703230 | 23   |
| 05539510693 | 31   | 07660701513 | 11   | 07660701888 | 17   | 07660702241 | 36   | 07660702621 | 7      | 07660703231 | 23   |
| 07660700151 | 11   | 07660701514 | 11   | 07660701889 | 8    | 07660702242 | 36   | 07660702622 | 7      | 07660703232 | 23   |
| 07660700152 | 11   | 07660701515 | 11   | 07660701909 | 31   | 07660702243 | 36   | 07660702623 | 11     | 07660703233 | 23   |
| 07660700153 | 11   | 07660701516 | 11   | 07660701910 | 31   | 07660702244 | 36   | 07660702624 | 11     | 07660703234 | 23   |
| 07660700154 | 11   | 07660701517 | 11   | 07660701911 | 31   | 07660702245 | 36   | 07660702625 | 11     | 07660703251 | 17   |
| 07660700155 | 11   | 07660701518 | 11   | 07660701912 | 31   | 07660702246 | 36   | 07660702626 | 11     | 07660703252 | 17   |
| 07660700156 | 11   | 07660701579 | 9    | 07660701913 | 31   | 07660702255 | 14   | 07660702627 | 11     | 07660703253 | 17   |
| 07660700157 | 11   | 07660701580 | 9    | 07660701914 | 31   | 07660702256 | 14   | 07660702628 | 11     | 07660703292 | 20   |
| 07660700158 | 11   | 07660701581 | 9    | 07660701915 | 31   | 07660702257 | 14   | 07660702629 | 11     | 07660703963 | 71   |
| 07660700159 | 11   | 07660701582 | 9    | 07660701916 | 31   | 07660702263 | 19   | 07660702630 | 11     | 07660703968 | 26   |
| 07660700160 | 11   | 07660701583 | 9    | 07660701919 | 17   | 07660702266 | 70   | 07660702631 | 11     | 07660703987 | 39   |
| 07660700354 | 8    | 07660701584 | 9    | 07660701920 | 17   | 07660702269 | 69   | 07660702632 | 7      | 07660703988 | 39   |
| 07660700355 | 8    | 07660701616 | 39   | 07660701921 | 17   | 07660702270 | 69   | 07660702633 | 7      | 07660704013 | 31   |
| 07660700356 | 8    | 07660701617 | 39   | 07660701966 | 37   | 07660702271 | 69   | 07660702636 | 7      | 07660704015 | 31   |
| 07660700357 | 8    | 07660701618 | 39   | 07660701967 | 71   | 07660702272 | 69   | 07660702637 | 7      | 07660704016 | 38   |
| 07660700358 | 8    | 07660701620 | 39   | 07660701973 | 28   | 07660702273 | 69   | 07660702638 | 7      | 07660704017 | 38   |
| 07660700365 | 8    | 07660701621 | 39   | 07660701975 | 28   | 07660702284 | 19   | 07660702639 | 7      | 07660704018 | 38   |
| 07660700935 | 14   | 07660701622 | 39   | 07660701981 | 28   | 07660702285 | 19   | 07660702640 | 7      | 07660704022 | 38   |
| 07660700936 | 14   | 07660701632 | 26   | 07660701986 | 28   | 07660702286 | 15   | 07660702641 | 7      | 07660704023 | 38   |
| 07660700937 | 14   | 07660701633 | 26   | 07660701987 | 28   | 07660702296 | 70   | 07660702642 | 7      | 07660704025 | 52   |
| 07660700938 | 14   | 07660701634 | 26   | 07660701989 | 28   | 07660702299 | 17   | 07660702670 | 14, 71 | 07660704030 | 15   |
| 07660700939 | 14   | 07660701635 | 26   | 07660701991 | 28   | 07660702314 | 33   | 07660702678 | 41     | 07660704031 | 15   |
| 07660700941 | 19   | 07660701636 | 26   | 07660701994 | 28   | 07660702315 | 33   | 07660702704 | 33     | 07660704032 | 15   |
| 07660700944 | 19   | 07660701637 | 26   | 07660701996 | 28   | 07660702316 | 33   | 07660702705 | 33     | 07660704033 | 23   |
| 07660700946 | 15   | 07660701641 | 27   | 07660701998 | 28   | 07660702317 | 33   | 07660702706 | 33     | 07660704034 | 23   |
| 07660700947 | 15   | 07660701642 | 27   | 07660702001 | 26   | 07660702318 | 33   | 07660702707 | 33     | 07660704035 | 23   |
| 07660700948 | 15   | 07660701643 | 27   | 07660702003 | 26   | 07660702320 | 26   | 07660702757 | 39     | 07660704036 | 23   |
| 07660700949 | 15   | 07660701644 | 27   | 07660702005 | 26   | 07660702343 | 10   | 07660702769 | 8      | 07660704037 | 23   |
| 07660700950 | 15   | 07660701645 | 27   | 07660702007 | 26   | 07660702344 | 10   | 07660702770 | 8      | 07660704038 | 23   |
| 07660700964 | 36   | 07660701646 | 27   | 07660702045 | 31   | 07660702345 | 10   | 07660702771 | 8      | 07660704041 | 23   |
| 07660700968 | 36   | 07660701647 | 27   | 07660702046 | 31   | 07660702388 | 32   | 07660702772 | 8      | 07660704056 | 26   |
| 07660700969 | 36   | 07660701650 | 27   | 07660702047 | 31   | 07660702389 | 32   | 07660702780 | 38     | 07660704057 | 26   |
| 07660701110 | 15   | 07660701651 | 27   | 07660702048 | 31   | 07660702390 | 32   | 07660702784 | 38     | 07660704058 | 26   |
| 07660701113 | 71   | 07660701652 | 27   | 07660702049 | 18   | 07660702391 | 32   | 07660702785 | 38     | 07660704059 | 26   |
| 07660701146 | 33   | 07660701654 | 20   | 07660702050 | 8    | 07660702395 | 32   | 07660702786 | 38     | 07660704060 | 26   |
| 07660701147 | 33   | 07660701655 | 20   | 07660702051 | 8    | 07660702396 | 32   | 07660702787 | 38     | 07660704061 | 26   |
| 07660701148 | 33   | 07660701656 | 20   | 07660702052 | 8    | 07660702397 | 32   | 07660702788 | 38     | 07660704062 | 26   |
| 07660701149 | 33   | 07660701693 | 30   | 07660702057 | 8    | 07660702398 | 32   | 07660702789 | 38     | 07660704063 | 26   |
| 07660701194 | 38   | 07660701703 | 30   | 07660702061 | 8    | 07660702399 | 32   | 07660702790 | 38     | 07660704064 | 26   |
| 07660701201 | 38   | 07660701715 | 19   | 07660702062 | 36   | 07660702400 | 32   | 07660702791 | 38     | 07660704065 | 15   |
| 07660701208 | 17   | 07660701717 | 35   | 07660702064 | 36   | 07660702401 | 32   | 07660702792 | 38     | 07660704066 | 15   |
| 07660701209 | 17   | 07660701720 | 37   | 07660702065 | 36   | 07660702411 | 21   | 07660702793 | 38     | 07660704067 | 15   |
| 07660701217 | 31   | 07660701721 | 37   | 07660702066 | 36   | 07660702412 | 21   | 07660703074 | 15     | 07660704068 | 15   |
| 07660701220 | 31   | 07660701722 | 37   | 07660702067 | 36   | 07660702450 | 48   | 07660703075 | 15     | 07660704069 | 15   |
| 07660701222 | 18   | 07660701726 | 49   | 07660702068 | 36   | 07660702451 | 48   | 07660703076 | 15     | 07660704070 | 15   |
| 07660701223 | 10   | 07660701727 | 49   | 07660702069 | 36   | 07660702452 | 48   | 07660703077 | 15     | 07660704145 | 8    |
| 07660701224 | 10   | 07660701728 | 49   | 07660702081 | 14   | 07660702453 | 48   | 07660703078 | 15     | 07660704146 | 8    |
| 07660701225 | 10   | 07660701729 | 49   | 07660702082 | 14   | 07660702463 | 20   | 07660703205 | 29     | 07660704147 | 8    |
| 07660701226 | 10   | 07660701740 | 36   | 07660702206 | 26   | 07660702464 | 20   | 07660703206 | 29     | 07660704148 | 8    |
| 07660701230 | 38   | 07660701741 | 36   | 07660702207 | 26   | 07660702465 | 20   | 07660703207 | 29     | 07660704153 | 8    |
| 07660701293 | 11   | 07660701742 | 36   | 07660702208 | 26   | 07660702466 | 20   | 07660703211 | 29     | 07660704154 | 8    |
| 07660701294 | 11   | 07660701743 | 36   | 07660702209 | 26   | 07660702487 | 19   | 07660703212 | 29     | 07660704155 | 8    |
| 07660701295 | 11   | 07660701744 | 36   | 07660702225 | 35   | 07660702498 | 27   | 07660703213 | 29     | 07660704157 | 70   |
| 07660701296 | 11   | 07660701745 | 36   | 07660702226 | 35   | 07660702499 | 27   | 07660703217 | 23     | 07660704169 | 18   |
| 07660701300 | 18   | 07660701809 | 27   | 07660702227 | 35   | 07660702500 | 27   | 07660703218 | 23     | 07660704171 | 18   |
| 07660701301 | 18   | 07660701811 | 27   | 07660702228 | 35   | 07660702533 | 17   | 07660703219 | 23     | 07660704173 | 18   |
| 07660701302 | 17   | 07660701812 | 27   | 07660702229 | 35   | 07660702534 | 17   | 07660703220 | 23     | 07660704657 | 45   |
| 07660701303 | 17   | 07660701815 | 27   | 07660702230 | 35   | 07660702535 | 17   | 07660703221 | 23     | 07660704659 | 45   |
| 07660701304 | 17   | 07660701845 | 19   | 07660702231 | 35   | 07660702536 | 31   | 07660703222 | 23     | 07660704682 | 45   |
| 07660701305 | 17   | 07660701860 | 17   | 07660702233 | 36   | 07660702600 | 14   | 07660703223 | 23     | 07660704683 | 45   |
| 07660701307 | 11   | 07660701861 | 17   | 07660702234 | 36   | 07660702612 | 7    | 07660703224 | 23     | 07660704684 | 45   |
| 07660701308 | 11   | 07660701862 | 17   | 07660702235 | 36   | 07660702613 | 7    | 07660703225 | 23     | 07660704685 | 45   |
| 07660701309 | 11   | 07660701863 | 17   | 07660702236 | 36   | 07660702616 | 7    | 07660703226 | 23     | 07660704735 | 14   |
| 07660701311 | 18   | 07660701864 | 17   | 07660702237 | 36   | 07660702617 | 7    | 07660703227 | 23     | 07660704746 | 17   |
| 07660701312 | 18   | 07660701875 | 14   | 07660702238 | 36   | 07660702618 | 7    | 07660703228 | 23     | 07660704747 | 17   |
| 07660701511 | 11   | 07660701885 | 15   | 07660702239 | 36   | 07660702619 | 7    | 07660703229 | 23     | 07660704748 | 18   |

| UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE   |
|-------------|------|-------------|------|-------------|------|-------------|------|-------------|------|-------------|--------|
| 07660704749 | 18   | 07660710104 | 72   | 07660748490 | 36   | 07660749256 | 35   | 07660768164 | 7    | 07660768348 | 24     |
| 07660705237 | 7    | 07660710466 | 45   | 07660748505 | 36   | 07660749258 | 35   | 07660768165 | 7    | 07660768349 | 24     |
| 07660705249 | 39   | 07660719359 | 62   | 07660748520 | 36   | 07660749259 | 35   | 07660768166 | 7    | 07660768350 | 24     |
| 07660705251 | 39   | 07660721602 | 33   | 07660748521 | 36   | 07660749262 | 35   | 07660768167 | 7    | 07660768351 | 24     |
| 07660705278 | 28   | 07660721741 | 14   | 07660748600 | 36   | 07660749264 | 35   | 07660768168 | 7    | 07660768352 | 24     |
| 07660705279 | 37   | 07660721763 | 18   | 07660748620 | 36   | 07660749265 | 35   | 07660768171 | 7    | 07660768353 | 24     |
| 07660705282 | 37   | 07660721764 | 18   | 07660748630 | 36   | 07660749266 | 35   | 07660768172 | 7    | 07660768354 | 24     |
| 07660705285 | 36   | 07660721765 | 18   | 07660748631 | 36   | 07660749268 | 35   | 07660768173 | 7    | 07660768355 | 24     |
| 07660705287 | 36   | 07660721766 | 18   | 07660748660 | 37   | 07660749270 | 35   | 07660768174 | 7    | 07660768356 | 24     |
| 07660705291 | 16   | 07660721767 | 18   | 07660748665 | 37   | 07660749271 | 35   | 07660768175 | 7    | 07660768357 | 24     |
| 07660705300 | 52   | 07660721775 | 14   | 07660748675 | 37   | 07660749272 | 35   | 07660768177 | 7    | 07660768358 | 24     |
| 07660705301 | 52   | 07660721886 | 72   | 07660748690 | 37   | 07660749274 | 35   | 07660768178 | 7    | 07660768359 | 24     |
| 07660705311 | 7    | 07660721888 | 72   | 07660748710 | 36   | 07660749276 | 35   | 07660768179 | 7    | 07660768360 | 24     |
| 07660705312 | 7    | 07660721890 | 72   | 07660748725 | 36   | 07660749277 | 35   | 07660768180 | 7    | 07660768361 | 24     |
| 07660705313 | 7    | 07660721891 | 72   | 07660748740 | 36   | 07660749278 | 35   | 07660768181 | 7    | 07660768362 | 24     |
| 07660705314 | 7    | 07660724376 | 44   | 07660748906 | 27   | 07660749502 | 14   | 07660768182 | 7    | 07660768363 | 24     |
| 07660705315 | 7    | 07660724419 | 44   | 07660748907 | 27   | 07660749503 | 14   | 07660768183 | 7    | 07660768364 | 24     |
| 07660705316 | 7    | 07660724549 | 44   | 07660748908 | 27   | 07660749504 | 14   | 07660768184 | 7    | 07660768365 | 24     |
| 07660705317 | 7    | 07660724564 | 44   | 07660748909 | 27   | 07660749505 | 14   | 07660768185 | 7    | 07660768418 | 20     |
| 07660705318 | 7    | 07660743140 | 8    | 07660748910 | 27   | 07660749506 | 14   | 07660768186 | 31   | 07660768419 | 20     |
| 07660705320 | 23   | 07660747710 | 8    | 07660748911 | 27   | 07660749507 | 14   | 07660768187 | 31   | 07660768420 | 20     |
| 07660705322 | 23   | 07660747720 | 8    | 07660748932 | 70   | 07660749600 | 35   | 07660768188 | 31   | 07660768421 | 20     |
| 07660705324 | 23   | 07660747725 | 8    | 07660749008 | 52   | 07660749602 | 35   | 07660768189 | 31   | 07660768422 | 46     |
| 07660705326 | 23   | 07660747735 | 8    | 07660749126 | 8    | 07660749604 | 35   | 07660768190 | 31   | 07660768423 | 46     |
| 07660705344 | 38   | 07660747740 | 8    | 07660749127 | 8    | 07660749610 | 35   | 07660768221 | 13   | 07660768424 | 46     |
| 07660705347 | 69   | 07660747750 | 8    | 07660749128 | 8    | 07660749611 | 35   | 07660768231 | 35   | 07660768425 | 46     |
| 07660705386 | 7    | 07660747765 | 8    | 07660749129 | 8    | 07660749612 | 35   | 07660768232 | 35   | 07660768426 | 46     |
| 07660705411 | 45   | 07660747769 | 42   | 07660749155 | 26   | 07660749613 | 35   | 07660768233 | 35   | 07660768427 | 46     |
| 07660705412 | 45   | 07660747805 | 9    | 07660749156 | 26   | 07660768100 | 17   | 07660768234 | 35   | 07660768428 | 46     |
| 07660705413 | 45   | 07660747820 | 9    | 07660749157 | 26   | 07660768101 | 17   | 07660768235 | 35   | 07660768429 | 46     |
| 07660705414 | 45   | 07660747835 | 9    | 07660749158 | 26   | 07660768102 | 17   | 07660768237 | 20   | 07660768430 | 46     |
| 07660705421 | 45   | 07660747855 | 9    | 07660749159 | 26   | 07660768103 | 17   | 07660768238 | 20   | 07660768431 | 46     |
| 07660705422 | 45   | 07660747965 | 9    | 07660749166 | 26   | 07660768104 | 21   | 07660768239 | 8    | 07660768432 | 46     |
| 07660705441 | 8    | 07660747980 | 9    | 07660749209 | 26   | 07660768105 | 21   | 07660768240 | 8    | 07660768433 | 46     |
| 07660705442 | 8    | 07660747990 | 9    | 07660749210 | 26   | 07660768106 | 21   | 07660768241 | 21   | 07660768434 | 46     |
| 07660705444 | 8    | 07660748010 | 9    | 07660749211 | 26   | 07660768107 | 21   | 07660768242 | 17   | 07660768435 | 46     |
| 07660705445 | 8    | 07660748025 | 9    | 07660749212 | 26   | 07660768108 | 8    | 07660768243 | 17   | 07660768437 | 25     |
| 07660705446 | 8    | 07660748052 | 10   | 07660749213 | 26   | 07660768109 | 8    | 07660768275 | 8    | 07660768438 | 25     |
| 07660705447 | 8    | 07660748053 | 10   | 07660749214 | 26   | 07660768110 | 8    | 07660768276 | 13   | 07660768439 | 25     |
| 07660705452 | 8    | 07660748054 | 10   | 07660749215 | 26   | 07660768111 | 8    | 07660768277 | 13   | 07660768440 | 25     |
| 07660705453 | 8    | 07660748055 | 10   | 07660749216 | 26   | 07660768112 | 49   | 07660768279 | 23   | 07660768441 | 25     |
| 07660705454 | 27   | 07660748058 | 10   | 07660749217 | 26   | 07660768113 | 49   | 07660768283 | 17   | 07660768442 | 25     |
| 07660705455 | 27   | 07660748060 | 10   | 07660749218 | 26   | 07660768114 | 49   | 07660768284 | 17   | 07660768443 | 25     |
| 07660705456 | 27   | 07660748080 | 10   | 07660749219 | 26   | 07660768115 | 49   | 07660768285 | 17   | 07660768444 | 25     |
| 07660705466 | 31   | 07660748090 | 10   | 07660749220 | 26   | 07660768116 | 49   | 07660768286 | 17   | 07660768445 | 25     |
| 07660705472 | 35   | 07660748110 | 10   | 07660749221 | 26   | 07660768117 | 49   | 07660768288 | 14   | 07660768446 | 25     |
| 07660705473 | 35   | 07660748130 | 8    | 07660749222 | 26   | 07660768118 | 49   | 07660768289 | 14   | 07660768447 | 25     |
| 07660705474 | 35   | 07660748132 | 8    | 07660749223 | 26   | 07660768122 | 34   | 07660768290 | 14   | 07660768448 | 25     |
| 07660705475 | 38   | 07660748143 | 16   | 07660749224 | 26   | 07660768123 | 34   | 07660768300 | 20   | 07660768449 | 25     |
| 07660705484 | 23   | 07660748144 | 16   | 07660749225 | 26   | 07660768124 | 34   | 07660768305 | 47   | 07660768450 | 25     |
| 07660705486 | 23   | 07660748145 | 16   | 07660749231 | 27   | 07660768126 | 34   | 07660768306 | 47   | 07660768451 | 25     |
| 07660705487 | 23   | 07660748146 | 50   | 07660749232 | 27   | 07660768127 | 34   | 07660768307 | 47   | 07660768452 | 20, 25 |
| 07660705488 | 23   | 07660748147 | 50   | 07660749236 | 27   | 07660768128 | 34   | 07660768308 | 47   | 07660768453 | 20, 25 |
| 07660705489 | 23   | 07660748148 | 50   | 07660749237 | 27   | 07660768129 | 34   | 07660768318 | 18   | 07660768454 | 20, 25 |
| 07660705490 | 23   | 07660748295 | 8    | 07660749238 | 27   | 07660768139 | 13   | 07660768319 | 18   | 07660768455 | 20, 25 |
| 07660705493 | 43   | 07660748300 | 8    | 07660749239 | 27   | 07660768140 | 13   | 07660768320 | 18   | 07660768456 | 20, 25 |
| 07660705494 | 43   | 07660748301 | 8    | 07660749240 | 27   | 07660768141 | 13   | 07660768321 | 18   | 07660768457 | 20, 25 |
| 07660705495 | 43   | 07660748302 | 8    | 07660749242 | 27   | 07660768142 | 47   | 07660768322 | 24   | 07660768459 | 23     |
| 07660705496 | 43   | 07660748310 | 8    | 07660749244 | 27   | 07660768143 | 47   | 07660768323 | 24   | 07660768460 | 23     |
| 07660705504 | 9    | 07660748325 | 8    | 07660749246 | 27   | 07660768156 | 7    | 07660768324 | 24   | 07660768461 | 24     |
| 07660705505 | 9    | 07660748335 | 8    | 07660749247 | 8    | 07660768157 | 7    | 07660768325 | 24   | 07660768462 | 24     |
| 07660705506 | 9    | 07660748353 | 8    | 07660749248 | 8    | 07660768158 | 7    | 07660768326 | 24   | 07660775936 | 41     |
| 07660705507 | 9    | 07660748354 | 8    | 07660749249 | 8    | 07660768159 | 7    | 07660768327 | 24   | 07660775938 | 41     |
| 07660706038 | 52   | 07660748355 | 8    | 07660749250 | 8    | 07660768160 | 7    | 07660768328 | 24   | 07660775940 | 41     |
| 07660706048 | 16   | 07660748430 | 36   | 07660749251 | 8    | 07660768161 | 7    | 07660768329 | 24   | 07660775942 | 41     |
| 07660706049 | 16   | 07660748450 | 36   | 07660749252 | 8    | 07660768162 | 7    | 07660768330 | 24   | 07660775956 | 41     |
| 07660710101 | 72   | 07660748465 | 36   | 07660749254 | 8    | 07660768163 | 7    | 07660768335 | 49   | 07660782063 | 13     |

| UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE   | UPC-A       | PAGE | UPC-A       | PAGE |
|-------------|------|-------------|------|-------------|------|-------------|--------|-------------|------|-------------|------|
| 07660782064 | 13   | 07660788283 | 45   | 63642506200 | 57   | 66252842019 | 41     | 66252938854 | 40   | 66254487444 | 59   |
| 07660782065 | 13   | 07660788285 | 45   | 63642506202 | 57   | 66252842025 | 39     | 66252938855 | 40   | 66254487446 | 59   |
| 07660782066 | 13   | 07660788286 | 45   | 63642506203 | 57   | 66252842026 | 39     | 66252939184 | 40   | 66254487447 | 59   |
| 07660782067 | 13   | 07660788290 | 45   | 63642506204 | 57   | 66252842036 | 39     | 66252939207 | 41   | 66254487448 | 59   |
| 07660782068 | 13   | 07660788295 | 45   | 63642506375 | 57   | 66252842177 | 40     | 66252939259 | 41   | 66254487449 | 59   |
| 07660782069 | 13   | 07660789000 | 42   | 63642506376 | 57   | 66252842178 | 40     | 66252940098 | 41   | 66254487450 | 59   |
| 07660782070 | 13   | 07660789005 | 42   | 63642506377 | 57   | 66252842179 | 41     | 66252940148 | 41   | 66260148820 | 45   |
| 07660782071 | 13   | 07660789010 | 42   | 63642536313 | 15   | 66252842180 | 39     | 66252942300 | 45   | 66261008108 | 50   |
| 07660782072 | 13   | 07660789050 | 42   | 63642542089 | 63   | 66252842202 | 39     | 66252942301 | 45   | 66261045600 | 50   |
| 07660782073 | 13   | 07660789055 | 42   | 63642542772 | 62   | 66252843171 | 42     | 66252942302 | 45   | 66261047583 | 50   |
| 07660782074 | 13   | 07660789070 | 42   | 63642543112 | 63   | 66252843172 | 42     | 66253021633 | 40   | 66261052254 | 59   |
| 07660782075 | 13   | 07660789086 | 42   | 63642543421 | 30   | 66252843173 | 42     | 66253021634 | 40   | 66261052267 | 59   |
| 07660782076 | 13   | 07660789088 | 42   | 63642543422 | 30   | 66252843174 | 42     | 66253044087 | 45   | 66261065293 | 59   |
| 07660782077 | 13   | 07660789089 | 42   | 63642543423 | 30   | 66252843175 | 42     | 66253044534 | 45   | 66261074000 | 50   |
| 07660782078 | 13   | 07660789096 | 42   | 63642543425 | 30   | 66252843177 | 41     | 66253044535 | 45   | 66261074700 | 50   |
| 07660782079 | 13   | 07660789097 | 42   | 63642543426 | 30   | 66252843178 | 41     | 66253048896 | 40   | 66261074800 | 50   |
| 07660782080 | 13   | 07660789098 | 42   | 63642543704 | 63   | 66252843179 | 41     | 66253048897 | 40   | 66261079600 | 50   |
| 07660782081 | 13   | 07660789275 | 40   | 63642543712 | 62   | 66252843208 | 39     | 66253048983 | 41   | 66261085302 | 62   |
| 07660782082 | 13   | 07660789390 | 44   | 63642552868 | 15   | 66252843209 | 39     | 66253048991 | 41   | 66261100245 | 12   |
| 07660782083 | 13   | 07660789391 | 44   | 63642552869 | 15   | 66252843210 | 39     | 66253048994 | 41   | 66261100285 | 12   |
| 07660782084 | 13   | 07660789392 | 44   | 63642552870 | 15   | 66252843211 | 41     | 66253049066 | 40   | 66261100290 | 12   |
| 07660782085 | 13   | 07660789395 | 44   | 63642585864 | 62   | 66252843212 | 41     | 66253049104 | 41   | 66261100295 | 12   |
| 07660782086 | 13   | 07660789399 | 43   | 66243411393 | 42   | 66252843213 | 41     | 66253144536 | 45   | 66261100315 | 12   |
| 07660782088 | 13   | 07660789400 | 43   | 66243411395 | 42   | 66252843214 | 41     | 66253160366 | 45   | 66261100320 | 12   |
| 07660782780 | 64   | 07660789405 | 43   | 66243411402 | 42   | 66252843215 | 41     | 66253207554 | 43   | 66261100325 | 12   |
| 07660784002 | 8    | 07660789451 | 42   | 66243510627 | 42   | 66252843216 | 41     | 66253263054 | 45   | 66261100330 | 12   |
| 07660784024 | 8    | 07660789453 | 42   | 66243510628 | 42   | 66252843217 | 41     | 66253263055 | 45   | 66261100335 | 12   |
| 07660784025 | 8    | 61463687795 | 68   | 66243510629 | 42   | 66252843218 | 41     | 66253263056 | 45   | 66261100915 | 18   |
| 07660784042 | 8    | 61463687800 | 68   | 66243510630 | 42   | 66252843233 | 41     | 66253263359 | 45   | 66261100920 | 18   |
| 07660784250 | 8    | 61463687830 | 68   | 66243510645 | 42   | 66252843234 | 41     | 66253263360 | 45   | 66261100935 | 18   |
| 07660784251 | 8    | 61463687840 | 68   | 66243510647 | 42   | 66252843235 | 41     | 66253268081 | 68   | 66261100940 | 18   |
| 07660784252 | 8    | 61463687845 | 68   | 66243510650 | 42   | 66252843236 | 41     | 66253268082 | 68   | 66261100945 | 18   |
| 07660785316 | 68   | 63642502122 | 30   | 66243510651 | 42   | 66252843244 | 41     | 66253306627 | 43   | 66261100950 | 18   |
| 07660787520 | 68   | 63642502161 | 63   | 66243510654 | 42   | 66252843245 | 41     | 66253410183 | 44   | 66261100955 | 18   |
| 07660787600 | 68   | 63642502162 | 63   | 66243510655 | 42   | 66252843246 | 41     | 66253410198 | 43   | 66261100960 | 18   |
| 07660787730 | 68   | 63642502538 | 15   | 66243510658 | 42   | 66252843247 | 41     | 66254419963 | 29   | 66261101150 | 12   |
| 07660787933 | 68   | 63642502768 | 63   | 66243510659 | 42   | 66252843254 | 43     | 66254419978 | 29   | 66261101155 | 12   |
| 07660787934 | 68   | 63642502842 | 64   | 66243527955 | 39   | 66252843321 | 40     | 66254419984 | 29   | 66261101160 | 12   |
| 07660787935 | 68   | 63642502981 | 62   | 66243527956 | 39   | 66252843322 | 40     | 66254419987 | 29   | 66261101165 | 12   |
| 07660787936 | 68   | 63642503111 | 64   | 66252801864 | 41   | 66252843323 | 40     | 66254419994 | 29   | 66261101170 | 12   |
| 07660787937 | 68   | 63642503117 | 64   | 66252801865 | 41   | 66252843324 | 40     | 66254419996 | 29   | 66261101175 | 12   |
| 07660787938 | 68   | 63642503121 | 63   | 66252809376 | 40   | 66252843326 | 40     | 66254419997 | 29   | 66261101255 | 11   |
| 07660787939 | 68   | 63642503147 | 64   | 66252823599 | 39   | 66252843328 | 40     | 66254420004 | 29   | 66261101385 | 12   |
| 07660787940 | 68   | 63642503726 | 64   | 66252823600 | 39   | 66252843331 | 40     | 66254420006 | 29   | 66261101390 | 12   |
| 07660788201 | 45   | 63642505457 | 63   | 66252823601 | 39   | 66252843332 | 40     | 66254420007 | 29   | 66261101488 | 12   |
| 07660788202 | 45   | 63642506126 | 62   | 66252823602 | 39   | 66252843334 | 40     | 66254420010 | 29   | 66261101489 | 12   |
| 07660788205 | 45   | 63642506127 | 62   | 66252823603 | 39   | 66252843359 | 41     | 66254420012 | 29   | 66261101490 | 12   |
| 07660788210 | 45   | 63642506128 | 62   | 66252823604 | 39   | 66252843591 | 41     | 66254420013 | 29   | 66261101495 | 12   |
| 07660788225 | 45   | 63642506129 | 62   | 66252830587 | 39   | 66252843593 | 41     | 66254421217 | 59   | 66261101500 | 12   |
| 07660788235 | 45   | 63642506130 | 62   | 66252830886 | 43   | 66252843594 | 41     | 66254480230 | 57   | 66261101505 | 12   |
| 07660788240 | 45   | 63642506131 | 62   | 66252835553 | 42   | 66252843596 | 41     | 66254480232 | 57   | 66261101525 | 12   |
| 07660788245 | 45   | 63642506132 | 62   | 66252837187 | 45   | 66252843598 | 41     | 66254480233 | 57   | 66261101530 | 12   |
| 07660788246 | 45   | 63642506133 | 62   | 66252837190 | 45   | 66252843599 | 41     | 66254487393 | 12   | 66261101535 | 12   |
| 07660788247 | 45   | 63642506135 | 62   | 66252837191 | 45   | 66252843600 | 41     | 66254487394 | 12   | 66261101555 | 12   |
| 07660788248 | 45   | 63642506136 | 62   | 66252837192 | 45   | 66252843602 | 41     | 66254487395 | 12   | 66261101560 | 12   |
| 07660788250 | 45   | 63642506137 | 62   | 66252837193 | 45   | 66252843604 | 39     | 66254487396 | 12   | 66261101861 | 12   |
| 07660788255 | 45   | 63642506138 | 62   | 66252837194 | 45   | 66252843605 | 41     | 66254487397 | 12   | 66261101862 | 12   |
| 07660788260 | 45   | 63642506139 | 63   | 66252841939 | 39   | 66252843607 | 41     | 66254487398 | 12   | 66261104714 | 17   |
| 07660788261 | 45   | 63642506140 | 63   | 66252842001 | 40   | 66252843609 | 41     | 66254487399 | 12   | 66261104716 | 17   |
| 07660788262 | 45   | 63642506141 | 63   | 66252842004 | 40   | 66252843611 | 41     | 66254487400 | 12   | 66261104717 | 17   |
| 07660788263 | 45   | 63642506142 | 63   | 66252842005 | 40   | 66252843613 | 41     | 66254487415 | 59   | 66261104718 | 17   |
| 07660788265 | 45   | 63642506143 | 63   | 66252842011 | 41   | 66252843614 | 41     | 66254487417 | 59   | 66261104719 | 17   |
| 07660788270 | 45   | 63642506145 | 63   | 66252842014 | 41   | 66252843615 | 41     | 66254487418 | 59   | 66261123573 | 56   |
| 07660788275 | 45   | 63642506146 | 63   | 66252842015 | 39   | 66252843616 | 41     | 66254487440 | 59   | 66261123574 | 56   |
| 07660788280 | 45   | 63642506160 | 62   | 66252842016 | 41   | 66252912626 | 39, 41 | 66254487441 | 59   | 66261123575 | 56   |
| 07660788281 | 45   | 63642506198 | 57   | 66252842017 | 41   | 66252917880 | 40     | 66254487442 | 59   | 66261123576 | 56   |
| 07660788282 | 45   | 63642506199 | 57   | 66252842018 | 41   | 66252917881 | 40     | 66254487443 | 59   | 66261123577 | 56   |

| UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE |
|-------------|------|-------------|------|-------------|------|-------------|------|-------------|------|-------------|------|
| 66261123578 | 56   | 66261127730 | 16   | 66261131475 | 58   | 66261131573 | 59   | 66261136582 | 28   | 66261140501 | 57   |
| 66261123580 | 56   | 66261127731 | 16   | 66261131476 | 58   | 66261131575 | 59   | 66261136583 | 28   | 66261140502 | 57   |
| 66261123582 | 56   | 66261127732 | 16   | 66261131477 | 58   | 66261131578 | 59   | 66261136584 | 28   | 66261140508 | 57   |
| 66261123584 | 56   | 66261127733 | 16   | 66261131478 | 58   | 66261131579 | 59   | 66261136585 | 28   | 66261140509 | 57   |
| 66261123588 | 56   | 66261128688 | 58   | 66261131479 | 58   | 66261131580 | 59   | 66261136586 | 28   | 66261140510 | 57   |
| 66261123589 | 56   | 66261130224 | 61   | 66261131480 | 58   | 66261131581 | 59   | 66261136587 | 28   | 66261140511 | 57   |
| 66261123590 | 56   | 66261130226 | 61   | 66261131481 | 58   | 66261131582 | 59   | 66261136588 | 28   | 66261140512 | 57   |
| 66261123591 | 56   | 66261130227 | 61   | 66261131488 | 58   | 66261131583 | 59   | 66261136589 | 28   | 66261140515 | 57   |
| 66261123592 | 56   | 66261130230 | 61   | 66261131490 | 58   | 66261131584 | 59   | 66261136592 | 28   | 66261140517 | 57   |
| 66261123593 | 56   | 66261130231 | 61   | 66261131492 | 58   | 66261131586 | 59   | 66261136593 | 28   | 66261140518 | 57   |
| 66261123596 | 56   | 66261130232 | 61   | 66261131493 | 58   | 66261131587 | 59   | 66261136594 | 28   | 66261140519 | 57   |
| 66261123598 | 56   | 66261130233 | 61   | 66261131494 | 58   | 66261131588 | 59   | 66261136595 | 28   | 66261140520 | 57   |
| 66261124977 | 56   | 66261130234 | 61   | 66261131495 | 58   | 66261131590 | 59   | 66261136596 | 28   | 66261140521 | 57   |
| 66261125244 | 56   | 66261130235 | 61   | 66261131496 | 58   | 66261131592 | 59   | 66261136600 | 28   | 66261140522 | 57   |
| 66261125307 | 56   | 66261130236 | 61   | 66261131497 | 58   | 66261131595 | 59   | 66261136601 | 28   | 66261140528 | 57   |
| 66261125436 | 56   | 66261130238 | 61   | 66261131498 | 58   | 66261131596 | 59   | 66261136602 | 28   | 66261140529 | 57   |
| 66261125444 | 56   | 66261130239 | 61   | 66261131503 | 58   | 66261131597 | 59   | 66261136604 | 28   | 66261140530 | 57   |
| 66261125573 | 56   | 66261130240 | 61   | 66261131505 | 58   | 66261131598 | 59   | 66261136606 | 28   | 66261140531 | 57   |
| 66261125615 | 28   | 66261130241 | 61   | 66261131507 | 58   | 66261131599 | 59   | 66261136607 | 28   | 66261140532 | 57   |
| 66261125616 | 28   | 66261130242 | 61   | 66261131508 | 58   | 66261131600 | 59   | 66261136613 | 28   | 66261142474 | 57   |
| 66261125684 | 56   | 66261130243 | 61   | 66261131509 | 58   | 66261131609 | 58   | 66261136614 | 28   | 66261144926 | 58   |
| 66261126266 | 16   | 66261130244 | 61   | 66261131510 | 58   | 66261131612 | 58   | 66261136615 | 28   | 66261147434 | 58   |
| 66261126267 | 16   | 66261130245 | 61   | 66261131511 | 58   | 66261131613 | 58   | 66261136620 | 28   | 66261148340 | 57   |
| 66261126268 | 16   | 66261130250 | 61   | 66261131512 | 58   | 66261131614 | 58   | 66261136625 | 28   | 66261149537 | 57   |
| 66261126269 | 16   | 66261130251 | 61   | 66261131513 | 58   | 66261131615 | 58   | 66261136630 | 28   | 66261149538 | 57   |
| 66261126270 | 16   | 66261130253 | 61   | 66261131514 | 58   | 66261131617 | 58   | 66261136635 | 28   | 66261149540 | 57   |
| 66261126271 | 16   | 66261130255 | 61   | 66261131515 | 58   | 66261131618 | 12   | 66261136995 | 58   | 66261149541 | 57   |
| 66261126272 | 16   | 66261130258 | 61   | 66261131519 | 58   | 66261131619 | 12   | 66261136996 | 58   | 66261149542 | 57   |
| 66261126273 | 16   | 66261130260 | 61   | 66261131521 | 58   | 66261131620 | 12   | 66261137308 | 55   | 66261149543 | 57   |
| 66261126274 | 16   | 66261130261 | 61   | 66261131524 | 58   | 66261131621 | 12   | 66261137309 | 55   | 66261149546 | 57   |
| 66261126275 | 16   | 66261130262 | 61   | 66261131526 | 58   | 66261131622 | 12   | 66261137310 | 55   | 66261149821 | 61   |
| 66261126276 | 16   | 66261130263 | 61   | 66261131527 | 58   | 66261131624 | 12   | 66261137322 | 55   | 66261149822 | 61   |
| 66261126278 | 16   | 66261130265 | 61   | 66261131528 | 58   | 66261131626 | 12   | 66261137323 | 55   | 66261149823 | 61   |
| 66261126279 | 16   | 66261130266 | 61   | 66261131532 | 58   | 66261131627 | 12   | 66261137333 | 55   | 66261149824 | 61   |
| 66261126280 | 16   | 66261130268 | 61   | 66261131533 | 58   | 66261131628 | 12   | 66261138452 | 30   | 66261149825 | 61   |
| 66261126281 | 16   | 66261130271 | 61   | 66261131534 | 58   | 66261131629 | 12   | 66261138453 | 30   | 66261149826 | 61   |
| 66261126282 | 16   | 66261130272 | 61   | 66261131535 | 58   | 66261131630 | 12   | 66261138454 | 30   | 66261149827 | 61   |
| 66261126283 | 16   | 66261130273 | 61   | 66261131536 | 58   | 66261131631 | 12   | 66261138456 | 30   | 66261149828 | 61   |
| 66261126284 | 16   | 66261130274 | 61   | 66261131537 | 58   | 66261131632 | 12   | 66261138457 | 30   | 66261149829 | 61   |
| 66261126285 | 16   | 66261130275 | 61   | 66261131538 | 58   | 66261131633 | 12   | 66261138561 | 30   | 66261149830 | 61   |
| 66261126286 | 16   | 66261130276 | 61   | 66261131539 | 58   | 66261131634 | 12   | 66261138562 | 30   | 66261149831 | 61   |
| 66261126287 | 16   | 66261130331 | 12   | 66261131541 | 58   | 66261131661 | 59   | 66261138563 | 30   | 66261149833 | 61   |
| 66261126288 | 16   | 66261130332 | 12   | 66261131542 | 58   | 66261131662 | 59   | 66261138590 | 30   | 66261149834 | 61   |
| 66261126289 | 16   | 66261130333 | 12   | 66261131543 | 58   | 66261131681 | 8    | 66261138591 | 30   | 66261149835 | 61   |
| 66261126290 | 16   | 66261130334 | 12   | 66261131544 | 58   | 66261131683 | 8    | 66261138592 | 30   | 66261149836 | 61   |
| 66261126291 | 16   | 66261131449 | 58   | 66261131545 | 58   | 66261131685 | 8    | 66261138593 | 30   | 66261149837 | 61   |
| 66261126292 | 16   | 66261131450 | 58   | 66261131546 | 58   | 66261131686 | 8    | 66261138594 | 30   | 66261149838 | 61   |
| 66261126293 | 16   | 66261131451 | 58   | 66261131547 | 58   | 66261131687 | 8    | 66261138600 | 30   | 66261149839 | 61   |
| 66261126294 | 16   | 66261131452 | 58   | 66261131548 | 58   | 66261131688 | 8    | 66261138601 | 30   | 66261149840 | 61   |
| 66261126295 | 16   | 66261131453 | 58   | 66261131549 | 58   | 66261131689 | 8    | 66261139360 | 12   | 66261149841 | 61   |
| 66261126296 | 16   | 66261131454 | 58   | 66261131550 | 59   | 66261131690 | 8    | 66261139361 | 12   | 66261149842 | 61   |
| 66261126297 | 16   | 66261131456 | 58   | 66261131551 | 59   | 66261134425 | 20   | 66261139362 | 12   | 66261149847 | 61   |
| 66261126298 | 16   | 66261131458 | 58   | 66261131552 | 59   | 66261135900 | 58   | 66261139363 | 12   | 66261149864 | 55   |
| 66261126299 | 16   | 66261131459 | 58   | 66261131553 | 59   | 66261136350 | 28   | 66261139364 | 12   | 66261149865 | 55   |
| 66261126330 | 12   | 66261131460 | 58   | 66261131554 | 59   | 66261136351 | 28   | 66261139365 | 12   | 66261149866 | 55   |
| 66261126331 | 12   | 66261131461 | 58   | 66261131555 | 59   | 66261136352 | 28   | 66261139366 | 12   | 66261149867 | 55   |
| 66261126332 | 12   | 66261131462 | 58   | 66261131556 | 59   | 66261136354 | 28   | 66261139367 | 12   | 66261149870 | 55   |
| 66261126333 | 12   | 66261131463 | 58   | 66261131558 | 59   | 66261136355 | 28   | 66261139377 | 12   | 66261149872 | 55   |
| 66261126334 | 12   | 66261131464 | 58   | 66261131559 | 59   | 66261136368 | 58   | 66261139378 | 12   | 66261149873 | 55   |
| 66261126335 | 12   | 66261131466 | 58   | 66261131560 | 59   | 66261136369 | 58   | 66261139379 | 12   | 66261149874 | 55   |
| 66261126336 | 12   | 66261131467 | 58   | 66261131561 | 59   | 66261136370 | 58   | 66261139380 | 12   | 66261149876 | 55   |
| 66261126337 | 12   | 66261131468 | 58   | 66261131562 | 59   | 66261136372 | 58   | 66261139381 | 12   | 66261149899 | 61   |
| 66261126338 | 12   | 66261131469 | 58   | 66261131563 | 59   | 66261136373 | 58   | 66261139382 | 12   | 66261149900 | 61   |
| 66261126339 | 12   | 66261131470 | 58   | 66261131564 | 59   | 66261136375 | 58   | 66261140385 | 58   | 66261149902 | 61   |
| 66261126340 | 12   | 66261131471 | 58   | 66261131565 | 59   | 66261136376 | 58   | 66261140498 | 57   | 66261149903 | 61   |
| 66261127728 | 16   | 66261131473 | 58   | 66261131566 | 59   | 66261136576 | 28   | 66261140499 | 57   | 66261149904 | 61   |
| 66261127729 | 16   | 66261131474 | 58   | 66261131571 | 59   | 66261136581 | 28   | 66261140500 | 57   | 66261149905 | 61   |

| UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE | UPC-A       | PAGE |
|-------------|------|-------------|------|-------------|------|-------------|------|-------------|------|-------------|------|
| 66261149906 | 61   | 66623355596 | 30   | 66623362936 | 60   | 66623390703 | 53   | 70184684546 | 38   | 78072727936 | 36   |
| 66261149907 | 61   | 66623355597 | 30   | 66623362937 | 60   | 66623390704 | 53   | 77696007745 | 54   | 78072727937 | 36   |
| 66261149908 | 61   | 66623355598 | 30   | 66623362938 | 60   | 66623390705 | 53   | 77696007753 | 54   | 78072727942 | 36   |
| 66261149909 | 61   | 66623355599 | 30   | 66623362939 | 60   | 66623390706 | 53   | 77696007755 | 54   | 78072727943 | 36   |
| 66261149911 | 61   | 66623355600 | 30   | 66623362940 | 60   | 66623390707 | 53   | 77696007756 | 54   | 78072727944 | 36   |
| 66261149912 | 61   | 66623355601 | 30   | 66623362941 | 60   | 66623390708 | 53   | 77696007757 | 54   | 78072727945 | 36   |
| 66261149913 | 61   | 66623355602 | 30   | 66623362942 | 60   | 66623390709 | 53   | 77696007760 | 54   | 78072727946 | 36   |
| 66261149914 | 61   | 66623355603 | 30   | 66623362943 | 60   | 66623390710 | 53   | 77696007762 | 54   | 78072727947 | 36   |
| 66261149915 | 61   | 66623355604 | 30   | 66623362944 | 60   | 66623390711 | 53   | 77696007763 | 54   | 78072727957 | 37   |
| 66261149916 | 61   | 66623357276 | 31   | 66623362945 | 60   | 69078609033 | 44   | 77696007765 | 54   | 78072727958 | 37   |
| 66261155373 | 57   | 66623357277 | 31   | 66623362946 | 60   | 69957348198 | 60   | 77696007768 | 54   | 78072727959 | 37   |
| 66261155374 | 57   | 66623357278 | 31   | 66623362947 | 60   | 69957348200 | 60   | 77696007770 | 54   | 78072727960 | 37   |
| 66261155376 | 57   | 66623357279 | 31   | 66623362948 | 60   | 69957348201 | 60   | 77696007773 | 54   | 78072727961 | 37   |
| 66261155377 | 57   | 66623357280 | 31   | 66623362949 | 60   | 69957348203 | 60   | 77696007774 | 54   | 78072727962 | 37   |
| 66261155378 | 57   | 66623357281 | 31   | 66623362950 | 60   | 69957348204 | 60   | 77696007775 | 54   | 78072727963 | 37   |
| 66261155380 | 57   | 66623357282 | 31   | 66623362951 | 60   | 69957348206 | 60   | 77696007776 | 54   | 78072727981 | 37   |
| 66261156659 | 20   | 66623357283 | 31   | 66623362952 | 60   | 69957348223 | 60   | 77696007777 | 54   | 78072727982 | 37   |
| 66261158171 | 20   | 66623357284 | 31   | 66623362953 | 60   | 69957352447 | 60   | 77696007778 | 54   | 78072727983 | 37   |
| 66261170640 | 25   | 66623357285 | 31   | 66623362954 | 60   | 70184623029 | 43   | 77696007781 | 54   | 78072727984 | 37   |
| 66261170641 | 25   | 66623357286 | 31   | 66623362955 | 60   | 70184645926 | 38   | 77696007784 | 54   | 78072727985 | 37   |
| 66261170642 | 25   | 66623357287 | 31   | 66623362956 | 60   | 70184645927 | 38   | 77696007785 | 54   | 78072727986 | 37   |
| 66261170643 | 25   | 66623357288 | 31   | 66623362957 | 60   | 70184681309 | 38   | 77696007786 | 54   | 78072727987 | 37   |
| 66261170644 | 25   | 66623357289 | 31   | 66623362958 | 60   | 70184681383 | 38   | 77696007787 | 54   | 78072727992 | 36   |
| 66261170645 | 25   | 66623357606 | 51   | 66623362959 | 60   | 70184681779 | 38   | 77696007788 | 54   | 78072727993 | 36   |
| 66623305608 | 57   | 66623357608 | 51   | 66623362960 | 60   | 70184682555 | 38   | 77696007791 | 54   | 78072727994 | 36   |
| 66623311870 | 12   | 66623357611 | 51   | 66623365598 | 30   | 70184682586 | 38   | 77696007793 | 54   | 78072735316 | 51   |
| 66623311871 | 12   | 66623357612 | 51   | 66623365600 | 30   | 70184682593 | 38   | 77696007795 | 54   | 78072757584 | 51   |
| 66623311873 | 12   | 66623357613 | 51   | 66623365788 | 60   | 70184682595 | 38   | 78072720875 | 37   | 78072757599 | 51   |
| 66623311874 | 12   | 66623357616 | 51   | 66623365789 | 60   | 70184683611 | 38   | 78072720885 | 37   | 78072757600 | 51   |
| 66623311875 | 12   | 66623362921 | 60   | 66623366015 | 30   | 70184683612 | 38   | 78072720890 | 37   | 78072757602 | 51   |
| 66623311876 | 12   | 66623362922 | 60   | 66623366071 | 60   | 70184684020 | 38   | 78072720895 | 37   | 78072780438 | 36   |
| 66623311877 | 12   | 66623362923 | 60   | 66623366074 | 60   | 70184684087 | 38   | 78072720900 | 37   | 78072780440 | 36   |
| 66623311878 | 12   | 66623362924 | 60   | 66623366075 | 60   | 70184684088 | 38   | 78072720905 | 37   | 78072780447 | 36   |
| 66623311879 | 12   | 66623362925 | 60   | 66623366077 | 60   | 70184684089 | 38   | 78072720910 | 37   | 78072780448 | 36   |
| 66623353306 | 31   | 66623362926 | 60   | 66623367394 | 60   | 70184684098 | 38   | 78072727922 | 36   | 78072780449 | 36   |
| 66623353309 | 31   | 66623362927 | 60   | 66623367398 | 60   | 70184684099 | 38   | 78072727923 | 36   | 78072780450 | 36   |
| 66623353310 | 31   | 66623362928 | 60   | 66623367399 | 60   | 70184684100 | 38   | 78072727924 | 36   | 78072780451 | 36   |
| 66623353311 | 31   | 66623362929 | 60   | 66623367400 | 60   | 70184684105 | 38   | 78072727925 | 36   | 78072781846 | 36   |
| 66623353312 | 31   | 66623362930 | 60   | 66623369778 | 60   | 70184684106 | 38   | 78072727926 | 36   | 78072781847 | 36   |
| 66623353313 | 31   | 66623362931 | 60   | 66623374368 | 23   | 70184684107 | 38   | 78072727927 | 36   |             |      |
| 66623353314 | 31   | 66623362932 | 60   | 66623376000 | 62   | 70184684361 | 38   | 78072727932 | 36   |             |      |
| 66623355578 | 30   | 66623362933 | 60   | 66623390700 | 53   | 70184684463 | 38   | 78072727933 | 36   |             |      |
| 66623355594 | 30   | 66623362934 | 60   | 66623390701 | 53   | 70184684464 | 38   | 78072727934 | 36   |             |      |
| 66623355595 | 30   | 66623362935 | 60   | 66623390702 | 53   | 70184684545 | 38   | 78072727935 | 36   |             |      |







**NORTON** MESH-POWER™  
SAINT-GOBAIN

# POWERFUL DUST EXTRACTION

FOR A BREATH OF FRESH AIR

Designed for virtually dust-free sanding, Norton MeshPower ceramic discs provide for a cleaner and healthier working environment, a better finish, and a much more comfortable sanding experience.

## NORTON MESHPOWER ADVANTAGE

- Mesh backing for optimum dust extraction
- Full ceramic grain for excellent cut rates and superior scratch pattern
- Norton No-Fil technology prevents clogging and creates a consistent cut throughout the product life
- Hook and loop design with no designated hole pattern is quick and easy to align to any backing pad – just apply and go!




## VISIT US ONLINE

See how Norton MeshPower can work for you and watch the video at <https://nortonsga.us/mpdiy> or visit us online at <https://nortonsga.us/meshpowerdiy>

# NORTON DO-IT-YOURSELF AND CONTRACTOR MARKET



**Flexibility and Conformability in the Palm of Your Hand.**  
Norton ProSand has every angle covered with various shapes, sizes and grit combinations of sanding sponges. Last longer than sandpaper.

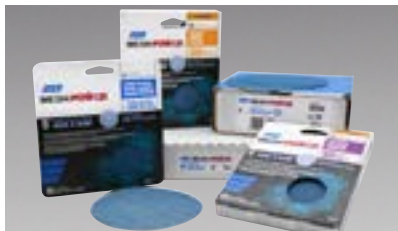

**For a Breath of Fresh Air.**  
With Norton MeshPower sanding discs feature powerful dust extraction for a virtually dust-free sanding; meaning a cleaner and healthier working environment, a better finish and a much more comfortable sanding experience.



**It's Time to Clean the Air.**  
Norton ProSand Multi-Air Cyclonic Discs feature a multi-hole design pattern that maximizes dust extraction for all 5" & 6" random orbital sanders. For all surfaces and coatings.



**Fast and Tough for the Most Demanding Jobs.**  
Norton Diamond Blades are the choice of professionals vs. abrasive blades with faster cut rate, constant depth of cut and less downtime.



**Bulk Up Fast with Norton WallSand.**  
Packaged in bulk, Norton WallSand bulk drywall sanding sheets meet the unique needs of drywall contractors and deliver flawless walls and ceilings with fewer trips to the store to stock up.



**Norton Has You Covered.**  
Norton Painter's Plastic protects virtually any area from sanding dust and paint overspray with ease - even after repositioning. Mono films and linear low-density plastics (LLDPE) don't compare.

## SANDING MADE **EASIER**™

[www.facebook.com/NortonAbrasivesNA](https://www.facebook.com/NortonAbrasivesNA) | [www.youtube.com/NortonAbrasives](https://www.youtube.com/NortonAbrasives) | [www.nortonabrasives.com](http://www.nortonabrasives.com)

### USA CUSTOMER SERVICE:

Toll Free Phone: 1 (800) 551-4415  
Phone: 1 (254) 918-2306  
Fax: 1 (254) 918-2309

**FORM #340** REV. 08/20

© Saint-Gobain August 2020

Norton, "Sanding Made Easier" and "Reshaping Your World" are registered trademarks of Saint-Gobain Abrasives. All other trademarks are the property of their respective owners.

