
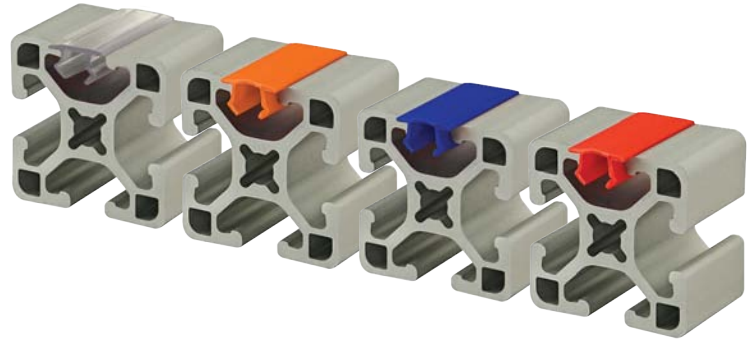


Economy T-slot Cover

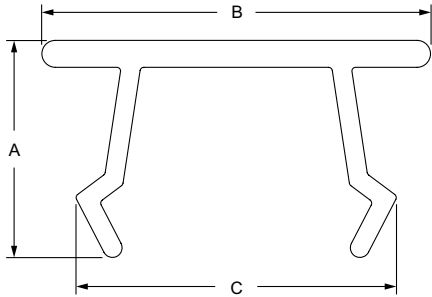

Part No.	Series	Color	Material	Finish	Process	A	B	C	Stock Length	Weight			
2819	10	Yellow	PVC	Matte	Extruded	.211"	.430"	.313"	72.500"	.080 lb			
2820	10	Black				.211"	.430"	.313"		.083 lb			
2821	10	Gray				.211"	.430"	.313"		.076 lb			
2818	10	Red				.211"	.430"	.313"		.098 lb			
2817	10	Blue				.211"	.430"	.313"		.080 lb			
2816	10	Orange				.211"	.430"	.313"		.091 lb			
2822	15	Yellow				.282"	.505"	.416"		.131 lb			
2823	15	Black				.282"	.505"	.416"	.133 lb				
2824	15	Gray				.282"	.505"	.416"	.126 lb				
2825	15	Red				.282"	.505"	.416"	.124 lb				
2826	15	Blue				.282"	.505"	.416"	.126 lb				
2827	15	Orange				.282"	.505"	.416"	.127 lb				
2871	15 40	Clear				.283"	.505"	.416"	.126 lb				
25-2819	25	Yellow				5.36mm	10.92mm	7.95mm	1841.50mm	.0354 kg			
25-2820	25	Black				5.36mm	10.92mm	7.95mm		.0363 kg			
25-2821	25	Gray				5.36mm	10.92mm	7.95mm		.0360 kg			
25-2818	25	Red				5.36mm	10.92mm	7.95mm		.0443 kg			
25-2817	25	Blue				5.36mm	10.92mm	7.95mm		.0386 kg			
25-2816	25	Orange				5.36mm	10.92mm	7.95mm		.0411 kg			
40-2822	40	Yellow				7.16mm	12.83mm	10.57mm		.0549 kg			
40-2823	40	Black				7.16mm	12.83mm	10.57mm	.0467 kg				
40-2824	40	Gray				7.16mm	12.83mm	10.57mm	.0521 kg				
40-2825	40	Red				7.16mm	12.83mm	10.57mm	.0544 kg				
40-2826	40	Blue				7.16mm	12.83mm	10.57mm	.0579 kg				
40-2827	40	Orange				7.16mm	12.83mm	10.57mm	.0602 kg				
14108	45	Yellow				Polypropylene			7.37mm	11.61mm	11.58mm	2000.00mm	.0514 kg
14107	45	Black							7.37mm	11.61mm	11.58mm		.0514 kg
14110	45	Gray	7.37mm	11.61mm	11.58mm				.0514 kg				
14123	45	Red	7.37mm	11.61mm	11.58mm				.0514 kg				
14121	45	Blue	7.37mm	11.61mm	11.58mm				.0514 kg				