

Optional harness

Optional Harness Adaptation List

Series	Model	Input harness	Output harness	Signal Harness
CUS-MP	CUS350MP-1000	HA-2-IN HA-7-IN	+ : HA-22-OU, - : HA-23-OU	HA-12-C
EVS	EVS300/R	—	—	HA-1-C
	EVS600/R	—	—	HA-6-C
EZA	EZA2500 EZA11K	—	—	EZA-CNHA-1
GXE	GXE600	—	—	HA-9-C
HWS-A	HWS50A/R~150A/R	—	—	HA-1-C
HWS	HWS300 HWS600	—	—	HWS-HA-02 HWS-HA-KIT01 (*) (* Housing, Terminal Pin)
	HWS1000 HWS1500 HWS1800T	—	—	HWS-HA-01 HWS-HA-02 HWS-HA-KIT01 (*) (* Housing, Terminal Pin)
HWS-P	HWS300P HWS600P	—	—	HA-3-C
SWS-L HWS-L/BAT	SWS600L SWS1000L HWS600L/BAT HWS1000L/BAT	—	—	HA-4-C HA-5-C
RWS-B	RWS300B/R	—	—	HA-2-C
	RWS600B RWS1000B RWS1500B	—	—	HA-6-C
VS-C	VS10C	HA-1-IN HA-6-IN	HA-1-OU	—
	VS15C	HA-1-IN HA-6-IN	HA-2-OU	—
	VS30C	HA-2-IN HA-7-IN	HA-3-OU	—
VS-E	VS50E	HA-2-IN HA-7-IN	HA-3-OU	—
	VS75E	HA-2-IN HA-7-IN	HA-4-OU	—
	VS100E	HA-2-IN HA-7-IN	HA-5-OU	—
	VS150E	HA-2-IN HA-7-IN	+ : HA-6-OU, - : HA-7-OU	—
ZBM	ZBM20		HA-4-OU	HA-13-C
ZBM-AC	ZBM-AC162	HA-13-IN	—	HA-14-C
ZWD-PAF	ZWD100PAF/J ZWD150PAF/J	HA-2-IN HA-7-IN	HA-14-OU	—
	ZWD225PAF/J	HA-2-IN HA-7-IN	HA-15-OU	—

Optional harness

Optional Harness Adaptation List

Series	Model	Input harness	Output harness	Signal Harness
ZWQ	ZWQ80	HA-2-IN HA-7-IN	V1,V2,V3:HA-9-OU V4:HA-10-OU	—
	ZWQ130	HA-2-IN HA-7-IN	V1:HA-11-OU V2,V3:HA-12-OU V4:HA-13-OU	—
ZWS-B	ZWS10B ZWS15B	HA-2-IN HA-7-IN	HA-16-OU	—
	ZWS30B ZWS50B	HA-2-IN HA-7-IN	HA-3-OU	—
	ZWS75B	HA-2-IN HA-7-IN	HA-4-OU	—
	ZWS100B	HA-2-IN HA-7-IN	HA-5-OU	—
	ZWS150B	HA-2-IN HA-7-IN	+ :HA-6-OU , - :HA-7-OU	—
ZWS-BAF	ZWS50BAF	HA-2-IN HA-7-IN	HA-3-OU	—
	ZWS75BAF	HA-2-IN HA-7-IN	HA-4-OU	—
	ZWS100BAF	HA-2-IN HA-7-IN	HA-5-OU	HA-1-C (* For /R option model only)
	ZWS150BAF	HA-2-IN HA-7-IN	+ :HA-6-OU , - :HA-7-OU	
	ZWS300BAF	HA-2-IN HA-7-IN	HA-5-OU	
ZWS-BP	ZWS150BP	HA-2-IN HA-7-IN	HA-4-OU	HA-1-C (* For /R option model only)
	ZWS240BP	HA-2-IN HA-7-IN	HA-5-OU	
ZWS-RC	ZWS240RC	—	HA-5-OU	—
	ZWS240RC/R	—	HA-5-OU	HA-1-C
	ZWS300RC	HA-2-IN HA-7-IN	HA-5-OU	—
	ZWS300RC/R			HA-1-C
	ZWS300RC/BM	HA-2-IN HA-7-IN		—
	ZWS300RC/RBM	HA-2-IN HA-7-IN CN2:HA-13-IN		HA-1-C

Optional harness

Input Harness

<p>Model HA-1-IN</p> <p>Housing XHP-7</p> <p>Terminal Pin SXH-001T-P0.6 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>22</td> <td>Black</td> </tr> <tr> <td>2, 3</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>22</td> <td>White</td> </tr> <tr> <td>5, 6</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>7</td> <td>UL1007</td> <td>22</td> <td>Green</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	22	Black	2, 3		—		4	UL1007	22	White	5, 6		—		7	UL1007	22	Green
Pin No.	Cable	AWG	Color																							
1	UL1007	22	Black																							
2, 3		—																								
4	UL1007	22	White																							
5, 6		—																								
7	UL1007	22	Green																							
<p>Model HA-2-IN</p> <p>Housing VHR-5N</p> <p>Terminal Pin SVH-21T-P1.1 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>White</td> </tr> <tr> <td>4</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Green</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2		—		3	UL1015	18	White	4		—		5	UL1015	18	Green
Pin No.	Cable	AWG	Color																							
1	UL1015	18	Black																							
2		—																								
3	UL1015	18	White																							
4		—																								
5	UL1015	18	Green																							
<p>Model HA-6-IN</p> <p>Housing XHP-7</p> <p>Terminal Pin SXH-001T-P0.6 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>22</td> <td>Black</td> </tr> <tr> <td>2, 3</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>22</td> <td>White</td> </tr> <tr> <td>5, 6</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>7</td> <td>UL1007</td> <td>22</td> <td>Green/Yellow</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	22	Black	2, 3		—		4	UL1007	22	White	5, 6		—		7	UL1007	22	Green/Yellow
Pin No.	Cable	AWG	Color																							
1	UL1007	22	Black																							
2, 3		—																								
4	UL1007	22	White																							
5, 6		—																								
7	UL1007	22	Green/Yellow																							
<p>Model HA-7-IN</p> <p>Housing VHR-5N</p> <p>Terminal Pin SVH-21T-P1.1 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>White</td> </tr> <tr> <td>4</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Green/Yellow</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2		—		3	UL1015	18	White	4		—		5	UL1015	18	Green/Yellow
Pin No.	Cable	AWG	Color																							
1	UL1015	18	Black																							
2		—																								
3	UL1015	18	White																							
4		—																								
5	UL1015	18	Green/Yellow																							
<p>Model HA-13-IN</p> <p>Housing VHR-3N (J.S.T)</p> <p>Terminal Pin SVH-21T-P1.1 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td></td> <td>—</td> <td></td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>White</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2		—		3	UL1015	18	White								
Pin No.	Cable	AWG	Color																							
1	UL1015	18	Black																							
2		—																								
3	UL1015	18	White																							

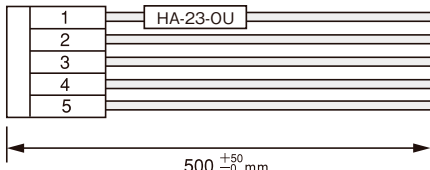
Output Harness

Model Housing Terminal Pin	HA-1-OU XHP-2 SXH-001T-P0.6 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>22</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>22</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	22	Black	2	UL1007	22	Red																								
Pin No.	Cable	AWG	Color																																				
1	UL1007	22	Black																																				
2	UL1007	22	Red																																				
Model Housing Terminal Pin	HA-2-OU XHP-4 SXH-001T-P0.6 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>22</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>22</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1007</td> <td>22</td> <td>Red</td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>22</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	22	Black	2	UL1007	22	Black	3	UL1007	22	Red	4	UL1007	22	Red																
Pin No.	Cable	AWG	Color																																				
1	UL1007	22	Black																																				
2	UL1007	22	Black																																				
3	UL1007	22	Red																																				
4	UL1007	22	Red																																				
Model Housing Terminal Pin	HA-3-OU VHR-4N SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2	UL1015	18	Black	3	UL1015	18	Red	4	UL1015	18	Red																
Pin No.	Cable	AWG	Color																																				
1	UL1015	18	Black																																				
2	UL1015	18	Black																																				
3	UL1015	18	Red																																				
4	UL1015	18	Red																																				
Model Housing Terminal Pin	HA-4-OU VHR-6N SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2	UL1015	18	Black	3	UL1015	18	Black	4	UL1015	18	Red	5	UL1015	18	Red	6	UL1015	18	Red								
Pin No.	Cable	AWG	Color																																				
1	UL1015	18	Black																																				
2	UL1015	18	Black																																				
3	UL1015	18	Black																																				
4	UL1015	18	Red																																				
5	UL1015	18	Red																																				
6	UL1015	18	Red																																				
Model Housing Terminal Pin	HA-5-OU VHR-8N SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>7</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>8</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2	UL1015	18	Black	3	UL1015	18	Black	4	UL1015	18	Black	5	UL1015	18	Red	6	UL1015	18	Red	7	UL1015	18	Red	8	UL1015	18	Red
Pin No.	Cable	AWG	Color																																				
1	UL1015	18	Black																																				
2	UL1015	18	Black																																				
3	UL1015	18	Black																																				
4	UL1015	18	Black																																				
5	UL1015	18	Red																																				
6	UL1015	18	Red																																				
7	UL1015	18	Red																																				
8	UL1015	18	Red																																				
Model Housing Terminal Pin	HA-6-OU VHR-6N SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Red	2	UL1015	18	Red	3	UL1015	18	Red	4	UL1015	18	Red	5	UL1015	18	Red	6	UL1015	18	Red								
Pin No.	Cable	AWG	Color																																				
1	UL1015	18	Red																																				
2	UL1015	18	Red																																				
3	UL1015	18	Red																																				
4	UL1015	18	Red																																				
5	UL1015	18	Red																																				
6	UL1015	18	Red																																				
Model Housing Terminal Pin	HA-7-OU VHR-7N SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>7</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2	UL1015	18	Black	3	UL1015	18	Black	4	UL1015	18	Black	5	UL1015	18	Black	6	UL1015	18	Black	7	UL1015	18	Black				
Pin No.	Cable	AWG	Color																																				
1	UL1015	18	Black																																				
2	UL1015	18	Black																																				
3	UL1015	18	Black																																				
4	UL1015	18	Black																																				
5	UL1015	18	Black																																				
6	UL1015	18	Black																																				
7	UL1015	18	Black																																				
Model Housing Terminal Pin	HA-9-OU VHR-8N SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>7</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>8</td> <td>UL1015</td> <td>18</td> <td>Purple</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Red	2	UL1015	18	Red	3	UL1015	18	Black	4	UL1015	18	Black	5	UL1015	18	Orange	6	UL1015	18	Gray	7	UL1015	18	Gray	8	UL1015	18	Purple
Pin No.	Cable	AWG	Color																																				
1	UL1015	18	Red																																				
2	UL1015	18	Red																																				
3	UL1015	18	Black																																				
4	UL1015	18	Black																																				
5	UL1015	18	Orange																																				
6	UL1015	18	Gray																																				
7	UL1015	18	Gray																																				
8	UL1015	18	Purple																																				

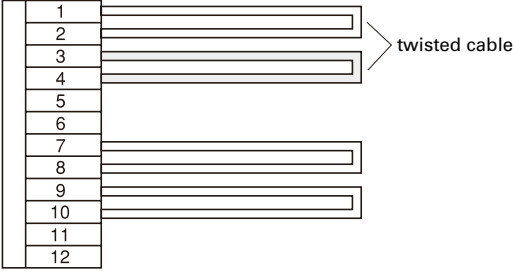
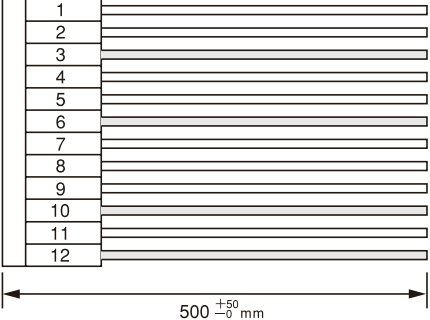
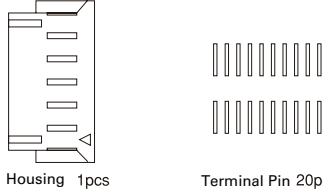
 
 
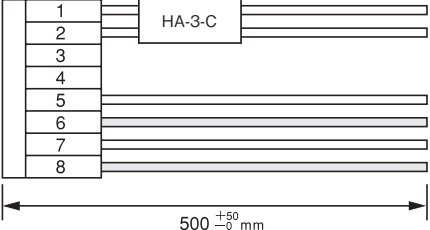
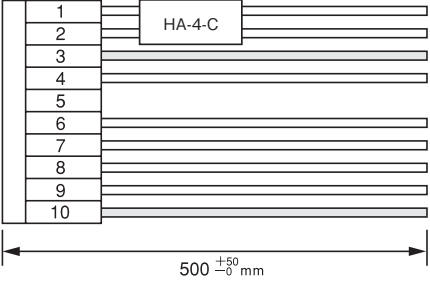
Output Harness

Model HA-10-OU Housing VHR-4N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Brown</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Brown</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Blue</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Blue</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Brown	2	UL1015	18	Brown	3	UL1015	18	Blue	4	UL1015	18	Blue																								
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Brown																																											
2	UL1015	18	Brown																																											
3	UL1015	18	Blue																																											
4	UL1015	18	Blue																																											
Model HA-11-OU Housing VHR-8N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>7</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>8</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Red	2	UL1015	18	Red	3	UL1015	18	Red	4	UL1015	18	Red	5	UL1015	18	Black	6	UL1015	18	Black	7	UL1015	18	Black	8	UL1015	18	Black								
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Red																																											
2	UL1015	18	Red																																											
3	UL1015	18	Red																																											
4	UL1015	18	Red																																											
5	UL1015	18	Black																																											
6	UL1015	18	Black																																											
7	UL1015	18	Black																																											
8	UL1015	18	Black																																											
Model HA-12-OU Housing VHR-3N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Purple</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Orange	2	UL1015	18	Gray	3	UL1015	18	Purple																												
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Orange																																											
2	UL1015	18	Gray																																											
3	UL1015	18	Purple																																											
Model HA-13-OU Housing VHR-6N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Brown</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Brown</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Brown</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Blue</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Blue</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Blue</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Brown	2	UL1015	18	Brown	3	UL1015	18	Brown	4	UL1015	18	Blue	5	UL1015	18	Blue	6	UL1015	18	Blue																
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Brown																																											
2	UL1015	18	Brown																																											
3	UL1015	18	Brown																																											
4	UL1015	18	Blue																																											
5	UL1015	18	Blue																																											
6	UL1015	18	Blue																																											
Model HA-14-OU Housing VHR-8N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>7</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>8</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Gray	2	UL1015	18	Gray	3	UL1015	18	Orange	4	UL1015	18	Orange	5	UL1015	18	Black	6	UL1015	18	Black	7	UL1015	18	Red	8	UL1015	18	Red								
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Gray																																											
2	UL1015	18	Gray																																											
3	UL1015	18	Orange																																											
4	UL1015	18	Orange																																											
5	UL1015	18	Black																																											
6	UL1015	18	Black																																											
7	UL1015	18	Red																																											
8	UL1015	18	Red																																											
Model HA-15-OU Housing VHR-10N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>3</td> <td>UL1015</td> <td>18</td> <td>Gray</td> </tr> <tr> <td>4</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>5</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>6</td> <td>UL1015</td> <td>18</td> <td>Orange</td> </tr> <tr> <td>7</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>8</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>9</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> <tr> <td>10</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Gray	2	UL1015	18	Gray	3	UL1015	18	Gray	4	UL1015	18	Orange	5	UL1015	18	Orange	6	UL1015	18	Orange	7	UL1015	18	Black	8	UL1015	18	Black	9	UL1015	18	Red	10	UL1015	18	Red
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Gray																																											
2	UL1015	18	Gray																																											
3	UL1015	18	Gray																																											
4	UL1015	18	Orange																																											
5	UL1015	18	Orange																																											
6	UL1015	18	Orange																																											
7	UL1015	18	Black																																											
8	UL1015	18	Black																																											
9	UL1015	18	Red																																											
10	UL1015	18	Red																																											
Model HA-16-OU Housing VHR-2N Terminal Pin SVH-21T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1015</td> <td>18</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1015</td> <td>18</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1015	18	Black	2	UL1015	18	Red																																
Pin No.	Cable	AWG	Color																																											
1	UL1015	18	Black																																											
2	UL1015	18	Red																																											
Model HA-22-OU Housing VHR-5N (J.S.T) Terminal Pin SVH-41T-P1.1 (J.S.T)		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1430</td> <td>16</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1430</td> <td>16</td> <td>Red</td> </tr> <tr> <td>3</td> <td>UL1430</td> <td>16</td> <td>Red</td> </tr> <tr> <td>4</td> <td>UL1430</td> <td>16</td> <td>Red</td> </tr> <tr> <td>5</td> <td>UL1430</td> <td>16</td> <td>Red</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1430	16	Red	2	UL1430	16	Red	3	UL1430	16	Red	4	UL1430	16	Red	5	UL1430	16	Red																				
Pin No.	Cable	AWG	Color																																											
1	UL1430	16	Red																																											
2	UL1430	16	Red																																											
3	UL1430	16	Red																																											
4	UL1430	16	Red																																											
5	UL1430	16	Red																																											

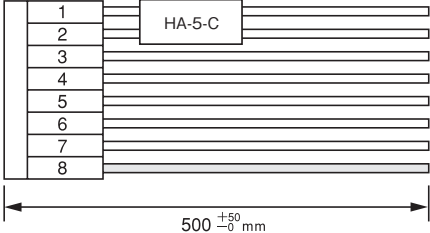
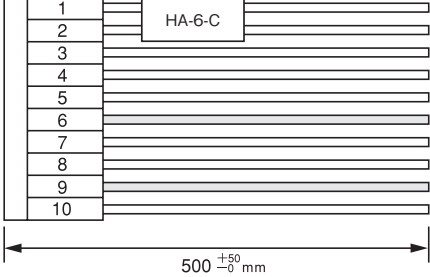
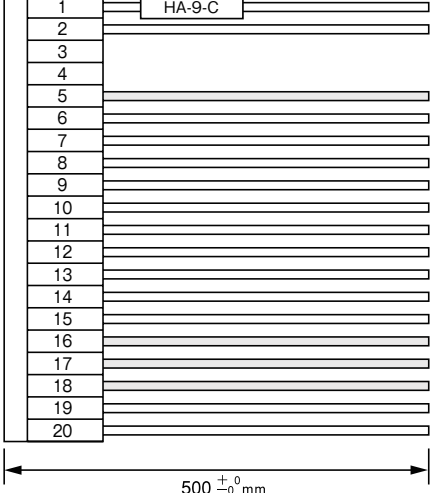
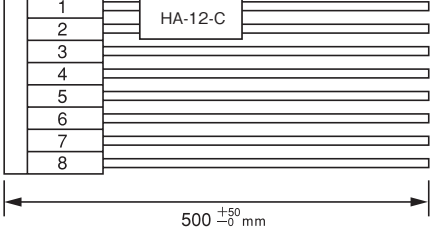
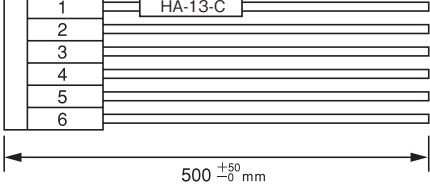
■ Output Harness

Model	HA-23-OU																												
Housing	VHR-5N (J.S.T)		<table border="1" style="width: 100%; border-collapse: collapse;"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1430</td> <td>16</td> <td>Black</td> </tr> <tr> <td>2</td> <td>UL1430</td> <td>16</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1430</td> <td>16</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1430</td> <td>16</td> <td>Black</td> </tr> <tr> <td>5</td> <td>UL1430</td> <td>16</td> <td>Black</td> </tr> </tbody> </table>			Pin No.	Cable	AWG	Color	1	UL1430	16	Black	2	UL1430	16	Black	3	UL1430	16	Black	4	UL1430	16	Black	5	UL1430	16	Black
Pin No.	Cable		AWG	Color																									
1	UL1430	16	Black																										
2	UL1430	16	Black																										
3	UL1430	16	Black																										
4	UL1430	16	Black																										
5	UL1430	16	Black																										
Terminal Pin	SVH-41T-P1.1 (J.S.T)																												

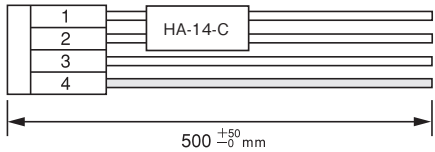
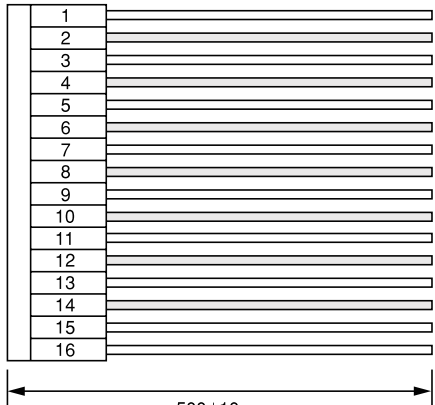
■ Signal Harness

<p>Model HWS-HA-01</p> <p>Housing PHDR-12VS</p> <p>Terminal Pin SPHD-001T-P0.5 (J.S.T)</p>		<table border="1" data-bbox="1078 371 1444 528"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1, 2</td> <td>UL1007</td> <td>24</td> <td>Red</td> </tr> <tr> <td>3, 4</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> <tr> <td>5, 6</td> <td>—</td> <td>—</td> <td>—</td> </tr> <tr> <td>7, 8</td> <td>UL1007</td> <td>24</td> <td>Brown</td> </tr> <tr> <td>9, 10</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>11, 12</td> <td>—</td> <td>—</td> <td>—</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1, 2	UL1007	24	Red	3, 4	UL1007	24	Black	5, 6	—	—	—	7, 8	UL1007	24	Brown	9, 10	UL1007	24	Yellow	11, 12	—	—	—																								
Pin No.	Cable	AWG	Color																																																			
1, 2	UL1007	24	Red																																																			
3, 4	UL1007	24	Black																																																			
5, 6	—	—	—																																																			
7, 8	UL1007	24	Brown																																																			
9, 10	UL1007	24	Yellow																																																			
11, 12	—	—	—																																																			
<p>Model HWS-HA-02</p> <p>Housing PHDR-12VS</p> <p>Terminal Pin SPHD-001T-P0.5 (J.S.T)</p>		<table border="1" data-bbox="1078 640 1444 936"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>24</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>24</td> <td>Orange</td> </tr> <tr> <td>3</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> <tr> <td>5</td> <td>UL1007</td> <td>24</td> <td>Brown</td> </tr> <tr> <td>6</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> <tr> <td>7</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>8</td> <td>UL1007</td> <td>24</td> <td>Brown</td> </tr> <tr> <td>9</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>10</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> <tr> <td>11</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> <tr> <td>12</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Red	2	UL1007	24	Orange	3	UL1007	24	Black	4	UL1007	24	Blue	5	UL1007	24	Brown	6	UL1007	24	Black	7	UL1007	24	Yellow	8	UL1007	24	Brown	9	UL1007	24	Yellow	10	UL1007	24	Black	11	UL1007	24	Blue	12	UL1007	24	Black
Pin No.	Cable	AWG	Color																																																			
1	UL1007	24	Red																																																			
2	UL1007	24	Orange																																																			
3	UL1007	24	Black																																																			
4	UL1007	24	Blue																																																			
5	UL1007	24	Brown																																																			
6	UL1007	24	Black																																																			
7	UL1007	24	Yellow																																																			
8	UL1007	24	Brown																																																			
9	UL1007	24	Yellow																																																			
10	UL1007	24	Black																																																			
11	UL1007	24	Blue																																																			
12	UL1007	24	Black																																																			
<p>Model HWS-HA-KIT01</p> <p>Housing PHDR-12VS</p> <p>Terminal Pin SPHD-001T-P0.5 (J.S.T)</p>		<p>※Housing, an application wire rod and the crimp tool please use an article of the maker designation</p>																																																				
<p>Model HA-1-C</p> <p>Housing XHP-2</p> <p>Terminal Pin SXH-001T-P0.6 (J.S.T)</p>		<table border="1" data-bbox="1078 1245 1444 1317"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Yellow	2	UL1007	24	Blue																																								
Pin No.	Cable	AWG	Color																																																			
1	UL1007	24	Yellow																																																			
2	UL1007	24	Blue																																																			
<p>Model HA-2-C</p> <p>Housing XAP-02V-1</p> <p>Terminal Pin SXA-01T-P0.6 (J.S.T)</p>		<table border="1" data-bbox="1078 1435 1444 1507"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Yellow	2	UL1007	24	Blue																																								
Pin No.	Cable	AWG	Color																																																			
1	UL1007	24	Yellow																																																			
2	UL1007	24	Blue																																																			
<p>Model HA-3-C</p> <p>Housing PHDR-08VS</p> <p>Terminal Pin SPHD-001T-P0.5 (J.S.T)</p>		<table border="1" data-bbox="1078 1592 1444 1798"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>24</td> <td>Brown</td> </tr> <tr> <td>3</td> <td>—</td> <td>—</td> <td>—</td> </tr> <tr> <td>4</td> <td>—</td> <td>—</td> <td>—</td> </tr> <tr> <td>5</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>6</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> <tr> <td>7</td> <td>UL1007</td> <td>24</td> <td>Green</td> </tr> <tr> <td>8</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Blue	2	UL1007	24	Brown	3	—	—	—	4	—	—	—	5	UL1007	24	Yellow	6	UL1007	24	Black	7	UL1007	24	Green	8	UL1007	24	Black																
Pin No.	Cable	AWG	Color																																																			
1	UL1007	24	Blue																																																			
2	UL1007	24	Brown																																																			
3	—	—	—																																																			
4	—	—	—																																																			
5	UL1007	24	Yellow																																																			
6	UL1007	24	Black																																																			
7	UL1007	24	Green																																																			
8	UL1007	24	Black																																																			
<p>Model HA-4-C</p> <p>Housing PHDR-10VS</p> <p>Terminal Pin SPHD-001T-P0.5 (J.S.T)</p>		<table border="1" data-bbox="1078 1854 1444 2107"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>24</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>24</td> <td>Orange</td> </tr> <tr> <td>3</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> <tr> <td>5</td> <td>—</td> <td>—</td> <td>—</td> </tr> <tr> <td>6</td> <td>UL1007</td> <td>24</td> <td>Brown</td> </tr> <tr> <td>7</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>8</td> <td>UL1007</td> <td>24</td> <td>Blue</td> </tr> <tr> <td>9</td> <td>UL1007</td> <td>24</td> <td>Yellow</td> </tr> <tr> <td>10</td> <td>UL1007</td> <td>24</td> <td>Black</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Red	2	UL1007	24	Orange	3	UL1007	24	Black	4	UL1007	24	Blue	5	—	—	—	6	UL1007	24	Brown	7	UL1007	24	Yellow	8	UL1007	24	Blue	9	UL1007	24	Yellow	10	UL1007	24	Black								
Pin No.	Cable	AWG	Color																																																			
1	UL1007	24	Red																																																			
2	UL1007	24	Orange																																																			
3	UL1007	24	Black																																																			
4	UL1007	24	Blue																																																			
5	—	—	—																																																			
6	UL1007	24	Brown																																																			
7	UL1007	24	Yellow																																																			
8	UL1007	24	Blue																																																			
9	UL1007	24	Yellow																																																			
10	UL1007	24	Black																																																			

■ Signal Harness

<p>Model Housing Terminal Pin</p>	<p>HA-5-C PHDR-08VS SPHD-001T-P0.5 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr><td>1</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>2</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>3</td><td>UL1007</td><td>24</td><td>Orange</td></tr> <tr><td>4</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>5</td><td>UL1007</td><td>24</td><td>Purple</td></tr> <tr><td>6</td><td>UL1007</td><td>24</td><td>Purple</td></tr> <tr><td>7</td><td>UL1007</td><td>24</td><td>Green</td></tr> <tr><td>8</td><td>UL1007</td><td>24</td><td>Black</td></tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Blue	2	UL1007	24	Blue	3	UL1007	24	Orange	4	UL1007	24	Yellow	5	UL1007	24	Purple	6	UL1007	24	Purple	7	UL1007	24	Green	8	UL1007	24	Black																																																
Pin No.	Cable	AWG	Color																																																																																				
1	UL1007	24	Blue																																																																																				
2	UL1007	24	Blue																																																																																				
3	UL1007	24	Orange																																																																																				
4	UL1007	24	Yellow																																																																																				
5	UL1007	24	Purple																																																																																				
6	UL1007	24	Purple																																																																																				
7	UL1007	24	Green																																																																																				
8	UL1007	24	Black																																																																																				
<p>Model Housing Terminal Pin</p>	<p>HA-6-C PHDR-10VS SPHD-001T-P0.5 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr><td>1</td><td>UL1007</td><td>24</td><td>Red</td></tr> <tr><td>2</td><td>UL1007</td><td>24</td><td>Orange</td></tr> <tr><td>3</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>4</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>5</td><td>UL1007</td><td>24</td><td>Green</td></tr> <tr><td>6</td><td>UL1007</td><td>24</td><td>Black</td></tr> <tr><td>7</td><td>UL1007</td><td>24</td><td>Brown</td></tr> <tr><td>8</td><td>UL1007</td><td>24</td><td>Purple</td></tr> <tr><td>9</td><td>UL1007</td><td>24</td><td>Black</td></tr> <tr><td>10</td><td>UL1007</td><td>24</td><td>Blue</td></tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Red	2	UL1007	24	Orange	3	UL1007	24	Yellow	4	UL1007	24	Blue	5	UL1007	24	Green	6	UL1007	24	Black	7	UL1007	24	Brown	8	UL1007	24	Purple	9	UL1007	24	Black	10	UL1007	24	Blue																																								
Pin No.	Cable	AWG	Color																																																																																				
1	UL1007	24	Red																																																																																				
2	UL1007	24	Orange																																																																																				
3	UL1007	24	Yellow																																																																																				
4	UL1007	24	Blue																																																																																				
5	UL1007	24	Green																																																																																				
6	UL1007	24	Black																																																																																				
7	UL1007	24	Brown																																																																																				
8	UL1007	24	Purple																																																																																				
9	UL1007	24	Black																																																																																				
10	UL1007	24	Blue																																																																																				
<p>Model Housing Terminal Pin</p>	<p>HA-9-C PHDR-20VS SPHD-001T-P0.5 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr><td>1</td><td>UL1007</td><td>24</td><td>Red</td></tr> <tr><td>2</td><td>UL1007</td><td>24</td><td>Orange</td></tr> <tr><td>3</td><td></td><td>—</td><td></td></tr> <tr><td>4</td><td></td><td>—</td><td></td></tr> <tr><td>5</td><td>UL1007</td><td>24</td><td>Black</td></tr> <tr><td>6</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>7</td><td>UL1007</td><td>24</td><td>Brown</td></tr> <tr><td>8</td><td>UL1007</td><td>24</td><td>Orange</td></tr> <tr><td>9</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>10</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>11</td><td>UL1007</td><td>24</td><td>Green</td></tr> <tr><td>12</td><td>UL1007</td><td>24</td><td>White</td></tr> <tr><td>13</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>14</td><td>UL10368</td><td>22</td><td>Red</td></tr> <tr><td>15</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>16</td><td>UL10368</td><td>22</td><td>Black</td></tr> <tr><td>17</td><td>UL1007</td><td>24</td><td>Black</td></tr> <tr><td>18</td><td>UL1007</td><td>24</td><td>Black</td></tr> <tr><td>19</td><td>UL1007</td><td>24</td><td>Orange</td></tr> <tr><td>20</td><td>UL1007</td><td>24</td><td>Purple</td></tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Red	2	UL1007	24	Orange	3		—		4		—		5	UL1007	24	Black	6	UL1007	24	Blue	7	UL1007	24	Brown	8	UL1007	24	Orange	9	UL1007	24	Yellow	10	UL1007	24	Blue	11	UL1007	24	Green	12	UL1007	24	White	13	UL1007	24	Yellow	14	UL10368	22	Red	15	UL1007	24	Yellow	16	UL10368	22	Black	17	UL1007	24	Black	18	UL1007	24	Black	19	UL1007	24	Orange	20	UL1007	24	Purple
Pin No.	Cable	AWG	Color																																																																																				
1	UL1007	24	Red																																																																																				
2	UL1007	24	Orange																																																																																				
3		—																																																																																					
4		—																																																																																					
5	UL1007	24	Black																																																																																				
6	UL1007	24	Blue																																																																																				
7	UL1007	24	Brown																																																																																				
8	UL1007	24	Orange																																																																																				
9	UL1007	24	Yellow																																																																																				
10	UL1007	24	Blue																																																																																				
11	UL1007	24	Green																																																																																				
12	UL1007	24	White																																																																																				
13	UL1007	24	Yellow																																																																																				
14	UL10368	22	Red																																																																																				
15	UL1007	24	Yellow																																																																																				
16	UL10368	22	Black																																																																																				
17	UL1007	24	Black																																																																																				
18	UL1007	24	Black																																																																																				
19	UL1007	24	Orange																																																																																				
20	UL1007	24	Purple																																																																																				
<p>Model Housing Terminal Pin</p>	<p>HA-12-C PHDR-08VS (J.S.T) SPHD-001T-P0.5 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr><td>1</td><td>UL1007</td><td>24</td><td>Gray</td></tr> <tr><td>2</td><td>UL1007</td><td>24</td><td>Purple</td></tr> <tr><td>3</td><td>UL1007</td><td>24</td><td>Gray</td></tr> <tr><td>4</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>5</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>6</td><td>UL1007</td><td>24</td><td>Orange</td></tr> <tr><td>7</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>8</td><td>UL1007</td><td>24</td><td>Orange</td></tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Gray	2	UL1007	24	Purple	3	UL1007	24	Gray	4	UL1007	24	Yellow	5	UL1007	24	Blue	6	UL1007	24	Orange	7	UL1007	24	Blue	8	UL1007	24	Orange																																																
Pin No.	Cable	AWG	Color																																																																																				
1	UL1007	24	Gray																																																																																				
2	UL1007	24	Purple																																																																																				
3	UL1007	24	Gray																																																																																				
4	UL1007	24	Yellow																																																																																				
5	UL1007	24	Blue																																																																																				
6	UL1007	24	Orange																																																																																				
7	UL1007	24	Blue																																																																																				
8	UL1007	24	Orange																																																																																				
<p>Model Housing Terminal Pin</p>	<p>HA-13-C XHP-6 (J.S.T) SXH-001T-P0.6 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr><td>1</td><td>UL1007</td><td>24</td><td>Blue</td></tr> <tr><td>2</td><td>UL1007</td><td>24</td><td>Brown</td></tr> <tr><td>3</td><td>UL1007</td><td>24</td><td>Gray</td></tr> <tr><td>4</td><td>UL1007</td><td>24</td><td>Yellow</td></tr> <tr><td>5</td><td>UL1007</td><td>24</td><td>White</td></tr> <tr><td>6</td><td>UL1007</td><td>24</td><td>Orange</td></tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	24	Blue	2	UL1007	24	Brown	3	UL1007	24	Gray	4	UL1007	24	Yellow	5	UL1007	24	White	6	UL1007	24	Orange																																																								
Pin No.	Cable	AWG	Color																																																																																				
1	UL1007	24	Blue																																																																																				
2	UL1007	24	Brown																																																																																				
3	UL1007	24	Gray																																																																																				
4	UL1007	24	Yellow																																																																																				
5	UL1007	24	White																																																																																				
6	UL1007	24	Orange																																																																																				

■ Signal Harness

<p>Model</p> <p>Housing</p> <p>Terminal Pin</p>	<p>HA-14-C</p> <p>XHP-4 (J.S.T)</p> <p>SXH-001T-P0.6 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>22</td> <td>Yellow</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>22</td> <td>Gray</td> </tr> <tr> <td>3</td> <td>UL1007</td> <td>22</td> <td>Red</td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>22</td> <td>Black</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	22	Yellow	2	UL1007	22	Gray	3	UL1007	22	Red	4	UL1007	22	Black																																																
Pin No.	Cable	AWG	Color																																																																				
1	UL1007	22	Yellow																																																																				
2	UL1007	22	Gray																																																																				
3	UL1007	22	Red																																																																				
4	UL1007	22	Black																																																																				
<p>Model</p> <p>Housing</p> <p>Terminal Pin</p>	<p>EZA-CNHA-1</p> <p>PADP-16V-1-S</p> <p>SPH-002T-P0.5L SPND-002T-C0.5 (J.S.T)</p>		<table border="1"> <thead> <tr> <th>Pin No.</th> <th>Cable</th> <th>AWG</th> <th>Color</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>UL1007</td> <td>28</td> <td>Red</td> </tr> <tr> <td>2</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>3</td> <td>UL1007</td> <td>28</td> <td>White</td> </tr> <tr> <td>4</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>5</td> <td>UL1007</td> <td>28</td> <td>Yellow</td> </tr> <tr> <td>6</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>7</td> <td>UL1007</td> <td>28</td> <td>Blue</td> </tr> <tr> <td>8</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>9</td> <td>UL1007</td> <td>28</td> <td>Green</td> </tr> <tr> <td>10</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>11</td> <td>UL1007</td> <td>28</td> <td>Orange</td> </tr> <tr> <td>12</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>13</td> <td>UL1007</td> <td>28</td> <td>Gray</td> </tr> <tr> <td>14</td> <td>UL1007</td> <td>28</td> <td>Black</td> </tr> <tr> <td>15</td> <td>UL1007</td> <td>28</td> <td>Purple</td> </tr> <tr> <td>16</td> <td>UL1007</td> <td>28</td> <td>Gray</td> </tr> </tbody> </table>	Pin No.	Cable	AWG	Color	1	UL1007	28	Red	2	UL1007	28	Black	3	UL1007	28	White	4	UL1007	28	Black	5	UL1007	28	Yellow	6	UL1007	28	Black	7	UL1007	28	Blue	8	UL1007	28	Black	9	UL1007	28	Green	10	UL1007	28	Black	11	UL1007	28	Orange	12	UL1007	28	Black	13	UL1007	28	Gray	14	UL1007	28	Black	15	UL1007	28	Purple	16	UL1007	28	Gray
Pin No.	Cable	AWG	Color																																																																				
1	UL1007	28	Red																																																																				
2	UL1007	28	Black																																																																				
3	UL1007	28	White																																																																				
4	UL1007	28	Black																																																																				
5	UL1007	28	Yellow																																																																				
6	UL1007	28	Black																																																																				
7	UL1007	28	Blue																																																																				
8	UL1007	28	Black																																																																				
9	UL1007	28	Green																																																																				
10	UL1007	28	Black																																																																				
11	UL1007	28	Orange																																																																				
12	UL1007	28	Black																																																																				
13	UL1007	28	Gray																																																																				
14	UL1007	28	Black																																																																				
15	UL1007	28	Purple																																																																				
16	UL1007	28	Gray																																																																				