


## Nylon Fully Insulated Female Disconnect Dimensions

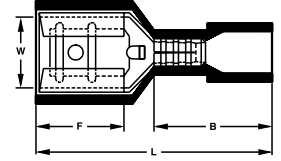

Wire Range (AWG)	Wire Range (mm <sup>2</sup> )	Tab Size (in.)	Tab Size (mm)	Max. Wire Ins. Dia. (in.)	Max Wire Ins. Dia. (mm)	Dimensions (in.)				Dimensions (mm)				Cat. No
						L	B	W	F	L	B	W	L	
22-18	0.5 - 1.0	.250 x .032	6.35 x 0.8	.150	3.8	.866	.433	.260	.287	22.0	11.0	6.6	7.3	<b>83-9771</b>
16-14	1.5 - 2.5	.250 x .032	6.35 x 0.8	.185	4.7	.866	.433	.260	.287	22.0	11.0	6.6	7.3	<b>83-9781</b> <b>84-9781</b>
12-10	4.0 - 6.0	.250 x .032	6.35 x 0.8	.244	6.2	.945	.512	.260	.287	24.0	13.0	6.6	7.3	<b>83-9791</b> <b>84-9791</b>

7105°C/300 Volts max.

