



Datasheet

RS PRO 2m Cat5e UTP PVC Networking Cable - Grey

Stock number: 2406342

EN


The RS Pro range of CAT5e networking cables run at speeds up to 10/100/1000 which is commonly referred to as Gigabit networking speeds.

The internal conductors are made from 24awg 100% Full copper, have a PVC jacket and the outer diameter is 5.4mm. The connectors are RJ45 (8P8C) and the pins are gold plated to help prevent corrosion.



The wiring uses the TIA/EIA-568B wiring which is standard for most networking uses.

The cables are UL certified to CM(UL) C(UL) CMH E164469.

We have a wide variety of colours and lengths.

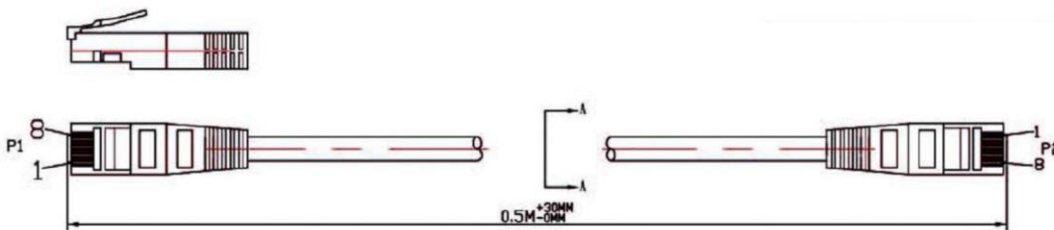

 Marking (Blue) : UTP CAT.5E PATCH ISO/IEC 11801 & EN 50288 & TIA/EIA-568-B.2 3P VERIFIED FOR GIGABIT ETHERNET 24AWG X 4P TYPE CM(UL) C(UL) E164469 - F5

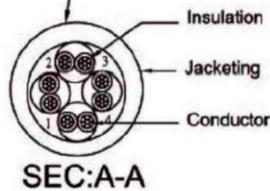

Conductor	Bare Copper 24AWG 7.0.196±0.015mm
Insulation	Diameter:0.95±0.05mm PE
Jacketing	Thickness:0.45±0.03mm Diameter:5.4±0.2mm PVC
WIRE	CAT.5E UTP 24AWG*4P PVC PATCH CORD , 7.0.196.5.4±0.2MM
PLUG	8P8C 50U*
Molding	GREY
WIRE COLOR	Various Colours

PA/R	PINOUT		
	P1(T568B)	WIRE	P2(T568B)
1	1	WHITE/ORANGE	1
	2	ORANGE	2
2	3	WHITE/GREEN	3
	4	BLUE	4
3	5	WHITE/BLUE	5
	6	GREEN	6
4	7	WHITE/BROWN	7
	8	BROWN	8

RoHS / REACH / CE / UKCA

rspro.com