


Features

- 50 Ω impedance
- Operating frequency is 4GHz
- Nickel plated body and gold plated centre contact
- Gold-plated contacts ensure maximum efficiency

RS PRO Straight 30 Ω Coaxial Adapter

RS Stock No.: 246-9497

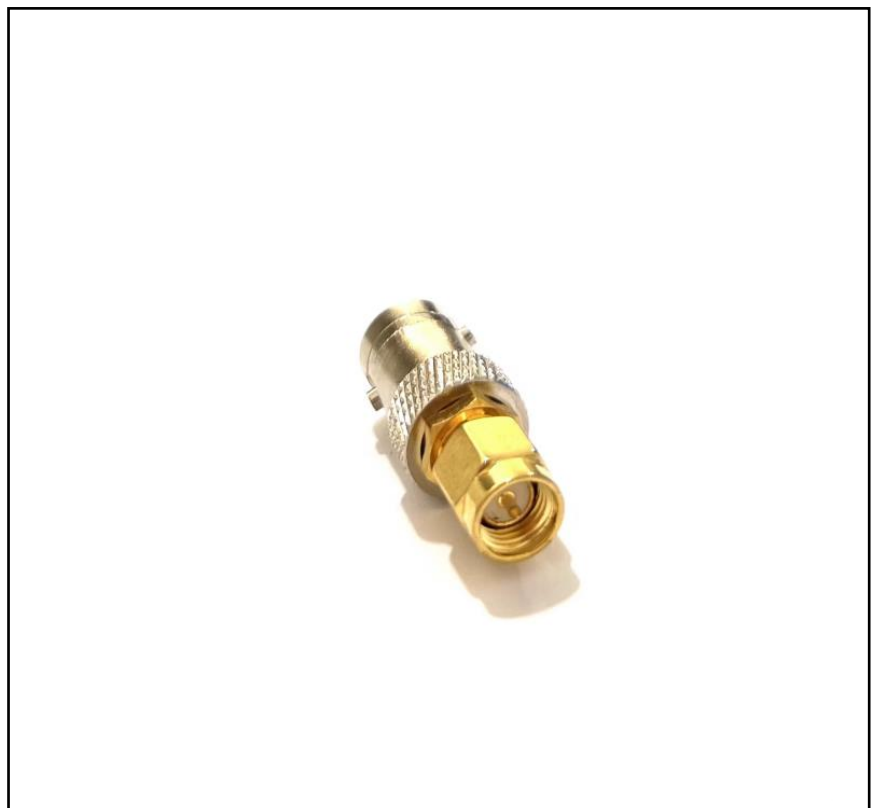

RS PRO Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

BNC connectors are typically used for lower frequency and power applications and are commonly used for analog signal applications such as pre-digital television broadcasts and laboratory test equipment.

General Specifications

Adapter Type	SMA Plug to BNC Jack
Adapter Type A	SMA
Adapter Type B	BNC
Gender A	Male
Gender B	Female
Body-1 Plating	Nickel 100u"
Body-2 Plating	Nickel
Body Material	Brass
Body Orientation	Straight
Contact Material	Copper
Contact Plating	Gold 3u"
Insulation Material	PTFE

Electrical Specifications

Temperature Range	-65°~+165°
Characteristic Impedance	50Ω
Frequency Range	0~4GHz
Working Voltage	500V
Insulation Resistance	≥1000MΩ
Medium Pressure	1000V(rms)
VSWR	≤1.3
Working Life	500Cycles

Approvals

Declarations	CE
Standards Met	RoHS

Similar Products

Stock No.	Brand	Product Name	Attribute 1	Attribute 2
8782378	RS PRO	RF Adapter	50Ω impedance	Operating frequency is 4GHz

