


Part Number: 8918

Type	Size	Rating	Description
Incandescent	T6	14V 100mA	T-1¾ Midget Flange Lamp

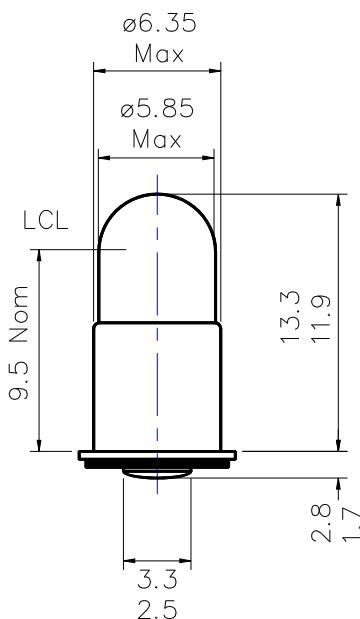

Dimensions in millimetres

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
14	90	100	110	4.7	6.3	7.9	10,000

Notes:

- 1 **Base Type** Nickel plated SX6s base to BS EN 60061-1
- 2 **Filament Shape** C-2F
- 3 **Lamp Marking** 8918 14V 100mA
- 4 **Environmental** RoHS & REACH SVHC compliant