

Part number

CX 8 J6M



Male RJ45 connector, crimp, 8 data contacts

Product description

Product type	Data connector
Connection type	RJ45
Gender	Male
Specification	Crimp RJ45, Cat. 6A

Technical data

Current	1 A
Voltage	50 V
Wire cross-section	0,40 mm ² - 0,61 mm ²

Further technical details

Weight	4,70 g
Operating temperature range (min, max)	-40°C...+70°C
UL 94 flammability rating	V-0

Material properties

RoHS conformity	Compliant
China RoHS - EFUP	E
REACH SVHC substances	No

General ordering information

EAN13 code	8015747206204
eCl@ss 8.1	27440205
ETIM 7.0	EC001121

Packaging Information


Packaging length	112,00 mm
Packaging height	95,00 mm
Packaging width	117,00 mm
Packaging weight	0,10 kg
Packaging volume	1,24 dm ³
Packaging description	Carton box
Packaging quantity	10 Pcs
Packaging EAN code	8015747292092
Sub-packaging description	Plastic bag
Sub-packaging quantity	1 Pcs
Sub-packaging EAN barcode	8015747206372

Part number

CX 8 J6M



Catalogue drawings

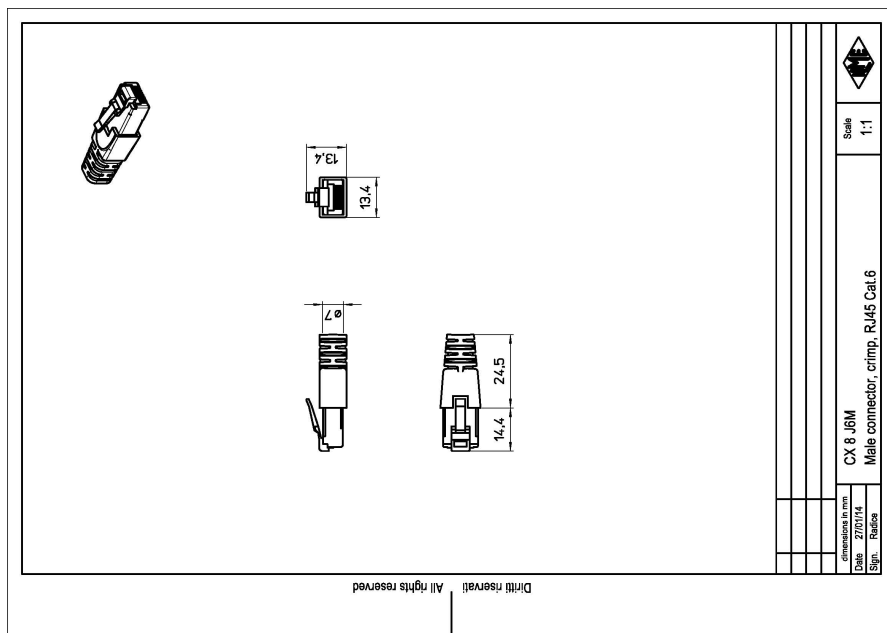

Notes

Dimensions shown in mm are not binding and may be changed without notice.