


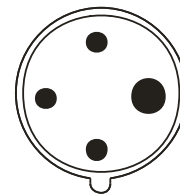
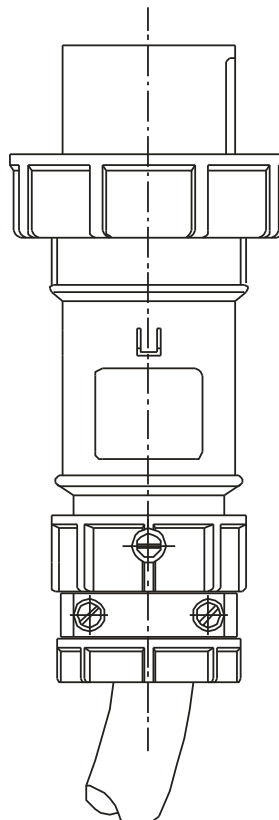
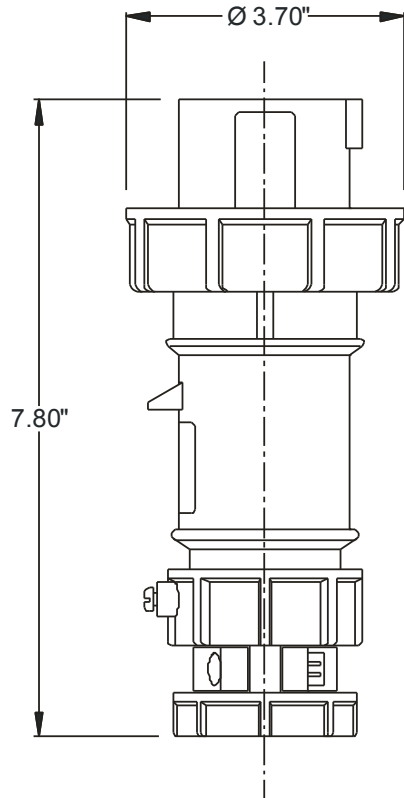
MENNEKES
Electrical Products
277 Fairfield Road
Fairfield, NJ 07004
800-882-7584
www.MENNEKES.com

PLUG, IN-LINE

Part No.	ME 430P9W
Description:	30 Amp 3Ø 250Vac 3 Pole, 4 Wire Plug
Construction:	UL Type 4X; IEC IP 67 Watertight
Approvals:	 to UL Standards 1682; 1686 and CSA C22.2 No. 182.1 UL Locked Rotor HP Rating – 3 HP IEC 60309-1; IEC 60309-2

IEC COLOR CODE: Blue

GROUND SOCKET: 3 Hour Position Mates with Female in 9 Hour Position.



Front View of Plug

Wire Range: #8 - #12 AWG
Cord Range: .43" - .94"
Threaded Cable Entry: 1" NPT

Drawing Not to Scale