

MENNEKES  
Electrical Products  
277 Fairfield Road  
Fairfield, NJ 07004  
800-882-7584  
www.MENNEKES.com


---

---

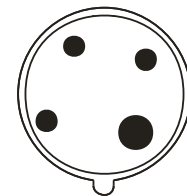
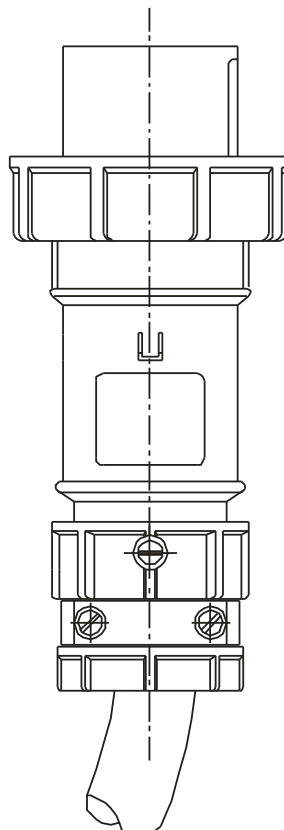
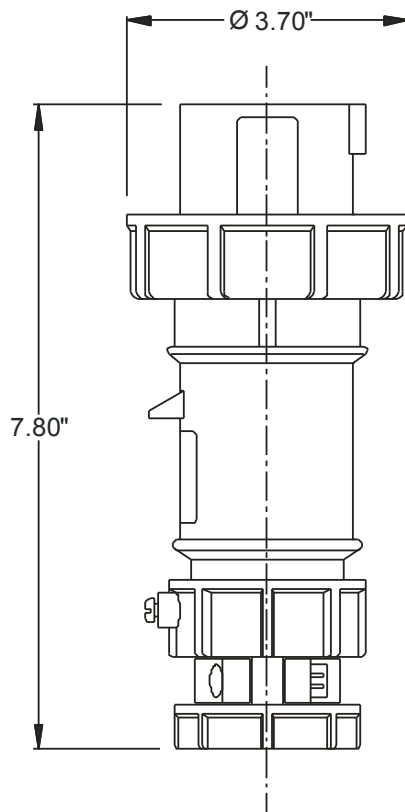
**PLUG, IN-LINE**

---

---

<b>Part No.</b>	ME 430P7W
<b>Description:</b>	30 Amp 3Ø 480Vac 3 Pole, 4 Wire Plug
<b>Construction:</b>	UL Type 4X; IEC IP 67 Watertight
<b>Approvals:</b>	 to UL Standards 1682; 1686 and CSA C22.2 No. 182.1 UL Locked Rotor HP Rating – 7.5 HP IEC 60309-1; IEC 60309-2

---

**IEC COLOR CODE:** Red**GROUND SOCKET:** 5 Hour Position Mates with Female in 7 Hour Position.

Front View of Plug

Wire Range: #8 - #12 AWG  
Cord Range: .43" - .94"  
Threaded Cable Entry: 1" NPT

Drawing Not to Scale