


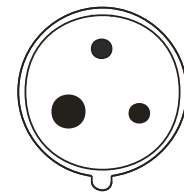
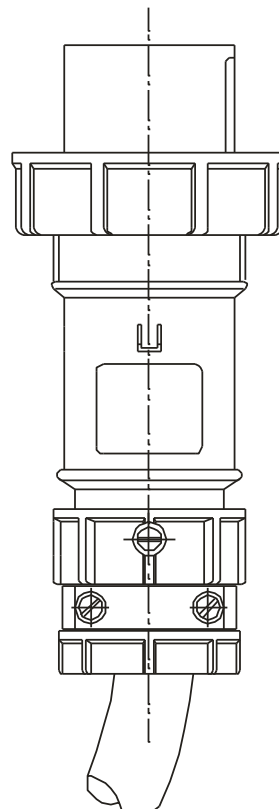
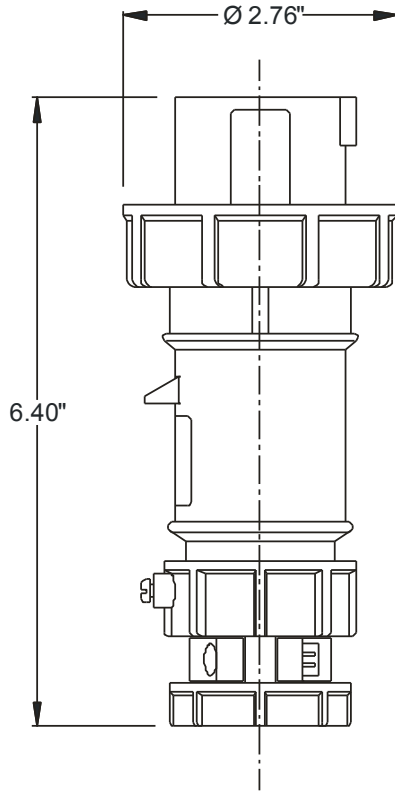
MENNEKES
Electrical Products
277 Fairfield Road
Fairfield, NJ 07004
800-882-7584
www.MENNEKES.com

PLUG, IN-LINE

Part No.	ME 320P4W
Description:	20 Amp 125Vac 2 Pole, 3 Wire Plug
Construction:	UL Type 4X; IEC IP 67 Watertight
Approvals:	 to UL Standards 1682; 1686 and CSA C22.2 No. 182.1 UL Locked Rotor HP Rating – 1 HP IEC 60309-1; IEC 60309-2

IEC COLOR CODE: Yellow

GROUND SOCKET: 8 Hour Position Mates with Female in 4 Hour Position.



Front View of Plug

Wire Range: #10 - #14 AWG
Cord Range: .36" - .76"
Threaded Cable Entry: 3/4" NPT

Drawing Not to Scale