

MENNEKES  
Electrical Products  
277 Fairfield Road  
Fairfield, NJ 07004  
800-882-7584  
www.MENNEKES.com


---

---

**CONNECTOR, IN-LINE**




---

---

<b>Part No.</b>	ME 320C6W
<b>Description:</b>	20 Amp 250Vac 2 Pole, 3 Wire Connector
<b>Construction:</b>	UL Type 4X; IEC IP 67 Watertight
<b>Approvals:</b>	 to UL Standards 1682; 1686 and CSA C22.2 No. 182.1 UL Locked Rotor HP Rating – 2 HP IEC 60309-1; IEC 60309-2

**IEC COLOR CODE:** Blue

**GROUND SOCKET:** 6 Hour Position Mates with Male in 6 Hour Position.

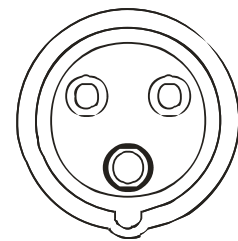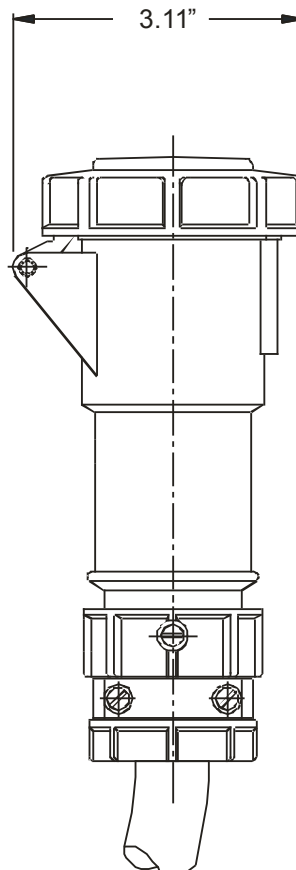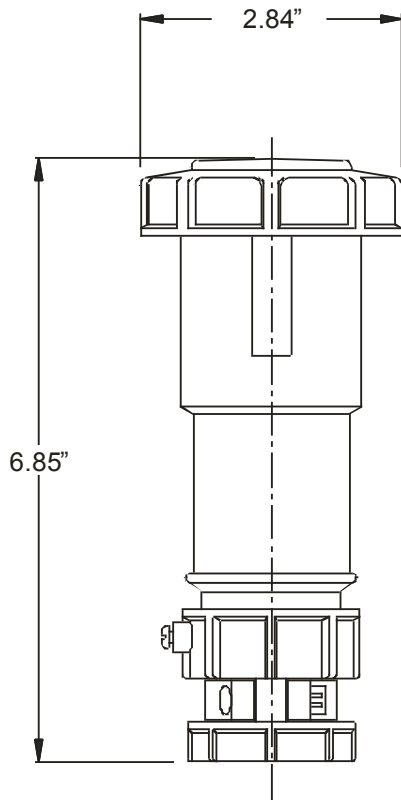

Front View of Connector

Wire Range: #10 - #14 AWG  
Cord Range: .36" - .76"  
Threaded Cable Entry: 3/4" NPT

Drawing Not to Scale