
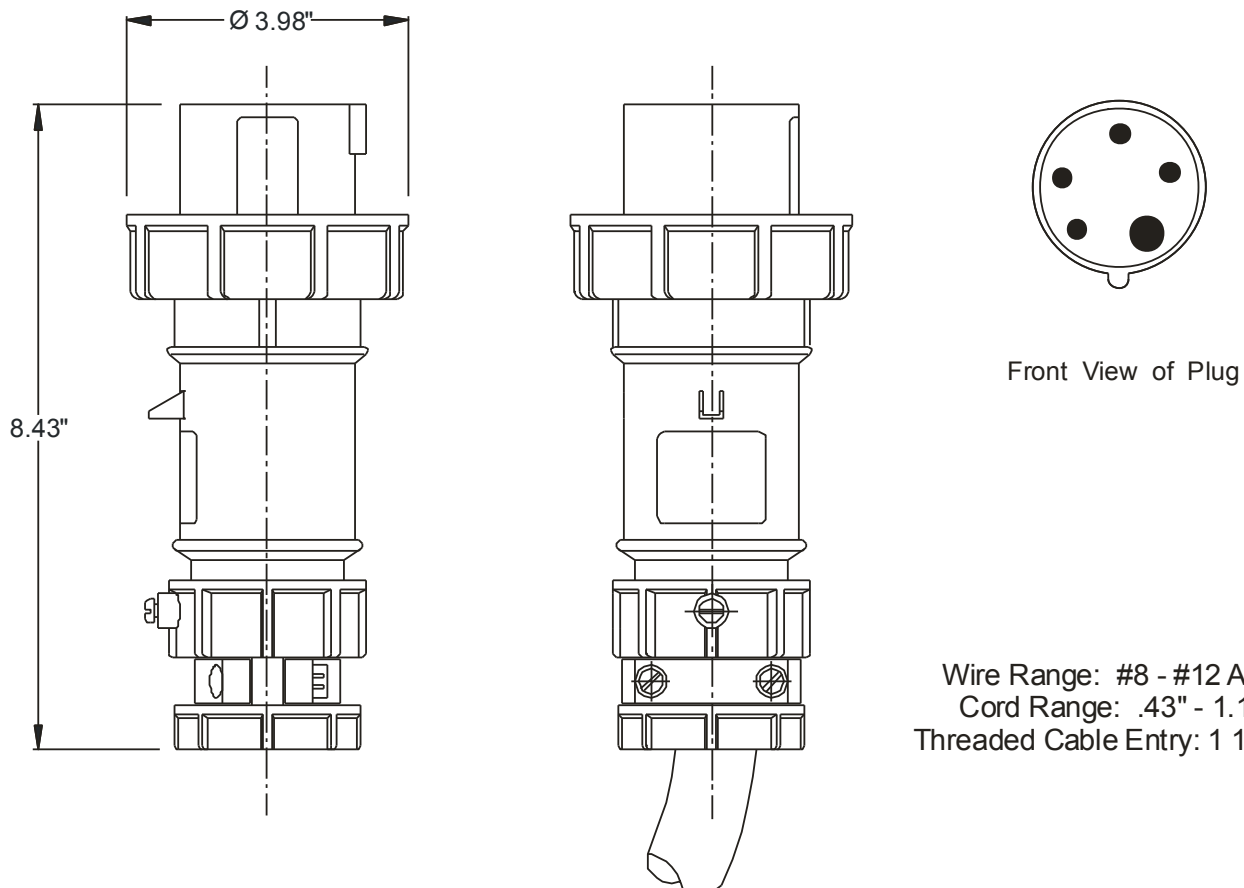


MENNEKES
Electrical Products
277 Fairfield Road
Fairfield, NJ 07004
800-882-7584
www.MENNEKES.com

PLUG, IN-LINE

Part No.	ME 530P7W
Description:	30 Amp 3ØY 277/480Vac 4 Pole, 5 Wire Plug
Construction:	UL Type 4X; IEC IP 67 Watertight
Approvals:	 to UL Standards 1682; 1686 and CSA C22.2 No. 182.1 UL Locked Rotor HP Rating – 7.5 HP IEC 60309-1; IEC 60309-2

IEC COLOR CODE: Red

GROUND SOCKET: 5 Hour Position Mates with Female in 7 Hour Position.

Front View of Plug

Wire Range: #8 - #12 AWG
Cord Range: .43" - 1.12"
Threaded Cable Entry: 1 1/4" NPT

Drawing Not to Scale