


Citrix EW3P0000559 Compatible SFP Module - 1000BASE-LX - 1GbE Single Mode Fiber SMF Optic Transceiver - 1GE Gigabit Ethernet SFP - LC 10km - 1310nm - DDM

**Product ID:** EW3P0000559-ST

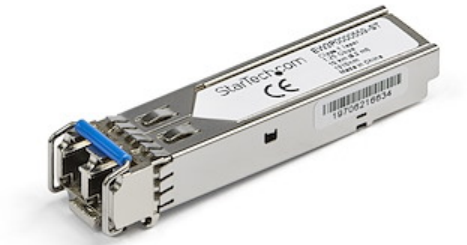

The EW3P0000559-ST is a Citrix EW3P0000559 compatible fiber transceiver module that has been designed, programmed and tested to work with Citrix brand switches and routers. It delivers dependable 1 GbE connectivity over fiber cable, for 1000BASE-LX compliant networks, with a maximum distance of up to 10 km (6.2 mi).

Technical Specifications:

- Wavelength: 1310nm
- Maximum Data Transfer Rate: 1000 Mbps (1 Gbps)
- Type: Single Mode Fiber
- Connection Type: LC Connector
- Maximum Transfer Distance: 10 km (6.2 mi)
- MTBF: 634,210,013 hours
- Power Consumption: < 1.3W
- Digital Diagnostics Monitoring (DDM): Yes

This SFP fiber module is hot-swappable, making upgrades and replacements seamless by minimizing network disruptions.

All StarTech.com SFP & SFP+ transceiver modules are backed by a lifetime warranty and free lifetime multilingual technical support. StarTech.com offers a wide variety of SFP modules and direct-attach SFP cables, providing the convenience and reliability you need to ensure dependable network performance.

## Certifications, Reports and Compatibility



## Applications

## Features

- **100% CITRIX EW3P0000559 COMPATIBLE SFP TRANSCEIVER:** Designed, programmed and tested to work with compatible Citrix switches and routers to deliver reliable 1GbE connectivity
- **TECHNICAL SPECS:** 1000BASE-LX 1Gbps Single Mode (SMF) LC Connector 1310nm Digital Diagnostic Monitoring (DDM) Distances up to 10km (6.2mi)
- **TESTED FOR OEM HOST COMPATIBILITY:** Hot-swappable in Citrix routers and switches; DDM support reports the transceiver's status to most SNMP network management tools
- **WORKS WITH MSA COMPLIANT SWITCHES:** Also works with switch models from Ubiquiti, D-Link, Netgear, Supermicro, TP-Link and more that accept uncoded modules
- **THE IT PRO'S CHOICE:** Designed and built for IT Professionals, this SFP module is backed for life (lifetime of module, not network switch), including free lifetime 24/5 multi-lingual technical assistance.

---

### Hardware

Warranty	Lifetime
Compatible Brand	Citrix
Industry Standards	IEEE 802.3z 1000BASE-LX

---

### Performance

Maximum Data Transfer Rate	1.25 Gbps
Max Transfer Distance	10 km (6.2 mi)
Type	Single Mode
Wavelength	1310nm
Fiber Operating Mode	Full-Duplex
DDM	Yes

Compatible Networks	1000 Mbps (1 Gbps)
MTBF	634,210,013 hours
Power Consumption (In Watts)	< 1.3W

---

**Connector(s)**

Connector A	1 - SFP Slot
Connector B	1 - Fiber Optic LC Duplex

---

**Physical Characteristics**

Product Length	0.5 in [1.4 cm]
Product Width	2.2 in [5.7 cm]
Product Height	0.5 in [1.2 cm]
Weight of Product	0.6 oz [18 g]

---

**Packaging Information**

Package Length	4.5 in [11.5 cm]
Package Width	3.5 in [9 cm]
Package Height	1.2 in [3.1 cm]
Shipping (Package) Weight	1.8 oz [50 g]

---

**What's in the Box**

Included in Package	1 - SFP Transceiver
---------------------	---------------------

---

*\*Product appearance and specifications are subject to change without notice.*