




# Datasheet

## RS PRO EC FAN 120x120x38mm

Stock Number: 230-3027

EN

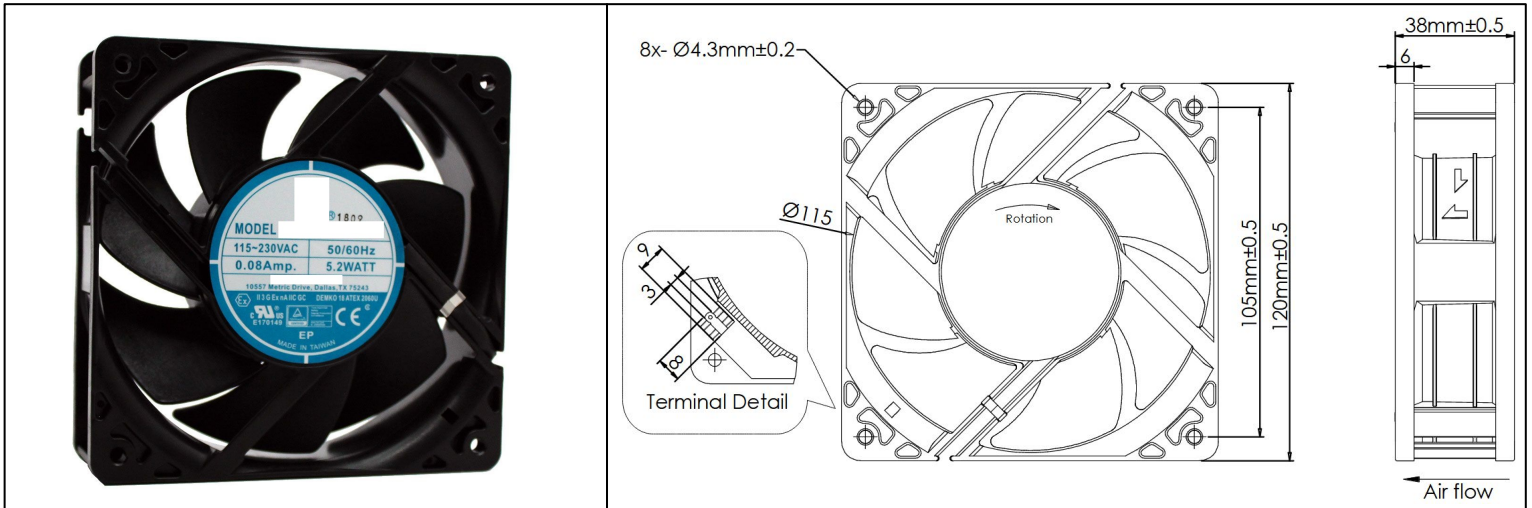

Frame	PBT, UL94 V-0 Plastic	<u>Operating Temperature</u> -20°C ~ +70°C	
Impeller	PBT, UL94 V-0 Plastic	<u>Storage Temperature</u> -30°C ~ +75°C	
Connection	Terminals	<u>Life Expectancy</u> 60,000 hours (L10 at 40°C)	
Motor	Brushless EC, Auto Cutoff, Auto Restart, Electronically Protected, Class A Insulation	Weight: 0.29Kgs (0.64 lbs)	
Bearing System	Dual Ball Bearings		
Dielectric Strength	1500VAC/min, <1mA		
Insulation Resistance	≥10M Ohm @ 500 VDC		

Model Number	
Rated Voltage	90- 265 VAC
Rated Power (Watts)	5.2 ± 15%
Rated Current (A)	0.06 ± 15%
Rated Speed (RPM)	3175 ± 15%
Airflow (CFM)	105 ± 15%
Noise Level (dB)	43
Max. Static Pressure	0.34\" H <sub>2</sub> O ± 15%