



Main

Range of product	Harmony XVP Universal
Product or component type	Base unit with cover
Mounting diameter	1.97 in (50 mm)
Component name	XVPC
Housing colour	Cream
Connections - terminals	Screw clamp terminals: $\leq 1 \times 1.5 \text{ mm}^2$ with or without cable end

Complementary

Fixing mode	Direct or tube fixing
Material	Acrylic butadiene styrene + polycarbonate on base unit Polyamide on cover unit
Assembly style	Customer assembly, up to 5 units
Marking	CE
[Ui] rated insulation voltage	250 V conforming to IEC 60947-1
[Uimp] rated impulse withstand voltage	4 kV conforming to IEC 60947-1
Terminals description ISO n°1	(COM-1)PW (COM-2)PW (COM-3)PW (COM-4)PW (COM-5)PW (GND)GROUND
Product weight	0.28 lb(US) (0.125 kg)

Environment


product certifications	CULus
standards	EN/IEC 60947-5-1
protective treatment	TC
ambient air temperature for storage	-40...158 °F (-40...70 °C)

Contractual warranty

Warranty period	18 months
-----------------	-----------


Base Unit for Indicator Banks

Panel Cut-out for Direct Fixing

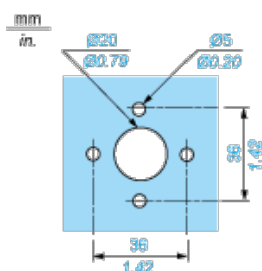

Indicator Bank

Wiring Diagram

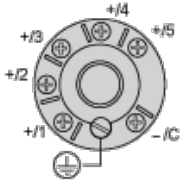

- +/1 Power supply for first unit
- +/2 Power supply for second unit
- +/3 Power supply for third unit
- +/4 Power supply for fourth unit
- +/5 Power supply for fifth unit
- /C Common for all units