



# Reinforced USB Memory Keys

Now available up to 64GB



We provide reinforced USB memory keys available in different capacities. When mated, the system is IP68. Shells are metallic with 1/4 turn bayonet coupling.

## Dimensions of rugged USBF Key:

### Environmental Protection


- Sealing: IP68 (when closed)
- Salt Spray: 48 h with Nickel plating (ROHS)  
> 96 h with Black coating (ROHS)  
> 500 h with Olive Drab Cadmium
- Vibrations: MIL-STD-810F method 514.5 fig 514.5.C cat 14
- Temperature Range: - 40°C / +85°C (MIL-STD-810F)

### Other features



- Type: USB2.0
- Voltage: 5V DC - 500 mA max
- Electromagnetic compatibility: 89/336/EEC and Part 15 Class B

### IMPORTANT NOTE


Compatible with any standard USB port

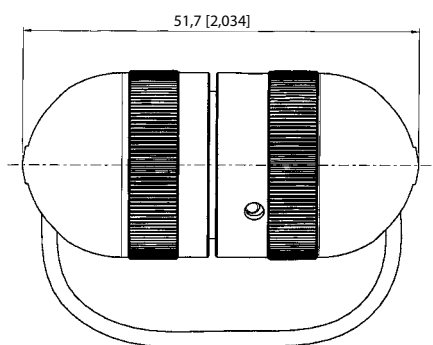


Up to memory size 4GB

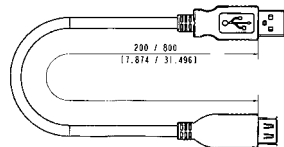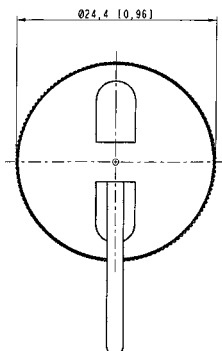

USB cordset is included with each memory key

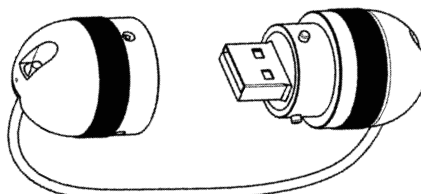

Rugged Metallic USB KEY with CAP SEALING: IP 67

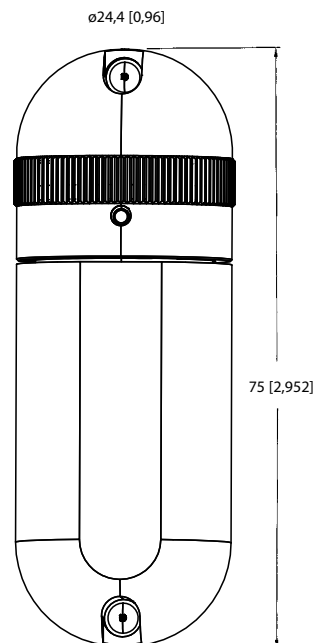

From 8 to 64 GB

## DEFINITION OF PART NUMBER

### USBF KEY

Beginning of every  
USB Key part number.  
Remains unchanged.

### 8192

#### Capacity of your USBF Key:

0512 | 1024 | 2048 | 4096 | 8192 | 16384 | 16384GT\* | 32768 | 64

Other capacity, please consult us at [contact@usbfield.com](mailto:contact@usbfield.com)

### N

#### Shell finish:

N: Natural

G: Green

B: Black

\* GT: Fast Data Transfert

EXAMPLE: **USBFKEY0512N**: USB MEMORY KEY - CAPACITY OF 512MB - SHELL FINISH: NATURAL

EXAMPLE: **USBFKEY1024G**: USB MEMORY KEY - CAPACITY OF 1024MB - SHELL FINISH: GREEN