


EAO – Your Expert Partner for Human Machine Interfaces

704.410.0 - Selector switch actuator 2 positions, short lever

704.410.0 - Selector switch actuator 2 positions, short lever

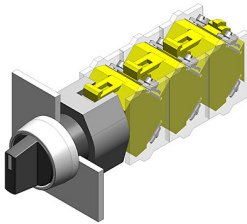

Attention: The preview is based on a sample product. This can differ from your current configuration.

Mounting

Mounting cut-out
Design Ø 22.5 mm
raised

Front

Front dimension
Front shape Ø 29 mm
round
Front ring material
Front ring colour Plastic
grey

Other Attributes

Weight 0.034 kg

Operating-/Indication part

Lever material
Lever colour
Switching angle Plastic
black
C = 90°

IP-Rating

Front protection IP 65

Actuator

Switching action Rest - Maintained

Switching element

Rotary positions 2


Function

Selector switch

EAO – Your Expert Partner for Human Machine Interfaces


704.410.0 - Selector switch actuator 2 positions, short lever

Dimensions

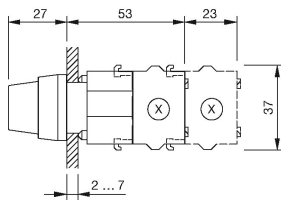

X = Screw terminal

Mounting cut-outs

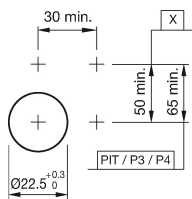


PIT = Push-in terminal

Wiring diagram



Switching positions

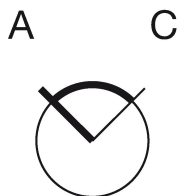

Additional information

Max. 3 switching elements can be clipped on

Legend

Switching action: A = Rest, C = Maintained