

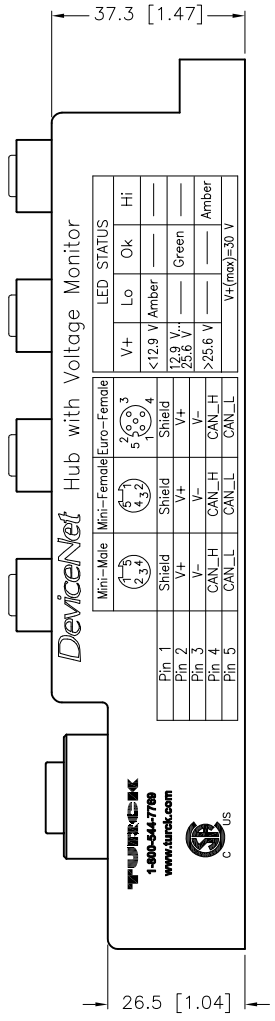
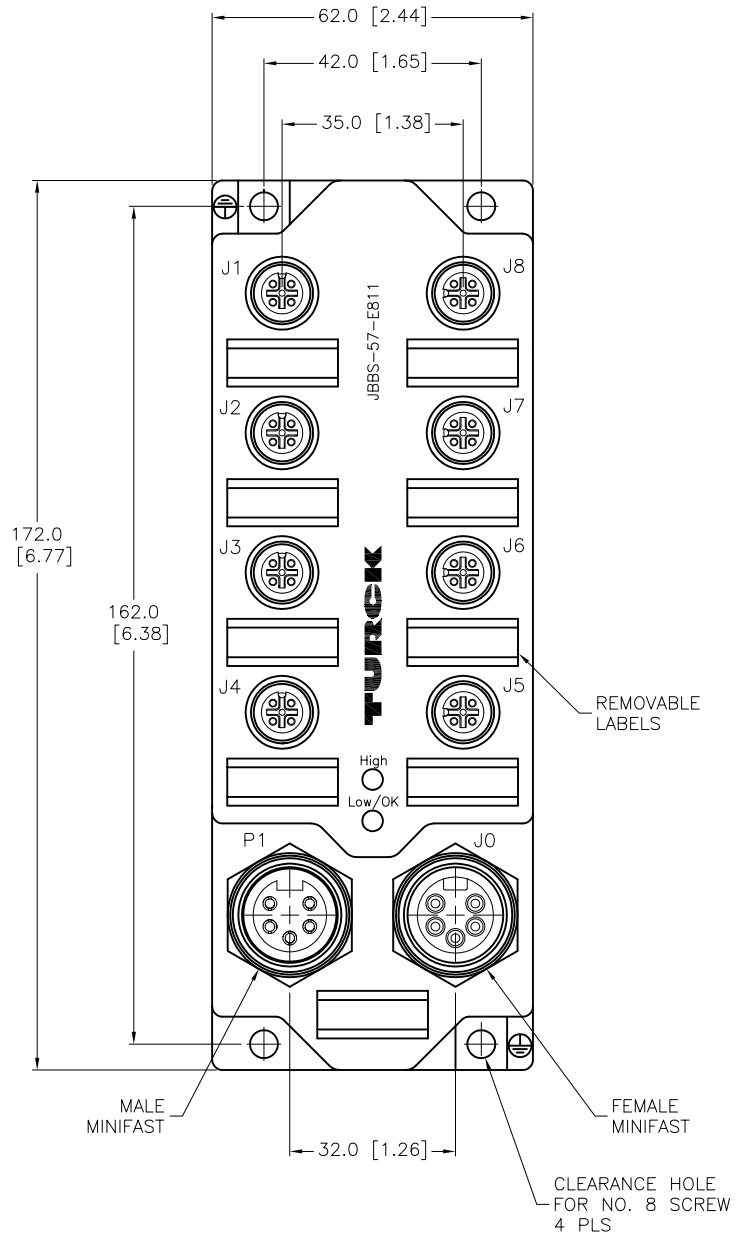


SPECIFICATIONS	
HOUSING MATERIAL	PA 6 (NYLON)
HOUSING FINISH/COLOR	BLUE GREY
RECEPTACLE HOUSING	NICKEL-PLATED BRASS
CONTACT CARRIERS/COLOR	TPU/BLUE-GRAY
CONTACTS	GOLD-PLATED BRASS
OPERATING VOLTAGE	300 V
OPERATING CURRENT	9.0 A (MINIFAST), 4.0 A (EUROFAST)
PROTECTION CLASS	NEMA 1,3,4,6P AND IP67 – ONLY WHEN ALL RECEPT. COVERED W/ PLUGS OR CONNECTED
OPERATING TEMPERATURE	-25°C to +70°C (-13°F to +158°F)
LED FUCTION	(2) POWER LEDs: 1 AMBER (LO)<12.9 V 1 GN (OK) 12.9V-25.6V, 2 AMBER (HI)>25.6V

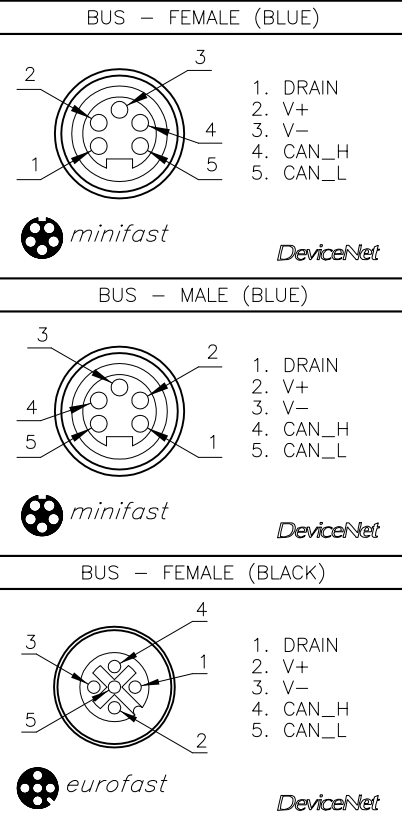

LED STATUS			
V+	Lo	Ok	Hi
<12.9 V	Amber	—	—
12.9 V - 25.6 V	—	Green	—
>25.6 V	—	—	Amber
V+(max)=30 V			

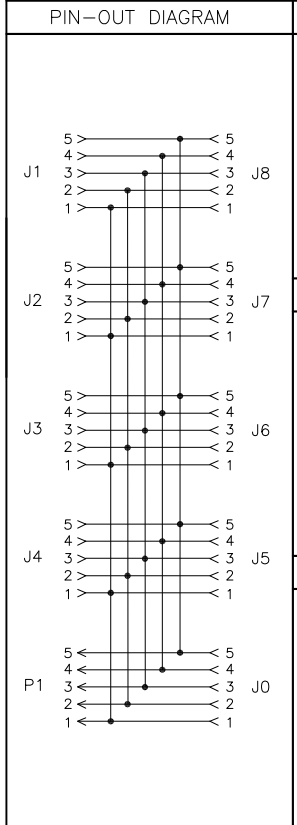

RELATED DOCUMENTS	3RD ANGLE PROJECTION	THIS DRAWING IS CONFIDENTIAL AND THE PROPERTY OF TURCK INC. USE OF THIS DOCUMENT WITHOUT WRITTEN PERMISSION IS PROHIBITED.	DRFT IK	DATE 5/17/99	DESCRIPTION
1. 2. 3. 4.			APVD GC	SCALE 1=1.5	JBBS-57-E811
MATERIAL	ALL DIMENSIONS DISPLAYED ON THIS DRAWING ARE FOR REFERENCE ONLY		UNIT OF MEASUREMENT		
FINISH	CONTACT TURCK FOR MORE INFORMATION		MILLIMETER [INCH]		IDENTIFICATION NO. U0205
			DO NOT SCALE THIS DRAWING		REV K

3000 CAMPUS DRIVE MINNEAPOLIS, MN 55441 1-800-544-7769 (763) 553-7300 (763) 553-0708 fax turck.com	
TURCK INC High Technology Sensors and Automation Controls	
TR 04/05/12	38534
BY	DATE
ECO NO.	
FILE: U0205	SHEET 1 OF 1

K	ADD CSA LOGO TO CLICHE PER ECO	TR	04/05/12	38534
REV	DESCRIPTION	BY	DATE	ECO NO.