
 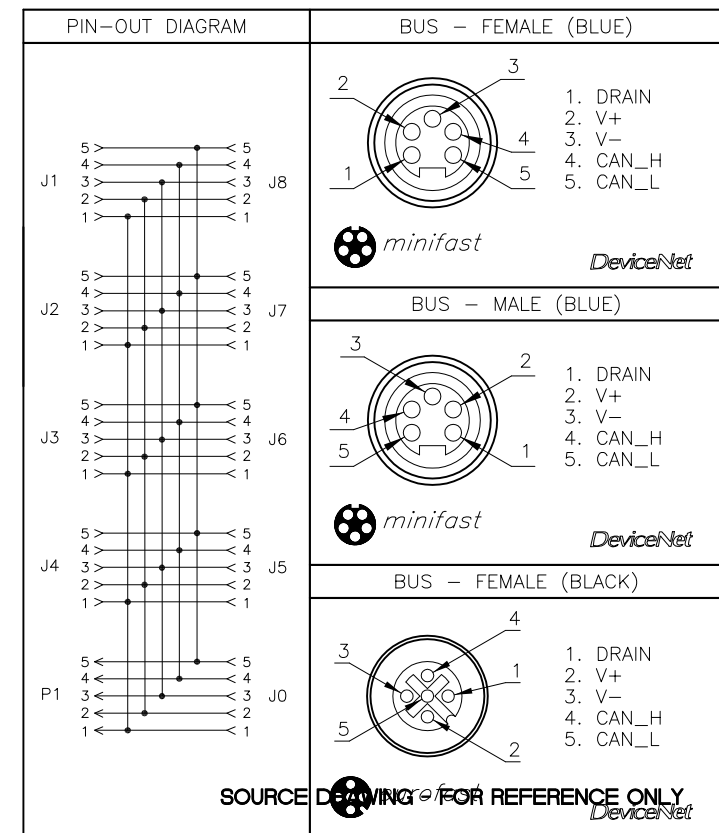


SPECIFICATIONS

HOUSING MATERIAL	NYLON GF 30
HOUSING FINISH/COLOR	BLUE GREY
RECEPTACLE HOUSING	NICKEL-PLATED BRASS
CONTACT CARRIERS/COLOR	TPU/BLUE-GRAY
CONTACTS	GOLD-PLATED BRASS
OPERATING VOLTAGE	300 V
OPERATING CURRENT	4.0 A PER CONDUCTOR
PROTECTION CLASS	IP 67 - ONLY WHEN ALL RECEPTACLES ARE COVERED WITH PLUGS OR CONNECTED
OPERATING TEMPERATURE	-30°C to +80°C (-22°F to +176°F)



RELATED DOCUMENTS 1. 2. 3. 4.	3RD ANGLE PROJECTION	THIS DRAWING IS CONFIDENTIAL AND THE PROPERTY OF TURCK INC. USE OF THIS DOCUMENT WITHOUT WRITTEN PERMISSION IS PROHIBITED.		<div>TURCK INC</div> <div>High Technology Sensors and Automation Controls</div> <div>3000 CAMPUS DRIVE MINNEAPOLIS, MN 55441 1-800-544-7769 (763) 553-7300 (763) 553-0708 fax turck.com</div>	
		DRFT	IK	DATE	01/04/98
	ALL DIMENSIONS DISPLAYED ON THIS DRAWING ARE FOR REFERENCE ONLY	APVD	GC	SCALE	1=1.5
		UNIT OF MEASUREMENT MILLIMETER [INCH]		DESCRIPTION JBBS-57-E812	
MATERIAL	CONTACT TURCK FOR MORE INFORMATION	IDENTIFICATION NO.			REV
FINISH		U0205-1			
		DO NOT SCALE THIS DRAWING			
		FILE: U0205-1			SHEET 1 OF 1

I	ADD CSA LOGO PER ECO	TR	04/05/12	38534
REV	DESCRIPTION	BY	DATE	ECO NO.