


RK 4.5T-x-WS 4.5T

Double-ended Cordset – Straight Female Connector to Right angle Male Connector

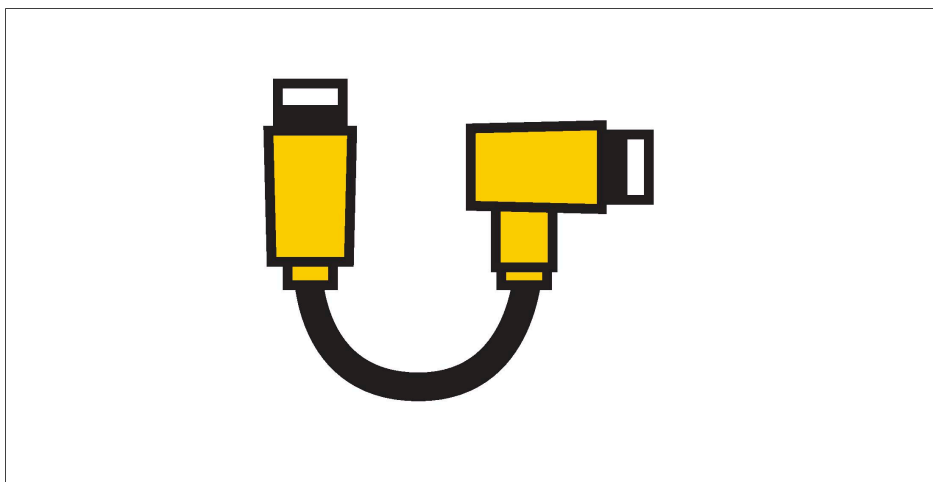

Features

- Straight Female M12 eurofast Connector
- Right angle Male M12 eurofast Connector

Technical data

Type	RK 4.5T-x-WS 4.5T
ID no.	777000631
Connector A	Female, M12, Straight
Number of Pins	5
Coupling nut	Brass, Nickel-plated
Connector B	Male, M12, Right Angle
Coupling nut	Brass, Nickel-plated
Cable data	
Cable jacket	PVC, Gray
Conductor size	5
Rated voltage	250 V
Current	4 A
Approvals	UL Listed CSA RoHS
Note	

RK 4.5T-x-WS 4.5T | 11/1/2021 12-34 | technical changes reserved