


## 54123-2 Product Details

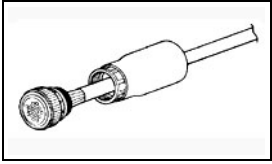

**54123-2**

TE Internal Number: 54123-2

 Active

 View 3D PDF

### CPC Accessories

 Always EU RoHS/ELV Compliant (Statement of Compliance)

### Product Highlights:

- Accessory Type = Cable Seal
- Shell Size = 13
- Cable Diameter Sealing Range = 6.35 - 9.53 mm
- RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process

Documentation & Additional Information	
<p><b>Product Drawings:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">STRAIN RELIEF ASSY, SHELL, SIZE 13, CPC (PDF, English)</a></li> </ul> <p><b>Catalog Pages/Data Sheets:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">AMP Circular Connectors for Commercial Signal &amp; Powe... (PDF, English)</a></li> </ul> <p><b>Product Specifications:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>Application Specifications:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>Instruction Sheets:</b></p> <ul style="list-style-type: none"> <li>• None Available</li> </ul> <p><b>CAD Files: (CAD Format &amp; Compression Information)</b></p> <ul style="list-style-type: none"> <li>• <a href="#">2D Drawing (DXF, Version U)</a></li> <li>• <a href="#">3D Model (IGES, Version U)</a></li> <li>• <a href="#">3D Model (STEP, Version U)</a></li> </ul>	<p><b>Additional Information:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">Product Line Information</a></li> </ul> <p><b>Related Products:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">Tooling</a></li> </ul>

Product Features (Please use the Product Drawing for all design activity)	
<p><b>Product Type Features:</b></p> <ul style="list-style-type: none"> <li>• Accessory Type = Cable Seal</li> <li>• Shell Size = 13</li> </ul> <p><b>Electrical Characteristics:</b></p> <ul style="list-style-type: none"> <li>• Recovered ID, Max. (mm [in]) = 4.95 [0.195]</li> </ul> <p><b>Dimensions:</b></p> <ul style="list-style-type: none"> <li>• Cable Diameter Sealing Range (mm [in]) = 6.35 - 9.53 [0.250 - 0.375]</li> <li>• Length (mm [in]) = 63.50 [2.500]</li> </ul> <p><b>Body Features:</b></p> <ul style="list-style-type: none"> <li>• Internal Sleeve Material = Nylon</li> <li>• Internal Sleeve Color = Black</li> <li>• Outer Tubing Material = Polyolefin</li> <li>• Outer Tubing Color = Black</li> </ul>	<p><b>Industry Standards:</b></p> <ul style="list-style-type: none"> <li>• <a href="#">RoHS/ELV Compliance</a> = RoHS compliant, ELV compliant</li> <li>• <a href="#">Lead Free Solder Processes</a> = Not relevant for lead free process</li> <li>• <a href="#">RoHS/ELV Compliance History</a> = Always was RoHS compliant</li> </ul> <p><b>Packaging Features:</b></p> <ul style="list-style-type: none"> <li>• Packaging Quantity = 50</li> </ul> <p><b>Other:</b></p> <ul style="list-style-type: none"> <li>• Brand = AMP</li> </ul>