
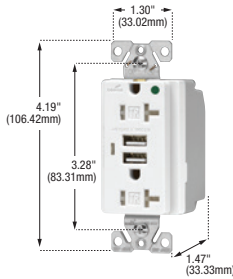


Hospital grade receptacles


Hospital grade straight blade receptacles

Product description


2-pole, 3-wire grounding
15A, 125V/AC; 20A, 125V/AC
NEMA 5-15R, 5-20R

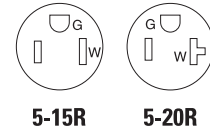


TR8345W

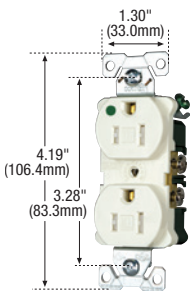

TR8200

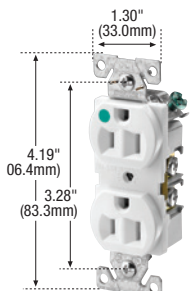

8200

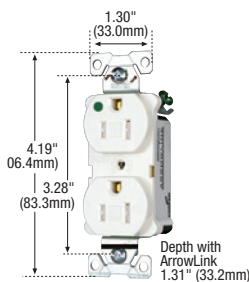

TR8200_M

Hospital grade combination USB charger



Rating		Description		Color suffix	Catalog no.
A	V/AC Amps	V/DC			
15	125 2.1	5	USB charger with hospital grade tamper resistant duplex receptacle	GY, LA, V, W, RD	□ TR8245__
20	125 2.1	5	USB charger with hospital grade tamper resistant duplex receptacle	GY, LA, V, W, RD	□ TR8345__

Tamper resistant hospital grade receptacles



Rating		Description		Color suffix	Catalog no.	
A	V/AC	NEMA				
15	125	5-15R	Duplex receptacle, back & side wire	GY, RD, V, W	□ TR8200__	▶ ● ● ●
20	125	5-20R	Duplex receptacle, back & side wire	B, GY, RD, V, W	□ TR8300__	▶ ● ● ●

Hospital grade receptacles



Rating		Description		Color suffix	Catalog no.	
A	V/AC	NEMA				
15	125	5-15R	Duplex receptacle, back & side wire	B, GY, RD, V, W	□ 8200__	▶ ● ● ● ●
20	125	5-20R	Duplex receptacle, back & side wire	B, GY, LA, RD, V, W	□ 8300__	▶ ● ● ● ●

Panel-mount special use hospital grade single receptacles



Rating		Description		Color suffix	Catalog no.	
A	V/AC	NEMA				
15	125	5-15R	Strap center to center spacing = 1.9375" (49.2mm), back & side wire	V	□ 8210MV	▶ ● ●
20	125	5-20R	Strap center to center spacing = 1.9375" (49.2mm), back & side wire	RD, V	□ 8310M__	▶ ● ●

Accessories for hospital grade NEMA 5-15 & 5-20 receptacles

Description	Color suffix	Catalog no.	
2-Gang, standard size duplex receptacle pre-marked wallplate "emergency"	Stainless Steel	□ EM93102	▶ ● ●
1-Gang, standard-size duplex receptacle wallplate, CuVerro®	CU, CUR	□ 93101__	▶ ● ●
1-Gang, mid-size duplex receptacle wallplate, "GFCI protected"	V, W	□ PJ8GF__	▶ ●
2-Gang, standard size decorator wallplate, CuVerro®	CU, CUR	□ 93402__	▶ ● ●
2-Gang, mid-size duplex receptacle pre-marked wallplate, "emergency"	RD	□ PJ82EMRD	▶ ●



Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: B (Brown), GY (Gray), LA (Light Almond), RD (Red), V (Ivory), W (White), CU (White Bronze) CuVerro® ONLY, CUR (Rose) CuVerro® ONLY



Specification information: Tamper resistant HG receptacles: A-28, Panel mount HG receptacles: A-28, HG receptacles: A-29, ArrowLink HG receptacles: A-29, CuVerro® wallplates: K-22

Compliances, specifications and availability are subject to change without notice.

- ▶ ArrowLink option available. Add "M" suffix to standard catalog number (example AH8300W, AH8300WM). For ordering information on ArrowLink & ArrowLink SPD connectors, see Page A-5
- ▶ Build-to-spec customizable devices - Page A-6
- ▶ Indicates NAFTA compliant - Page Q-30
- ▶ RoHS compliant - Page Q-30
- ▶ Tamper resistant