
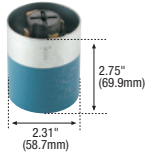



Power lock industrial grade locking devices

Product description

4-pole, 5-wire grounding
20A, 250V/DC; 30A, 600V/AC
Non-NEMA

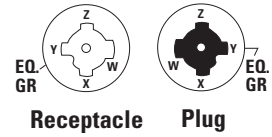

25415

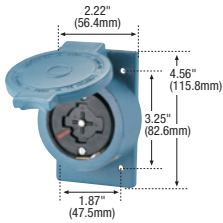

25250

Industrial grade plugs & connectors

A	Rating V/DC	V/AC	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.	
20/	250	600	Auto grip nylon	0.40-1.06" (10.2-27.0mm)	BL	□ 25415N	□ 25414N	•
30			Armored	0.62-1.00" (15.9-25.4mm)	BL	□ 25415	□ 25414	•

Industrial grade receptacles

A	Rating V/AC	V/AC	Description	Color	Single receptacle
20/	250	600	In cast iron cover and steel shell	BK	□ 25403
30			In cast aluminum cover w/ weather protective lift lid	BK	□ 25250

Dimensional information:
C-82, C-83

Plug & connector specification information:

Power lock: C-94

Receptacle specification information:

Power lock: C-95

Inlet specification information:

Power lock: C-94

Color information:

BK (Black), BL (Blue)



(Black)

(Blue)

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-30