
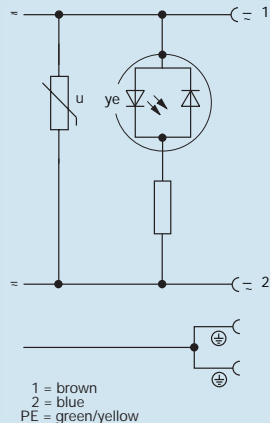

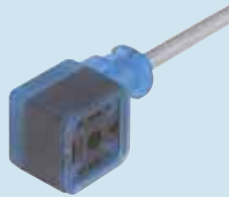

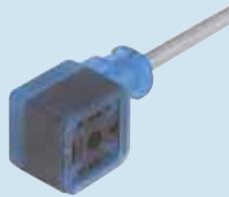


RECTANGULAR CONNECTORS GDM-SERIES

OpenConnector GDM > GAN

Type	GAN-DLFE7X-AG0200C1-XC607-AD
Order No.	934 562-029
	 <p>Cable socket with integrally molded lead (2 m), function indicator (LED), protective circuit (varistor), gasket (captive) and central screw M3 (stainless steel, Phillips cross-head)</p>
Product description Other standard types Number of contacts Cable material Cable color Cable length Cable diameter Conductor size Cable specification Cable type Standard Housing Color Construction type	cable length 5 m: order no. 934 562-030 2 + PE / connected) PVC grey 2 m 5.5 mm 0.75 mm LIYY 3G x 0.75 mm ² fire resist. IEC 60332-1, DIN VDE 0472 Part 804 type B DIN EN 175 301-803-A transparent blue A
Description of Wiring LED color Voltage rectifier Suppressor Other characteristics	LED yellow (bipolar) - varistor for pressure switch
Drawing	 <p>1 = brown 2 = blue PE = green/yellow</p>
Technical data Contact dimensions Wire stranding Rated voltage Rated current Contact resistance Mounting	6.3 mm x 0.8 mm, 4.8 mm x 0.8 mm 24 x 0.2 AC/DC 250 V 10 A ≤ 10 mOhm central nut M3
Material Contact surface material Contact bearer material Housing material	Cu/Sn PA 66 PUR
Environmental conditions Protection class (IEC 60529) Pollution severity Temperature range	IP 65, IP 67 3 -25 °C to +80 °C, notice derating
Inflammability class Housing Cable Contact bearer	94 HB fire resist. IEC 60332-1 94 V0
Approvals UL VDE	- VDE
Packing unit Packaging unit	50 pieces

Type	GAN-DLFE7X-AG0500C1-XC607-AC	GAN-DLFE7X-DN0500C1-XC607-AC
Order No.	934 562-030	934 562-066
	 <p>Cable socket with integrally molded lead (5 m), function indicator (LED), protective circuit (varistor), gasket (captive) and central screw M3 (stainless steel, Phillips cross-head)</p>	 <p>Cable socket with integrally molded lead (5 m), function indicator (LED), protective circuit (varistor), gasket (captive) and central screw M3 (stainless steel, Phillips cross-head)</p>
Product description		
Other standard types	cable length 2 m: order no. 934 562-029	cable length 2 m: order no. 934 562-065
Cable material	PVC	PVC
Cable length	5 m	5 m
Cable diameter	5.5 mm	5.8 mm
Cable specification	LiYY 3G x 0.75 mm ²	LiYY 3G x 0.75 mm ²
Technical data		
Wire stranding	24 x 0.2	42 x 0.15
Approvals		
UL	-	UL pending
Packing unit		
Packaging unit	25 pieces	25 pieces

Type	GAN-DLFE7X-FS0200C1-XC607-AD	GAN-DLFE7X-FS0500C1-XC607-AC
Order No.	934 562-055	934 562-056
	 <p>Cable socket with integrally molded lead (2 m), function indicator (LED), protective circuit (varistor), gasket (captive) and central screw M3 (stainless steel, Phillips cross-head)</p>	 <p>Cable socket with integrally molded lead (5 m), function indicator (LED), protective circuit (varistor), gasket (captive) and central screw M3 (stainless steel, Phillips cross-head)</p>
Product description		
Other standard types	cable length 5 m: order no. 934 562-056	cable length 2 m: order no. 934 562-055
Cable material	PUR	PUR
Cable length	2 m	5 m
Cable diameter	5.8 mm	5.8 mm
Cable specification	Li9Y11Y-HF 3G x 0.75 mm ²	Li9Y11Y-HF 3G x 0.75 mm ²
Technical data		
Wire stranding	42 x 0.15	42 x 0.15
Approvals		
UL	UL pending	UL pending
Packing unit		
Packaging unit	50 pieces	25 pieces