


Clamp-type test probes

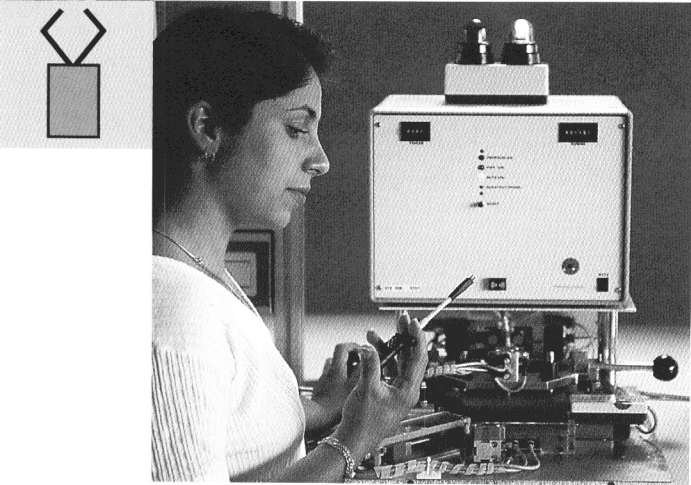

Product description

Clamp-type test probes provide the simple, rapid measurement of voltages.


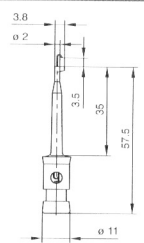
 
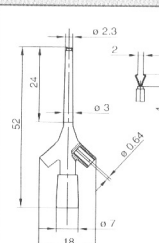

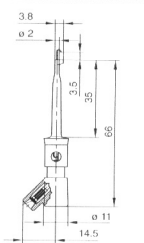

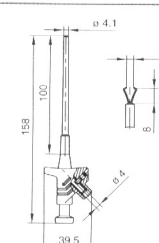

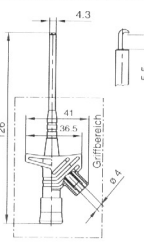
 
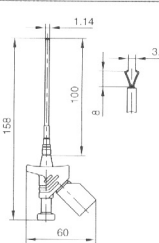

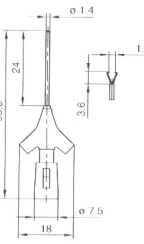
 
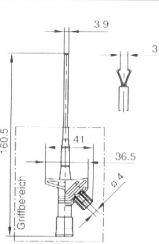
A variety of types and sizes permit the measuring point to be accessed and gripped without difficulty.

The ergonomic design has been optimised to facilitate handling to the utmost extent.

The KLEPS 2700 permits a lead to be tested without the insulation being stripped.

The KLEPS 2800 is provided with claw-type clamps with which large


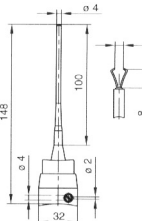
 
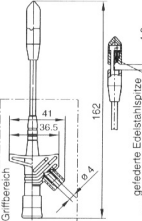
 
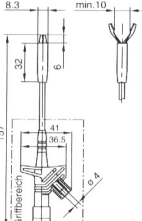
test specimens can be gripped. It is also suitable for testing currents. The classic KLEPS 30, used in millions of applications worldwide, serves as a versatile voltage tap.

*System Article type	Technical Data	Order no. Colour	*System Article type	Technical Data	Order no. Colour
 KLEPS 2		Clamping range max. \varnothing 2 mm, contact hook, solder contact 931 467-100 ● 931 467-101 ●	 KLEPS 3 ST		Very thin wires and densely packed contact points, clamping range \varnothing 3.5 mm 973 592-100 ● 973 592-101 ●
 KLEPS 2-BU		Clamping range max. \varnothing 2 mm, contact hook 973 501-100 ● 973 501-101 ●	 KLEPS 30		Clamping range \varnothing 4 mm 930 113-100 ● 930 113-101 ●
 KLEPS 2900		20 A clamping range 5.5 mm 972 309-100 ● 972 309-101 ●	 KLEPS 250		300 V = clamping range \varnothing 4 mm 973 528-100 ● 973 528-101 ●
 MICRO-KLEPS		Very thin wires and densely packed contact points, clamping range \varnothing 2 mm 973 972-100 ● 973 972-101 ●	 KLEPS 2600		Clamping range \varnothing 4 mm 972 306-100 ● 972 306-101 ●

* System: (64) = 0.64 mm system / (2) $\hat{=}$ 2 mm system / (4) $\hat{=}$ 4 mm system / ● $\hat{=}$ 4 mm safety system / \leftrightarrow $\hat{=}$ 4 mm sliding sleeve system

Clamp-type test probes



*System Article type	Technical Data	Order no. Colour	Notes
(4)  KLEPS 60		Clamping range ø 4 mm 973 053-100 ● 973 053-101 ●	
(2)  KLEPS 2700		0.25 mm ² up to 1.5 mm ² (ø 3.5 mm) contact without the need to strip them „Piercing Clip“	972 307-100 ● 972 307-101 ●
(2)  KLEPS 2800		20 A clamping range ø 10 mm, grip claws	972 308-100 ● 972 308-101 ●

* System: (64) = 0.64 mm system / (2) ≙ 2 mm system / (4) ≙ 4 mm system / (●) ≙ 4 mm safety system / (↔) ≙ 4 mm sliding sleeve system