

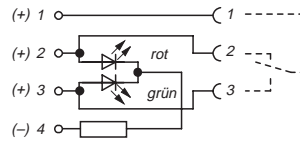
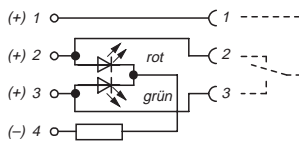

GDML 3011 LED 24 RG
GDML 3011 LED 230 RG

transparent transp. transp.
932 857-002

transparent transp. transp.
933 748-212
933 748-712

50 Stück each pièces

50 Stück each pièces



3 + ⊕

DIN EN 175 301-803-A

Funktionsanzeige (2 LED's) für Druckschalter

function indicator (2 LEDs) for pressure switch
affichage des fonctions (2 DEL) pour manoccontacteur

3 + ⊕

DIN EN 175 301-803-A

Funktionsanzeige (2 LED's) für Druckschalter

function indicator (2 LEDs) for pressure switch
affichage des fonctions (2 DEL) pour manoccontacteur

Seite Page Page 8

DC 24 V (=)

3
8 A

LED grün LED green DEL vert (3)
LED rot LED red DEL rouge (2)

Druckschalter

pressure switch
manoccontacteur
-40 °C ... +90 °C

Pg 11

ø 4,5 ... 11 mm / max. 1 mm²

Schrauben screw visser

Seite Page Page 8

UC 250 V (≈)

3
8 A

LED grün LED green DEL vert (3)
LED rot LED red DEL rouge (2)

Druckschalter

pressure switch
manoccontacteur
-40 °C ... +90 °C

Pg 11

ø 4,5 ... 11 mm / max. 1,5 mm²

Schrauben screw visser

GDM 3-7 730 801-002
GDM 3-21 731 739-002
GDM 3-16 731 531-002
GDM 3011-8 732 574-001
GDM 3011 RF-1 734 363-001

GDM 3-7 730 801-002
GDM 3-21 731 739-002
GDM 3-16 731 531-002
GDM 3011-8 732 574-001
GDM 3011 RF-1 734 363-001