



Datasheet

Stock No: 267-3953

ENGLISH

RS Pro SNYDL Series Insulated Crimp Spade Connector, 12 → 10 AWG, M4.5 (#8), Yellow Nylon



Product Details:

Spade

Red 0.5 - 1.5 mm²

Blue 1 - 2.6 mm²


Yellow 4.0 - 6.5 mm²

Approvals


UL Listed; UL Listed for Canada

Specifications:

Wire Size:	12 → 10 AWG
Stud Size:	M4.5 (#8)
Width:	9mm
Insulation:	Insulated
Colour:	Yellow
Insulation Material:	Nylon
Overall Length:	25.5mm
Series:	SNYD
Contact Material:	Copper
Thickness:	1mm

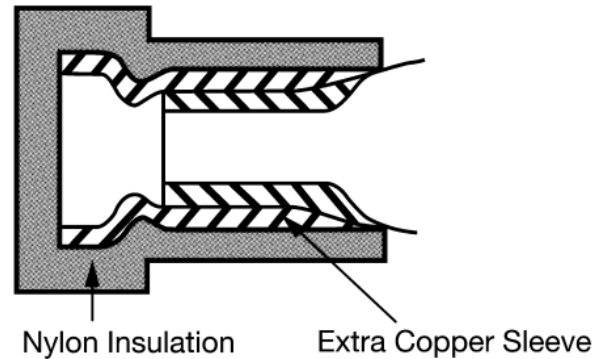

Temperature rating:	-55°C to 105°C
Terminal Material:	
Receptacles	High grade brass
Other terminals	High grade copper
Voltage rating	
Brass	300V
Copper	600V
Additional Sleeve Material:	High grade copper

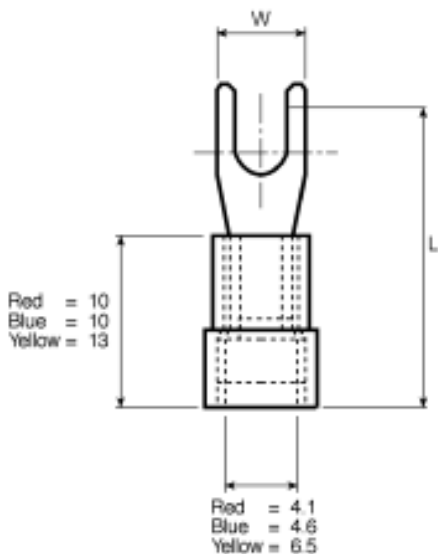

Type	Stud Size	Red		Blue		Yellow	
		W	L	W	L	W	L
M8	8.4					14.0	30.2
M6	6.5	12.0	27.0	12.0	27.0	12.0	31.5
M5	5.3	9.5	20.9	9.3	20.9	9.0	25.2
M4.5	4.3	8.1	21.2	7.9	20.9	9.0	25.2
M4	4.3	7.2	21.2	7.2	21.2	8.3	25.2
M3.5	3.7	6.4	21.1	6.0	21.2	8.3	24.2
M3	3.2	5.7	21.1	5.6	21.0		