



RhinoPro 5000 Handheld Printer

Versatile high-performance identification and labelling

The Rhino Pro 5000 is perfect for the professional user who needs an affordable label printer for on-site applications that's tough and easy to use. Contractors, panel builders and facility managers will save time and money by using the special hot keys that provide labels at the touch of a button including wire cable wraps, module marking, fixed length, serialization, vertical printing, barcodes, symbols and much more.

Its clear, smudge-free, high-performance labels stick permanently to a variety of surfaces and provides remarkable MIL-spec print permanence on Heat Shrink Tubing. Print media is offered in easy-to-load cassettes and includes and optimized ribbon and choice of material including, Heat Shrink & Nylon Cloth, Vinyl, Polyester and Polypropylene labels.

RhinoPro Handheld Printer

KEY FEATURES & BENEFITS

- Affordable
- Easy to Use
- Special Hot Key functionality
- Extra large 30-character backlit display
- Oversized keys
- Bright yellow in colour ensuring it will not get lost
- Rubber bumper for extra protection
- Also available in kit form
- Easy to install cassettes

TECHNICAL SPECIFICATIONS

Printing Method

- Thermal Transfer Printhead (180dpi)

Physical Characteristics : Dimensions

- Length 70mm
- Width 114mm
- Height 212mm
- Weight 519grams

Keyboard

- ABC-layout
- To access international characters, Rapid accepted Character Entry, according to the mobile phone principle.

LCD Display

- 2 lines
- Rechargeable battery pack life indicator
- Display backlighting

Extra Protective Bumper

Cutter

Operating Characteristics


- Operating conditions : T° : 4°C-40°C
- Humidity : 10%-90% RH
- Storage conditions : T° : 0°C-90°C
- Humidity : 10%-90% RH
- CE approved



WIRE & CABLE HEATSHRINK



HOTKEYS

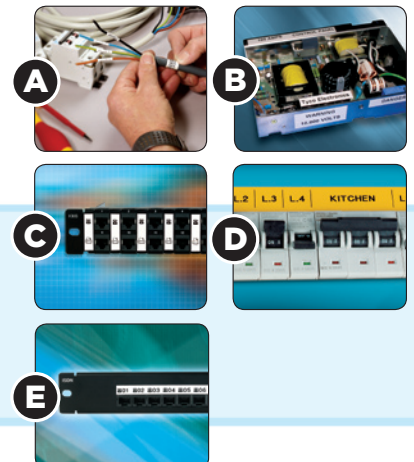

- A : Wrapping
- B : Fixed Length
- C : Vertical Printing
- D : Module Marking
- E : Patch Panel

RhinoPro Handheld Printer

HANDHELD PART DESCRIPTIONS

PRINTER AND ACCESSORIES



Description	MOQ & Std Pack	
PRO-5000-PRINTER-KIT-UK ¹	Printer Kit - UK adaptor included	1 PC
PRO-5000-PRINTER-KIT-EU ¹	Printer Kit - European adaptor included	1 PC
PRO-5000-PRINTER	Printer only (European)	1 PC
PRO-5000-EU-A/C-ADAPTOR ²	EU Power adaptor	1 PC
PRO-5000-UK/ASIA-A/C-ADAPTOR ²	UK & Asia A/C Power adaptor	1 PC
PRO-5000-BATTERY PACK ³	Rechargeable battery pack	1 PC

Printer Kit Contents : Printer, rubber protection bumper, user guide, 6AA batteries, power adaptor, hard carry case and two tape cassettes (19mm white flexible nylon tape & 19mm white permanent polyester tape.)



CASSETTES⁴

Description	Material	MOQ & Std Pack	Cable Diameter range	Length	Shrink Ratio	colour
PRO-5000-TMS-3.9-4	Heat shrink tubing	1 PC	1.18mm - 2.33mm	1.5m	3:1	Yellow
PRO-5000-TMS-3.9-9	Heat shrink tubing	1 PC	1.18mm - 2.33mm	1.5m	3:1	White
PRO-5000-TMS-5.2-4	Heat shrink tubing	1 PC	1.73mm - 3.73mm	1.5m	3:1	Yellow
PRO-5000-TMS-5.2-9	Heat shrink tubing	1 PC	1.73mm - 3.73mm	1.5m	3:1	White
PRO-5000-TMS-7.9-4	Heat shrink tubing	1 PC	2.97mm - 5.13mm	1.5m	3:1	Yellow
PRO-5000-TMS-7.9-9	Heat shrink tubing	1 PC	2.97mm - 5.13mm	1.5m	3:1	White
PRO-5000-TMS-13.2-4	Heat shrink tubing	1 PC	4.64mm - 8.70mm	1.5m	3:1	Yellow
PRO-5000-TMS-13.2-9	Heat shrink tubing	1 PC	4.64mm - 8.70mm	1.5m	3:1	White



Description	Material	MOQ & Std Pack	Width	Length	colour
PRO-5000-NC-12-4	Nylon cloth	1 PC	12mm	3.5m	Yellow
PRO-5000-NC-12-9	Nylon cloth	1 PC	12mm	3.5m	White
PRO-5000-NC-19-9	Nylon cloth	1 PC	19mm	3.5m	White
PRO-5000-PPNA-6-9	Non adhesive tag	1 PC	6mm	5.5m	White
PRO-5000-PPNA-9-9	Non adhesive tag	1 PC	9mm	5.5m	White
PRO-5000-V-12-4	Coloured vinyl	1 PC	12mm	5.5m	Yellow
PRO-5000-V-12-9	Coloured vinyl	1 PC	12mm	5.5m	White
PRO-5000-V-19-2	Coloured vinyl	1 PC	19mm	5.5m	Red
PRO-5000-V-19-4	Coloured vinyl	1 PC	19mm	5.5m	Yellow
PRO-5000-V-19-5	Coloured vinyl	1 PC	19mm	5.5m	Green
PRO-5000-V-19-9	Coloured vinyl	1 PC	19mm	5.5m	White
PRO-5000-WP-12-9	Polyester	1 PC	12mm	5.5m	White
PRO-5000-WP-19-9	Polyester	1 PC	19mm	5.5m	White
PRO-5000-MP-12-8A	Polyester	1 PC	12mm	5.5m	Metallized
PRO-5000-MP-19-8A	Polyester	1 PC	19mm	5.5m	Metallized
PRO-5000-CP-12-X	Polyester	1 PC	12mm	5.5m	Clear
PRO-5000-CP-19-X	Polyester	1 PC	19mm	5.5m	Clear



Tyco Electronics Corporation
Technical Support Center

USA: +1 (800) 522-6752
Canada: +1 (905) 470-4425
Mexico & Central America: + 52(0) 55-1106-0814
South America: +55 (0) 11-2103-6000
Germany: +49 (0) 6251-133-1999
UK: + 44 (0) 8706-080208
France: +33 (0) 1-3420-8686
Netherlands: +31 (0) 73-6246-999
China: +86 (0) 400-820-6015

www.tycoelectronics.com
uksales@tycoelectronics.com

©2009 Tyco Electronics Corporation
5-1773441-1 2/2009

TE logo and Tyco Electronics are trademarks.

Rhino and Dymo are trademarks of their respective owners.

While Tyco Electronics and its affiliates referenced herein have made every reasonable effort to ensure the accuracy of the information contained in this catalog, Tyco Electronics cannot assure that this information is error free. For this reason, Tyco Electronics does not make any representation or offer any guarantee that such information is accurate, correct, reliable or current. Tyco Electronics reserves the right to make any adjustments to the information at any time. Tyco Electronics expressly disclaims any implied warranty regarding the information contained herein, including, but not limited to, the implied warranties of merchantability or fitness for a particular purpose. Tyco Electronics' only obligations are those stated in Tyco Electronics' Standard Terms and Conditions of Sale. Tyco Electronics will in no case be liable for any incidental, indirect or consequential damages arising from or in connection with, including, but not limited to, the sale, resale, use or misuse of its products. Users should rely on their own judgment to evaluate the suitability of a product for a certain purpose and test each product for its intended application.

 **Tyco Electronics**
Our commitment. Your advantage.