



4 U, 8 slot, with rear I/O, for 19" PSU

Part no.: 24579-106

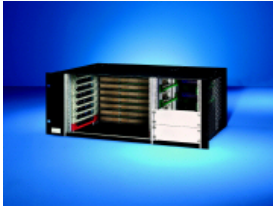

Features:

- System for horizontal boards
 - Front: 6 U, 160 mm deep
 - Rear I/O: 6 U, 80 mm deep
- Backplane (signal and power backplane in one unit)
 - 8 slot, 6 U, 64 bit
 - System slot on the left
 - Power connector (2 x P 47)
- Prepared for the assembly of two 19" CompactPCI power supplies (3 U, 8 HP)
- Heat dissipation by hot-swap fan unit (from left towards right)

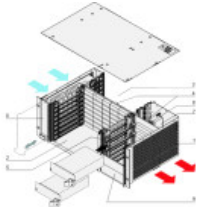

Technical information:

Description	Colour, finish	Height	Width	Depth
4 U, 8 slot, with rear I/O, for 19" PSU	black powder-coated, RAL 9005	4 U	84 HP	275 mm

Delivery comprises: completely assembled, wired and tested

Item	Qty	Description
1	1	Shielded 19" chassis, St, powder-coated, black, RAL 9005
2	8	Front slot; IEEE guide rails, incl. ESD clip (ESD clip mounted front right), for horizontal board mounting (6 U, 160 mm deep)
3	8	Rear slot; IEEE guide rails, incl. ESD clips (ESD clips fitted front right), for horizontal mounting of rear I/O boards (6 U, 80 mm deep)
4	1	Backplane for 6 U boards and voltage supply (2 x P 47 socket), 8 slot, 64 bit; System slot left, conforms to PICMG 2.0 rev. 3.0
5	1, 2	Space for 19" CompactPCI PSU (3 U, 8 HP)
6	1	Hot-swap fan unit, 4 fans
7	1	AC input (IEC plug), mains filter module, fuse, mains switch
8	1	Cable harness to connect all system components
9	1	3 U, 8 HP front panel, front mounted

Note:

- System in accordance with IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11); Backplane, conforms to PICMG 2.0 rev. 3
- Please order power supply separately
- Please order equipment cable separately
- -48 VDC version on request
- Please order system accessories separately