



PRODUCTS » CONNECTORS »

RG6Q F-Type Nickel SealSmart Coaxial Compression Connectors



RG6Q F-Type Nickel SealSmart Coaxial Compression Connectors

Product Number: 18001

Platinum Tools' SealSmart Compression Connectors provide simple, fast and reliable terminations. The perfect solution for CATV, DSS, Security, Home Theater and Residential Structured wiring installations.

- Molded in gasket provides a weather tight seal at cable entry.
- Single crimp termination with captive center contact design.
- Universal crimp tool terminates all three SealSmart Connector designs.



RG6Q F-Type Nickel SealSmart Coaxial Compression Connectors



RG6Q F-Type Nickel SealSmart Coaxial Compression Connectors

Use on RG59, RG6 and RG6 Quad shield cables. Connectors are color coded for cable type.

- Cable Retention: > 40 lbs
- Insertion Force: < 20 lbs
- Moisture Migration: PASSES SCTE IPS TP 013
- Return Loss: > 30 dB to 1 GHz
- Shielding: > 80 dB to 1 GHz
- Salt Spray: PASS
Tightening Torque: PASS
- Port Interface: Meets SCTE IPS SP 401




RG6Q F-Type Nickel SealSmart Coaxial Compression Connectors



RG6Q F-Type Nickel SealSmart Coaxial Compression Connectors

Part #	UPC	Description
18001		RG 6 Quad - Bulk Package
18002		RG 6 Quad - 10 pc. Clamshell
28001J		RG 6 Quad - Jar of 75
18006		RG 6 - Bulk Package
18007		RG 6 - 10 pc. Clamshell
28006J		RG 6 - Jar of 75
18011		RG 59 - Bulk Package
18012		RG 59 - 10 pc. Clamshell
28011J		RG 59 - Jar of 75
18101		SealSmart F Connector Gasket
18102		Waterproof 'O' Rings

SealSmart II Compression Tool

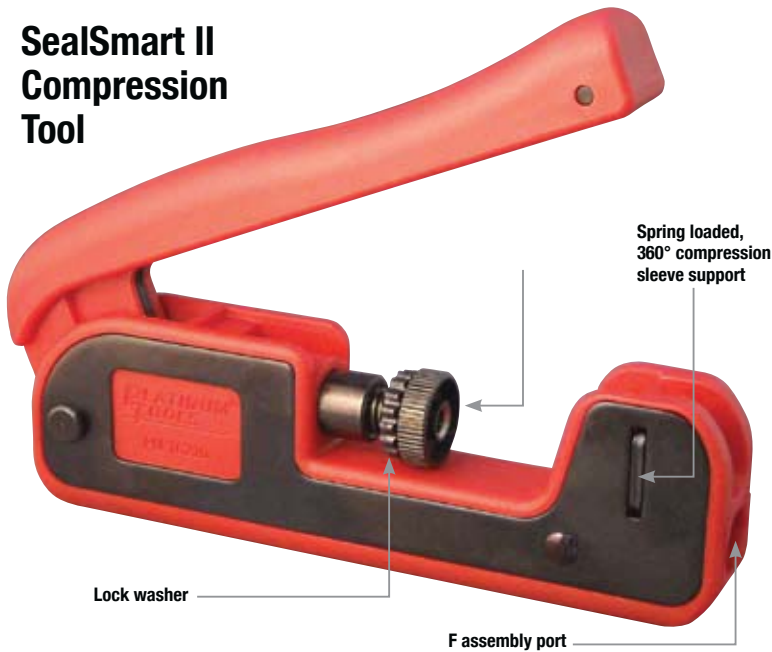

ProStrip 25R

The ProStrip 25R is a rugged 2 level coaxial cable stripper featuring quick change blade cartridges pre-set for industry standard 1/4" cable preparation. Two stripping ports and stainless steel rollers provide smooth non-binding rotation on a wide range of cables. No adjustments required!

- Strip RG 6 and RG 59 in the large port
- Strip RGB/Mini 59 (23, 24 & 25 AWG) in the small port



15028	ProStrip 25R Cable Stripper
15029	Replacement blade cartridge for ProStrip 25R

SealSmart Coaxial Compression Connectors

Cable Type →	F Connectors			BNC Connectors			RCA Connectors		
	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59
Plating/Packaging									
Nickel/Bulk Package	18001	18006	18011	18035	18038	18041	18065	18051	18060
Nickel Plate/Jar of 75	28001J	28006J	28011J						
Nickel Plate/Jar of 50								28051J	28060J
Nickel Plate/Jar of 40					28038J	28041J			
Nickel/6 pc. Clamshell				18036	18039	18042	18066	18051C	18061
Nickel/10 pc. Clamshell	18002	18007	18012						
Gold/Bulk Package	18004	18009	18015	18020	18025	18030	18057	18052	18055
Gold/6 pc. Clamshell				18021	18026	18031	18058	18053	18056
Gold/10 pc. Clamshell	18005	18010	18016						

Right Angle Connectors

Cable Type →	F Connectors			BNC Connectors			RCA Connectors		
	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59
Plating/Packaging									
Nickel/Bulk Package	18001RA	18006RA	18011RA	18035RA	18038RA	18041RA	18065RA	18051RA	18060RA
Nickel/3 pc. Clamshell	18003	18008	18013	18037	18040	18043	18067	18054	18062

RGB Mini Coax-Connectors

Center Conductor Size	F Connectors			BNC Connectors			RCA Connectors		
	23 AWG	24 AWG	25 AWG	23 AWG	24 AWG	25 AWG	23 AWG	24 AWG	25 AWG
Plating/Packaging									
Nickel/Bulk Package	18210	18200	18220	18240	18230	18250	18270	18260	18280
Gold/Bulk Package	18215	18205	18225	18245	18235	18255	18275	18265	18285

SealSmart Color Bands

SealSmart color bands provide a simple cable management solution when installing video and audio cable compression connectors. Slide the color band onto your cable prior to stripping. After termination, slide the band over the rear of the connector for easy cable to port identification. Will not stretch or slip.



# 18105Y-C	SealSmart Color Bands, Yellow 20 pc.
#18105R-C	SealSmart Color Bands, Red 20 pc.
#18105B-C	SealSmart Color Bands, Blue 20 pc.
#18105GR-C	SealSmart Color Bands, Green 20 pc.
#18105W-C	SealSmart Color Bands, White 20 pc.
#18105BK-C	SealSmart Color Bands, Black 20 pc.