

SealSmart PROCON Compression Tool

PLATINUM TOOLS®

SealSmart™ PROCON Compression Tool

Patented rotating head allows for quick change between RG11 & RG6.

Terminate standard F, BNC, RCA & Right Angle compression connectors.

- Versatile
- Fast
- Reliable

The newest addition to the SealSmart product line is designed for professional contractors installing CATV & CCTV networks. Provides quick, reliable results every time! Engineered for long life, this rugged tool features a patented rotating connector positioner-head and multi-head adapter – switch coax cable sizes and connector types on the fly.

- Head rotates to switch from RG6Q/6 to RG11/7
- Connector positioner rotates to change between F, BNC or RCA
- Adjustable crimp stroke
- Accommodates all standard compression F, BNC, RCA & right angle connectors
- Convenient, easy to use, all-in-one compression tool
- Guide rule on side of tool
- High carbon tool steel frame – built to last
- Comfortable, molded handle

Application

- CATV
- CCTV
- Satellite
- Security
- Home Theater
- Residential and commercial structured wiring

Technical Data

- Dimensions: 7" X 2 1/2" X 1"
- Weight: 15.2 oz.

Compression Connector Types	Coax Cable Types
F	RG7
BNC	RG11
RCA	RG6 Quad
Right Angle	RG6
	RG59



NEW!

Ordering Information


Description	P/N	UPC CODE
SealSmart PROCON Compression Tool	16213C	899740003620

Phone: 800.749.5783
Fax: 800.749.5784

806 Calle Plano
Camarillo, CA 93012
www.platinumtools.com

We Make Connections EZ!

SealSmart *PROCON* Compression Tool

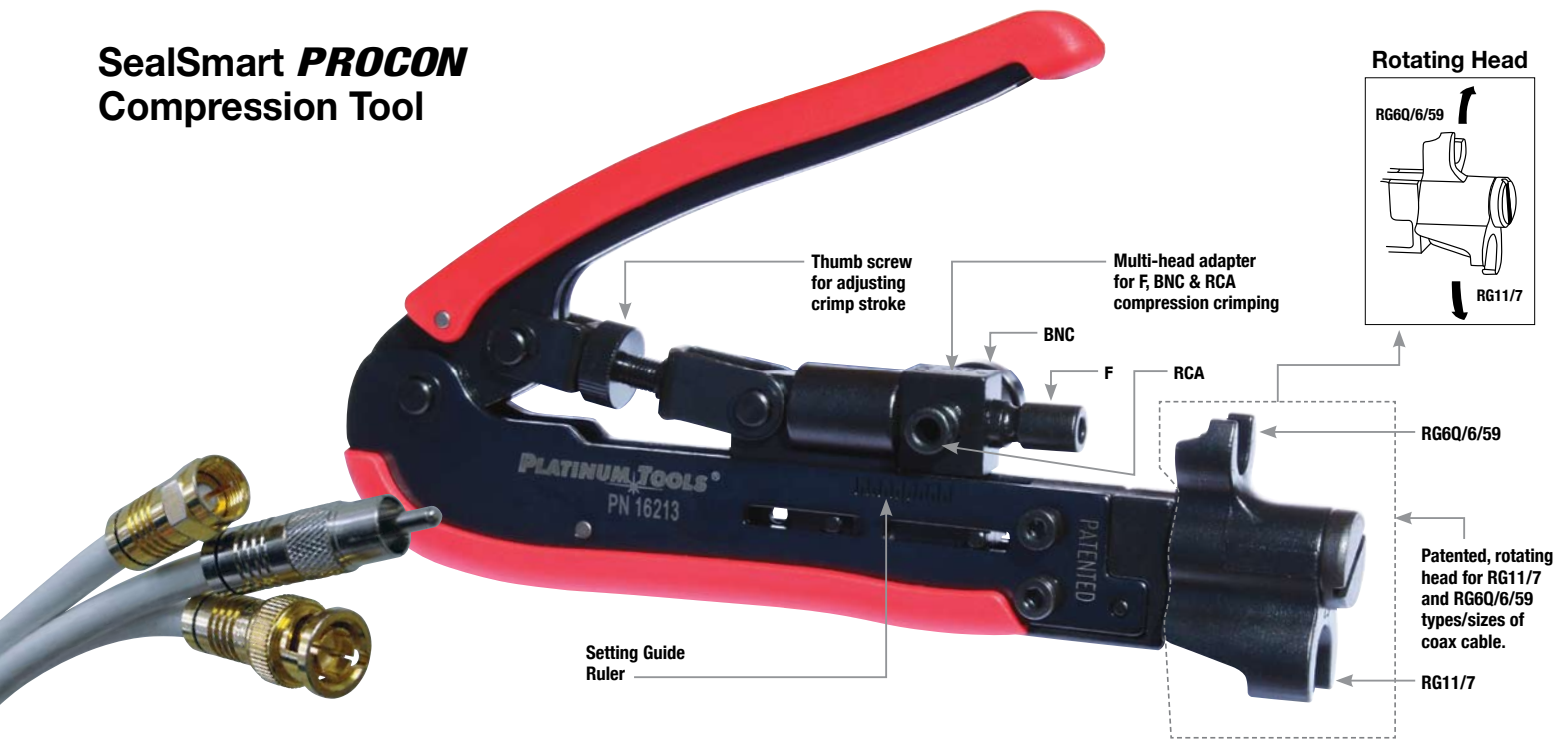

Double-Ended Coax Stripper

This lightweight, compact tool quickly and easily strips a broad range of coax cables, in a single step, without any adjustments. The blades are designed so the ultimate result is a 1/4" braid, 2-level strip, the standard preparation for compression connectors.

- Works with RG7/11/213/8 and RG59/6/6 Quad cable types
- Quickly and easily remove the cable jacket and inner conductors in a single step
- Control the cutting depth by the number of rotations made around the cable
- Preset, no adjustments required



15020C Double-Ended Coax Stripper -
RG7/11/213/8 and RG59/6/6 Quad

SealSmart Coaxial Compression Connectors

Cable Type →	F Connectors				BNC Connectors			RCA Connectors		
	RG11	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59
Plating/Packaging										
Nickel/Bulk Package	18311	18001	18006	18011	18035	18038	18041	18065	18051	18060
Nickel Plate/Jar of 75		28001J	28006J	28011J						
Nickel Plate/Jar of 50									28051J	28060J
Nickel Plate/Jar of 40						28038J	28041J			
Nickel/4 pc. Clamshell	18312									
Nickel/6 pc. Clamshell					18036	18039	18042	18066	18051C	18061
Nickel/10 pc. Clamshell		18002	18007	18012						
Gold/Bulk Package		18004	18009	18015	18020	18025	18030	18057	18052	18055
Gold/6 pc. Clamshell					18021	18026	18031	18058	18053	18056
Gold/10 pc. Clamshell		18005	18010	18016						

Right Angle Connectors

Cable Type →	F Connectors			BNC Connectors			RCA Connectors		
	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59	RG6 Quad	RG6	RG59
Plating/Packaging									
Nickel/Bulk Package	18001RA	18006RA	18011RA	18035RA	18038RA	18041RA	18065RA	18051RA	18060RA
Nickel/3 pc. Clamshell	18003	18008	18013	18037	18040	18043	18067	18054	18062