


### Combination Kits

Used to combine series specific enclosures to make larger units. Connect horizontally or vertically.

#### Fitting Type Combination Kit

Threaded with locknut seal for connecting sidewalls. Fits standard Pg knockouts. Drilling template included to ensure enclosure ingress integrity.

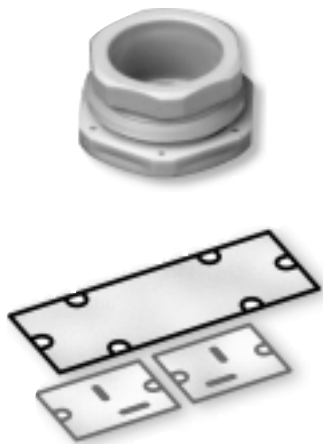

#### Pin Type Combination Set

For combining AKII and AKL Series Enclosures.

### Conduit Connectors

#### Pg Unthreaded

- Includes locknut
- Fittings for smooth Pg conduit
- Polystyrene



#### Pg Threaded

- Includes locknut
- Fittings for threaded Pg conduit
- Polystyrene



#### NPT Unthreaded

- Includes locknut
- Fittings for smooth NPT conduit
- Polystyrene



#### NPT Threaded

- Includes locknut
- Fittings for threaded NPT conduit
- Polystyrene

### Din Rails

DIN rails allow for mounting DIN Terminal Blocks and other control components. All required hardware included.

#### TS15x5 mm



Type / Size	For Series	Cat. No.	Std. Pack
CK/Pg16	TK, EK	192-001	1
CK/Pg21	TK, EK	192-002	1
CK/Pg29	TK, EK	192-003	1

CK/AKII	AKII, AKL	791-001	1
---------	-----------	---------	---

Mounting Hole Type	Mounting Hole Dia. mm (in)	Conduit Type	Cat. No.	Std. Pack
Pg13.5	21.0 (0.83)	Pg13.5	263-403	30
Pg13.5	21.0 (0.83)	Pg16	263-404	30
Pg16	23.0 (0.91)	Pg13.5	264-403	30
Pg16	23.0 (0.91)	Pg16	264-404	30
Pg21	29.0 (1.14)	Pg16	265-404	25
Pg21	29.0 (1.14)	Pg21	265-405	20
Pg13.5	21.0 (0.83)	Pg13.5	293-403	30
Pg13.5	21.0 (0.83)	Pg16	293-404	30
Pg16	23.0 (0.91)	Pg13.5	294-403	30
Pg16	23.0 (0.91)	Pg16	294-404	30
Pg21	29.0 (1.14)	Pg16	295-404	25
Pg21	29.0 (1.14)	Pg21	295-405	20
Pg16	23.0 (0.91)	NPT 1/2"	274-050	30
Pg16	23.0 (0.91)	NPT 3/4"	274-075	25
Pg21	29.0 (1.14)	NPT 1/2"	275-050	25
Pg21	29.0 (1.14)	NPT 3/4"	275-075	20
Pg21	29.0 (1.14)	NPT 1"	275-100	15
Pg16	23.0 (0.91)	NPT 1/2"	294-050	30
Pg16	23.0 (0.91)	NPT 3/4"	294-075	25
Pg21	29.0 (1.14)	NPT 1/2"	295-050	25
Pg21	29.0 (1.14)	NPT 3/4"	295-075	20
Pg21	29.0 (1.14)	NPT 1"	295-100	15

Type	For Series	Cat. No.	Std. Pack
TS15/63	Abox040	Z-628	1
TS15/49.5	TK77, 97	Z-629	1
TS15/80	TK97, 99	Z-630	1
TS15/87	TK1111, Abox060	Z-631	1
TS15/111	TK1309, 1313	Z-632	1
TS15/154	TK1809	Z-636	1