


Lock Nuts, Polyamide

Material:
Polyamide 6
25 % Glass fiber Reinforced

Characteristic feature:
PG / metric and NPT thread

Temperature Range PA
-30 to 120° C (-22 to 248° F)

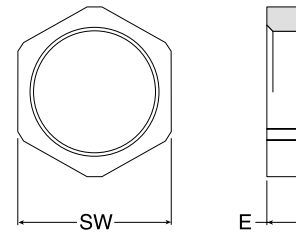

Thread	Thickness (E) mm	SW mm	Cat. No. Light grey	Cat. No. Black	Std. Pk.
PG (DIN 46 320)					
PG 7	5	19	7211881	7211851	50
PG 9	5	22	7211882	7211852	50
PG 11	5	24	7211883	7211853	50
PG 13.5	6	27	7211884	7211854	50
PG 16	6	30	7211885	7211855	50
PG 21	6.5	36	7211886	7211856	20
PG 29	7.5	46	7211887	7211857	20
PG 36	8	60	7211888	7211858	10
PG 42	9	65	7211889	7211859	5
PG 48	9.5	70	7211890	7211860	5
Metric					
M 12 x 1.5	5	19	7211979	7211974	50
M 16 x 1.5	5	22	7211980	7211975	50
M 20 x 1.5	5	24	7211981	7211976	50
M 25 x 1.5	6	30	7211982	7211977	50
M 32 x 1.5	7.5	38	7211983	7211978	50
M 40 x 1.5	8	50	7211984	7211990	20
M 50 x 1.5	9	60	7211985	7211991	10
M 63 x 1.5	10	75	7211986	7211992	5
NPT					
NPT 3/8"	5	22	7211485	7211495	50
NPT 1/2"	6	27	7211486	7211496	20
NPT 3/4"	7	36	7211487	7211497	20
NPT 1"	7	41	7211488	7211498	20