


535090-4 Product Details

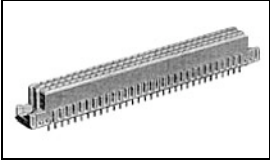


535090-4

TE Internal Number: 535090-4

 [Active](#)

 [View 3D PDF](#)

Eurocard Type C

 [5 of 6 EU RoHS/ELV Compliant](#) ([Find RoHS Compliant Alternates/Statement of Compliance](#))

Product Highlights:

- Connector
- Receptacle
- Type = Type C
- 96 Positions
- Rows Loaded = A, B, C

[View all Features](#)

Documentation & Additional Information

Product Drawings:

- [RECEPTACLE ASSEMBLY, EUROCARD, TYPE C, 96 POSITION](#) (PDF, English)

Catalog Pages/Data Sheets:

- [EUROCARD CONNECTORS PER DIN 41612 AND IEC 603-2](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- [Eurocard Connectors Types B,C,M,Q,R, & Enhanced Typ...](#) (PDF, English)

Instruction Sheets:

- None Available

CAD Files: ([CAD Format & Compression Information](#))

- [2D Drawing](#) (DXF, Version J)
- [3D Model](#) (IGES, Version J)
- [3D Model](#) (STEP, Version J)

[List all Documents](#)

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Connector
- [Gender](#) = Receptacle
- [Number of Positions](#) = 96
- [PCB Retention Feature](#) = No
- [PCB Mount Angle](#) = Vertical
- [Post Type](#) = Solder Post
- [Size](#) = Standard
- [Make First / Break Last](#) = No
- [Bus Type](#) = FUTUREBUS, MULTIBUS (II), NUBUS, VMEbus, VXIBus
- [DIN Level](#) = II
- [Mounting Ears](#) = With
- Toolless (Flat Rock) = No

Termination Related Features:

Contact Related Features:

- Contact Base Material = Phosphor Bronze

Housing Related Features:

- Housing Material = Polyester
- Housing Flammability Rating = UL 94V-0

Industry Standards:

- [RoHS/ELV Compliance](#) = ELV compliant, 5 of 6 Compliant
- [Lead Free Solder Processes](#) = Wave solder capable to 240°C
- [Flux-Tight Coating](#) = Without

Conditions for Usage:

- [Terminate To](#) = Printed Circuit Board
- [High Temperature Housing](#) = No

- [Termination Post Length \(mm \[in\]\)](#) = 3.30 [0.130]

Body Related Features:

- [Type](#) = Type C
- [Rows Loaded](#) = A, B, C
- [Contact Cross Section \(mm \[in\]\)](#) = 0.30 x 0.61
[.012 x .024]

Other:

- Brand = AMP