



 Deutsche
Version

- [Home](#)
- [About Us](#)
- [Products](#)
- [Support](#)
- [News](#)
- [Sitemap](#)

[Search](#)

[Products only](#)

© Neutrik® AG
All rights reserved
[Legal Notices](#)



Audio

NYS 1/4" Plugs


[back](#)

[Print](#)

NYS224L



1/4" plug, 2-pole, long turned brass handle, no rivet. With large cable outlet of 8 mm

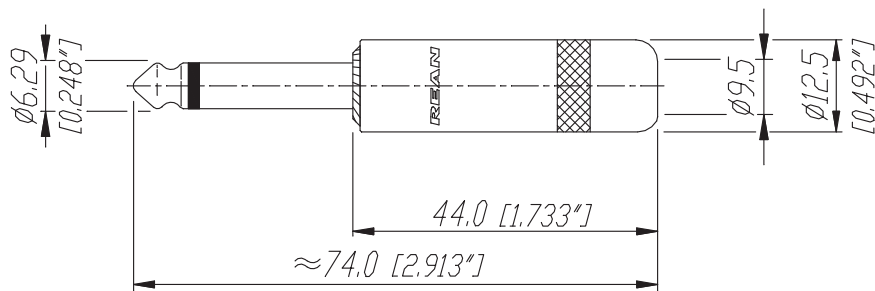

Ind.	Aenderung	Datum	Name	Werkstoff:	Massstab:	Datum	Name	
				*Lieferant darf ohne Ruecksprache nicht geaendert werden	1:1	Gezeichnet	29.01.01	Battlogg
				Zeichnung urheberrechtlich geschuetzt (DIN 34) (C)		Geprueft		
				Benennung: 1/4" Phone Plugs NYS 224L		Gesehen		
						Ersetzt durch:		Blatt
						Ersatz fuer:		von Blatt
				REAN		Zeichn. Nr.	3102 ST 22 19	



NYS 1/4" Plugs



Audio

NYS224L

There are no technical infos for this product.

Product	
Electrical	
Contact resistance	< 10 mΩ
Dielectric strength	0,5 kVdc
Rated current per contact	depends on mated connector A
Mechanical	
Cable O.D.	≤ 8 mm
Material	
Contact plating	2 μm Ni
Contacts	CuZn39Pb3
Insert	PA 66 30 % GR+insulation board
Shell	CuZn39Pb3 gal 2 ?m Ni plated
Environmental	
Solderability	Complies with IEC 68-2-20
Temperature range	-20 °C to +70 °C
Optical	
Mobile Cables	