



 Deutsche
Version

- [Home](#)
- [About Us](#)
- [Products](#)
- [Support](#)
- [News](#)
- [Sitemap](#)

[Search](#)

[Products only](#)

© Neutrik® AG
All rights reserved
[Legal Notices](#)



Audio

NYS 1/4" Plugs


[back](#)

[Print](#)

NYS225



1/4" plug, 2-pole, with large shell for speaker cable. Large metal handle, rubber bushing

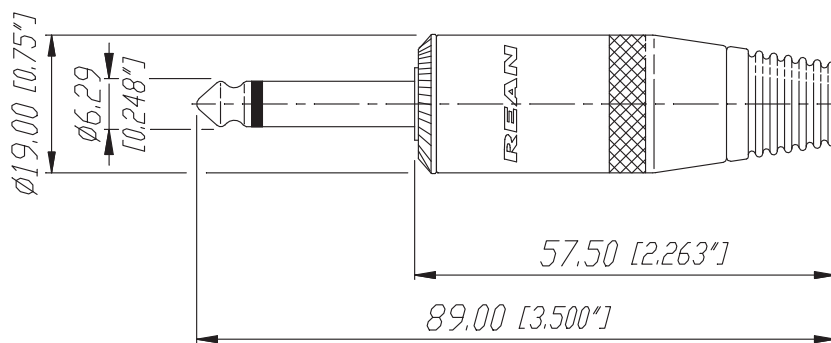

					Werkstoff:	Massstab:		Datum	Name
				*Lieferant darf ohne Ruecksprache nicht geaendert werden		1:1	Gezeichnet	04.04.02	Battlogg
				Zeichnung urheberrechtlich geschuetzt (DIN 34) (C)			Geprueft		
				Benennung:	1/4" Phone Plugs			Ersetzt durch:	Blatt
					NYS 225			Ersatz fuer:	von Blatt
					REAN			Zeichn. Nr.	3102 ST 22 63
Ind.	Aenderung	Datum	Name						



NYS 1/4" Plugs



NYS225

There are no technical infos for this product.

Product	
Electrical	
Contact resistance	< 10 mΩ
Dielectric strength	0,5 kVdc
Rated current per contact	depends on mated connector A
Mechanical	
Cable O.D.	≤ 8 mm
Wire size	12 AWG
Material	
Contact plating	2 μm Ni
Contacts	CuZn39Pb3
Insert	PA 66 30 % GR+insulation board
Shell	ZnAl4Cu1, gal 2 μm Ni plated
Environmental	
Solderability	Complies with IEC 68-2-20
Temperature range	-20 °C to +70 °C
Optical	
Mobile Cables	