

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0009501081**
Status: **Active**
Overview: SPOX Connector System
Description: 3.96mm Pitch SPOX Crimp Housing, Female, with Friction Ramp, 8 Circuits, Natural

Documents:

3D Model	Product Specification PS-5195-007-001 (PDF)
Drawing (PDF)	Product Specification PS-5273-003 (PDF)
Product Specification PS-5195-003 (PDF)	Product Specification PS-5273-004 (PDF)
Product Specification PS-5195-005-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	<u>5195</u>
Application	Signal, Wire-to-Board
Overview	<u>SPOX Connector System</u>
Product Name	SPOX
UPC	800753534483

Physical


Circuits (maximum)	8
Color - Resin	Natural
Flammability	94V-2
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Nylon
Net Weight	2249.300/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.96mm
Pitch - Termination Interface	3.96mm
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Engineering Number	5195-08
--------------------	---------

Reference - Drawing Numbers

Product Specification	PS-5195-003, PS-5195-005-001, PS-5195-007-001, PS-5273-003, PS-5273-004
Sales Drawing	SD-5195-N

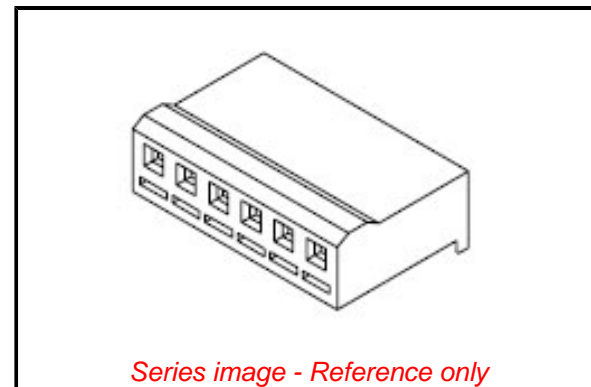

EU ELV

Not Relevant

EU RoHS

Compliant
REACH SVHC

Not Contained Per - ED/61/2018 (27 June 2018)

Halogen-Free
Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

5195 Series

Mates With

5272 , 5273 , 5274 right angle PCB header, 5096 , 53405 , 5271

Use With

5194 , 5225