


Catalog Number: WMG-PC4
Product ID: 7TAD105280R0004
UPC Number: 78621077001
EAN Number: 05414363164814
Status: Active

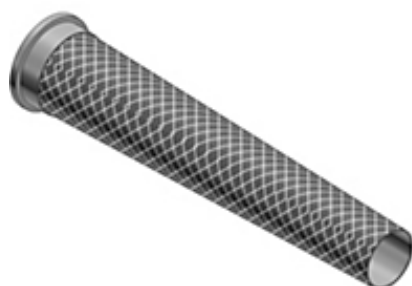

Actual



Representative

Stainless Steel Wire Mesh Grip for Use with Liquidtight Cord Fittings, Grip Range 0.500 to 0.625 Inch

- Prevents severe cord bends and pullouts.
- Used with aluminum and/or steel fittings.
- Provides high gripping strength for adequate cable support and strain relief without damage to the cable sheath.

Header

3D Model Available on Website

North American Specifications (UNSPSC)

UNSPSC	39121431 Cable gland connector
IGCC	4601 Cable gland connector
Brand Name	T&B
Type	Wiremesh Grips
Special Features	Prevents Severe Cord Bends and Pullouts
Application	Provides High Gripping Strength for Adequate Cable Support and Strain Relief Without Damage to the Cable Sheath
Standard	UL E13938, CSA
Conductor Range	0.500 to 0.625 Inch
Material	Stainless Steel
Environmental Conditions	Ordinary Locations

Packaging

Inner Quantity	5
Inner Dimensions (inches)	4x4x3
Outer Quantity	25
Outer Dimensions (inches)	16.2x4.7x4.9
Weight Uom	2.5 lbs. per 100

Documents / Support Tools

Technical Data Sheet CA	Available on Website
Technical Data Sheet Global	tds000055
Instruction Sheet 1	ta00083-tb2

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email: techsupport@tnb.com