


FS106B

Pos-E-Kon™

Female screw terminal insert. For use with B series, 6 contacts with ground.

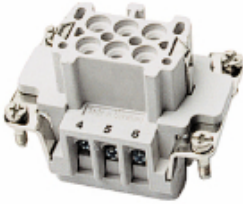

General

Type: 35 A 600 VAC
T&B UPC: 78621011636
T&B Status: M
Series: B series
Approvals: MEIE, EZU, SEV
Insert Material: Glass-filled thermoplastic
Special Features: IP65 locked positions per DIN VDE 0470, IEC 529
Voltage Rating: 600 VAC
Material: Die-cast aluminum alloy

Dimension Information

Wire Size: 20-10 AWG (0.5-6 mm²)
Contact Material: Solid drilled copper alloy
Contact Surface: Hard silver plated, Hard gold plated
Contact Type: 6 contacts with ground
EPDM Seal Gaskets: Epoxy powder-coat finish