


Kits

30A – 800A, 600V, 3 pole ①
UL fuse class J, CC, T, L

Each kit includes:
 1 three pole switch
 1 handle
 1 shaft
 1 terminal lug kit

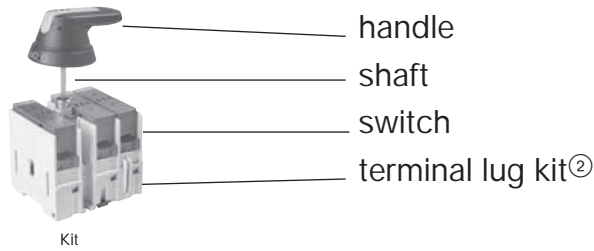

Kits with selector handles

UL general purpose amp rating	UL Fuse type 600V	Maximum horsepower rating					Kit catalog number	List price
		Three phase						
		200V	208V	240V	480V	600V		
30	J	5	7.5	7.5	15	20	OSJ30B2A1-180	\$ 314
30	CC	5	7.5	7.5	15	20	OSC30B2A1-180	314

Kits with pistol handles

UL general purpose amp rating	UL Fuse type 600V	Maximum horsepower rating					Kit catalog number	List price
		Three phase						
		200V	208V	240V	480V	600V		
30	J	5	7.5	7.5	15	20	OSJ30B6-150	\$ 374
30	CC	5	7.5	7.5	15	20	OSC30B6-150	374
60	J	15	15	15	30	50	OSJ60B6-150	472
100	J②	25	25	30	60	75	OSJ100B8-150	646
200	J	50	50	60	125	150	OSKJ200B8-290	1566
400	J②	100	125	125	250	350	OSJ400B4-280	2176
600	J②	150	150	200	400	500	OSJ600B4-280	3406
800	L	200	200	250	500	600	OSL800B4-280	5266

Components for kits with selector handles

Kit catalog number	Switch		Handle ④			Shaft			Terminal lugs		
	Catalog number	NEMA type	Marking	Handle Defeat-able	Mounting catalog number	Length depth⑤ (inches)	Shaft (inches/mm)	Catalog number	Wire size	Wire type	Catalog number
OSJ30B2A1-180	OS30AJ12	1, 3R, 12	I/O & Off/On	—	OHB2AJ1	6.3 - 9.5	7.1/180	OXS5X180	#18 - 8	Cu	Integral
OSC30B2A1-180	OS30ACC12	1, 3R, 12	I/O & Off/On	—	OHB2AJ1	6.3 - 9.5	7.1/180	OXS5X180	#18 - 8	Cu	Integral

Components for kits with pistol handles

Kit catalog number	Switch		Handle ④			Shaft			Terminal lugs		
	Catalog number	NEMA type	Marking	Handle Defeat-able	Mounting catalog number	Length depth⑤ (inches)	Shaft (inches/mm)	Catalog number	Wire size	Wire type	Catalog number
OSJ30B6-150	OS30AJ12	1, 3R, 12	I/O & Off/On	Yes	OHB65J5	5.3 - 8.3	5.9/150	OSP5X150	#18 - 8	Cu	Integral
OSC30B6-150	OS30ACC12	1, 3R, 12	I/O & Off/On	Yes	OHB65J5	5.3 - 8.3	5.9/150	OSP5X150	#18 - 8	Cu	Integral
OSJ60B6-150	OS60J12	1, 3R, 12	I/O & Off/On	Yes	OHB65J6	5.5 - 8.5	5.9/150	OSP6X150	#14 - 4	Cu	Integral
OSJ100B8-150	OS100J03	1, 3R, 12	I/O & Off/On	Yes	OHB80J6	5.5 - 8.5	5.9/150	OSP6X150	#14 - 2/0	Cu/Al	OZXA-24
OSKJ200B8-290	OS200J03	1, 3R, 12	I/O & Off/On	Yes	OHB80J6	10.5 - 12.7	11.4/290	OSP6X290	#6 - 300kcmil	Cu/Al	OZXA-200
OSJ400B4-280	OES400J3	1, 3R, 12	I/O & Off/On	Yes	OHB145J12	7.9 - 12.2	11.0/280	OSP12X280	#2 - 600kcmil	Cu/Al	OZXA-26
OSJ600B4-280	OES600J3	1, 3R, 12	I/O & Off/On	Yes	OHB145J12	11.2 - 14.0	11.0/280	OSP12X280	(2) #2 - 600kcmil	Cu/Al	OZXA-27
OSL800B4-280	OES800J3	1, 3R, 12	I/O & Off/On	Yes	OHB145J12	11.2 - 14.0	11.0/280	OSP12X280	(2) #2 - 600kcmil	Cu/Al	OZXA-27

If other handles or shafts are desired, please order from the individual component pages 18.83 – 18.92.

① Other pole configurations available. Please see the individual component pages.
 ② 30A and 60-A fusible switches include standard integral terminal lugs.
 ③ J type fuse clips are standard. If 600V Type "T" fuse clips are desired, please select a fuse adapter kit from the individual component pages.
 ④ All handles are black and accept three padlocks. For others, please see the individual component pages.
 ⑤ Mounting depth is the distance from the outside of the door to the disconnect switch mounting plate. Shaft can be cut to desired length.