



CONTACT • REQUEST A QUOTE

PRODUCTS

RESOURCES

COMPANY

PART NUMBER SEARCH

search site



« Clamping Knobs

## Round Fluted Clamping Knobs

### Series #2965

Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.

A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.


Perfect for the industrial machinery, medical, general equipment and other industrial applications.

Knobs can be decorated or customized to your specific need.

Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.



Colors available upon request.

Please note: Not all variations available are listed below. Please [contact Customer Service](#) to inquire about all available options.

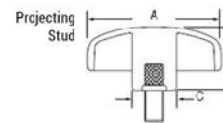

REQUEST CAD DRAWING

  REQUEST A QUOTE



Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color
2965	0.88	0.5	0.625	Thermoset	0.25	Plain Molded Hole	0.44	BLACK
2965-H	0.88	0.5	0.625	Thermoset	8-32	Female Insert	0.25	BLACK
2965BW	0.88	0.5	0.625	Thermoset	10-32	Female Insert	0.31	BLACK
2965DC	0.88	0.75	0.625	Thermoset	10-32	Projecting Stud	0.625	BLACK
2965DJ	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.44	BLACK
2965DY	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.625	BLACK
2965ED	0.88	0.95	0.625	Thermoset	10-32	Female Insert	0.375	BLACK
2965EG	0.88	0.57	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
2965EN	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.00	GREEN
2965EQ	0.88	0.75	0.625	Thermoset	10-32	Projecting Stud	0.75	BLACK
2965EX	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.375	BLACK
2965FA	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.25	BLACK
2965FB	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.75	BLACK
2965FC	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.375	BLACK
2965FF	0.88	0.5	0.625	Thermoset	10-24	Projecting Stud	0.31	BLACK

2965FH	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.50	BLACK
2965FJ	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.56	BLACK
2965FP	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.31	BLACK
2965FY	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.875	BLACK
2965FZ	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.31	BLACK
2965GA	0.88	0.5	0.625	Thermoset	1/4-28	Projecting Stud	0.94	BLACK
2965GM	0.88	0.5	0.625	Thermoset	10-24	Projecting Stud	0.375	BLACK
2965GQ	0.88	0.5	0.625	Thermoset	10-24	Projecting Stud	0.50	BLACK
2965GS	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	1.25	BLACK
2965GZ	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	1.00	BLACK
2965HG	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.625	BLACK
2965HH	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	1.125	BLACK
2965HJ	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
2965HR	0.88	0.94	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
2965HW	0.88	0.625	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
2965JA	0.88	0.94	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
2965JB	0.88	0.75	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
2965JH	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
2965JJ	0.88	0.625	0.625	Thermoset	10-24	Female Insert	0.375	BLACK
2965JL	0.88	0.94	0.625	Thermoset	10-32	Projecting Stud	0.25	BLACK
2965JM	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.375	BLACK
2965JN	0.88	0.95	0.625	Thermoset	10-32	Projecting Stud	0.75	BLACK
2965JT	0.88	0.625	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
2965JV	0.88	0.625	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
2965KD	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	1.00	BLACK
2965KG	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.75	BLACK
2965KM	0.88	0.75	0.625	Thermoset	10-24	Female Insert	0.375	BLACK
2965KN	0.88	0.625	0.625	Thermoset	10-32	Projecting Stud	1.00	BLACK
2965LC	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	0.875	BLACK
2965LE	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	1.25	BLACK
2965LG	0.88	0.75	0.625	Thermoset	10-32	Projecting Stud	1.25	BLACK
2965LJ	0.88	0.5	0.625	Thermoset	5/16-18	Projecting Stud	0.75	BLACK
2965LM	0.88	0.625	0.625	Thermoset	1/4-20	Projecting Stud	2	BLACK
2965LP	0.88	0.625	0.625	Thermoset	1/4-20	Tapped Thread	0.375	WHITE
2965LV	0.88	0.625	0.625	Thermoset	1/4-20	Female Insert	0.375	WHITE
2965MB	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.00	BLACK
2965MG	0.88	0.75	0.625	Thermoset	M6	Projecting Stud	1.375	BLACK
2965NQ	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	1.75	BLACK
2965NS	0.88	0.75	0.625	Thermoset	10-24	Projecting Stud	1.00	BLACK
2965NU	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.25	BLACK
2965NV	0.88	0.625	0.625	Thermoset	10-32	Projecting Stud	1.00	BLACK
2965NY	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.625	BLACK
2965PC	0.88	0.75	0.625	Thermoset	10-24	Female Insert	0.375	BLACK
2965PG	0.88	0.5	0.625	Thermoset	10-32	Projecting Stud	0.25	BLACK
2965PH	0.88	0.5	0.625	Thermoset	0.25	Plain Molded Hole	0.44	BLACK
2965PJ	0.88	0.625	0.625	Thermoset	1/4-20	Female Insert	0.375	GREEN
2965PU	0.88	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
2965PV	0.88	0.625	0.625	Thermoset	5/16-18	Projecting Stud	2.25	BLACK
2965PW	0.88	0.5	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK

PRODUCTS

- Knobs
- Handles
- Leveling Feet
- Latches
- Hinges
- Indexing Plungers
- Electronic Enclosures
- Two-Shot / Soft Touch
- Frac Balls
- Custom Molding

RESOURCES

- Engineering Specifications
- Distributor Listing
- Sales Representative Listing

COMPANY

- About Us
- Capabilities
- Certifications
- Contact Us
- Blog
- Careers

QUESTIONS ?

questions / comments

Copyright © 2016 Davies Molding, LLC. All Rights Reserved.  
350 Kehoe Blvd. | Carol Stream, IL 60188-1818 | Phone: (800) 554-9208 | Fax: (630) 510-9944