



CONTACT • REQUEST A QUOTE

PRODUCTS

RESOURCES

COMPANY

PART NUMBER SEARCH

search site

« Clamping Knobs

Round Fluted Clamping Knobs

Series #3008

Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.

A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.


Perfect for the industrial machinery, medical, general equipment and other industrial applications.

Knobs can be decorated or customized to your specific need.

Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.



Colors available upon request.

Please note: Not all variations available are listed below. Please [contact Customer Service](#) to inquire about all available options.

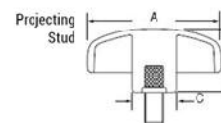

REQUEST CAD DRAWING

  REQUEST A QUOTE



Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color
3008	1.25	0.75	0.625	Thermoset	0.25	Plain Molded Hole	0.50	BLACK
3008-A	1.25	0.75	0.625	Thermoset	0.25	Bushing	0.50	BLACK
3008-B	1.25	0.75	0.625	Thermoset	10-24	Female Insert	0.375	BLACK
3008-N	1.25	0.75	0.62	Thermoset	0.25	Plain Molded Hole	0.50	BLACK
3008-W	1.25	0.75	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
3008AK	1.25	0.75	0.625	Thermoset	10-32	Female Insert	0.375	BLACK
3008AP	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.56	BLACK
3008BG	1.25	0.78	0.625	Thermoset	5/16-18	Female Insert	0.50	BLACK
3008BN	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.31	BLACK
3008BR	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
3008CW	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.00	BLACK
3008DX	1.25	0.75	0.625	Thermoset	5/16-18	Projecting Stud	0.75	BLACK
3008EA	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.44	BLACK
3008EG	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.50	BLACK
3008EQ	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.625	BLACK

3008EV	1.25	0.75	0.625	Thermoset	3/8-16	Projecting Stud	1.00	BLACK
3008FE	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	1.25	BLACK
3008FM	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
3008FW	1.25	0.75	0.625	Thermoset	5/16-18	Projecting Stud	1.00	BLACK
3008FZ	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	2	BLACK
3008GG	1.25	0.75	0.625	Thermoset	3/8-16	Projecting Stud	0.50	BLACK
3008HK	1.25	0.75	0.625	Thermoset	1/4-20	Projecting Stud	2.50	BLACK
3008HS	1.25	0.75	0.625	Thermoset	5/16-18	Projecting Stud	0.375	BLACK
3008JB	1.25	0.78	0.62	Thermoset	5/16-18	Female Insert	0.50	RED
3008JC	1.25	0.78	0.62	Thermoset	5/16-18	Female Insert	0.50	WHITE
3008JL	1.25	0.78	0.62	Thermoset	5/16-18	Female Insert	0.50	YELLOW
3008JQ	1.25	0.78	0.62	Thermoset	5/16-18	Female Insert	0.50	BLUE
3008JT	1.25	0.78	0.62	Thermoset	1/4-20	Female Insert	0.375	WHITE
3008JZ	1.25	0.75	0.62	Thermoset	3/8-16	Projecting Stud	0.75	BLACK
3008KB	1.25	0.75	0.62	Thermoset	5/16-18	Projecting Stud	0.875	BLACK

PRODUCTS

- Knobs
- Handles
- Leveling Feet
- Latches
- Hinges
- Indexing Plungers
- Electronic Enclosures
- Two-Shot / Soft Touch
- Frac Balls
- Custom Molding

RESOURCES

- Engineering Specifications
- Distributor Listing
- Sales Representative Listing

COMPANY

- About Us
- Capabilities
- Certifications
- Contact Us
- Blog
- Careers

QUESTIONS ?

Copyright © 2016 Davies Molding, LLC. All Rights Reserved.
 350 Kehoe Blvd. | Carol Stream, IL 60188-1818 | Phone: (800) 554-9208 | Fax: (630) 510-9944