



CONTACT • REQUEST A QUOTE

PRODUCTS

RESOURCES

COMPANY

PART NUMBER SEARCH



« Clamping Knobs

Mini Clamp Clamping Knobs Series #2715

Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.

A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.


Perfect for the industrial machinery, medical, general equipment and other industrial applications.

Knobs can be decorated or customized to your specific need.

Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.

Colors available upon request.

Please note: Not all variations available are listed below. Please [contact Customer Service](#) to inquire about all available options.

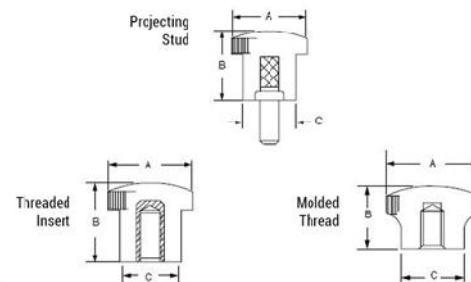

[REQUEST CAD DRAWING](#) [REQUEST A QUOTE](#)

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color
2715-A	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	0.56	BLACK
2715-C	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	0.25	BLACK
2715-E	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.375	BLACK
2715-F	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	0.375	BLACK
2715-G	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.50	BLACK
2715-H	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.875	BLACK
2715-J	0.72	0.55	0.625	Thermoplastic	0.25	Plain Molded Hole	0.28	BLACK
2715-K	0.72	0.55	0.44	Thermoplastic	10-24	Projecting Stud	0.50	BLACK
2715-L	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.50	BLACK
2715-M	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.75	BLACK
2715-N	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.625	BLACK
2715-Q	0.72	0.55	0.44	Thermoplastic	10-24	Projecting Stud	0.75	BLACK
2715-S	0.72	0.55	0.44	Thermoplastic	1/4-20	Projecting Stud	0.375	BLACK
2715-T	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	0.31	BLACK
2715-V	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	0.31	BLACK

2715-W	0.72	0.55	0.44	Thermoplastic	1/4-20	Projecting Stud	0.75	BLACK
2715-X	0.72	0.55	0.44	Thermoplastic	1/4-20	Projecting Stud	0.50	BLACK
2715-Z	0.72	0.55	0.44	Thermoplastic	10-32	Projecting Stud	1.00	BLACK
2715AF	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	1.00	BLACK
2715AK	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	0.375	WHITE
2715AQ	0.72	0.55	0.44	Thermoplastic	1/4-20	Projecting Stud	1.50	BLACK
2715AR	0.72	0.55	0.44	Thermoplastic	1/4-20	Projecting Stud	1.00	BLACK
2715AT	0.72	0.55	0.44	Thermoplastic	8-32	Projecting Stud	0.75	BLACK
2715AV	0.72	0.55	0.44	Thermoplastic	10-24	Projecting Stud	0.625	BLACK
2715AX	0.72	0.55	0.44	Thermoplastic	1/4-20	Projecting Stud	1.25	BLACK
2715AY	0.72	0.55	0.44	Thermoplastic	10-24	Projecting Stud	1.25	WHITE

PRODUCTS

- Knobs
- Handles
- Leveling Feet
- Latches
- Hinges
- Indexing Plungers
- Electronic Enclosures
- Two-Shot / Soft Touch
- Frac Balls
- Custom Molding

RESOURCES

- Engineering Specifications
- Distributor Listing
- Sales Representative Listing

COMPANY

- About Us
- Capabilities
- Certifications
- Contact Us
- Blog
- Careers

QUESTIONS ?

Copyright © 2016 Davies Molding, LLC. All Rights Reserved.
 350 Kehoe Blvd. | Carol Stream, IL 60188-1818 | Phone: (800) 554-9208 | Fax: (630) 510-9944