



CONTACT • REQUEST A QUOTE

PRODUCTS

RESOURCES

COMPANY

PART NUMBER SEARCH

search site



« Clamping Knobs

## Four Arm Clamping Knobs

### Series #2820

Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.

A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.




Perfect for the industrial machinery, medical, general equipment and other industrial applications.

Knobs can be decorated or customized to your specific need.

Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.

Colors available upon request.

Please note: Not all variations available are listed below. Please [contact Customer Service](#) to inquire about all available options.

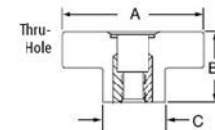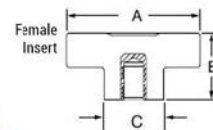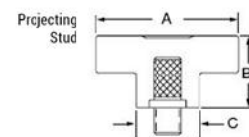

REQUEST CAD DRAWING

REQUEST A QUOTE

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color
2820	1.5	1.00	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
2820-A	1.5	1.00	0.625	Thermoset	5/16-18	Female Insert	0.50	BLACK
2820-B	1.5	1.00	0.625	Thermoset	3/8-16	Female Insert	0.50	BLACK
2820-C	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.56	BLACK
2820-D	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	0.50	BLACK
2820-E	1.5	1.00	0.625	Thermoset	3/8-16	Projecting Stud	1.00	BLACK
2820-F	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
2820-G	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	1.00	BLACK
2820-H	1.5	1.00	0.625	Thermoset	3/8-24	Female Insert	0.625	BLACK
2820-J	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	1.00	BLACK
2820-N	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	0.75	BLACK
2820-R	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	1.125	BLACK
2820-T	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	1.25	BLACK
2820-X	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	1.25	BLACK
2820-Y	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	1.75	BLACK

2820AC	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.875	BLACK
2820AE	1.5	1.00	0.625	Thermoset	3/8-16	Projecting Stud	0.50	BLACK
2820AG	1.5	1.00	0.625	Thermoset	1/4-20	Female Insert	0.375	RED
2820AK	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
2820AL	1.5	1.00	0.625	Thermoset	3/8-16	Projecting Stud	1.50	BLACK
2820AM	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.31	BLACK
2820AP	1.5	1.00	0.625	Thermoset	1/4-20	Thru-Hole		TAN
2820AT	1.5	1.00	0.625	Thermoset	1/4-20	Thru-Hole		BLACK
2820AU	1.5	1.00	0.625	Thermoset	5/16-18	Thru-Hole		BLACK
2820AV	1.5	1.00	0.625	Thermoset	3/8-16	Thru-Hole		BLACK
2820AW	1.5	1.00	0.625	Thermoset	1/4-20	Female Insert	0.50	BLACK
2820BA	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
2820BE	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.375	BLACK
2820BF	1.5	1.00	0.625	Thermoset	1/4-20	Female Insert	0.375	WHITE
2820BG	1.5	1.00	0.625	Thermoset	10-24	Projecting Stud	0.50	BLACK
2820BH	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	1.50	BLACK
2820BJ	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	2.25	BLACK
2820BL	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLUE
2820BM	1.5	1.00	0.625	Thermoset	M6	Female Insert	0.50	BLACK

PRODUCTS

- Knobs
- Handles
- Leveling Feet
- Latches
- Hinges
- Indexing Plungers
- Electronic Enclosures
- Two-Shot / Soft Touch
- Frac Balls
- Custom Molding

RESOURCES

- Engineering Specifications
- Distributor Listing
- Sales Representative Listing

COMPANY

- About Us
- Capabilities
- Certifications
- Contact Us
- Blog
- Careers

QUESTIONS ?

Copyright © 2016 Davies Molding, LLC. All Rights Reserved.  
 350 Kehoe Blvd. | Carol Stream, IL 60188-1818 | Phone: (800) 554-9208 | Fax: (630) 510-9944