



CONTACT • REQUEST A QUOTE

PRODUCTS

RESOURCES

COMPANY

PART NUMBER SEARCH

search site



« Clamping Knobs

Three Arm Clamping Knobs

Series #3035

Clamping knobs are available in different materials, thermoplastic, and phenolic for a multiple of applications.

A variety of shapes and diameters with plain, tapped bosses or with studs are available with standard threads to fit the application.




Perfect for the industrial machinery, medical, general equipment and other industrial applications.

Knobs can be decorated or customized to your specific need.

Davies Molding is pleased to introduce our series of soft touch knobs and handles. Our soft touch parts are molded with a soft thermoplastic overmolded "rubber" top with a tough thermoplastic body underneath. The soft feel of the knob provides a comfortable touch with a sure grip.

Colors available upon request.

Please note: Not all variations available are listed below. Please [contact Customer Service](#) to inquire about all available options.

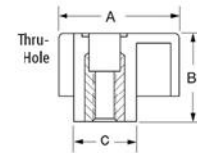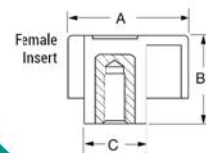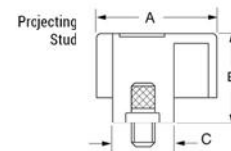

REQUEST CAD DRAWING

REQUEST A QUOTE

Item #	Diameter A	Height B	Hub C	Material Type	Mounting Diameter	Mounting Type	Thread Length/Depth	Color
3035-G	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.31	BLACK
3035-J	1.5	0.75	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
3035-N	1.5	0.875	0.625	Thermoset	3/8-16	Projecting Stud	0.625	BLACK
3035AH	1.5	1.00	0.625	Thermoset	5/16-18	Projecting Stud	1.25	BLACK
3035AM	1.5	1.00	0.625	Thermoset	10-24	Female Insert	0.375	BLACK
3035AS	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.56	BLACK
3035AU	1.5	0.875	0.625	Thermoset	5/16-18	Female Insert	0.50	BLACK
3035AW	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
3035AX	1.5	0.875	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
3035AY	1.5	0.875	0.625	Thermoset	10-32	Female Insert	0.375	BLACK
3035AZ	1.5	0.875	0.625	Thermoset	10-32	Projecting Stud	0.625	BLACK
3035BB	1.5	0.875	0.625	Thermoset	10-24	Female Insert	0.375	BLACK
3035BC	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	1.00	BLACK
3035BE	1.5	0.75	0.625	Thermoset	0.25	Bushing	0.47	BLACK
3035BF	1.5	0.875	0.625	Thermoset	3/8-16	Projecting Stud	1.00	BLACK

3035BG	1.5	0.875	0.625	Thermoset	5/16-18	Projecting Stud	0.75	BLACK
3035BJ	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	1.50	BLACK
3035BK	1.5	0.875	0.625	Thermoset	1/4-20	Thru-Hole		BLACK
3035BL	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	1.25	BLACK
3035BN	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.375	BLACK
3035BR	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
3035BS	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.625	BLACK
3035CA	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	1.50	BLACK
3035CQ	1.5	0.75	0.625	Thermoset	5/16-18	Projecting Stud	1.125	BLACK
3035CY	1.5	1.25	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
3035CZ	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.875	BLACK
3035DA	1.5	0.75	0.625	Thermoset	5/16-18	Projecting Stud	1.50	BLACK
3035DD	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	1.75	BLACK
3035DM	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	2	BLACK
3035DP	1.5	0.875	0.625	Thermoset	5/16-18	Projecting Stud	1.00	BLACK
3035DX	1.5	0.875	0.625	Thermoset	3/8-16	Projecting Stud	1.75	BLACK
3035EU	1.5	0.875	0.625	Thermoset	5/16-18	Projecting Stud	0.50	BLACK
3035EY	1.5	0.875	0.625	Thermoset	3/8-16	Projecting Stud	0.75	BLACK
3035FA	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.75	BLACK
3035FE	1.5	0.875	0.625	Thermoset	M8	Female Insert	0.55	BLACK
3035FP	1.5	0.875	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
3035FT	1.5	0.875	0.625	Thermoset	5/16-18	Projecting Stud	1.75	BLACK
3035GN	1.5	0.875	0.625	Thermoset	10-32	Projecting Stud	0.50	BLACK
3035HC	1.5	0.875	0.625	Thermoset	3/8-16	Projecting Stud	1.50	BLACK
3035HJ	1.5	1.00	0.625	Thermoset	3/8-16	Projecting Stud	0.75	RED
3035HM	1.5	0.875	0.625	Thermoset	1/4-20	Female Insert	0.375	BLACK
3035HU	1.5	1.00	0.625	Thermoset	1/4-20	Projecting Stud	0.50	BLACK
3035HW	1.5	0.625	0.625	Thermoset	1/4-20	Projecting Stud	1.375	BLACK
3035JA	1.5	1.25	0.625	Thermoset	1/4-20	Projecting Stud	1.375	BLACK
3035JD	1.5	0.75	0.625	Thermoset	1/4-20	Thru-Hole		BLACK
3035JE	1.5	0.75	0.625	Thermoset	5/16-18	Thru-Hole		BLACK
3035JJ	1.5	0.875	0.625	Thermoset	10-32	Projecting Stud	0.75	BLACK

PRODUCTS

- Knobs
- Handles
- Leveling Feet
- Latches
- Hinges
- Indexing Plungers
- Electronic Enclosures
- Two-Shot / Soft Touch
- Frac Balls
- Custom Molding

RESOURCES

- Engineering Specifications
- Distributor Listing
- Sales Representative Listing

COMPANY

- About Us
- Capabilities
- Certifications
- Contact Us
- Blog
- Careers

QUESTIONS ?

your name

your e-mail

[select your industry]

questions / comments