


## 12-Outlet Vertical Power Strip, 120V, 20A, Hardwired Input, 36 in.

MODEL NUMBER: **PS3612-20HW**

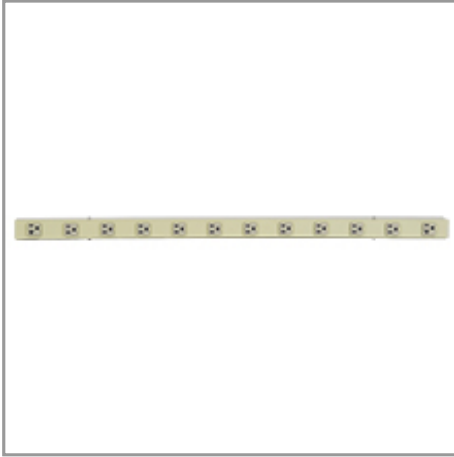

### Highlights

- AC input hardwired via knockout on unit
- 12 outlets
- 20-amp capacity
- Ideal for applications requiring permanent installation

### Package Includes

- [PS3612-20HW](#)
- Instruction manual

### Description

Tripp Lite's [PS3612-20HW](#) Power Strip offers 20 amp multi-outlet AC power distribution in a convenient 36 inch hardwire cabinet. Includes knockout panels to accept 3/4 in. conduit fittings for hardwire installation and 12 output receptacles with 2.99 inch center-to-center spacing. Ideal for horizontal or vertical raceway style power distribution in office, workbench, industrial, networking and telecom applications. INPUT/OUTPUT: Input: Hardwire access via knockout panels that accept 3/4 inch conduit fittings

Output: 12 Outlets total (2 NEMA 5-15/20R and 10 NEMA 5-15R) ELECTRICAL: 120V AC, 50/60Hz, 20A (no circuit breaker) FORMAT: 36 inch strip format

### Features

- Versatile all-metal 36 inch format with outlets arranged in a single row
- Knockout panels for 3/4 inch conduit fittings allow permanent hardwire installation
- Ideal for horizontal or vertical raceway style power distribution in office, workbench, industrial, networking and telecom applications
- 12 outlets total: 2 NEMA 5-15/20R (20A) and 10 NEMA 5-15R (15A)
- 20 amp electrical capacity
- 120VAC, 50/60Hz electrical compatibility

## Specifications

OUTPUT	
Frequency Compatibility	50 / 60 Hz



Output Receptacles	(2) 5-15/20R; (10) 5-15R
Output (Watts)	2400
Outlet Spacing	2.99 in.
<b>INPUT</b>	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	20A 120V
Input Connection Type	Hardwire
Input Cord Length (ft.)	0
Input Cord Length (m)	0.00
Voltage Compatibility (VAC)	120
<b>PHYSICAL</b>	
Unit Dimensions (hwd / in.)	36 x 1.5 x 1.5
Unit Dimensions (hwd / cm)	91.44 x 3.8 x 3.8
Material of Construction	Metal
Integrated Keyhole Mounting Tabs	Mount through housing supports bolt down installation to a variety of flat surfaces
Receptacle Color	Almond
Outlets Measurement (Center to Center)	101.60mm
<b>CERTIFICATIONS</b>	
cUL / CSA (Canada)	cUL
Approvals	UL
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2017 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>